

DIALIGHT LED Panel Mount Indicators

Dialight
A Robson Group Company

Dialight


LED PANEL MOUNT INDICATORS

This product is RoHS compliant.
DIMENSIONS: in.

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Dialight Part No.	Fig.	Color	Voltage (Max)	Current (mA)	mcd	Price Each			
							1	25	100	500
605 Series, 5mm Mounting Hole										
645-605-1111-110F	605-1111-110F	A	Red	2	10	1.2	2.74	2.49	1.99	1.49
645-605-1311-110F	605-1311-110F	A	Yellow	2	15	2	2.94	2.00	1.88	1.70
645-605-1211-110F	605-1211-110F	A	Green	2	15	0.8	2.94	2.00	1.88	1.70
606 Series, 6mm Mounting Hole										
645-606-1111-110F	606-1111-110F	B	Red	2	5	2.4	2.58	1.76	1.65	1.49
645-606-1311-110F	606-1311-110F	B	Yellow	2	10	3.7	2.94	2.00	1.88	1.70
645-606-1211-110F	606-1211-110F	B	Green	2	15	3	2.94	2.00	1.88	1.70
645-606-2111-110F	606-2111-110F	C	Red	2	5	2.4	2.58	1.76	1.65	1.49
645-606-2211-110F	606-2211-110F	C	Green	2	15	3	2.94	2.00	1.88	1.70
645-606-2415-110F	606-2415-110F	D	Red/Green	2	5/20	.6/1	5.27	4.12	3.86	3.51
645-606-2415-120F	606-2415-120F	D	Red/Green	6	5/20	.6/1	5.93	4.63	4.34	3.95
645-606-2415-130F	606-2415-130F	D	Red/Green	12	5/20	.6/1	5.93	4.63	4.34	3.95
607 Series, 7mm Mounting Hole										
645-607-2112-110F	607-2112-110F	E	Red	2	15	8	2.77	2.16	2.03	1.84
645-607-2312-110F	607-2312-110F	E	Yellow	2	15	2.2	3.49	2.37	2.22	2.02
645-607-2212-110F	607-2212-110F	E	Green	2	15	8	3.49	2.37	2.22	2.02
645-607-2112-120F	607-2112-120F	F	Red	6	15	8	4.17	3.24	2.62	2.16
645-607-2112-130F	607-2112-130F	F	Red	12	15	8	4.17	3.24	2.62	2.16
645-607-2312-120F	607-2312-120F	F	Yellow	6	15	2.2	4.43	3.44	2.78	2.29
645-607-2312-130F	607-2312-130F	F	Yellow	12	15	2.2	4.43	3.44	2.78	2.29
645-607-2212-120F	607-2212-120F	F	Green	6	15	8	4.43	3.44	2.78	2.29
645-607-2212-130F	607-2212-130F	F	Green	12	15	8	4.43	3.44	2.78	2.29
645-607-3132-120F	607-3132-120F	G	Red	6	15	8	2.99	2.72	2.18	1.63
645-607-3232-120F	607-3232-120F	G	Green	6	15	8	3.07	2.08	1.95	1.77
645-607-3232-130F	607-3232-130F	G	Green	12	15	8	3.07	2.08	1.95	1.77
608 Series, 8mm Mounting Hole										
645-608-1131-110F	608-1131-110F	H	Red	2	15	20	2.37	1.61	1.51	1.37
645-608-1331-110F	608-1331-110F	H	Yellow	2	15	4	2.42	2.08	1.96	1.54
645-608-1231-110F	608-1231-110F	H	Green	2	15	15	2.67	1.82	1.70	1.54
645-608-1132-220F	608-1132-220F	I	Red	6	15	20	3.03	2.06	1.93	1.76
645-608-1132-230F	608-1132-230F	I	Red	12	15	20	3.03	2.06	1.93	1.76
645-608-1332-220F	608-1332-220F	I	Yellow	6	15	10	3.44	3.13	2.50	1.88
645-608-1232-220F	608-1232-220F	I	Green	6	15	20	3.25	2.21	2.07	1.88
645-608-1232-230F	608-1232-230F	I	Green	12	15	20	3.25	2.21	2.07	1.88
645-608-3131-110F	608-3131-110F	J	Red	2	15	20	2.37	1.61	1.51	1.37
645-608-3231-110F	608-3231-110F	J	Green	2	15	15	2.67	1.82	1.70	1.54
645-608-3331-110F	608-3331-110F	J	Yellow	2	15	4	2.67	1.82	1.70	1.54
609 Series, 9mm Mounting Hole										
645-609-1112-130F	609-1112-130F	K	Red	12	15	20	3.95	3.07	2.48	2.04
645-609-1212-130F	609-1212-130F	K	Green	12	15	15	3.95	3.07	2.48	2.04
645-609-2112-120F	609-2112-120F	L	Red	6	15	20	3.95	3.07	2.48	2.04
645-609-2112-130F	609-2112-130F	L	Red	12	15	20	3.95	3.07	2.48	2.04
645-609-2312-130F	609-2312-130F	L	Yellow	12	15	4	4.02	3.66	2.93	2.19
645-609-2212-130F	609-2212-130F	L	Green	12	15	15	3.95	3.07	2.48	2.04
610 Series, 10mm Mounting Hole										
645-610-3132-120F	610-3132-120F	M	Red	6	10	250	3.39	2.27	2.13	1.93
645-610-3332-120F	610-3332-120F	M	Yellow	6	10	12	3.49	2.37	2.22	2.02
645-610-3232-120F	610-3232-120F	M	Green	6	10	15	3.49	2.37	2.22	2.02
645-610-4132-120F	610-4132-120F	N	Red	6	10	250	2.76	2.65	2.46	1.93
645-610-4232-120F	610-4232-120F	N	Green	6	10	15	3.70	3.37	2.22	2.02

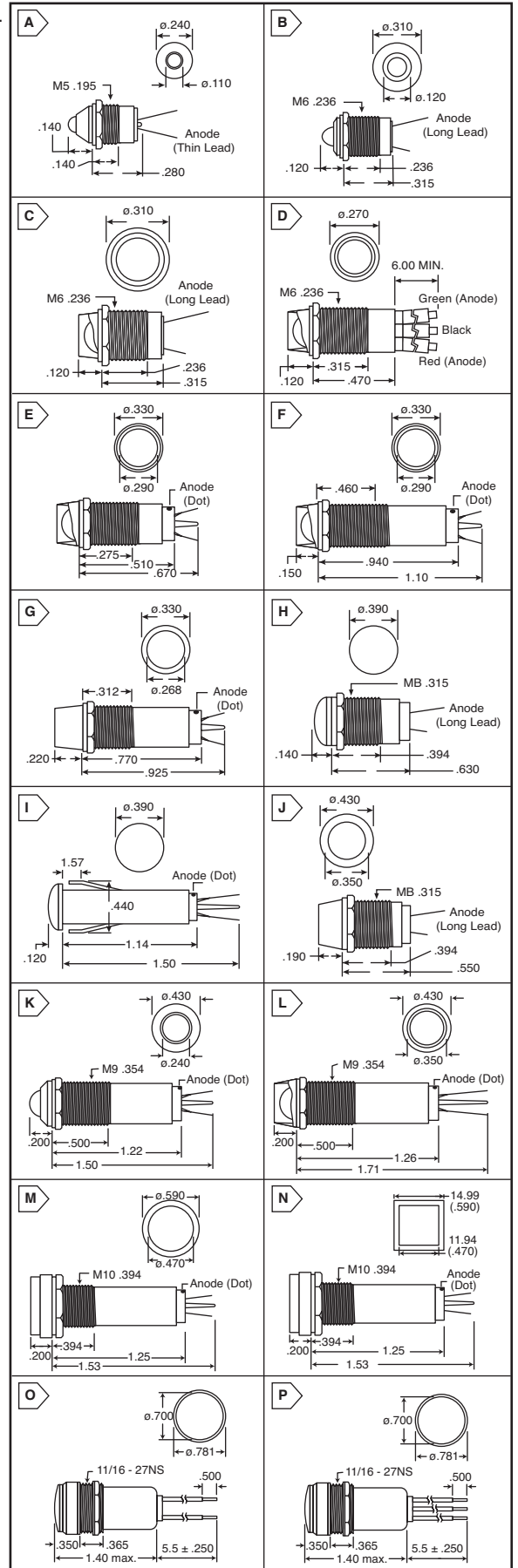

Dialight 11/16" MOUNTING HOLE, WATERTIGHT

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Dialight Part No.	Fig.	Color	Voltage (Max)	Current (mA)	mcd	Price Each			
							1	25	100	500
Superbright										
645-557-1502-203F	557-1502-203F	O	Red	5	80	1000	13.59	12.08	10.57	9.06
645-557-1503-203F	557-1503-203F	O	Red	12	20	1000	13.59	12.08	10.57	9.06
645-557-1505-203F	557-1505-203F	O	Red	24	20	1000	13.59	12.08	10.57	9.06
645-557-1702-203F	557-1702-203F	O	Yellow	5	80	1000	11.18	10.27	9.61	8.62
645-557-1703-203F	557-1703-203F	O	Yellow	12	20	1000	11.18	10.27	9.61	8.62
645-557-1705-203F	557-1705-203F	O	Yellow	24	20	1000	11.18	10.27	9.61	8.62
645-557-1602-203F	557-1602-203F	O	Green	5	16	1000	12.36	11.36	10.63	9.54
645-557-1603-203F	557-1603-203F	O	Green	12	16	1000	12.36	11.36	10.63	9.71
645-557-1605-203F	557-1605-203F	O	Green	24	16	1000	12.36	11.36	10.63	9.71
645-557-1802-203F	557-1802-203F	O	Blue	5	16	250	12.36	11.36	10.63	9.54
645-557-1803-203F	557-1803-203F	O	Blue	12	16	250	12.36	11.36	10.63	9.54
645-557-1805-203F	557-1805-203F	O	Blue	24	16	250	12.36	11.36	10.63	9.54
Bi-Color Superbright										
645-557-1412-203F	557-1412-203F	P	R/G	5	70/16	400/1000	14.43	12.99	12.27	10.82
645-557-1432-203F	557-1432-203F	P	Y/G	5	70/16	400/1000	16.50	14.85	14.02	12.37