


# 3M™ IDC Flat Cable

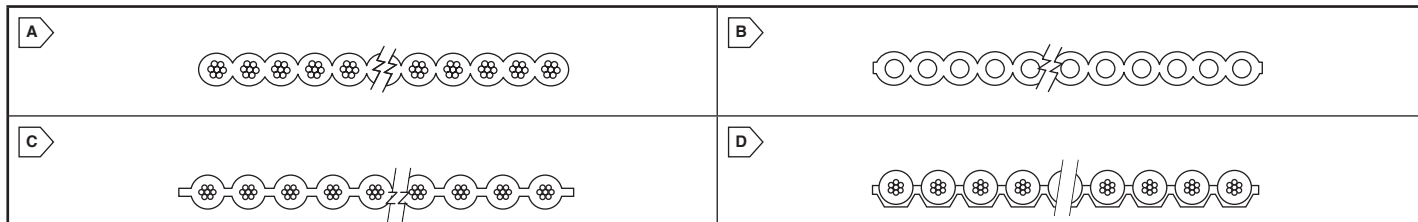

## ROUND CONDUCTOR IDC FLAT CABLE

\* Mass Termination

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per Spool
<b>3756 Series .025" - 100' Foot Spool</b>								
517-3756/26	3756/26-100	A	26	30AWG	TPE	Tinned Stranded Copper	Gray	63.71
517-3756/34	3756/34-100	A	34	30AWG	TPE	Tinned Stranded Copper	Gray	79.62
517-3756/40	3756/40-100	A	40	30AWG	TPE	Tinned Stranded Copper	Gray	93.66
517-3756-50	3756/50-100	A	50	30AWG	TPE	Tinned Stranded Copper	Gray	116.31
517-3756/68	3756/68-100	A	68	30AWG	TPE	Tinned Stranded Copper	Gray	154.69
517-3756/80	3756/80-100	A	80	30AWG	TPE	Tinned Stranded Copper	Gray	181.99
517-3756/100	3756/100-100	A	100	30AWG	TPE	Tinned Stranded Copper	Gray	227.50
<b>3754 Series .025" - 300' Foot Spool</b>								
517-3754/20-300	3754/20-300	A	20	30AWG	PVC	Tinned Stranded Copper	Gray	91.91
517-3754/30-300	3754/30-300	A	30	30AWG	PVC	Tinned Stranded Copper	Gray	137.85
517-3754/34-300	3754/34-300	A	34	30AWG	PVC	Tinned Stranded Copper	Gray	151.77
517-3754/40-300	3754/40-300	A	40	30AWG	PVC	Tinned Stranded Copper	Gray	178.56
517-3754/50-300	3754/50-300	A	50	30AWG	PVC	Tinned Stranded Copper	Gray	223.20
<b>3801 Series .050" - 100' Foot Spool</b>								
517-3801/09	3801/09-100	A	9	26AWG	PVC	Tinned Stranded Copper	Gray	20.42
517-3801/10	3801/10-100	A	10	26AWG	PVC	Tinned Stranded Copper	Gray	22.79
517-3801/14	3801/14-100	A	14	26AWG	PVC	Tinned Stranded Copper	Gray	32.38
517-3801/16	3801/16-100	A	16	26AWG	PVC	Tinned Stranded Copper	Gray	37.00
517-3801/18	3801/18-100	A	18	26AWG	PVC	Tinned Stranded Copper	Gray	41.38
517-3801/20	3801/20-100	A	20	26AWG	PVC	Tinned Stranded Copper	Gray	46.28
517-3801/24	3801/24-100	A	24	26AWG	PVC	Tinned Stranded Copper	Gray	55.52
517-3801/25	3801/25-100	A	25	26AWG	PVC	Tinned Stranded Copper	Gray	57.85
517-3801/26	3801/26-100	A	26	26AWG	PVC	Tinned Stranded Copper	Gray	60.15
517-3801/34	3801/34-100	A	34	26AWG	PVC	Tinned Stranded Copper	Gray	75.19
517-3801/40	3801/40-100	A	40	26AWG	PVC	Tinned Stranded Copper	Gray	88.46
517-3801/50	3801/50-100	A	50	26AWG	PVC	Tinned Stranded Copper	Gray	110.57
517-3801/60	3801/60-100	A	60	26AWG	PVC	Tinned Stranded Copper	Gray	132.68
<b>3625 Series 1.0MM - 30' Meter Spool</b>								
517-3625/10	3625/10-30M	A	10	28AWG	PVC	Tinned Stranded Copper	Gray	32.52
517-3625/12	3625/12-30M	A	12	28AWG	PVC	Tinned Stranded Copper	Gray	39.03
517-3625/20	3625/20-30M	A	20	28AWG	PVC	Tinned Stranded Copper	Gray	65.03
517-3625/26	3625/26-30M	A	26	28AWG	PVC	Tinned Stranded Copper	Gray	84.57
517-3625/34	3625/34-30M	A	34	28AWG	PVC	Tinned Stranded Copper	Gray	110.55
517-3625/44	3625/44-30M	A	44	28AWG	PVC	Tinned Stranded Copper	Gray	143.07
517-3625/50	3625/50-30M	A	50	28AWG	PVC	Tinned Stranded Copper	Gray	162.60
<b>3749 Series .025" - 100' Foot Spool</b>								
517-3749/20	3749/20-100	B	20	30AWG	TPE	Tinned Copper	Gray	41.69
517-3749/26	3749/26-100	B	26	30AWG	TPE	Tinned Copper	Gray	54.26
517-3749/36	3749/36-100	B	36	30AWG	TPE	Tinned Copper	Gray	75.05
517-3749/40	3749/40-100	B	40	30AWG	TPE	Tinned Copper	Gray	79.82
517-3749-50	3749/50-100	B	50	30AWG	TPE	Tinned Copper	Gray	99.76
517-3749/68	3749/68-100	B	68	30AWG	TPE	Tinned Copper	Gray	135.51
517-3749/80	3749/80-100	B	80	30AWG	TPE	Tinned Copper	Gray	154.87
517-3749/100	3749/100-100	B	100	30AWG	TPE	Tinned Copper	Gray	193.57
<b>3601 Series .050" - 100' Foot Spool</b>								
517-3601/10	3601/10-100	C	10	28AWG	FEP	Silver Plated Stranded Copper Alloy	Blue	213.56
517-3601/15	3601/15-100	C	15	28AWG	FEP	Silver Plated Stranded Copper Alloy	Blue	345.00
517-3601/20	3601/20-100	C	20	28AWG	FEP	Silver Plated Stranded Copper Alloy	Blue	381.43
517-3601/40	3601/40-100	C	40	28AWG	FEP	Silver Plated Stranded Copper Alloy	Blue	797.32

### 3365 SERIES .050"

Can be purchased by 100ft. spool or by the foot.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Color	Price Per 100' Spool	MOUSER STOCK NO.	Price Per Foot		
									1	10	25
517-3365/9	3365/09-100SF	D	9	28AWG Stranded	PVC	Gray	28.16	517-3365/9FT	.22	.20	.18
517-3365/10	3365/10-100SF	D	10	28AWG Stranded	PVC	Gray	30.21	517-3365/10FT	.24	.234	.214
517-3365/14	3365/14-100SF	D	14	28AWG Stranded	PVC	Gray	38.50	517-3365/14FT	.30	.27	.25
517-3365/15	3365/15-100SF	D	15	28AWG Stranded	PVC	Gray	34.26	517-3365/15FT	.31	.29	.26
517-3365/16	3365/16-100SF	D	16	28AWG Stranded	PVC	Gray	42.69	517-3365/16FT	.33	.30	.28
517-3365/20	3365/20-100SF	D	20	28AWG Stranded	PVC	Gray	51.64	517-3365/20FT	.50	.44	.40
517-3365/25	3365/25-100SF	D	25	28AWG Stranded	PVC	Gray	49.91	517-3365/25FT	.50	.46	.42
517-3365/26	3365/26-100SF	D	26	28AWG Stranded	PVC	Gray	66.73	517-3365/26FT	.57	.52	.494
517-3365/34	3365/34-100SF	D	34	28AWG Stranded	PVC	Gray	75.64	517-3365/34FT	.68	.62	.57
517-3365/40	3365/40-100SF	D	40	28AWG Stranded	PVC	Gray	102.76	517-3365/40FT	.80	.76	.712
517-3365/50	3365/50-100SF	D	50	28AWG Stranded	PVC	Gray	99.01	517-3365/50FT	.99	.95	.89
517-3365/64	3365/64-100SF	D	64	28AWG Stranded	PVC	Gray	131.48	517-3365/64FT	1.27	1.17	1.07