


Flat Cable, Discrete Wire and Data Cable

RoHS Compliant This product is RoHS compliant.

 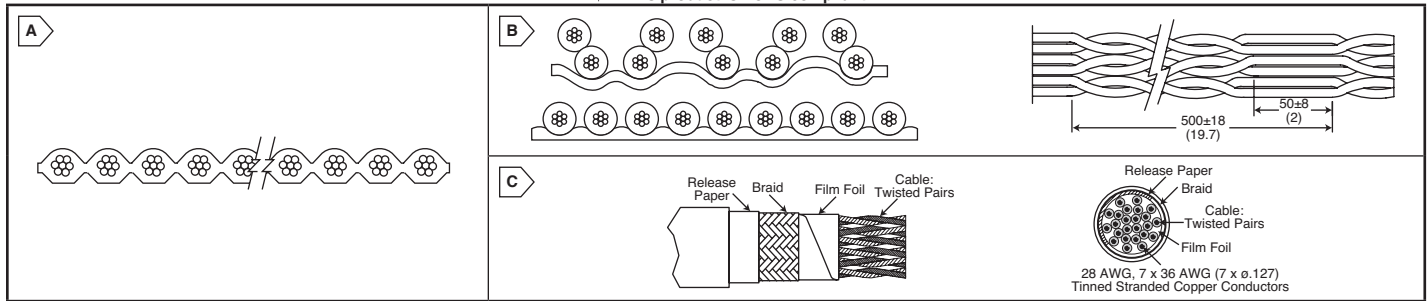


3M TWIN AXIAL CABLE

Features:

- 100Ohm differential pairs
- .88 mm thick
- Four pairs with and without sidebands
- The cable is UL AWM 21008 (150V, 80C); file number E42769
- Solid polyolefin insulation
- Halogen free

NEW!
TECHNOLOGY



Cut Length

3M Part No.	Description	MOUSER STOCK NO.	Price Per Foot	MOUSER STOCK NO.	Price Per Reel
SL8802/08-211N5-00	4PR, 2 GND, Sn	517-SL880208211NCUT	1.04	517-SL880208211N500	401.59
SL8802/08-201N5-00	4PR, 2 GND, Ag	517-SL880208201NCUT	1.34	-	-
SL8801/12-111A5-00	4PR, with 4 Sideband, Sn	517-SL880112111ACUT	1.14	517-SL880112111A500	439.92
SL8801/12-101A5-00	4PR, with 4 Sideband, Ag	517-SL880112101ACUT	1.44	-	-

ROUND CONDUCTOR FLAT CABLE AND DISCRETE WIRE

3302 Series .050" Color Coded Flat Cable

Can be purchased by 100ft. spool or by the foot.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 1000' Spool	MOUSER STOCK NO.	Price Per Foot		
										1	10	25
517-3302/9	3302/09-100	A	9	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	33.26	517-3302/9FT	.36	.33	.298
517-3302/10	3302/10-100	A	10	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	36.94	517-3302/10FT	.37	.34	.31
517-3302/14	3302/14-100	A	14	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	53.20	517-3302/14FT	.53	.505	.473
517-3302/16	3302/16-100	A	16	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	59.12	517-3302/16FT	.64	.578	.54
517-3302/20	3302/20-100	A	20	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	73.90	517-3302/20FT	.76	.722	.676
517-3302/25	3302/25-100	A	25	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	95.60	517-3302/25FT	.99	.915	.83
517-3302/26	3302/26-100	A	26	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	96.06	517-3302/26FT	.98	.931	.879
517-3302/34	3302/34-100	A	34	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	130.00	517-3302/34FT	1.35	1.25	1.14
517-3302/37	3302/37-100	A	37	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	142.19	517-3302/37FT	1.47	1.35	1.23
517-3302/40	3302/40-100	A	40	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	152.97	517-3302/40FT	1.59	1.46	1.33
517-3302/50	3302/50-100	A	50	28AWG Stranded	PVC	Tinned Stranded Copper	10 color repeat	191.19	517-3302/50FT	1.90	1.81	1.69

Twisted Pair Flat Cable 1700 Series .050"

Can be purchased by 100ft. spool or by the foot.

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 1000' Spool	MOUSER STOCK NO.	Price Per Foot		
										1	10	25
517-1700/10	1700/10-100	B	10	28AWG	PVC	Tinned Stranded Copper	10 color repeat	30.77	517-1700/10FT	.38	.35	.32
517-1700/14	1700/14-100	B	14	28AWG	PVC	Tinned Stranded Copper	10 color repeat	43.08	-	-	-	-
517-1700/16	1700/16-100	B	16	28AWG	PVC	Tinned Stranded Copper	10 color repeat	49.23	517-1700/16FT	.61	.56	.51
517-1700/26	1700/26-100	B	26	28AWG	PVC	Tinned Stranded Copper	10 color repeat	79.53	517-1700/26FT	.99	.92	.86
517-1700/34	1700/34-100	B	34	28AWG	PVC	Tinned Stranded Copper	10 color repeat	100.00	517-1700/34FT	1.45	1.30	1.24
517-1700/40	1700/40-100	B	40	28AWG	PVC	Tinned Stranded Copper	10 color repeat	117.65	517-1700/40FT	1.66	1.53	1.40
517-1700/50	1700/50-100	B	50	28AWG	PVC	Tinned Stranded Copper	10 color repeat	142.86	517-1700/50FT	1.90	1.75	1.61

Round, Shielded/Jacketed, Discrete Wire Cable 3600X Series

MOUSER STOCK NO.	3M Part No.	Fig.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 300' Spool
517-3600B/14	3600B/14-300	C	14	28AWG	PVC	Tinned Stranded Copper	Beige	180.19
517-3600B/20-300	3600B/20-300	C	20	28AWG	PVC	Tinned Stranded Copper	Beige	249.60
517-3600B/26-300	3600B/26-300	C	26	28AWG	PVC	Tinned Stranded Copper	Beige	314.34
517-3600B/36	3600B/36-300	C	36	28AWG	PVC	Tinned Stranded Copper	Beige	406.23
517-3600B/68-300	3600B/68-300	C	68	28AWG	PVC	Tinned Stranded Copper	Beige	742.56

KOBICONN .050" FLAT IDC RIBBON CABLE

- By the 100ft. Spool
- RoHS Compliant per Kobiconn documentation

MOUSER STOCK NO.	No. of Conductors	Wire Gauge	Insulation Material	Conductors	Color	Price Per 1000' Spool		
						1	5	10
172-0902-E	9	28AWG	PVC	Tinned Stranded Copper	Gray	27.29	24.81	22.55
172-1010-E	10	28AWG	PVC	Tinned Stranded Copper	Gray	30.34	27.58	25.07
172-1402-E	14	28AWG	PVC	Tinned Stranded Copper	Gray	42.15	38.32	34.84
172-6002-E	60	28AWG	PVC	Tinned Stranded Copper	Gray	147.87	134.43	122.21



KOBICONN FLAT MODULAR TELEPHONE AND DATA CABLE

This modular telephone cable is available in 4, 6, and 8 conductor in three colors: silver satin, black and white. It is sold in 1000' spools.

Features:

- Available in black, white, or silver satin
- Tinned copper conductors prevent corrosion
- Compatible with all USOC modular plugs
- RoHS Compliant per Kobiconn documentation

Specifications:

- 26AWG, 7 x 34 stranding
- Conductors are USOC color coded
- PVC jacket

MOUSER STOCK NO.	No. of Conductors	Color	Price Per 1000' Spool	
			1	5
172-UL4010-E	4	Silver	121.34	110.31
172-UL6010-E	6	Silver	202.80	184.36
172-UL8010-E	8	Silver	269.29	244.80
172-UL4110-E	4	Black	124.79	113.45
172-UL6110-E	6	Black	184.84	168.03
172-UL8110-E	8	Black	236.17	220.72
172-UL4210-E	4	White	124.79	113.45
172-UL6210-E	6	White	184.84	168.03

