

AMPHENOL Spectra-Strip Cable

Amphenol®

RoHS Compliant This product is RoHS compliant.

SKewCLEAR PLUS 1X & 4X INFINIBAND CABLE

The InfiniBand specification provides for data rates over high performance copper lengths: 1x (500MBytes/s 4x (2GBytes/s)




* 12x (6GBytes/s) available-please contact your Mouser Sales Representative

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	AWG	Application	Price Per 1000' Spool
523-160-2499-997	160-2499-997	2	24	1X	1585.63
523-166-2499-998	166-2499-998	8	24	4X	2357.00
523-166-2899-997	166-2899-997	8	28	4X	3.99

.025" TWIST'N'FLAT 125 SERIES

- Programmable twist-length sections
- Ideal for single-ended, LVD SCSI, Ultra320 higher
- 1.707 (in.) width (A)
- 1.675 ± 0.010 (in.) width (B)

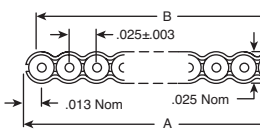


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Price Per Foot		
			1	50	100
523-125-3017-068	125-3017-068	32	4.61	3.48	3.16
523-125-3011-068	125-3011-068	32	4.15	3.15	3.15
523-125-3007-068	125-3007-068	32	4.42	3.22	3.22
523-125-3096-900	125-3096-900	32	4.02	3.46	3.24
523-125-3096-996	125-3096-996	32	5.24	4.19	3.81

TWIST'N'FLAT .050" CENTERS COLOR CODED FLAT CABLE

- Rapid mass termination of twisted pair cable
- 28AWG, 7/36 strand tinned copper
- Temperature rating: 176°F (80°C)
- Terminates to standard IDC connectors

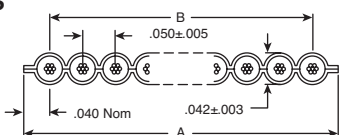


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Total Width		Price Per 100' Spool
			A (in.)	B (in.)	
523-132-2801-010	132-2801-010	5	0.526	0.450±0.015	48.96
523-132-2801-016	132-2801-016	8	0.826	0.750±0.015	67.49
523-132-2801-020	132-2801-020	10	1.026	0.950±0.015	89.25
523-132-2801-026	132-2801-026	13	1.326	1.250±0.015	103.07
523-132-2801-034	132-2801-034	17	1.726	1.650±0.015	153.34
523-132-2801-050	132-2801-050	25	2.526	2.450±0.020	183.80
523-132-2801-060	132-2801-060	30	3.026	2.950±0.025	216.00
523-132-2801-064	132-2801-064	32	3.226	3.150±0.025	213.60

ROUND TWIST'N'FLAT LOOSE PAIR .050" FLAT CABLE

 - 28AWG, 7/36 strand tinned copper
- Voltage Rating: 300V
- Temperature rating: 221°F (105°C)




For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Total Width		Price Per 100' Spool
			A (in.)	B (in.)	
523-169-2832-010	169-2832-010	5	0.526	0.450±0.015	177.27
523-169-2832-020	169-2832-020	10	1.026	0.950±0.015	205.25
523-169-2832-026	169-2832-026	13	1.326	1.25±0.015	245.44
523-169-2832-034	169-2832-034	17	1.726	1.65±0.020	252.23
523-169-2832-050	169-2832-050	25	2.526	2.45±0.020	342.31

ROUND'N'FLAT .050" CENTERS ZIP CABLE

 - 28AWG, 7/36 strand tinned copper
- Voltage Rating: 300V
- Internal cable is gray with a red edge
- Temperature rating: 221°F (105°C)
- Black PVC jacket with indicators for cable flats




For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Pairs	Total Width		Price Per 100' Spool
			A (in.)	B (in.)	
523-159-2801-010	159-2801-010	10	0.500	0.450±0.015	144.11
523-159-2801-016	159-2801-016	16	0.800	0.750±0.015	160.70
523-159-2801-020	159-2801-020	20	1.000	0.950±0.020	159.22
523-159-2801-025	159-2801-025	25	1.250	1.200±0.011	153.64
523-159-2801-026	159-2801-026	26	1.300	1.250±0.011	159.33
523-159-2801-034	159-2801-034	34	1.700	1.650±0.011	190.87
523-159-2801-040	159-2801-040	40	2.000	1.950±0.015	204.02
523-159-2801-050	159-2801-050	50	2.500	1.450±0.015	233.31

HIGH FLEX ZIP 191-2811 SERIES

- Designed for applications that require repeated flexing without circuit interruption

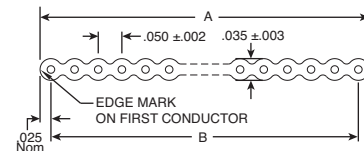


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Conductors	Total Width A (in.)	Total Width B (in.)	Price Per 100' Spool
523-191-2811-010	191-2811-010	10	0.500	0.450±0.007	125.39
523-191-2811-016	191-2811-016	16	0.800	0.750±0.011	202.15
523-191-2811-020	191-2811-020	20	1.000	0.950±0.011	254.66

SPECTRA-ZIP .050" CENTERS GRAY FLAT CABLE

- 28AWG, 7/36 strand tinned copper
- Current Rating: 1A
- Voltage rating: 300V
- Temperature rating: 221°F (105°C)

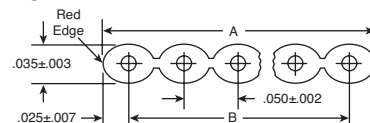


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Conductors	Total Width		Price Per 100' Spool
			A (in.)	B (in.)	
523-191-2801-110	191-2801-110	10	0.500	0.450±0.007	22.12
523-191-2801-114	191-2801-114	14	0.700	0.650±0.007	26.96
523-191-2801-116	191-2801-116	16	0.800	0.750±0.011	29.80
523-191-2801-120	191-2801-120	20	1.000	0.950±0.011	37.25
523-191-2801-124	191-2801-124	24	1.200	1.150±0.011	41.17
523-191-2801-125	191-2801-125	25	1.250	1.200±0.011	42.82
523-191-2801-126	191-2801-126	26	1.300	1.250±0.011	40.66
523-191-2801-134	191-2801-134	34	1.700	1.650±0.011	51.05
523-191-2801-136	191-2801-136	36	1.800	1.750±0.015	91.97
523-191-2801-140	191-2801-140	40	2.000	1.950±0.015	61.94
523-191-2801-150	191-2801-150	50	2.500	2.450±0.015	81.20
523-191-2801-160	191-2801-160	60	3.000	2.950±0.015	93.15
523-191-2801-164	191-2801-164	64	3.200	3.150±0.015	85.88

JACKETED AND SHIELDED ZIP .050" FLAT CABLE

- Rugged flexible black PVC jacket
- EMI/RFI internal shielding
- Terminates to standard IDC connectors
- 28 AWG, 7/36 strand tinned copper
- Temperature rating: 221°F (105°C)
- Voltage rating: 300V

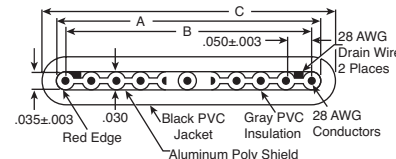


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Cond.	Total Width			Price Per 100' Spool
			A (in.)	B (in.)	C (in.)	
523-151-2831-010	151-2831-010	10	0.500	0.450	0.560	140.77
523-151-2831-015	151-2831-015	15	0.750	0.700	0.810	155.96
523-151-2831-016	151-2831-016	16	0.800	0.750	0.860	192.50
523-151-2831-020	151-2831-020	20	1.000	0.950	1.060	237.93
523-151-2831-040	151-2831-040	40	2.000	1.950	2.060	365.40
523-151-2831-050	151-2831-050	50	2.500	2.450	2.560	529.92

3C COLOR CODED .050" CENTERS FLAT CABLE

- 28AWG, 7/36 strand tinned copper
- Temperature rating: 221°F (105°C)
- Terminates to standard IDC connector
- Current Rating: 1A
- Voltage rating: 300V
- Precise spacing for controlled electrical current

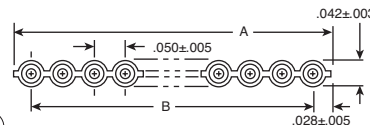

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	No. of Conductors	Total Width		Price Per 100' Spool
			A (in.)	B (in.)	
523-135-2801-010	135-2801-010	10	0.505	0.450±0.015	45.68
523-135-2801-014	135-2801-014	14	0.705	0.650±0.015	58.71
523-135-2801-016	135-2801-016	16	0.805	0.750±0.015	67.19
523-135-2801-020	135-2801-020	20	1.005	0.950±0.015	69.99
523-135-2801-025	135-2801-025	25	1.255	1.200±0.015	92.67
523-135-2801-026	135-2801-026	26	1.305	1.250±0.015	83.34
523-135-2801-040	135-2801-040	40	2.005	1.950±0.020	132.89
523-135-2801-050	135-2801-050	50	2.505	2.450±0.020	162.72
523-135-2801-064	135-2801-064	64	3.205	3.150±0.020	215.38