

DIALIGHT IP67/NEMA 4X Panel Mount LED Indicators




657 SERIES PANEL MOUNT INDICATORS


RoHS Compliant This product is RoHS compliant.

Features/Benefits:

- IP67/NEMA 4X
- Cool-to-the-touch Operation
- Daylight Viewable
- Resistant to shock and vibration
- Anti-Capillary Wire
- LED Technology engineered for up to 100k hours of operation

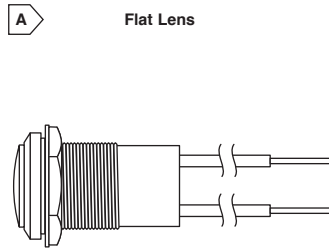

Flat Lens

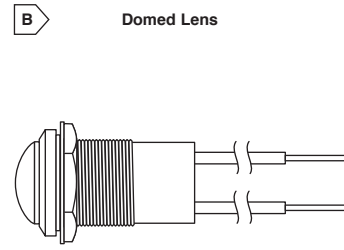

Domed Lens

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Dialight Part No.	Fig.	Color	Lens Color	Intensity (fL)	Voltage (V) Typical	Current (mA)	Price Each			
								1	25	100	250
645-657-1502-103F	657-1502-103F	A	Red	Tinted Diffused	350fl	5V	19	12.69	11.10	9.51	8.56
645-657-1502-303F	657-1502-303F	A	Red	White Diffused	350fl	5V	19	12.69	11.10	9.51	8.56
645-657-1503-103F	657-1503-103F	A	Red	Tinted Diffused	350fl	12V	20	12.69	11.10	9.51	8.56
645-657-1503-303F	657-1503-303F	A	Red	White Diffused	350fl	12V	20	12.69	11.10	9.51	8.56
645-657-1504-103F	657-1504-103F	A	Red	Tinted Diffused	350fl	24V	19	12.69	11.10	9.51	8.56
645-657-1504-303F	657-1504-303F	A	Red	White Diffused	350fl	24V	19	12.69	11.10	9.51	8.56
645-657-1902-103F	657-1902-103F	A	Orange	Tinted Diffused	475fl	5V	19	14.90	11.10	9.51	8.56
645-657-1902-303F	657-1902-303F	A	Orange	White Diffused	475fl	5V	19	12.69	11.10	9.51	8.56
645-657-1903-103F	657-1903-103F	A	Orange	Tinted Diffused	475fl	12V	20	12.69	11.10	9.51	8.56
645-657-1903-303F	657-1903-303F	A	Orange	White Diffused	475fl	12V	20	12.69	11.10	9.51	8.56
645-657-1904-103F	657-1904-103F	A	Orange	Tinted Diffused	475fl	24V	19	12.69	11.10	9.51	8.56
645-657-1904-303F	657-1904-303F	A	Orange	White Diffused	475fl	24V	19	12.69	11.10	9.51	8.56
645-657-1702-103F	657-1702-103F	A	Yellow	Tinted Diffused	350fl	5V	19	12.69	11.10	9.51	8.56
645-657-1702-303F	657-1702-303F	A	Yellow	White Diffused	350fl	5V	19	12.69	11.10	9.51	8.56
645-657-1703-103F	657-1703-103F	A	Yellow	Tinted Diffused	350fl	12V	20	12.69	11.10	9.51	8.56
645-657-1703-303F	657-1703-303F	A	Yellow	White Diffused	350fl	12V	20	12.69	11.10	9.51	8.56
645-657-1704-103F	657-1704-103F	A	Yellow	Tinted Diffused	350fl	24V	19	12.69	11.10	9.51	8.56
645-657-1704-303F	657-1704-303F	A	Yellow	White Diffused	350fl	24V	19	12.69	11.10	9.51	8.56
645-657-1602-103F	657-1602-103F	A	Green	Tinted Diffused	350fl	5V	18	14.03	12.28	10.52	9.47
645-657-1602-303F	657-1602-303F	A	Green	White Diffused	350fl	5V	18	14.03	12.28	10.52	9.47
645-657-1603-103F	657-1603-103F	A	Green	Tinted Diffused	350fl	12V	20	14.03	12.28	10.52	9.47
645-657-1603-303F	657-1603-303F	A	Green	White Diffused	350fl	12V	20	14.03	12.28	10.52	9.47
645-657-1604-103F	657-1604-103F	A	Green	Tinted Diffused	350fl	24V	20	14.03	12.28	10.52	9.47
645-657-1604-303F	657-1604-303F	A	Green	White Diffused	350fl	24V	20	14.03	12.28	10.52	9.47
645-657-1802-103F	657-1802-103F	A	Blue	Tinted Diffused	125fl	5V	18	14.03	12.28	10.52	9.47
645-657-1802-303F	657-1802-303F	A	Blue	White Diffused	125fl	5V	18	14.03	12.27	10.52	9.47
645-657-1803-103F	657-1803-103F	A	Blue	Tinted Diffused	125fl	12V	20	14.03	12.27	10.52	9.47
645-657-1803-303F	657-1803-303F	A	Blue	White Diffused	125fl	12V	20	14.03	12.28	10.52	9.47
645-657-1804-103F	657-1804-103F	A	Blue	Tinted Diffused	125fl	24V	20	14.03	12.28	10.52	9.47
645-657-1804-303F	657-1804-303F	A	Blue	White Diffused	125fl	24V	20	14.03	12.28	10.52	9.47
645-657-1002-303F	657-1002-303F	A	White	White Diffused	100fl	5V	18	14.03	12.28	10.52	9.47
645-657-1003-303F	657-1003-303F	A	White	White Diffused	100fl	12V	20	14.03	12.28	10.52	9.47
645-657-1004-303F	657-1004-303F	A	White	White Diffused	100fl	24V	20	14.03	12.28	10.52	9.47
645-657-2502-103F	657-2502-103F	B	Red	Tinted Diffused	400fl	5V	19	12.69	11.10	9.32	8.45
645-657-2502-303F	657-2502-303F	B	Red	White Diffused	400fl	5V	19	12.69	11.10	9.51	8.56
645-657-2503-103F	657-2503-103F	B	Red	Tinted Diffused	400fl	12V	20	12.69	11.10	9.32	8.45
645-657-2503-303F	657-2503-303F	B	Red	White Diffused	400fl	12V	20	12.69	11.10	9.32	8.45
645-657-2504-103F	657-2504-103F	B	Red	Tinted Diffused	400fl	24V	19	12.69	11.10	9.32	8.45
645-657-2504-303F	657-2504-303F	B	Red	White Diffused	400fl	24V	19	12.69	11.10	9.51	8.56
645-657-2902-103F	657-2902-103F	B	Orange	Tinted Diffused	675fl	5V	19	12.69	11.10	9.51	8.56
645-657-2902-303F	657-2902-303F	B	Orange	White Diffused	675fl	5V	19	12.69	11.10	9.51	8.56
645-657-2903-103F	657-2903-103F	B	Orange	Tinted Diffused	675fl	12V	20	12.69	11.10	9.32	8.45
645-657-2903-303F	657-2903-303F	B	Orange	White Diffused	675fl	12V	20	12.69	11.10	9.32	8.45
645-657-2904-103F	657-2904-103F	B	Orange	Tinted Diffused	675fl	24V	19	12.69	11.10	9.51	8.56
645-657-2904-303F	657-2904-303F	B	Orange	White Diffused	675fl	24V	19	12.69	11.10	9.51	8.56
645-657-2702-103F	657-2702-103F	B	Yellow	Tinted Diffused	400fl	5V	19	12.69	11.10	9.32	8.45
645-657-2702-303F	657-2702-303F	B	Yellow	White Diffused	400fl	5V	19	12.69	11.10	9.51	8.56
645-657-2703-103F	657-2703-103F	B	Yellow	Tinted Diffused	400fl	12V	20	12.69	11.10	9.32	8.45
645-657-2703-303F	657-2703-303F	B	Yellow	White Diffused	400fl	12V	20	12.69	11.10	9.32	8.45
645-657-2704-103F	657-2704-103F	B	Yellow	Tinted Diffused	400fl	24V	19	12.69	11.10	9.32	8.45
645-657-2704-303F	657-2704-303F	B	Yellow	White Diffused	400fl	24V	19	12.69	11.10	9.51	8.56
645-657-2602-103F	657-2602-103F	B	Green	Tinted Diffused	400fl	5V	18	14.03	12.28	10.31	9.35
645-657-2602-303F	657-2602-303F	B	Green	White Diffused	400fl	5V	18	14.03	12.28	10.52	9.47
645-657-2603-103F	657-2603-103F	B	Green	Tinted Diffused	400fl	12V	20	14.03	12.28	10.31	9.35
645-657-2603-303F	657-2603-303F	B	Green	White Diffused	400fl	12V	20	14.03	12.28	10.52	9.47
645-657-2604-103F	657-2604-103F	B	Green	Tinted Diffused	400fl	24V	20	14.03	12.28	10.31	9.35
645-657-2604-303F	657-2604-303F	B	Green	White Diffused	400fl	24V	20	14.03	12.28	10.52	9.47
645-657-2802-103F	657-2802-103F	B	Blue	Tinted Diffused	175fl	5V	18	14.03	12.28	10.52	9.47
645-657-2802-303F	657-2802-303F	B	Blue	White Diffused	175fl	5V	18	14.03	12.28	10.52	9.47
645-657-2803-103F	657-2803-103F	B	Blue	Tinted Diffused	175fl	12V	20	14.03	12.28	10.31	9.35
645-657-2803-303F	657-2803-303F	B	Blue	White Diffused	175fl	12V	20	14.03	12.28	10.31	9.35
645-657-2804-103F	657-2804-103F	B	Blue	Tinted Diffused	175fl	24V	20	14.03	12.28	10.52	9.47
645-657-2804-303F	657-2804-303F	B	Blue	White Diffused	175fl	24V	20	14.03	12.28	10.52	9.47
645-657-2002-303F	657-2002-303F	B	White	White Diffused	100fl	5V	18	14.03	12.28	10.52	9.47
645-657-2003-303F	657-2003-303F	B	White	White Diffused	100fl	12V	20	14.03	12.28	10.31	9.35
645-657-2004-303F	657-2004-303F	B	White	White Diffused	100fl	24V	20	14.03	12.28	10.52	9.47