

# BELDEN Hook-Up Wire, Dispenser Kits & Test Prod Wire **BELDEN**

This product is RoHS compliant.

### Color Code Chart

To order replace \_\_\_ with applicable code for color desired.

01=Brown	04=Yellow	07=Violet	09=White	13=Dark Blue
02=Red	05=Green	08=Gray	10=Black	18=Green/Yellow

## HOOK UP/LEAD PPO HOOK-UP WIRE 600V, 105°C AWM STYLE

Electrical panel builders, Electrical/electronic manufacturers, Appliance manufacturers, Furniture, Computer manufacturers, Automotive companies and their sub-suppliers, Buildings




Belden Part No.	Conductor AWG	Strand	Nominal O.D. (in.)	100 ft. Spools			1000 ft. Spools		
				MOUSER STOCK NO.	Stocked Colors	Price Per 100' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 1000' Spool
39114	14	41x30	0.097	<a href="#">566-39114-100-</a>	01-02, 04-05, 07-10, 13, 18	122.62	<a href="#">566-39116-1000-</a>	01-02, 04-05, 07-10, 13, 18	607.33
39116	16	26x30	0.083	<a href="#">566-39116-100-</a>	01-02, 04-05, 07-10, 13, 18	84.65	<a href="#">566-39116-1000-</a>	01-02, 04-05, 07-10, 13, 18	607.33
39118	18	16x30	0.069	<a href="#">566-39118-100-</a>	01-02, 04-05, 07-10, 13, 18	68.12	<a href="#">566-39120-1000-</a>	01-02, 04-05, 07-10, 13, 18	326.46
39120	20	10x30	0.061	<a href="#">566-39120-100-</a>	01-02, 04-05, 07-10, 13	52.52	<a href="#">566-39120-1000-</a>	01-02, 04-05, 07-10, 13	326.46
39122	22	7x30	0.053	<a href="#">566-39122-100-</a>	01-02, 04-05, 07-10, 13	40.91	<a href="#">566-39122-1000-</a>	01-02, 04-05, 07-10, 13	252.33
39124	24	7x32	0.048	<a href="#">566-39124-100-</a>	01-02, 04-05, 07-10, 13	37.13	<a href="#">566-39124-1000-</a>	01-02, 04-05, 07-10, 13	225.92
39126	26	7x34	0.043	<a href="#">566-39126-100-</a>	01-02, 04-05, 07-10, 13	32.90	<a href="#">566-39126-1000-</a>	01-02, 04-05, 07-10, 13	198.94
39128	28	7x36	0.039	<a href="#">566-39128-100-</a>	01-02, 04-05, 07-10, 13	30.86	<a href="#">566-39128-1000-</a>	01-02, 04-05, 07-10, 13	186.73

## UL AWM STYLE 3340 AND 3374 600V

### Stranded Tinned Copper Conductor

- Stranded tinned copper conductor
- 125°C Flex/150°C No Flex

Belden Part No.	AWG (Strand)	Nominal O.D. (in.)	Description	500 ft. Spools		
				MOUSER STOCK NO.	Stocked Colors	Price Per 500' Spool
37118	18 (16x30)	.142	Stranded Conductor	<a href="#">566-37118-500-</a>	02, 05, 09, 10	172.83
37116	16 (26x30)	.154	Stranded Conductor	<a href="#">566-37116-500-</a>	02, 04, 05, 10, 13	214.84
37114	14 (41x30)	.169	Stranded Conductor	<a href="#">566-37114-500-</a>	02, 10	343.50
37112	12 (65x30)	.190	Stranded Conductor	<a href="#">566-37112-500-</a>	02, 10	483.35
37110	10 (65x28)	.240	Stranded Conductor	<a href="#">566-37110-500-</a>	10	686.21
37108	8 (84x27)	.327	Separator Over Conductor	<a href="#">566-37108-500-</a>	10	1173.48

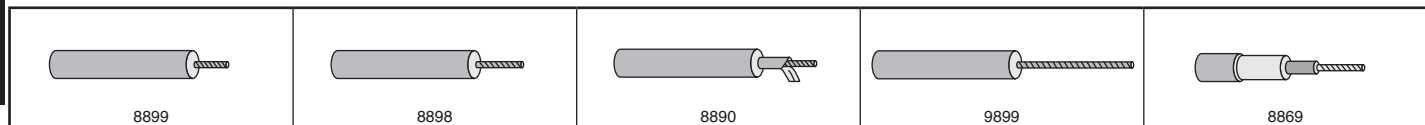

## TEST PROD WIRE

### Tinned Copper, Rubber Insulated

Belden Part No.	Conductor AWG	Strand	Nominal O.D. (in.)	25 ft. Spools			100 ft. Spools			500 ft. Spools		
				MOUSER STOCK NO.	Stocked Colors	Price Per 25' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 100' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 500' Spool
8899	18	65x36	0.144	<a href="#">566-8899-25-</a>	02, 10	38.18	<a href="#">566-8899-100-</a>	02, 04, 05, 09, 10	108.37	<a href="#">566-8899-500-</a>	02, 05, 10	375.09
8898	18	65x36	0.229	-	-	-	<a href="#">566-8898-100-</a>	02, 10	154.58	<a href="#">566-8898-500-</a>	10	662.28
8890	24	45x40	0.066	-	-	-	<a href="#">566-8890-100-</a>	10	65.34	<a href="#">566-8890-500-</a>	02, 10	293.63

### Tinned Copper, PVC Insulated

Use test probe leads for electrical and electronic measuring for test equipment.

Belden Part No.	Conductor AWG	Strand	Nominal O.D. (in.)	25 ft. Spools			100 ft. Spools			500 ft. Spools		
				MOUSER STOCK NO.	Stocked Colors	Price Per 25' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 100' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 500' Spool
9899	18	65x36	0.144	-	-	-	<a href="#">566-9899-100-</a>	02, 10	86.38	<a href="#">566-9899-500-</a>	02, 10	337.24

### Tinned Copper, Polyethylene Insulated, PVC Jacket

Conductive polyethylene over inner conductor provides uniform distribution of voltage stress. PVC jacket in black.

Belden Part No.	Conductor AWG	Strand	Nominal O.D. (in.)	25 ft. Spools			100 ft. Spools			500 ft. Spools		
				MOUSER STOCK NO.	Stocked Colors	Price Per 25' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 100' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 500' Spool
8869	22	7x30	0.120	-	-	-	-	-	-	<a href="#">566-8869-500</a>	10	243.75

## HOOK-UP WIRE DISPENSER KITS

Great for R and D labs, engineers, servicemen and hobbyists. Kits are available in five 100' spools or eight 25' spools. Each spool is a different color and comes in a portable dispenser rack.

Belden Part No.	Wire	Temp. Rating	Stocked Colors	100 ft. Spools		
				MOUSER STOCK NO.	1	2
9531	22AWG (7x30) Stranded Tinned PVC (8524)	80°C	Red, Green, White, Light Blue, Black	<a href="#">566-9531</a>	197.48	178.01
8825	20AWG (7x28) Stranded Tinned PVC (8502)	80°C	Red, Green, White, Yellow, Black	<a href="#">566-8825</a>	256.36	231.09

Belden Part No.	Wire	Temp. Rating	Stocked Colors	25 ft. Spools		
				MOUSER STOCK NO.	1	2
8824	20AWG (10x30) Stranded Tinned PVC (8523)	80°C	Brown, White, Black, Orange, Green, Red, Light Blue, Yellow	<a href="#">566-8824</a>	177.57	160.07
8816	18AWG (16x30) Stranded Tinned PVC (8522)	80°C	Brown, White, Black, Orange, Green, Red, Light Blue, Yellow	<a href="#">566-8816</a>	186.91	168.49

