


BELDEN 50 Ohm Coaxial Cables



RoHS Compliant This product is RoHS compliant.

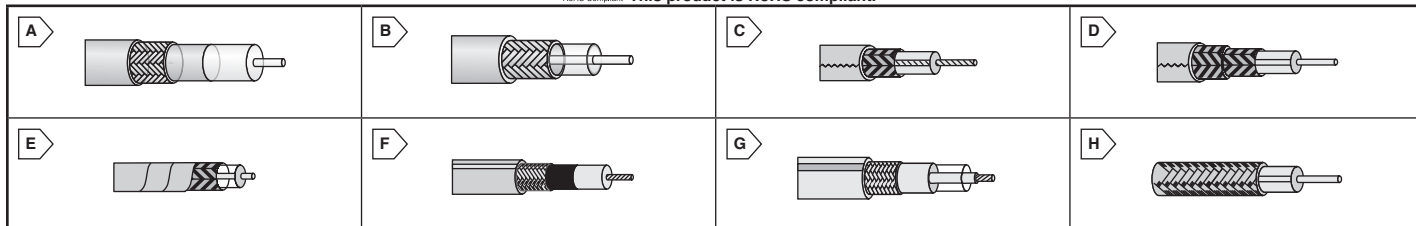

BELDEN TRANSMISSION CABLES

Low Loss Transmission Cable - CMR Rated



Belden Part No.	Fig.	RG Type	AWG (Stranded)	Nom. O.D. (in.)	500 ft. Spool		1000 ft. Spool		
					MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool	
Beldfoil® + 90% Tinned Copper Braid Shield									
7805	A	RG-174	25(Solid)	.110	566-7805-500	342.52	566-7805-1000	685.10	
Duofoil® Tape + 90% Tinned Copper Braid									
7805R	A	RG174	24.5 (Solid)	.110	566-7805R-500-08	353.75	566-7805R-1000-08	787.71	
7806R	A	RG58	19 (Solid)	.195	566-7806R-500	415.84	566-7806R-1000-10	963.91	
Duofoil® + 95% Tinned Copper Braid Shield									
7807A	A	RG-58	17(Solid)	.195	566-7807A-500	384.28	566-7807A-1000	883.62	
Duofoil® Tape + 95% Tinned Copper Braid									
7807R	A	RG58/U	17 (Solid)	.195	566-7807R-500	442.68	566-7807R-1000	973.83	
Duofoil® II + 95% Tinned Copper Braid Shield									
7808A	A	RG-8X	15(Solid)	.240	566-7808A-500	524.31	566-7808A-1000	1127.86	
Duobond® II + 95% Tinned Copper Braid									
7808R	A	RG-8X	15 (Solid)	.240	566-7808R-500-10	622.42	566-7808R-1000-10	1244.86	
7809R	A	- - -	13 (Solid)	.300	566-7809R-500-10	726.01	566-7809R-1000-10	1452.04	
Duobond® II + Tinned Copper Braid Shield									
7809A	A	Intermediate	13(Solid)	.300	566-7809A-500	659.19	566-7809A-1000	1317.56	
Duobond® II + Tinned Copper Braid Shield									
7810A	A	RG-8	10(Solid)	.403	566-7810A-500	734.84	566-7810A-1000	1635.25	
Bonded Duofoil® Tape + 95% Tinned Copper Braid									
7810R	A	RG8/U	10 (Solid)	.403	566-7810R-500-10	904.50	566-7810R-1000-10	1809.01	
Duofoil® + 90% Tinned Copper Braid Shield									
7977R	A	- - -	5.5 (Solid)	.590	566-7977R-500	1426.60	566-7977R-1000	2853.26	

MIL-C-17G QPL Cable



Belden Part No.	Fig.	RG Type	AWG (Stranded)	Nom. O.D. (in.)	100 ft. Spool		500 ft. Spool		1000 ft. Spool	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
Military Specification M/155-00001, 95% Tinned Copper Braid, Black PVC Jacket										
8262	B	RG-58 C/U	20 (19 x 33)	.195	- - - - -	-	566-8262-500	344.44	566-8262-1000	787.93
Military Specification M17/169-00001, 96% Silver Coated Copper Braid, White FEP Jacket										
83265	C	RG-178B/U	30 (7 x 38)	.071	566-83265-100	151.26	- - - - -	-	- - - - -	-
Military Specification M/17/172-00001, 95% Silver Plated Copper Braid										
83284	C	RG-316/U	26 (7 x 34)	.098	566-83284-100	199.23	566-83284-500	950.19	566-83284-1000	1818.23
Military Specification M17/60-RG142, 96% Silver Coated Copper Braid and Silver Coated Copper Braid, Plenum										
84142	D	RG-142/U	18 (Solid)	.195	566-84142-100	683.58	566-84142-500	2969.60	566-84142-1000	6828.68

Transmission and Computer Cable



Belden Part No.	Fig.	RG Type	AWG (Stranded)	Nom. O.D. (in.)	100 ft. Spool		500 ft. Spool		1000 ft. Spool	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
95% Tinned Copper Braid, Black PVC Jacket										
8259	B	RG58 A/U	20 (19 x 33)	.192	566-8259-100	80.13	566-8259-500	243.49	566-8259-1000	547.98
Military Specification MIL-C-17D, 96% Silver Coated Copper Braid, White FEP Tape Jacket										
83269	E	RG-188A/U	26 (7x34)	.098	566-83269-100	260.62	566-83269-500	1306.17	566-83269-1000	2612.37

BELDEN LOW TRIBOELECTRIC NOISE COAX CABLE



Belden Part No.	Fig.	RG Type	AWG (Stranded)	Nom. O.D. (in.)	100 ft. Spool		500 ft. Spool		1000 ft. Spool	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
Maximum Peak-to-Peak Noise Level: 5mv, 90% Tinned Copper Braid, Black PVC Jacket										
9239	F	RG-174/U	26 (7 x 34)	.101	566-9239-100	100.82	566-9239-500	374.04	566-9239-1000	855.81
Maximum Peak-to-Peak Noise Level: 8mv, Bonded Duofoil® Tape and 95% Tinned Copper Braid										
9223	G	RG-58/U	22 (7 x 30)	.195	566-9223-100	147.63	566-9223-500	581.34	- - - - -	-

BELDEN CONFORMABLE COAX MICROWAVE CABLE

Belden Part No.	Fig.	RG Type	AWG (Stranded)	Nom. O.D. (in.)	50 ft. Spool		500 ft. Spool		1000 ft. Spool	
					MOUSER STOCK NO.	Price Per 50' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
100% Copper-Tin Composite										
1671A	H	RG-405/U	24 (Solid)	.085	566-1671A-50	370.92	566-1671A-500	2250.82	566-1671A-1000	5033.93
100% Copper-Tin Composite										
1673A	H	RG-402/U	19 (Solid)	.138	566-1673A-50	290.56	566-1673A-500	2809.68	- - - - -	-
100% Cooper-Tin Composite Shield										
1674A	H	M17/151	29 (Solid)	.047	- - - - -	-	566-1674A-500	2974.82	- - - - -	-
100% Cooper-Tin Composite Shield										
1671J	B	RG-405/U	24 (Solid)	.127	- - - - -	-	566-1671J-500	2713.98	- - - - -	-



Wire & Cable Belden