


BELDEN Audio Cables



RoHS Compliant This page of product is compliant.

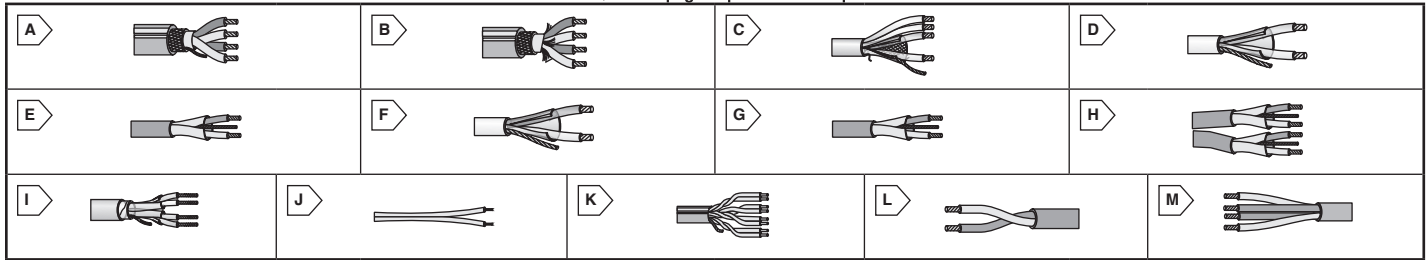

BELDEN FOUR-CONDUCTOR STAR QUAD, LOW IMPEDANCE CABLES

High-Conductivity Copper

- Polyethylene Insulation
- TC "French Braid" Shield (95% Coverage)
- Matte PVC Jacket



Color Code Chart		
To order replace with applicable code for color desired.		
02=Red	05=Green	08=Gray
04=Yellow	06=Blue	10=Black

Belden Part No.	Fig.	No. of Cond.	AWG (Stranded)	Nom. OD (in.)	100 ft. Spools			500 ft. Spools			1000 ft. Spools		
					MOUSER STOCK NO.	Stocked Colors	Price Per 100' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 500' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 1000' Spool
1172A	A	4	26 (30x40)	.190	-----	-	197.91	566-1172A-500-___	10	538.47	566-1172A-1000-___	02, 04, 05, 06, 08, 10	1238.19
1192A	B	4	24 (42x40)	.245	566-1192A-100-___	10	197.91	566-1192A-500-___	06, 10	786.04	566-1192A-1000-___	02, 04, 05, 06, 08, 10	1576.07

BELDEN Brilliance SPECIAL APPLICATION CABLE



- Applications:**
- Audio
 - Communication
 - Instrumentation

- Features:**
- PVC Jacket
 - Tinned Copper Conductors
 - Drain Wire: 18AWG (16x30)

Belden Part No.	Fig.	Description	NEC Type	No. of Pairs	AWG (Stranded)	Nom. OD (in.)	500 ft. Spool	
							MOUSER STOCK NO.	Price Per 500' Spool
1502R	C	Black Flame Retardant Jacket	CMR	2	22 (7x30)	.250	566-1502R-500-10	320.41

BELDEN Brilliance AUDIO CONTROL AND INSTRUMENTATION CABLE

Shielded, Twisted Pairs

- Tinned Copper
- Beldfoil® Aluminum-Polyester Shield
- † Drain Wire: 18AWG (16x30)
- * Available in box only



Color Code Chart		
To order replace with applicable code for color desired.		
01=Brown	04=Yellow	08=Gray
02=Red	06=Blue	09=White
03=Orange	07=Violet	10=Black

Belden Part No.	Fig.	Description	NEC Type	No. of Pairs	AWG (Stranded)	Nom. OD (in.)	100 ft. Spools		500 ft. Spools		1000 ft. Spools		
							MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Stocked Colors	Price Per 1000' Spool
88641	D	Red FEP Jacket	CMP	1	24 (7x32)	.106	566-88641-100	250.23	-	-	-	-	-
82761	E	Natural Flammarrest® Jacket	CMP	1	22 (7x30)	.116	-----	-----	566-82761-500	504.30	566-82761-1000	---	1084.83
88761	D	Red FEP Jacket	CMP	1	22 (7x30)	.119	566-88761-100	189.07	-----	-----	-----	-----	-----
9451P	E	Black Flammarrest® Jacket	CMP	1	22 (7x30)	.127	-----	-----	-----	-----	* 566-9451P-U1000-10	---	627.52
9451	E	Bonded Jacket and Shield	CMR	1	22 (7x30)	.135	-----	-----	566-9451-500	134.28	-----	---	-----
8451	F	Black PVC Jacket	CMR	1	22 (7x30)	.138	566-8451-100	27.21	566-8451-500	123.64	566-8451-1000	---	277.42
88760	D	Red FEP Jacket	CMP	1	18 (19x30)	.140	-----	-----	* 566-88760-500	906.18	-----	---	-----
1503A	G	Brown PVC Jacket	CM	1	22 (7x30)	.142	-----	-----	-----	-----	* 566-1503A-1000U-___	01-10	260.65
82760	E	Natural Flammarrest® Jacket	CMP	1	18 (19x30)	.146	-----	-----	* 566-82760-U500	770.22	566-82760-1000	---	1540.49
8719	F	Chrome PVC Jacket	CM/CL2	1	16 (19x29)	.320	-----	-----	566-8719-500	506.94	-----	---	-----
8720	F	Chrome PVC Jacket	CL2	1	14 (19x27)	.355	-----	-----	566-8720-500	652.83	566-8720-1000	---	1501.15
9451DP	H	White Flammarrest® Jacket	CMP	2	22 (7x30)	.127x.269	-----	-----	-----	-----	566-9451DP-1000-09	---	1283.99
82723	I	Natural Flammarrest® Jacket	CMP	2	22 (7x30)	.153	-----	-----	* 566-82723-U500	629.37	-----	---	-----
8723	I	Chrome PVC Jacket	CM	2	† 22 (7x30)	.165	566-8723-100	60.44	566-8723-500	224.47	566-8723-1000	---	448.94

AES/EBU Digital Audio Cable

- 110 Ohms Impedance
- Low Capacitance
- Unshielded

1353A	J	Black PVC Jacket	CMR	1	24 (7x32)	.126	-----	-----	566-1353A-500-10	77.20	566-1353A-1000-10	---	176.69
-------	---	------------------	-----	---	-----------	------	-------	-------	------------------	-------	-------------------	-----	--------

BELDEN Brilliance 4 PAIR VIDEO TWIST LOW-SKEW UTP CABLES

Belden Part No.	Fig.	Description	NEC Type	No. of Pairs	AWG (Stranded)	Max Delay Skew per 100M	Category	Nominal O.D. (in.)	1000 ft. Spools		1000 ft. Boxes	
									MOUSER STOCK NO.	Price Per 1000' Spool	MOUSER STOCK NO.	Price Per 1000' Box
7987R	K	Maroon PVC Jacket	CMR	4	24 (solid)	2.2nsec	-	.195	-----	-----	566-7987R-U1000	339.33
7987P	K	Maroon Flammarrest® Jacket	CMR	4	24 (solid)	2.2nsec	-	.200	-----	-----	566-7987P-U1000	762.89
7988R	K	Green PVC Jacket	CMR	4	24 (solid)	9nsec	5E	.200	-----	-----	566-7988R-U1000	366.41
7988P	K	Green PVC Jacket	CMR	4	24 (solid)	9nsec	5E	.200	-----	-----	566-7988P-U1000	807.44
7989R	K	BLUE PVC Jacket	CMR	4	23 (solid)	10nsec	6	.365x.165	566-7989R-1000-13	468.97	-----	-----
7989P	K	Blue Flammarrest® Jacket	CMP	4	23 (solid)	10nsec	6	.365x.165	566-7989P-1000-13	1164.58	-----	-----

Two Conductor Speaker Wire

Belden Part No.	Fig.	Cable Type	No. of Cond.	AWG	Stranded	Nom. OD (in.)	Color	500 ft. Spools		1000 ft. Spools	
								MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
8782	J	Parallel	2	24	7x32	.058x.115	Clear	-----	-----	566-8782-1000	156.94
9708	J	Parallel	2	18	16x30	.110x.220	Clear	566-9708-500	231.13	566-9708-1000	531.46
9717	J	Parallel	2	14	19x27	.146x.292	Clear	-----	-----	566-9717-1000	1098.74
9718	J	Parallel NEC Type CL3	2	12	65x30	.185x.370	Clear	566-9718-500	1071.66	-----	-----

BELDEN Brilliance LOW CAP OFHC SPEAKER CABLES

Belden Part No.	Fig.	Cable Type	No. of Cond.	AWG	Stranded	Nom. OD (in.)	Color	100 ft. Spools		500 ft. Boxes		1000 ft. Spools	
								MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Box	MOUSER STOCK NO.	Price Per 1000' Spool
1307A	L	CMR, CL3R	2	16	65x34	.210	Black	-----	-----	566-1307A-U500-10	185.81	566-1307A-1000-10	431.14
1308A	M	CMR, CL3R	4	16	65x34	.270	Black	-----	-----	566-1308A-U500-10	383.01	566-1308A-1000-10	804.44
1309A	L	CMR, CL3R	2	14	105x34	.264	Black	-----	-----	566-1309A-U500-10	367.75	566-1309A-1000-10	818.88
1310A	M	CMR, CL3R	4	14	105x34	.319	Black	-----	-----	566-1310A-U500-10	680.17	566-1310A-1000-10	1564.03
1311A	M	CMR, CL3R	2	12	168x34	.352	Black	566-1311A-500-10	565.95	-----	-----	566-1311A-1000-10	1131.92
1312A	M	CMR, CL3R	4	12	168x34	.423	Black	566-1312A-500-10	1061.46	-----	-----	566-1312A-1000-10	2122.96
1313A	L	CMR, CL3R	2	10	259x34	.428	Black	566-1313A-500-10	858.98	-----	-----	566-1313A-1000-10	1717.97