


BELDEN Audio, Control and Instrumentation Cable



RoHS Compliant This product is RoHS compliant.

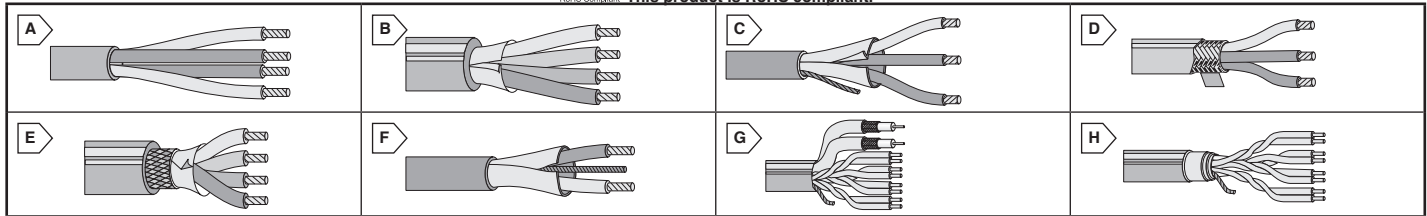

BELDEN AUDIO WIRE AND CABLE

Multi-Conductor Unshielded Control Cable (Plenum)

- FEP Insulation
- Red FEP Jacket
- Suitable for Outdoor and Direct Burial Applications
- Tinned Copper Conductor

RoHS Compliant

AlphaWire Recommend Heat Shrink **FT1400**

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal OD (in.)	100 ft. Spools		500 ft. Spools	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
88444	A	4	22 (7 x 30)	.121	566-88444-100	178.51	-----	-

Multi-Conductor Overall Beldfoil® Shield (Non-Plenum)

- UL AWM Style 2094
- (300V 75°C)
- Polyethylene Insulation
- White PVC Jacket
- Has three solid and one Stranded Tinned-Copper-Coated Steel drain wires

AlphaWire Recommend Heat Shrink **FT1221**

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal OD (in.)	100 ft. Spools		500 ft. Spools	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
8729	B	4	22 (19 x 34)	.257	-----	-	566-8729-500	964.80

Multi-Conductor Overall Beldfoil® Shield (Non-Plenum) w/TC Drain Wire

- (300V RMS)
- Polyethylene Insulation
- Brown PVC Jacket

AlphaWire Recommend Heat Shrink **FT1221**

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal OD (in.)	100 ft. Spools		500 ft. Spools	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
9770	C	3	22 (7 x 30)	.145	-----	-	566-9770-500	331.16

High-Temperature Overall Braid Shield; MIL-W-16878/4, Type E

- (600V RMS, -65°C to 200°C)
- Extruded TFE Teflon® Insulation
- White TFE Teflon® Tape-Wrapped Jacket

83318E	D	2	24 (19 x 36)	.131	566-83318-100	442.82	-----	-
83319E	D	2	22 (19 x 34)	.143	566-83319-100	558.22	-----	-

Multi-Conductor Plenum-Rated Overall Foil/Braid Shield

- FEP Insulation
- Red FEP Jacket
- 100% Beldfoil® + 85% Tinned Copper Braid Shield

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal OD (in.)	100 ft. Spools		500 ft. Spools	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
83562	E	12	22 (7 x 30)	.234	-----	-	566-83562-500	5901.62

High-Temperature Control and Instrumentation Cables

- (300V RMS 105°C)
- Tefzel® Insulation
- Clear Tefzel® Jacket
- Overall 100% Beldfoil® Aluminum-Kapton® Shield

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal OD (in.)	100 ft. Spools		500 ft. Spools	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
85231	F	2	16 (19 x 29)	.210	-----	-	566-85231-500	4995.17

Multi-Conductor Overall Beldfoil® Shield (Non-Plenum)

- Polyethylene Insulation
- Chrome PVC Jacket

AlphaWire Recommend Heat Shrink **FT1221**

Belden Part No.	Fig.	Cable Type	NEC Type	No. of Cond.	AWG (Stranded)	Nominal OD (in.)	% Type Shield	500 ft. Spools		1000 ft. Spools	
								MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
8771	C	UL2093	CM	3	22 (7 x 30)	.199	100 Foil	566-8771-500	280.00	566-8771-1000	560.00
8770	C	UL2093	CM	3	18 (16 x 30)	.246	100 Foil	566-8770-500	370.31	566-8770-1000	755.34

BELDEN BRILLIANCE® DIGITAL AND ANALOG AUDIO/VIDEO COMPOSITE CABLES



Matte Black Overall PVC Jacket

RoHS Compliant

Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG (Stranded)	Nominal OD (in.)	Nom Imp.	% Type Shield	500 ft. Spools		1000 ft. Spools	
								MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
1347A	G	CMR	2-Coax 4-pair	20 (solid) 22 (7x30)	.630	75	95	566-1347A-500	2406.33	566-1347A-1000	4812.69

BELDEN BRILLIANCE® CATSNAKE TACTICAL HEAVY DUTY CAT5E AUDIO/VIDEO COMPOSITE CABLES



- 100 ohms impedance

RoHS Compliant

Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG (Stranded)	Nominal OD (in.)	Nom Imp.	% Type Shield	500 ft. Spools		1000 ft. Spools	
								MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
1304A	H	----	4	24 (7x32)	.245	----	----	566-1304A-500	471.28	566-1304A-1000	1078.35
1305A	H	----	4	24 (7x32)	.295	----	----	566-1305A-500	583.23	566-1305A-1000	1273.81

BELDEN HDMI CABLE ASSEMBLIES

- Gold Connector
- Male to Male
- UL NEC/C(UL): CM or CL2
- Conductor: BC - Bare Copper
- Foam Polyolefin Insulation

For quantities of 5 and up, call for quote.

Belden Part No.	AWG (Stranded)	Length (ft.)	MOUSER STOCK NO.	Price Each	
				1	2
HD2001	26 (7x34)	3.28	566-HD2001	24.02	23.07
HD2002	26 (7x34)	6.56	566-HD2002	33.73	31.44
HD2003	26 (7x34)	9.84	566-HD2003	40.48	36.48
HD2004	26 (7x34)	13.12	566-HD2004	47.38	45.90
HD2007	26 (7x34)	22.96	566-HD2007	80.47	72.53



Wire & Cable

Belden