


BELDEN Computer and Instrumentation Cable **BELDEN**

RoHS Compliant This product is RoHS compliant.

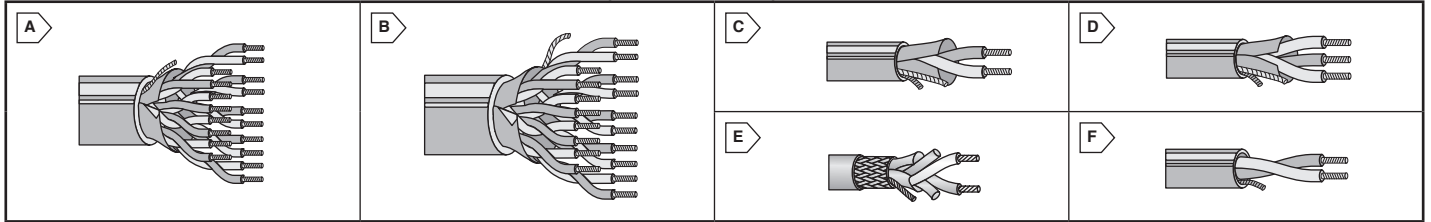

BELDEN OVERALL BELDFOIL® SHIELDED, INSTRUMENTATION, & COMPUTER CABLE

• 24AWG Stranded Conductors (7 x 32) • Tinned Copper, PVC Insulated, Twisted Pairs • UL AVM Style 2464 (300V 80°C), CSA AVM I A • Chrome PVC Jacket

AlphaWire Recommend Heat Shrink **FT221**

Belden Part No.	Fig.	Number of Pairs	Nominal O.D. (in.)	100 ft. Spools		500 ft. Spools		1000 ft. Spools	
				MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
9502	A	2	.222	566-9502-100	67.18	566-9502-500	282.50	566-9502-1000	649.58
9503	A	3	.232	566-9503-100	92.43	566-9503-500	365.17	566-9503-1000	839.68
9504	A	4	.265	566-9504-100	106.96	566-9504-500	449.76	566-9504-1000	899.51
9505	A	5	.289	566-9505-100	127.33	566-9505-500	520.67	566-9505-1000	1158.64
9506	A	6	.289	566-9506-100	167.41	566-9506-500	735.34	-	-
9507	A	7	.294	566-9507-100	177.76	-	-	-	-
9508	A	8	.324	566-9508-100	214.65	566-9508-500	877.84	-	-
9509	A	9	.334	566-9509-100	224.67	-	-	-	-
9510	A	10	.368	566-9510-100	270.08	566-9510-500	1062.67	-	-
9515	A	15	.417	566-9515-100	377.86	-	-	-	-
9519	A	19	.448	566-9519-100	505.42	-	-	-	-

BELDEN INDUSTRIAL AUTOMATION AND PROCESS CONTROL CABLES

Shielded, Instrumentation 300V Power-Limited Tray Cables

† Number of Triads

• Tinned Copper, Twisted Pairs • Overall 100% Beldfoil® Shield • Flame Retardant PVC Insulation and PVC Jacket • Chrome Jacket Color

AlphaWire Recommend Heat Shrink **FT221**

Belden Part No.	Fig.	No. of Pairs	Nom. OD (in.)	AWG (Stranded)	500 ft. Spools		500 ft. Unreel Boxes		1000 ft. Unreel Boxes	
					MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 500' Box	MOUSER STOCK NO.	Price Per 100' Box
9322	B	1	.200	22 (7 x 30)	-	-	-	566-9322-1000U	501.13	
9512	B	2	.310	22 (7 x 30)	566-9512-500	433.92	-	-	-	
9513	B	3	.324	22 (7 x 30)	566-9513-500	530.41	-	-	-	
9514	B	4	.356	22 (7 x 30)	566-9514-500	756.98	-	-	-	
9516	B	6	.418	22 (7 x 30)	566-9516-500	1025.33	-	-	-	
9316	C	1	.256	16 (19 x 29)	-	-	566-9316-500U	599.05	-	
9320	C	1	.217	20 (19 x 32)	-	-	566-9320-500U	349.12	-	
9365	D	† 1	.245	18 (19 x 30)	-	-	566-9365-500U	780.97	-	

BELDEN BLUEHOSE® CABLES

Twinaxial, Foil/Braid Shield

Belden Part No.	Fig.	AWG (Stranded)	Nom. OD (in.)	Nominal Impedance	% Type Shield	100 ft. Spools		500 ft. Spools		1000 ft. Spools	
						MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
9463	E	20 (7 x 28)	.238	78	100	566-9463-100	112.93	566-9463-500	445.09	566-9463-1000	940.80

Unshielded, Instrumentation 300V Power-Limited Tray Cables

• Flame Retardant PVC Insulation and PVC Jacket • Chrome Jacket Color

Belden Part No.	Fig.	Number of Pairs	Nominal O.D. (in.)	AWG (Stranded)	500 ft. Unreel Boxes	
					MOUSER STOCK NO.	Price Per 500' Box
9407	F	1	.198	22 (7 x 30)	566-9407-500U	201.45
9410	F	1	.254	16 (19 x 29)	566-9410-500U	495.78

Wire & Cable Belden