


BELDEN Audio, Security, Alarm and Camera Cables



RoHS Compliant This product is RoHS compliant.

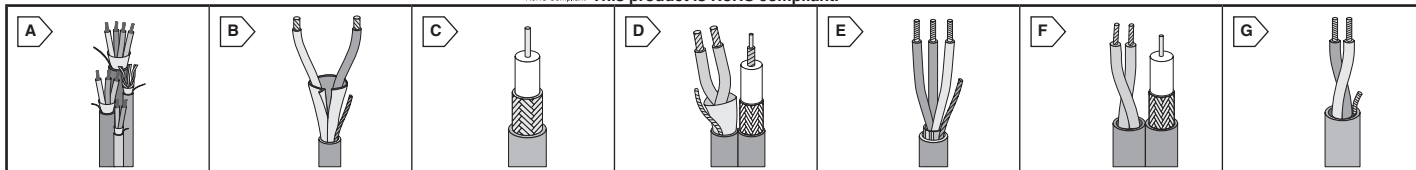

BELDEN® NEW GENERATION® WATERDOG CABLES

• Water and Moisture Resistant • UL Listed for a Range of Indoor/Outdoor and Direct Burial Installations

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal OD (in.)	500 ft. Spools		1000 ft. Spools	
					MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
Stranded Tinned Copper, PVC Jacketed, Unshielded								
5300U1	A	2	18 (7 x 26)	.207	-----	-	566-5300U1-1000-08	262.85
Stranded Tinned Copper, PVC Jacketed, Shielded								
5500F1	B	2	22 (7 x 30)	.192	-----	-	566-5500F1-1000-08	148.65
5400F1	B	2	20 (7 x 28)	.206	-----	-	566-5400F1-1000-08	272.49
5300F1	B	2	18 (7 x 26)	.222	-----	-	566-5300F1-1000-08	351.46
Stranded Tinned Copper, PVC Jacketed, Unshielded								
5302U1	A	4	18 (7 x 26)	.254	-----	-	566-5302U1-1000-10	464.51
5202U1	A	4	16 (7 x 24)	.291	-----	-	566-5202U1-1000-10	596.43
5102U1	A	4	14 (19 x 27)	.341	-----	-	566-5102U1-1000-10	1212.32
Stranded Tinned Copper, PVC Jacketed, Shielded								
5302F1	B	4	18 (7 x 26)	.255	-----	-	566-5302F1-1000-10	539.68
5202F1	B	4	16 (7 x 24)	.295	-----	-	566-5202F1-1000-10	697.90
Bare Copper Coax, PVC Jacket, Aluminum Braid Plus 100% Foil Shield (CATV)								
5339W5	C	-	18 (solid)	.270	-----	-	566-5339W5-1000-10	211.26
Bare Copper Coax, PVC Jacket, Bare Cooper Braid Shield (CCTV)								
5439X5	C	-	20 (solid)	.244	-----	-	566-5439X5-1000-10	386.58
5339X5	C	-	18 (solid)	.277	-----	-	566-5339X5-1000-10	468.41
Bare Copper Coax, PVC Jacket, Tinned Copper Braid Shield Plus 100% Foil Shield (CCTV/MATV)								
5439W5	C	-	20 (solid)	.236	566-5439W5-500-10	177.72	566-5439W5-1000-10	351.32
COAX: Solid Bare Copper, PAIR: Stranded Bare Copper, PVC Jacket (CCTV + Power)								
5399X5	D	-	18(cx) Solid 16(pr) 7/w	.279 x .549	-----	-	566-5399X5-1000-10	852.57
5499X5	D	-	20(cx) Solid 18(pr) 7/w	.249 x .497	-----	-	566-5499X5-1000-10	655.92

BELDFOIL® SHIELD AUDIO, SECURITY, AND ALARM CABLE

• Bare Copper Conductors • Cabled Beldfoil® Shield Tape • Sequential footage marking every two feet • PVC Insulation (Aluminum side out) with drain wire • Gray PVC Jacket * Available in box only

5000FE	B	2	12 (19 x 25)	0.272	566-5000FE-500-08	379.60	566-5000FE-1000-08	822.78
5200FE	B	2	16 (19 x 29)	0.188	566-5200FE-500-08	154.75	566-5200FE-1000-08	297.59
5300FE	B	2	18 (7 x 26)	0.165	566-5300FE-500-08	110.00	566-5300FE-1000-08	198.53
5301FE	B	3	18 (7 x 26)	0.175	566-5301FE-500-08	149.44	566-5301FE-1000-08	315.16
5302FE	B	4	18 (7 x 26)	0.192	566-5302FE-500-08	203.11	566-5302FE-1000-08	401.20
5304FE	B	6	18 (7 x 26)	0.23	-----	-	566-5304FE-1000-08	537.75
5400FE	B	2	20 (7 x 28)	0.145	-----	-	566-5400FE-1000-08	169.68
5500FE	B	2	22 (7 x 30)	0.150	566-5500FE-500-08	60.25	566-5500FE-1000-08	124.12
5502FE	B	4	22 (7 x 30)	0.152	566-5502FE-500-08	102.84	566-5502FE-1000-08	195.17
5504FE	B	6	22 (7 x 30)	0.179	-----	-	* 566-5504FE-U1000-08	285.97

UNSHIELDED AUDIO, SECURITY, AND ALARM CABLE

• Bare Copper Conductors • PVC Insulation with rip cord • Sequential footage marking every two feet • Gray PVC Jacket * Available in box only

5100UE	E	2	14 (19 x 26)	.234	566-5100UE-500-08	213.80	566-5100UE-1000-08	423.39
5200UE	E	2	16 (19 x 29)	.184	566-5200UE-500-08	134.52	566-5200UE-1000-08	260.72
5202UE	E	4	16 (19 x 29)	.216	566-5202UE-500-08	248.23	566-5202UE-1000-08	485.45
5300UE	E	2	18 (7 x 26)	.161	566-5300UE-500-08	87.83	566-5300UE-1000-08	180.51
5302UE	E	4	18 (7 x 26)	.188	-----	-	566-5302UE-1000-08	304.68
5500UE	E	2	22 (7 x 30)	.128	-----	-	566-5500UE-1000-08	103.38
5502UE	E	4	22 (7 x 30)	.148	* 566-5502UE-U500-08	87.93	* 566-5502UE-U1000-08	151.13
5504UE	E	6	22 (7 x 30)	.177	566-5504UE-500-08	119.60	566-5504UE-1000-08	235.33

• Bare Copper Conductors • Flammarrest® Insulation • Conductors Cabled • Natural Flammarrest® Jacket with rip cord • Sequential footage marking every two feet • Plenum-Rated

6200UE	E	2	16 (19 x 29)	.180	566-6200UE-500	145.97	-----	-
6300UE	E	2	18 (7 x 26)	.157	566-6300UE-500	98.51	566-6300UE-1000	178.38
6301UE	E	3	18 (7 x 26)	.168	566-6301UE-500	151.29	566-6301UE-1000	282.47
6302UE	E	4	18 (7 x 26)	.186	566-6302UE-500	190.50	566-6302UE-1000	373.38
6502UE	E	4	22 (7 x 30)	.143	566-6502UE-500	94.23	566-6502UE-1000	175.81

CAMERA CABLES (FOR CCTV APPLICATIONS)

Banana Peel Jacketless Cables • Bare Copper Shielded • No Overall Jacket • PVC Insulation • PVC Jacket

Fig.	Component Description	AWG (Stranded)	Flame-Retardant				Flammarrest®					
			Belden Part No.	500 ft. Spool		1000 ft. Spool		Belden Part No.	500 ft. Spool		1000 ft. Spool	
				MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool		MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
F	4-Conductors 3-Pair 2-Conductors 4-Conductors	18 (7 x 26) 22 (7 x 30) 22 (7 x 30) 22 (7 x 30)	558AFS	566-558AFS-500	615.90	566-558AFS-1000	1241.46	658AFS	566-658AFS-500	722.10	566-658AFS-1000	1819.53

Camera Cables

Belden Part No.	Fig.	Component Description	AWG (Stranded)	Shielding	500 ft. Spools		1000 ft. Spools	
					MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
Composite Camera Cable								
9265	D	75 Ohm Coax RG-59/U Foil Shielded Twisted Pair	22 (7 x 30) 22 (7 x 30)	95% Bare Copper Braid Beldfoil®	566-9265-500	750.83	566-9265-1000	1496.90
549945	F	75 Ohm Coax RG-59/U 1 Twisted Pair	20 (Solid) 18 (7 x 26)	95% Bare Copper Braid Unshielded	566-549945-500	187.34	566-549945-1000	353.29
539945	F	75 Ohm Coax RG-6/U 1 Twisted Pair	18 (Solid) 18 (7)	95% Bare Copper Braid Unshielded	566-539945-500-10	267.84	566-539945-1000-10	445.40
75 Ohm Coaxial Camera Cable								
543945	G	RG-59/U	20 (Solid)	95% Bare Copper Braid	566-543945-500-10	120.24	566-543945-1000-10	253.23
533945	G	RG-6/U	18 (Solid)	95% Bare Copper Braid	566-533945-500	186.88	566-533945-1000	332.75
513945	G	RG-11/U	14 (Solid)	95% Bare Copper Braid	-----	-	566-513945-1000-10	684.72