

BELDEN Multi-Conductor Cables




This product is RoHS compliant.

UNSHIELDED AUDIO, CONTROL, AND INSTRUMENTATION CABLE

- Tinned copper stranded, PVC insulated, conductor cabled. Chrome PVC jacket
- Non-Plenum

Recommend Heat Shrink
FT221

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal O.D. (in.)	100 ft. Spools		500 ft. Spools		1000 ft. Spools	
					MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
UL AWM Style 2464, (300V 80°C)										
9439	A	7	20 (7 x 28)	.260	566-9439-100	144.21	566-9439-500	655.06	-	-
9444	A	4	20 (7 x 28)	.217	566-9444-100	76.67	566-9444-500	325.09	566-9444-1000	747.50
9445	A	5	20 (7 x 28)	.239	566-9445-100	103.76	566-9445-500	410.41	-	-
9455	A	9	20 (7 x 28)	.317	566-9455-100	185.58	-	-	-	-
UL AWM Style 2598, (300V 60°C)										
8489	A	4	18 (19 x 30)	.257	566-8489-100	110.70	566-8489-500	374.63	-	-
8465	A	5	18 (19 x 30)	.282	566-8465-100	119.59	566-8465-500	503.07	-	-
8467	A	7	18 (19 x 30)	.314	566-8467-100	193.98	-	-	-	-
8466	A	12	18 (19 x 30)	.412	566-8466-100	297.27	-	-	-	-
8468	A	15	18 (19 x 30)	.500	566-8468-100	374.70	-	-	-	-
8619	A	19	18 (19 x 30)	.490	566-8619-100	587.80	-	-	-	-
600V RMS 80°C										
8620	A	4	16 (19 x 29)	.376	566-8620-100	212.86	-	-	-	-
8621	A	7	16 (19 x 29)	.458	566-8621-100	356.33	-	-	-	-
9721	A	8	16 (19 x 29)	.496	566-9721-100	427.02	-	-	-	-
UL AVM Style 2576, (150V 80°C)										
8443	B	3	22 (7 x 30)	.172	-	-	566-8443-500	192.81	566-8443-1000	407.69
8444	B	4	22 (7 x 30)	.185	-	-	566-8444-500	230.23	566-8444-1000	455.85
8445	B	5	22 (7 x 30)	.194	566-8445-100	90.50	-	-	-	-
9430	B	7	22 (7 x 30)	.214	-	-	566-9430-500	374.52	-	-
9421	B	8	22 (7 x 30)	.229	566-9421-100	110.28	-	-	566-9421-1000	1003.42
9423	B	9	22 (7 x 30)	.244	566-9423-100	122.42	566-9423-500	484.60	-	-
8456	B	10	22 (7 x 30)	.264	566-8456-100	139.79	-	-	-	-
8457	B	12	22 (7 x 30)	.272	566-8457-100	151.43	-	-	-	-
9431	B	20	22 (7 x 30)	.345	566-9431-100	312.17	-	-	-	-
8459	B	25	22 (7 x 30)	.387	566-8459-100	391.91	-	-	-	-
9432	B	30	22 (7 x 30)	.400	566-9432-100	483.68	-	-	-	-
9433	B	40	22 (7 x 30)	.455	566-9433-100	829.49	-	-	-	-

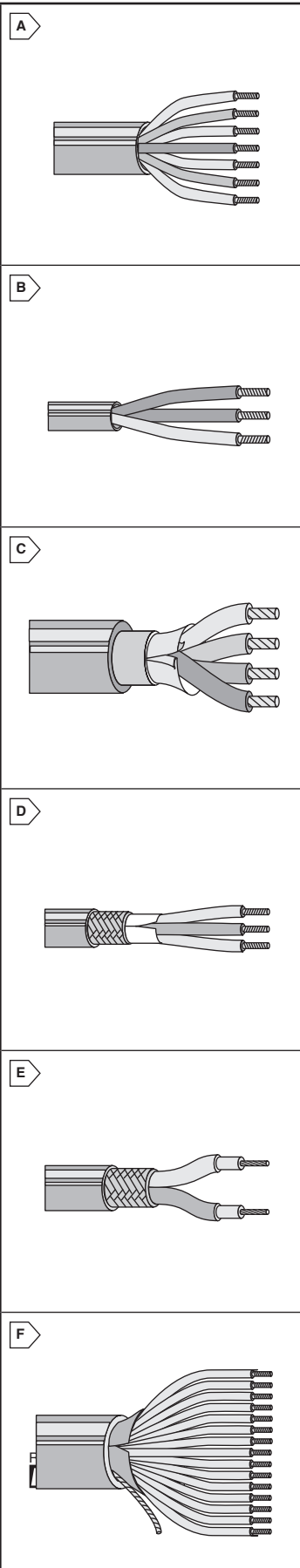

Wire & Cable
Belden

OVERALL FOIL / BRAID SHIELD COMPUTER CABLES

- Computer Cables for EIA RS-232 Applications
- Chrome PVC Jacket
- Tinned Copper Stranded
- UL AWM Style 2464 (300V 80°C)
- Semi-Rigid PVC Insulation

AlphaWire
Recommend Heat Shrink
FT221

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal O.D. (in.)	100 ft. Spool		500 ft. Spool		1000 ft. Spool	
					MOUSER STOCK NO.	Price Per Spool	MOUSER STOCK NO.	Price Per Spool	MOUSER STOCK NO.	Price Per Spool
9939	C	3	22 (7 x 30)	.202	566-9939-100	94.29	566-9939-500	372.50	-	-
9940	C	4	22 (7 x 30)	.215	566-9940-100	113.97	566-9940-500	429.62	-	-
9941	C	5	22 (7 x 30)	.23	566-9941-100	127.53	-	-	-	-
9942	C	6	22 (7 x 30)	.245	566-9942-100	152.42	566-9942-500	602.34	566-9942-1000	1385.07
9943	C	7	22 (7 x 30)	.245	566-9943-100	200.22	-	-	-	-
9944	C	8	22 (7 x 30)	.260	566-9944-100	182.46	566-9944-500	772.59	-	-
9945	C	9	22 (7 x 30)	.280	566-9945-100	239.67	-	-	-	-
9946	C	10	22 (7 x 30)	.300	566-9946-100	251.14	566-9946-500	983.07	-	-
9947	C	15	22 (7 x 30)	.34	566-9947-100	368.24	566-9947-500	1284.24	-	-
9949	C	37	22 (7 x 30)	.460	566-9949-100	991.88	-	-	-	-
9608	C	3	24 (7 x 32)	.190	566-9608-100	102.21	-	-	-	-
9609	C	4	24 (7 x 32)	.200	566-9609-100	133.91	-	-	-	-
9610	C	5	24 (7 x 32)	.215	566-9610-100	139.71	566-9610-500	587.59	-	-
9611	C	6	24 (7 x 32)	.225	566-9611-100	170.67	-	-	-	-
9612	C	7	24 (7 x 32)	.225	566-9612-100	197.95	-	-	-	-
9613	C	8	24 (7 x 32)	.240	566-9613-100	224.62	-	-	-	-
9614	C	9	24 (7 x 32)	.253	566-9614-100	279.02	-	-	566-9614-1000	2698.59
9615	C	10	24 (7 x 32)	.27	566-9615-100	348.52	-	-	-	-
9616	C	15	24 (7 x 32)	.3003	566-9616-100	464.91	-	-	-	-

- UL AWM Style 2919 (30V 80°C)
- Datallene® Insulation
- Chrome PVC Jacket
- Low-Capacitance Computer Cable for EIA RS-232 and EIA RS-423 Applications

9925	C	3	24 (7 x 32)	.215	566-9925-100	85.50	-	-	566-9925-1000	844.68
------	---	---	-------------	------	--------------	-------	---	---	---------------	--------

OVERALL BRAID AUDIO, CONTROL, AND INSTRUMENTATION CABLE

- 200V RMS 105°C
- Chrome PVC Jacket
- Polypropylene Insulation
- 95% Tinned Copper Braid Shield

Recommend Heat Shrink
FT221

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal O.D. (in.)	100 ft. Spool		250 ft. Spool		
					MOUSER STOCK NO.	Price Per Spool	MOUSER STOCK NO.	Price Per Spool	
8643	D	3	30 (7 x 38)	.096	-	-	566-8643-250	411.36	393.78

OVERALL BRAID COMMUNICATION AND INSTRUMENTATION SHIELD CABLE

- 600V RMS 105°C
- 90% Tinned Copper Braid Shield
- MIL-W-16878 (Type) Conductors, Shielded, and Jacketed
- PVC Insulation and White PVC Jacket

Recommend Heat Shrink
FT221

9962	E	2	20 (19 x 32)	.192	566-9962-100	180.60	-	-	-	-
------	---	---	--------------	------	--------------	--------	---	---	---	---

OVERALL 100% BELDFOIL® SHIELD

- Computer Cables for EIA RS-232 Applications
- UL AVM Style 2464, (300V 80°C)
- Chrome PVC Jacket
- Semi-Rigid PVC Insulation

AlphaWire
Recommend Heat Shrink
FT221

Belden Part No.	Fig.	Number of Conductors	AWG (Stranded)	Nominal O.D. (in.)	100 ft. Spools		500 ft. Spools		1000 ft. Spools			
					MOUSER STOCK NO.	Price Per Spool	MOUSER STOCK NO.	Price Per Spool	MOUSER STOCK NO.	Price Per Spool		
9533	F	3	24 (7 x 32)	.162	566-9533-100	48.39	566-9533-500	203.44	194.72	566-9533-1000	470.00	454.33
9535	F	5	24 (7 x 32)	.189	566-9535-100	78.88	566-9535-500	333.96	323.52	566-9535-1000	637.08	608.98
9536	F	6	24 (7 x 32)	.209	566-9536-100	91.13	566-9536-500	333.44	319.15	566-9536-1000	666.87	638.29
9537	F	7	24 (7 x 32)	.209	566-9537-100	110.15	-	-	-	-	-	-
9538	F	8	24 (7 x 32)	.224	566-9538-100	121.48	566-9538-500	411.27	393.65	-	-	-
9540	F	10	24 (7 x 32)	.244	566-9540-100	127.06	566-9540-500	510.17	486.62	-	-	-
9541	F	15	24 (7 x 32)	.284	566-9541-100	177.07	566-9541-500	668.47	648.51	-	-	-
9543	F	25	24 (7 x 32)	.339	566-9543-100	345.89	-	-	-	-	-	-
9544	F	30	24 (7 x 32)	.380	566-9544-100	586.65	-	-	-	-	-	-