


# BELDEN LAN and Computer Cables

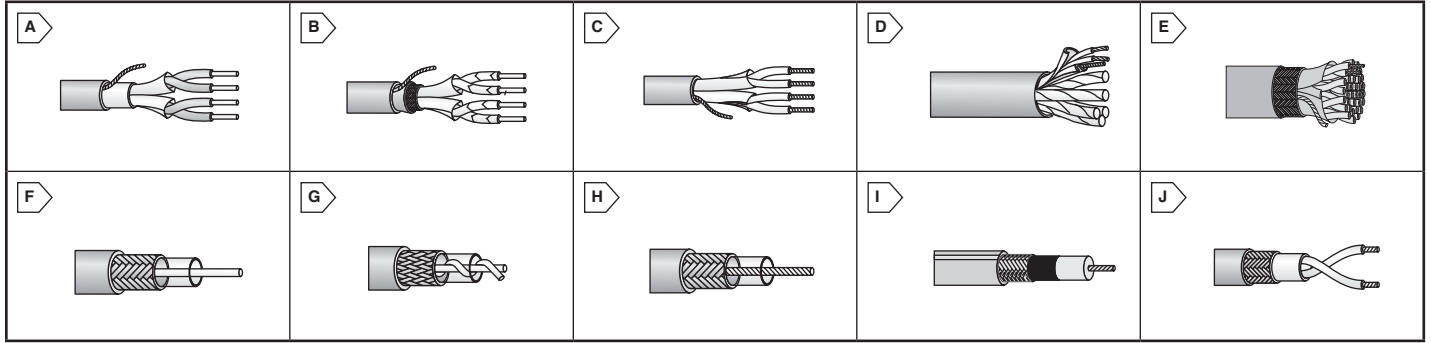

RoHS Compliant This page of product is compliant.



## BELDEN IBM TYPE CABLES

IBM Type 1A, IEEE 802.5 • Strand: Solid



Belden Part No.	Fig.	Cable Type	IBM Part No.	NEC Type	AWG	No. of Pairs	Nominal OD (in.)	Nom. Imp. Ω	% Type Shield	500 ft. Spools		1000 ft. Spools	
										MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
9688	A	Non-Plenum	4716748	MPG/CMG	22	2	.296 x .431	150	100/Foil, 65 Braid	566-9688-500	342.76	566-9688-1000	685.57
82688	B	Plenum	4716749	CMP	22	2	.248 x .348	150	100/Foil, 65 Braid	-----	-	566-82688-1000	2223.84

## BELDEN COMPUTER CABLES, PAIRED, AND INDIVIDUALLY SHIELDED



Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG (Stranded)	Nom. OD (in.)	Nom. Imp. Ω	% Type Shield	100 ft. Spools		500 ft. Spools		1000 ft. Spools	
								MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
8777	D	CM	3	22 (7 x 30)	.273	50	100 Foil	566-8777-100	124.57	566-8777-500	484.78	566-8777-1000	1204.63
8778	D	CM	6	22 (7 x 30)	.362	50	100 Foil	566-8778-100	259.36	566-8778-500	1041.94	566-8778-1000	2395.94
9773	D	CM	3	18 (19 x 30)	.404	50	100 Foil	566-9773-100	217.70	-----	-	566-9773-1000	1958.48

## BELDEN LAN TRUNK CABLE

### BELDEN NEW GENERATION® STP PLENUM-RATED CABLES

Low capacitance, plenum-rated 2- and 3-pair STP cables have individually foil-shielded pairs, a particularly small OD and they are made with Low Smoke Flammarest® PVC insulations and jackets.



Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG (Stranded)	Nominal OD (in.)	Nominal Imp. Ω	% Type Shield	100 ft. Spools		500 ft. Spools	
								MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
1325A	C	CMP	2	22 (7 x 30)	.158	15	100	566-1325A-500-09	274.67	566-1325A-1000-09	496.93
1326A	C	CMP	3	22 (7 x 30)	.190	8.6	100	566-1326A-500-09	602.90	566-1326A-1000-09	1205.84

## BELDEN LOW-CAPACITANCE COMPUTER CABLES

For EIA RS-232 and EIA RS-485 Applications



Belden Part No.	Fig.	NEC Type	No. of Pairs	AWG (Stranded)	Nominal OD (in.)	Nominal Imp. Ω	% Type Shield	100 ft. Spools		500 ft. Spools	
								MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool
8132FO	E	CL2	2	28 (7 x 36)	.215	23.1	100	566-8132FO-500	440.49	566-8132FO-1000	1012.87
8134FO	E	CL2	4	28 (7 x 36)	.270	20	100	566-8134FO-500	670.36	566-8134FO-1000	1417.15
8135FO	E	CL2	5	28 (7 x 36)	.280	20	100	566-8135FO-500	747.81	566-8135FO-1000	1580.91
8138FO	E	CL2	8	28 (7 x 36)	.310	17.7	100	-----	-	566-8138FO-1000	2072.16

## BELDEN COMPUTER CABLES

\* Available in box only



Belden Part No.	Fig.	Description	AWG (Stranded)	Nom. OD (in.)	Nom. Imp. Ω	% Type Shield	100 ft. Spools		500 ft. Spools		1000 ft. Spools	
							MOUSER STOCK NO.	Price Per 100' Spool	MOUSER STOCK NO.	Price Per 500' Spool	MOUSER STOCK NO.	Price Per 1000' Spool
8240	F	51.5Ω Transmission Cable, RG58 /U	20 (Solid)	.193	51.5	95	566-8240-100	75.09	566-8240-500	242.42	566-8240-1000	518.28
9201	F	51.5Ω Transmission Cable, RG58 /U	20 (Solid)	.193	51.5	78	-----	-	566-9201-500-10	216.31	566-9201-1000-10	511.43
82240	F	RG 58/U Type, Plenum	20 (Solid)	.159	53.5	95	-----	-	* 566-82240-U500	984.95	566-82240-1000	1969.95
9269	G	RG 62A/U Type	22 (Solid)	.239	93	95	-----	-	566-9269-500	318.80	566-9269-1000	733.04
82269	G	RG 62/U Type, Plenum	22 (Solid)	.200	93	94	-----	-	-----	-	566-82269-1000	1763.74
8216	H	RG 174/U Type	26 (7 x 34)	.110	50	90	566-8216-100	65.00	566-8216-500	257.98	566-8216-1000	448.55
8219	H	RG 58A/U	20 (19 x 32)	.194	53.5	93	-----	-	566-8219-500	330.59	566-8219-1000	683.72
9311	I	RG 58A/U	20 (19 x 32)	.193	50	55	-----	-	566-9311-500-10	484.36	566-9311-1000-10	1101.34
9207	J	Twinaxial, Foil / Braid Shield	20 (7 x 28)	.330	100	86	566-9207-100	157.32	566-9207-500	728.31	566-9207-1000	1456.64