

# TE I/O Cable Assemblies



RoHS Compliant This product is RoHS compliant.



## USB 2.0 CABLE ASSEMBLIES

### Features:

- High density design
- Supports "Plug and Play" peripheral connectivity
- 480MB/s transfer rate

 
### Specifications:

- Applied Voltage Rating: 30VAC
- Mating Force: 1oz.
- Durability: 1500 Cycles
- 28AWG


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Description	Color	Length (M)	Price Each			
						1	5	10	25
571-1487594-3	1487594-3	A	A-B, 28/28	Black	.16	2.82	2.56	2.30	2.18
571-1487586-3	1487586-3	A	A-B, 28/28	White	.16	2.94	2.68	2.45	2.29
571-1487594-2	1487594-2	A	A-B, 28/28	Black	.25	4.72	4.29	3.93	3.63
571-1487586-2	1487586-2	A	A-B, 28/28	White	.25	2.70	2.46	2.22	2.09
571-1487594-4	1487594-4	A	A-B, 28/28	Black	.31	4.00	3.90	3.59	3.25
571-1487586-4	1487586-4	A	A-B, 28/28	White	.31	3.31	2.98	2.71	2.56
571-1487594-1	1487594-1	A	A-B, 28/28	Black	.5	3.46	3.16	2.92	2.71
571-1487586-1	1487586-1	A	A-B, 28/28	White	.5	4.86	4.42	4.05	3.73
571-1487595-3	1487595-3	A	A-B, 28/26	Black	.83	4.30	3.90	3.58	3.30
571-1487587-3	1487587-3	A	A-B, 28/26	White	.83	2.91	2.63	2.40	2.28
571-1487595-1	1487595-1	A	A-B, 28/26	Black	1	5.19	4.72	4.18	3.87
571-1487587-1	1487587-1	A	A-B, 28/26	White	1	4.30	3.90	3.76	3.53
571-1487595-2	1487595-2	A	A-B, 28/26	Black	1.3	4.42	4.02	3.62	3.42
571-1487596-2	1487596-2	A	A-B, 28/24	Black	1.5	5.72	5.34	4.99	4.72
571-1487596-3	1487596-3	A	A-B, 28/24	Black	1.8	5.50	5.10	4.68	4.39
571-1487588-3	1487588-3	A	A-B, 28/24	White	1.8	3.68	3.36	3.19	3.09
571-1487596-1	1487596-1	A	A-B, 28/24	Black	2	4.73	4.45	4.17	3.94
571-1487588-1	1487588-1	A	A-B, 28/24	White	2	6.50	6.09	5.82	5.42
571-1487597-2	1487597-2	A	A-B, 25/22	Black	2.5	7.14	6.54	6.03	5.71
571-1487589-2	1487589-2	A	A-B, 25/22	White	2.5	8.36	7.66	7.07	6.57
571-1487597-1	1487597-1	A	A-B, 25/22	Black	3	8.91	8.10	7.29	6.88
571-1487589-1	1487589-1	A	A-B, 25/22	White	3	6.95	6.36	5.88	5.45
571-1487598-1	1487598-1	A	A-B, 25/20	Black	4	11.20	10.08	9.52	8.96
571-1487590-1	1487590-1	A	A-B, 25/20	White	4	11.20	10.08	9.52	8.96
571-1487598-2	1487598-2	A	A-B, 25/20	Black	5	16.24	14.76	13.28	12.55
571-1487590-2	1487590-2	A	A-B, 25/20	White	5	14.56	13.10	12.38	12.01
571-1487599-1	1487599-1	B	A-BLUNT, 28/28	Black	.83	3.09	2.99	2.79	2.69
571-1487591-1	1487591-1	B	A-BLUNT, 28/28	White	.83	2.68	2.44	2.20	2.07
571-1487600-1	1487600-1	B	A-BLUNT, 28/26	Black	1	4.59	4.15	3.76	3.48
571-1487592-1	1487592-1	B	A-BLUNT, 28/26	White	1	2.96	2.69	2.46	2.27
571-1487601-2	1487601-2	B	A-BLUNT, 28/24	Black	1.5	4.31	3.92	3.53	3.23
571-1487593-2	1487593-2	B	A-BLUNT, 28/24	White	1.5	3.65	3.32	2.98	2.82
571-1487601-1	1487601-1	B	A-BLUNT, 28/24	Black	2	5.43	4.94	4.71	4.44
571-1487593-1	1487593-1	B	A-BLUNT, 28/24	White	2	5.86	5.32	4.88	4.55


A




B

 


C

 


D

 

E

 

F

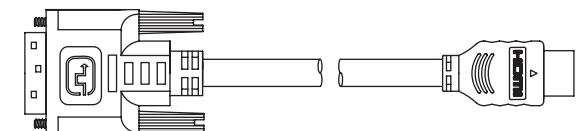

Cable Assemblies

TE Connectivity

## DVI CABLE ASSEMBLIES

### Features:

- Designed to meet the Digital Display Working Group, Digital Visual Interface (DVI) specification
- Bridges the transition from analog to digital video display designs
- Supports digital and/or analog video functions

### Specifications:

- Applied Voltage Rating: 40VAC
- Mating Force: 10.0lbs. Max.
- Durability: 100 Cycles

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Description	Length (M)	Price Each			
					1	5	10	25
571-1653927-3	1653927-3	C	DVI-D to DVI-D Single Link	3	25.32	23.94	22.84	21.50
571-1653928-1	1653928-1	C	DVI-D to DVI-D Dual Link	1	18.64	16.77	15.84	14.91
571-1653928-3	1653928-3	C	DVI-D to DVI-D Dual Link	3	29.47	27.26	25.05	23.58
571-1653929-1	1653929-1	C	DVI-I to DVI-I	1	22.56	20.87	19.17	18.05
571-1653929-2	1653929-2	C	DVI-I to DVI-I	2	25.63	22.19	20.90	19.12
571-1653932-1	1653932-1	D	DVI-A to 15 POSN VGA	1	12.98	12.01	11.03	10.38
571-1653932-2	1653932-2	D	DVI-A to 15 POSN VGA	2	20.10	18.59	17.08	16.09
571-1653932-3	1653932-3	D	DVI-A to 15 POSN VGA	3	17.47	16.16	14.84	13.97

## HDMI CABLE ASSEMBLIES

### Features:

- Simple User Friendly Connector
- Replaces existing audio and digital cabling in one assembly
- Full shielding for ESD protection and lead-free process capable

### Specifications:

- Applied Voltage Rating: 40VAC
- Mating Force: 9.9lbs. Max.
- Durability: 10,000 Cycles

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Description	Length (M)	Price Each			
					1	5	10	25
571-1770019-5	1770019-5	E	HDMI to HDMI	.75	21.48	18.98	17.41	16.62
571-1770019-6	1770019-6	E	HDMI to HDMI	1.0	23.41	21.17	19.05	17.36
571-1770019-1	1770019-1	E	HDMI to HDMI	2.0	17.28	16.07	14.98	13.44
571-1770019-2	1770019-2	E	HDMI to HDMI	3.0	26.18	23.56	22.26	20.94
571-1770020-3	1770020-3	F	HDMI to DVI	.25	19.93	19.31	18.53	17.82
571-1770020-1	1770020-1	F	HDMI to DVI	2.0	29.83	27.97	25.18	23.19
571-1770020-2	1770020-2	F	HDMI to DVI	3.0	29.35	27.47	26.03	22.82