


AIM-CAMBRIDGE BNC & Network Cable Assemblies

AIM-Cambridge
Connectivity Solutions
EMERSON
Network Power

BNC THIN ETHERNET COAXIAL CABLES

Features:

- Body Plating: Nickel
- Center Contact Plating: Gold
- Impedance: 50ohm
- Cable Color: Black PVC
- AWG: 20 stranded

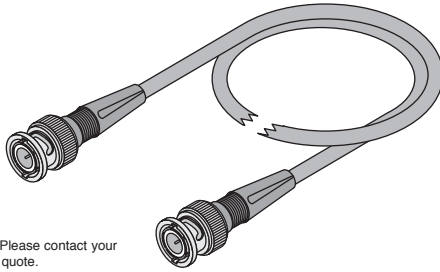


Custom assemblies are available. Please contact your Mouser Sales Representative for a quote.

This product is RoHS compliant.

USB CABLE ASSEMBLIES

Features:

- USB version 2.0
- Color: Beige
- Contacts: Gold plated
- AWG: 20-28 for power; 28 for signal

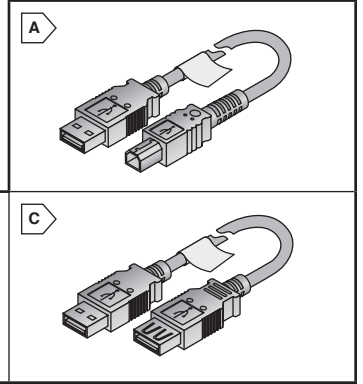

MOUSER STOCK NO.	AIM-Cambridge Part No.	Boot Color	Length: ft (m)	Price Each			
				1	10	25	100
BNC plug to BNC plug, RG-58AU							
601-736300-3	73-6300-3	Black	3 (.914)	12.48	10.95	9.49	8.00
601-736351-3	73-6351-3	Blue	3 (.914)	12.62	11.08	10.21	8.87
601-736353-3	73-6353-3	Red	3 (.914)	10.46	9.51	8.72	8.05
601-736354-3	73-6354-3	Yellow	3 (.914)	9.66	8.78	8.05	7.43
601-736351-6	73-6351-6	Blue	6 (1.829)	16.36	14.72	14.09	12.46
601-736352-6	73-6352-6	Green	6 (1.829)	16.36	14.72	14.09	12.46
601-736300-10	73-6300-10	Black	10 (3.05)	14.87	13.72	12.74	11.89
601-736352-10	73-6352-10	Green	10 (3.05)	11.69	9.70	9.03	8.46
601-736353-10	73-6353-10	Red	10 (3.05)	18.40	16.70	15.03	13.46
601-736300-25	73-6300-25	Black	25 (7.62)	32.31	28.25	26.61	24.21
601-736351-25	73-6351-25	Blue	25 (7.62)	19.95	14.30	13.20	12.26
601-736352-25	73-6352-25	Green	25 (7.62)	19.95	14.30	13.20	12.26
601-736353-25	73-6353-25	Red	25 (7.62)	36.40	33.09	28.00	26.00
601-736354-25	73-6354-25	Yellow	25 (7.62)	36.40	33.09	28.00	26.00
BNC plug to BNC plug, RG-58 Thin							
601-736340-3	73-6340-3	Black	3 (.914)	10.06	9.15	8.38	7.74
601-736361-3	73-6361-3	Blue	3 (.914)	10.54	9.25	8.77	7.36
601-736362-3	73-6362-3	Green	3 (.914)	12.54	10.25	8.77	6.53
601-736364-3	73-6364-3	Yellow	3 (.914)	12.54	10.25	8.77	6.53
601-736340-6	73-6340-6	Black	6 (1.829)	10.13	7.40	6.83	6.34
601-736361-6	73-6361-6	Blue	6 (1.829)	12.13	9.55	8.97	7.95
601-736362-6	73-6362-6	Green	6 (1.829)	11.66	10.60	9.72	8.97
601-736363-6	73-6363-6	Red	6 (1.829)	12.13	10.53	8.95	8.46
601-736364-6	73-6364-6	Yellow	6 (1.829)	12.13	10.53	9.95	8.46
601-736340-10	73-6340-10	Black	10 (3.05)	13.70	12.45	11.42	9.79
601-736361-10	73-6361-10	Blue	10 (3.05)	13.71	11.23	10.52	9.91
601-736362-10	73-6362-10	Green	10 (3.05)	12.71	9.23	8.52	7.91
601-736363-10	73-6363-10	Red	10 (3.05)	12.71	9.23	8.52	7.91
601-736364-10	73-6364-10	Yellow	10 (3.05)	14.71	12.23	10.52	9.94
601-736340-25	73-6340-25	Black	25 (7.62)	35.13	33.53	31.34	26.82
601-736361-25	73-6361-25	Blue	25 (7.62)	31.13	25.67	24.46	23.43
601-736363-25	73-6363-25	Red	25 (7.62)	21.13	15.67	14.46	13.43
601-736364-25	73-6364-25	Yellow	25 (7.62)	37.58	34.16	31.32	26.84

Cable Assemblies

AIM-Cambridge

BNC AUDIO/VIDEO COAXIAL CABLES

Features:

- Body Plating: Nickel
- Center Contact Plating: Gold
- AWG: 22 stranded
- Matching color boot and cable
- Impedance: 75ohm

Custom assemblies are available. Please contact your Mouser Sales Representative for a quote.

BNC Plug to BNC Plug, RG-59

MOUSER STOCK NO.	AIM-Cambridge Part No.	Boot Color	Length: ft (m)	Price Each			
				1	10	25	100
601-736310-3	73-6310-3	Black	3 (.914)	10.77	8.08	7.46	6.92
601-736311-3	73-6311-3	Blue	3 (.914)	9.16	8.42	7.80	7.28
601-736312-3	73-6312-3	Green	3 (.914)	7.00	6.25	5.85	5.50
601-736313-3	73-6313-3	Red	3 (.914)	8.56	6.42	6.35	5.93
601-736314-3	73-6314-3	Yellow	3 (.914)	10.15	7.62	7.02	6.77
601-736310-6	73-6310-6	Black	6 (1.829)	13.47	10.42	9.68	9.15
601-736311-6	73-6311-6	Blue	6 (1.829)	15.00	13.64	12.50	11.54
601-736312-6	73-6312-6	Green	6 (1.829)	11.20	9.93	9.10	8.40
601-736313-6	73-6313-6	Red	6 (1.829)	10.85	9.27	8.50	7.92
601-736310-10	73-6310-10	Black	10 (3.05)	16.70	15.18	13.92	12.85
601-736311-10	73-6311-10	Blue	10 (3.05)	19.50	14.88	13.81	12.89
601-736312-10	73-6312-10	Green	10 (3.05)	18.22	17.92	16.38	15.93
601-736314-10	73-6314-10	Yellow	10 (3.05)	19.92	16.60	15.32	13.28
601-736310-25	73-6310-25	Black	25 (7.62)	33.90	30.50	28.25	26.21
601-736312-25	73-6312-25	Green	25 (7.62)	36.62	32.47	31.51	30.68


MOUSER STOCK NO.	AIM-Cambridge Part No.	Fig.	Length: ft (m)	Price Each			
				1	10	25	100
USB Type A Male to USB Type B Male							
601-30-3007-3	30-3007-3	A	3 (.914)	3.07	1.70	1.57	1.46
601-30-3007-6	30-3007-6	A	6 (1.829)	3.30	2.10	1.94	1.87
601-30-3007-10	30-3007-10	A	10 (3.05)	4.75	3.19	2.95	2.74
601-30-3007-15	30-3007-15	A	15 (4.572)	7.16	4.42	4.07	3.78
USB Type A Male to USB Type A Male							
601-30-3006-6	30-3006-6	B	6 (1.829)	3.86	2.29	2.12	1.98
601-30-3006-10	30-3006-10	B	10 (3.05)	4.66	2.75	2.54	2.36
USB Type A Male to USB Type A Female Extension							
601-30-3008-6	30-3008-6	C	6 (1.829)	4.21	2.18	2.02	1.87

MOLDED AND BOOTED LAN PATCH CABLES - CAT 5E AND CAT 6

Features:

- 24AWG Round UTP stranded
- Unshielded twisted pair cable
- Cat 5E-350MHz; Cat6-500MHz
- Tested to meet and exceed ANSI/TIA-568-B.2-1
- Cat 6 industry standards
- Flexible low-profile snagless strain relief

Custom assemblies are available. Please contact your Mouser Sales Representative for a quote.

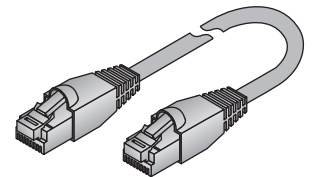

MOUSER STOCK NO.	AIM-Cambridge Part No.	Color	Length: ft (m)	Price Each			
				1	10	25	100
Cat 5E							
601-737790-3	73-7790-3	Gray	3 (.914)	2.00	1.54	1.43	1.33
601-737791-3	73-7791-3	Black	3 (.914)	2.01	1.55	1.44	1.34
601-737792-3	73-7792-3	Blue	3 (.914)	2.02	1.56	1.45	1.35
601-737793-3	73-7793-3	Green	3 (.914)	2.02	1.56	1.45	1.35
601-737794-3	73-7794-3	Red	3 (.914)	2.02	1.56	1.45	1.35
601-737795-3	73-7795-3	Yellow	3 (.914)	2.01	1.55	1.44	1.34
601-737796-3	73-7796-3	White	3 (.914)	2.02	1.56	1.45	1.35
601-737790-7	73-7790-7	Gray	7 (2.13)	2.55	2.03	1.93	1.86
601-737791-7	73-7791-7	Black	7 (2.13)	3.18	2.53	2.34	2.17
601-737792-7	73-7792-7	Blue	7 (2.13)	3.18	2.53	2.34	2.17
601-737793-7	73-7793-7	Green	7 (2.13)	3.19	2.54	2.35	2.18
601-737794-7	73-7794-7	Red	7 (2.13)	3.19	2.54	2.35	2.18
601-737795-7	73-7795-7	Yellow	7 (2.13)	2.55	2.34	2.19	2.05
601-737796-7	73-7796-7	White	7 (2.13)	3.19	2.54	2.35	2.18
601-737790-14	73-7790-14	Gray	14 (4.27)	5.41	4.27	3.94	3.65
601-737791-14	73-7791-14	Black	14 (4.27)	5.43	4.29	3.96	3.67
601-737792-14	73-7792-14	Blue	14 (4.27)	5.43	4.29	3.96	3.67
601-737793-14	73-7793-14	Green	14 (4.27)	5.43	4.29	3.96	3.67
601-737794-14	73-7794-14	Red	14 (4.27)	5.43	4.29	3.96	3.67
601-737795-14	73-7795-14	Yellow	14 (4.27)	5.43	4.29	3.96	3.67
601-737796-14	73-7796-14	White	14 (4.27)	5.43	4.29	3.96	3.67
601-737790-25	73-7790-25	Gray	25 (7.62)	11.84	9.30	8.60	7.98
601-737791-25	73-7791-25	Black	25 (7.62)	9.33	7.33	6.78	6.29
601-737792-25	73-7792-25	Blue	25 (7.62)	9.33	7.33	6.78	6.29
601-737793-25	73-7793-25	Green	25 (7.62)	9.33	7.33	6.78	6.29
601-737794-25	73-7794-25	Red	25 (7.62)	9.33	7.33	6.78	6.29
601-737795-25	73-7795-25	Yellow	25 (7.62)	9.33	7.33	6.78	6.29
601-737796-25	73-7796-25	White	25 (7.62)	9.34	7.34	6.79	6.30
601-737790-50	73-7790-50	Gray	50 (15.24)	13.11	10.92	10.08	9.48
601-737791-50	73-7791-50	Black	50 (15.24)	15.56	12.96	11.96	11.11
601-737792-50	73-7792-50	Blue	50 (15.24)	15.56	12.96	11.96	11.11
601-737793-50	73-7793-50	Green	50 (15.24)	15.56	12.96	11.96	11.11
601-737794-50	73-7794-50	Red	50 (15.24)	15.56	12.96	11.96	11.11
601-737796-50	73-7796-50	White	50 (15.24)	15.56	12.96	11.96	11.11
Cat 6							
601-738890-3	73-8890-3	Gray	3 (.914)	2.66	1.89	1.74	1.62
601-738892-3	73-8892-3	Blue	3 (.914)	2.67	1.90	1.76	1.64
601-738890-7	73-8890-7	Gray	7 (2.13)	3.96	2.93	2.71	2.51
601-738892-7	73-8892-7	Blue	7 (2.13)	3.96	2.93	2.71	2.51
601-738890-10	73-8890-10	Gray	10 (3.05)	6.20	3.88	3.58	3.32
601-738892-10	73-8892-10	Blue	10 (3.05)	6.10	3.82	3.52	3.27
601-738890-14	73-8890-14	Gray	14 (4.27)	5.10	4.70	4.37	4.09
601-738892-14	73-8892-14	Blue	14 (4.27)	6.48	5.13	4.74	4.40