

# CRYSTEK CORPORATION RF Cable Assemblies



RoHS Compliant This page of product is compliant.

## RG174: 50Ω COAXIAL CABLE ASSEMBLIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Crystek Part No.	Fig.	Cable Type	Length (in.)	Price Each	
					1	5
<b>BNC (Male) to Alligator Clip</b>						
549-CCBNCL-MC-30	CCBNCL-MC-30	A	RG 174	30	23.96	23.49
<b>SMA Straight (Male) to BNC Straight (Male)</b>						
549-BNS-MM-RG174-18	CCBNS-MM-RG174-18	A	RG 174	18	12.55	10.69
<b>SMA Straight (Male) to SMA Straight (Male)</b>						
549-SMA-MM-RG174-6	CCSMA-MM-RG174-6	A	RG 174	6	14.37	12.01
549-SMA-MM-RG174-12	CCSMA-MM-RG174-12	A	RG 174	12	14.53	12.15
549-SMA-MM-RG174-24	CCSMA-MM-RG174-24	A	RG 174	24	15.51	12.96
549-SMA-MM-RG174-36	CCSMA-MM-RG174-36	A	RG 174	36	15.67	13.10
549-SMA-MM-RG174-48	CCSMA-MM-RG174-48	A	RG 174	48	17.56	13.37
<b>SMA Straight (Male) to SMA Right Angle (Male)</b>						
549-SMA1-MM-RG174-6	CCSMA1-MM-RG174-6	A	RG 174	6	15.12	12.64
549-SMA1-MM-RG174-12	CCSMA1-MM-RG174-12	A	RG 174	12	15.28	12.78
549-SMA1-MM-RG174-24	CCSMA1-MM-RG174-24	A	RG 174	24	16.11	13.46
549-SMA1-MM-RG174-36	CCSMA1-MM-RG174-36	A	RG 174	36	16.26	13.59
<b>SMA Straight (Male) to Alligator Clip</b>						
549-CCSMA-LL-MC-24	CCSMA-LL-MC-24	A	RG 174	24	23.96	23.49

## 50Ω 18GHZ COAXIAL CABLE W/STAINLESS STEEL CONNECTORS

LL142: Low Loss

For quantities greater than listed, call for quote.

SMA Straight (Male) to SMA Straight (Male)	Crystek Part No.	Fig.	Cable Type	Length (in.)	Price Each	
					1	5
549-SMA-MMLL142-24	CCSMA-MM-LL142-24	B	LL 142	24	129.74	95.36
549-SMA-MMLL142-48	CCSMA-MM-LL142-48	B	LL 142	48	123.09	114.18
549-SMAMMLL33536	CCSMA-MM-LL335-36	B	LL 335	36	231.76	270.91
<b>Armored SMA Straight (Male) to SMA Straight (Male)</b>						
549-CCASMA-MMLL142-36	CCASMA-MM-LL142-36	C	LL 142	36	295.03	290.96
549-CCASMA-MMLL142-48	CCASMA-MM-LL142-48	C	LL 142	48	319.02	314.60
<b>N Straight (Male) to N Straight (Male)</b>						
549-CCN-MM-LL335-36	CCN-MM-LL335-36	D	LL 335	36	507.74	471.46

SS402: Precision

For quantities greater than listed, call for quote.

SMA Straight (Male) to SMA Straight (Male)	Crystek Part No.	Fig.	Cable Type	Length (in.)	Price Each	
					1	5
549-SMA-MMSS402-12	CCSMA-MM-SS402-12	E	SS 402	12	76.22	74.75
549-SMA-MMSS402-24	CCSMA-MM-SS402-24	E	SS 402	24	80.05	78.50
549-SMA-MMSS402-60	CCSMA-MM-SS402-60	E	SS 402	60	102.54	100.56
549-SMA-MMSS402-120	CCSMA-MM-SS402-120	E	SS 402	120	133.04	133.04

## RG316DS: 50Ω DOUBLE SHIELDED COAXIAL CABLE ASSEMBLIES

\* Sold in pairs

For quantities greater than listed, call for quote.

<b>SMA Straight (Male) to BNC Straight (Male)</b>						
549-BNS-MM-RG316DS6	CCBNS-MM-RG316DS-6	F	RG 316DS	6	14.11	12.29
549-BNS-MM-RG316DS12	CCBNS-MM-RG316DS-12	F	RG 316DS	12	14.67	12.61
549-BNS-MM-RG316DS36	CCBNS-MM-RG316DS-36	F	RG 316DS	36	17.60	16.25
<b>SMA Straight (Male) to SMA Straight (Male)</b>						
549-SMA-MMRG316DS6	CCSMA-MM-RG316DS-6	F	RG 316DS	6	14.31	12.99
549-SMA-MMRG316DS12	CCSMA-MM-RG316DS-12	F	RG 316DS	12	14.87	13.31
549-SMA-MMRG316DS24	CCSMA-MM-RG316DS-24	F	RG 316DS	24	16.05	14.98
549-SMA-MMRG316DS36	CCSMA-MM-RG316DS-36	F	RG 316DS	36	18.81	17.55
549-SMA-MMRG316DS48	CCSMA-MM-RG316DS-48	F	RG 316DS	48	23.72	22.13
<b>SMA Straight (Male) To SMA Right Angle (Male)</b>						
549-SMA1-MMRG316DS6	CCSMA1-MM-RG316DS-6	F	RG 316DS	6	15.06	13.62
549-SMA1-MMRG316DS12	CCSMA1-MM-RG316DS-12	F	RG 316DS	12	15.62	13.94
549-SMA1-MMRG316DS24	CCSMA1-MM-RG316DS-24	F	RG 316DS	24	17.31	15.61
<b>SMA Right Angle (Male) to SMA Right Angle (Male)</b>						
549-SMA2-MMRG316DS6	CCSMA2-MM-RG316DS-6	F	RG 316DS	6	15.81	14.25
549-SMA2-MMRG316DS12	CCSMA2-MM-RG316DS-12	F	RG 316DS	12	16.37	14.57
549-SMA2-MMRG316DS24	CCSMA2-MM-RG316DS-24	F	RG 316DS	24	18.06	16.24
549-SMA2-MMRG316DS36	CCSMA2-MM-RG316DS-36	F	RG 316DS	36	19.30	18.14
<b>SMA Straight (Male) to SMA Straight (Male) - Electrically Matched Pairs</b>						
* 549-SMAMMRG316DS12P	CCSMA-MM-RG316DS-12P	F	RG 316DS	12	42.53	42.53
* 549-SMAMMRG316DS24P	CCSMA-MM-RG316DS-24P	F	RG 316DS	24	45.50	45.50

## 26.5GHZ HAND FORMABLE COAX CABLES



For quantities greater than listed, call for quote.

<b>SMA Straight (Male) to SMA Straight (Male)</b>						
549-CCSMA26.5MM-86-3	CCSMA26.5-MM-86-3	G	.086	3	41.17	39.59
549-CCSMA26.5MM-86-4	CCSMA26.5-MM-86-4	G	.086	4	41.58	39.98
549-CCSMA26.5MM-86-5	CCSMA26.5-MM-86-5	G	.086	5	42.25	40.63
549-CCSMA26.5MM-86-6	CCSMA26.5-MM-86-6	G	.086	6	42.91	41.26
549-CCSMA26.5MM-86-7	CCSMA26.5-MM-86-7	G	.086	7	43.61	41.94
549-CCSMA26.5MM-86-8	CCSMA26.5-MM-86-8	G	.086	8	44.35	42.65
549-CCSMA26.5MM-86-10	CCSMA26.5-MM-86-10	G	.086	10	46.74	44.95
549-CCSMA26.5MM-86-12	CCSMA26.5-MM-86-12	G	.086	12	47.72	45.89

## 26.5GHZ LOW LOSS COAXIAL CABLES


For quantities greater than listed, call for quote.

<b>2.92mm (K) Straight (Male) to 2.92mm (K) Straight (Male)</b>						
549-CCK265MM190-30	CCK26.5-MM-190-30	H	190	30	246.86	243.45
549-CCK265MM190-36	CCK26.5-MM-190-36	H	190	36	276.58	246.95
549-CCK265MM190-39.4	CCK26.5-MM-190-39.4	H	190	39.4	262.45	255.55
549-CCK265MM190-48	CCK26.5-MM-190-48	H	190	48	276.69	269.45
<b>SMA Straight (Male) to SMA Straight (Male)</b>						
549-SMA265MM190-30	CCSMA26.5-MM-190-30	H	190	30	241.91	235.55
549-SMA265MM190-36	CCSMA26.5-MM-190-36	H	190	36	271.24	242.17
549-SMA265MM190-39.4	CCSMA26.5-MM-190-39.4	H	190	39.4	277.33	247.61
549-SMA265MM190-48	CCSMA26.5-MM-190-48	H	190	48	292.68	271.77

## 50Ω 40 GHZ LOW LOSS COAX CABLE ASSEMBLIES

For quantities greater than listed, call for quote.

<b>2.9mm (K) Straight (Male) to 2.9mm (K) Straight (Male)</b>						
549-CCK40-MM-160-36	CCK40-MM-160-36	H	160	36	228.39	219.61
549-CCK40-MM-160-48	CCK40-MM-160-48	H	160	48	247.40	237.90

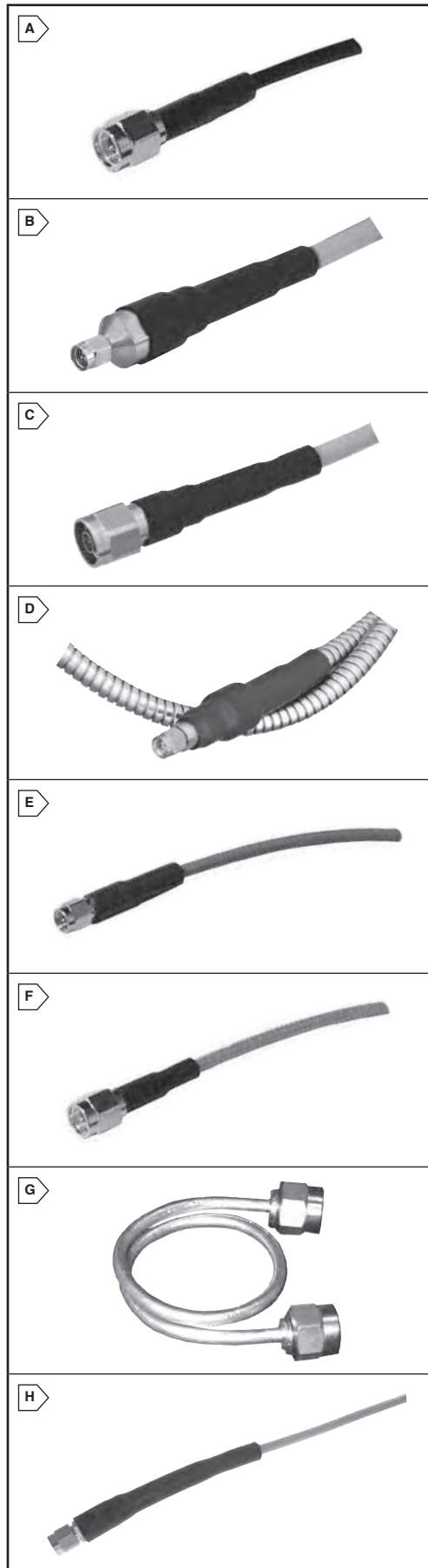

Cable Assemblies Crystek Corporation

