


KOBICONN Cable Assemblies and Adapters

KOBICONN

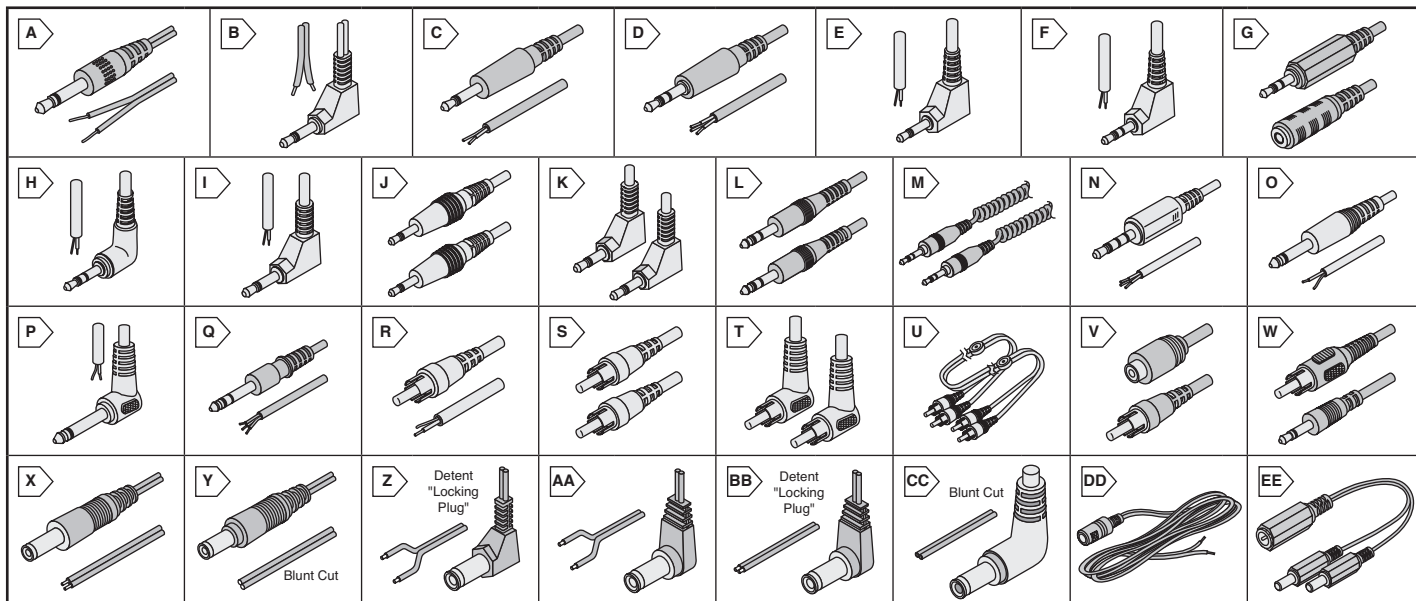

PHONE TYPE CABLES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Meters	Color	Termination	Termination	Price Each		
						1	10	100
2.5mm Connector, Parallel Cable								
172-2133	A	.914	Black	Mono plug	Stripped & tinned	2.35	1.81	1.64
172-2103	A	1.82	Black	Mono plug	Stripped & tinned	3.02	2.32	2.11
172-2003	B	1.82	Gray	Mono, 90° plug	Stripped & tinned	2.89	2.22	2.02
2.5mm Connector, Shielded Cable								
172-2104	C	1.82	Black	Mono plug	Stripped & tinned	3.16	2.43	2.21
172-2114	C	3.05	Black	Mono plug	Stripped & tinned	4.38	3.37	3.06
172-2134	C	.914	Black	Mono plug	Stripped & tinned	2.48	1.90	1.73
172-2234	D	.914	Black	Stereo plug	Stripped & tinned	4.01	3.09	2.81
172-2204	D	1.82	Black	Stereo plug	Stripped & tinned	5.14	3.96	3.60
172-2214	D	3.05	Black	Stereo plug	Stripped & tinned	6.92	5.32	4.84
172-2304	D	1.82	Gray	Stereo plug	Stripped & tinned	4.94	3.80	3.46
172-2009	E	.914	Black	Mono, 90° plug	Stripped & tinned	2.83	2.17	1.98
172-2069	E	1.82	Black	Mono, 90° plug	Stripped & tinned	3.26	2.51	2.28
172-2019	E	3.05	Black	Mono, 90° plug	Stripped & tinned	4.46	3.43	3.12
172-2310	F	.914	Black	Stereo, 90° plug	Stripped & tinned	4.35	3.35	3.05
172-2101	F	1.82	Black	Stereo, 90° plug	Stripped & tinned	5.63	4.32	3.93
172-2533	G	.914	Black	Stereo plug	Stereo Jack	5.41	4.16	3.78
172-2574	G	1.82	Black	Stereo plug	Stereo Jack	5.90	4.54	4.13
172-7446-E	H	1.82	Black	4 Cond Stereo 90°	Stripped & tinned	4.62	3.34	3.04
172-MC254-EX	I	1.82	Black	4 Cond 90° plug, use w/161-2828-E only	Stripped & tinned	19.50	15.00	13.64

PHONE TYPE CABLES (CONT.)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Meters	Color	Termination	Termination	Price Each		
						1	10	100
1/4" Connector, Unshielded Cable								
172-0108	Q	1.82	Black	Stereo plug	Stripped & tinned	4.97	3.82	3.47

RCA SHIELDED PHONO TYPE CABLES/ADAPTERS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Meters	Color	Termination	Termination	Price Each		
						1	10	100
172-1133	R	.914	Black	RCA plug	Stripped & tinned	2.16	1.66	1.51
172-1103	R	1.82	Black	RCA plug	Stripped & tinned	3.57	2.75	2.51
172-1113	R	3.05	Black	RCA plug	Stripped & tinned	4.53	3.48	3.17
17FH101	S	.914	Gray	RCA plug	RCA plug	3.27	2.52	2.29
172-1101	S	.914	Black	RCA plug	RCA plug	2.77	2.13	1.94
172-1166	S	1.82	Black	RCA plug	RCA plug	3.30	2.54	2.31
172-1112	S	1.82	Gray	RCA plug	RCA plug	4.17	3.21	2.91
172-1001	T	.914	Gray	90° RCA plug	90° RCA plug	3.14	2.42	2.20
172-1110	T	3.05	Gray	90° RCA plug	90° RCA plug	5.72	4.40	4.00
172-0004	U	1.82	Black	1red/1blk RCA plug	1red/1blk RCA plug	5.42	4.17	3.79
172-0023	V	.914	Black	RCA plug	RCA jack	2.96	2.28	2.07
172-0020	V	1.82	Black	RCA plug	RCA jack	3.30	2.54	2.31
172-0002	W	1.82	Black	RCA plug	3.5mm mono plug	3.23	2.48	2.25
172-0013	W	3.05	Black	RCA plug	3.5mm mono plug	4.72	3.63	3.30

DC POWER CABLES

* Detent Locking Plugs † Blunt Cut

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Length: in. (m)	AWG	P.D. Dimensions: mm			Price Each		
					I.D.	O.D.	Length	1	10	100
Straight • Cord Type: Parallel with striped pin indicator										
* 172-4206	X	Black	120 (3.05)	24	1.3	3.4	9.0	4.27	3.29	2.99
172-1370	X	Gray	72 (1.83)	24	1.3	3.4	12	4.19	3.22	2.93
172-0171	X	Black	72 (1.83)	24	1.7	4.0	9.5	3.40	2.61	2.38
172-0172	X	Black	72 (1.83)	24	1.7	4.8	9.5	3.20	2.46	2.24
172-7443-B-E	X	Black	72 (1.83)	24	2.1	5.5	11	3.39	2.61	2.37
172-7443-E	X	Red/White	72 (1.83)	24	2.1	5.5	11	3.39	2.61	2.37
172-4204	X	Black	36 (.914)	24	2.1	5.5	12	1.94	1.49	1.35
† 172-4203	Y	Black	24 (.61)	24	2.1	5.5	12	1.97	1.53	1.39
17FH114	X	Black	72 (1.83)	24	2.5	5.5	12	3.20	2.46	2.24
172-0014	X	Gray	72 (1.83)	24	2.5	5.5	11	2.97	2.29	2.08
172-7444-E	X	Black	72 (1.83)	18	2.5	5.5	12	4.31	3.32	3.02
172-8336-E	X	Black	180 (4.57)	18	2.5	5.5	12	5.13	3.42	3.11
172-4205	X	Black	36 (.914)	24	2.5	5.5	12	2.19	1.68	1.53
† 172-4202	Y	Black	24 (.61)	18	2.5	5.5	12	3.08	2.37	2.15
Right Angle										
* 172-1373	Z	Black	120 (3.05)	24	1.3	3.4	9.0	4.37	3.36	3.06
† 172-0173	AA	Black	72 (1.83)	24	1.7	4.0	9.5	2.76	2.12	1.93
* 172-1015	BB	Black	120 (3.05)	24	2.1	5.5	14	4.97	3.82	3.47
172-4001	AA	Gray	72 (1.83)	24	2.1	5.5	11	3.30	2.54	2.31
* 172-1016	BB	Black	6 (1.52)	24	2.1	5.5	14	1.76	1.35	1.23
172-1018	AA	Black	120 (3.05)	24	2.5	5.5	12	2.68	2.06	1.87
172-4000	AA	Black	72 (1.83)	24	2.5	5.5	12	3.52	2.71	2.46
172-4208	AA	Black	24 (.61)	18	2.5	5.5	12	3.15	2.42	2.20
172-1017	AA	Black	6 (1.52)	24	2.5	5.5	12	2.09	1.61	1.46
† 172-7445-E	CC	Black	24 (.61)	18	2.1	5.5	12	2.91	1.94	1.76
Straight Jack										
172-7426-E	DD	Black	72 (1.83)	24	2.1	5.5	9.5	3.86	2.57	2.34
172-0250	DD	Black	72 (1.83)	24	2.5	5.5	9.5	3.81	2.93	2.66
Y Adapters										
172-2111	EE	Black	8 (203)	26	2.1 JK	-	-	7.41	5.70	5.18
172-2555	EE	Black	8 (203)	26	2.5 JK	-	-	7.58	5.83	5.30

Cable Assemblies

Kobiconn