

QUALTEK Cable Assemblies

RoHS Compliant This product is RoHS compliant.

302 SERIES: USB 3.0 CABLES


Features:

- Color: Black
- Conn. Plating: Nickel
- Nickel plated ground indents for superior connectivity with low cost
- Gold plated contacts for industry leading connectivity
- Aluminum-Foil/Mylar shield reduces cross-talk and interference
- Molded strain reliefs bend easily without sacrificing durability
- Devices utilizing increased speeds of USB 3.0 include external Blu-Ray players, externa high capacity HDD drives, high mega pixel cameras, high definition video capture devices, multi-channel audio interfaces, high capacity jump drives



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Length (m)	Price Each	
					1	10
562-3023001-01M	3023001-01M	A	USB 3.0 A-A	1	8.66	7.32
562-3023003-01M	3023003-01M	B	USB 3.0 A-B	1	8.26	7.54
562-3023005-01M	3023005-01M	A	USB 3.0 A - MICRO B	1	9.64	8.80
562-3023007-01M	3023007-01M	C	USB 3.0 MICRO AB - MICRO B	1	11.22	10.25
562-3023009-01M	3023009-01M	D	USB 3.0 MICRO AB - B	1	9.85	9.20
562-3023011-01M	3023011-01M	E	USB 3.0 A - MICRO B + Power Cable	1	10.60	9.81
562-3023013-02M	3023013-02M	B	USB 3.0 A-A	2	9.64	8.80
562-3023015-02M	3023015-02M	F	USB 3.0 A-B	2	10.24	9.35
562-3023017-02M	3023017-02M	G	USB 3.0 A - MICRO B	2	10.10	9.34
562-3023019-02M	3023019-02M	H	USB 3.0 MICRO AB - MICRO B	2	11.30	10.45
562-3023021-02M	3023021-02M	C	USB 3.0 MICRO AB - B	2	10.25	9.30
562-3023023-02M	3023023-02M	D	USB 3.0 A - MICRO B + Power Cable	2	12.14	11.23
562-3023025-03M	3023025-03M	A	USB 3.0 A-A	3	10.10	9.34
562-3023027-03M	3023027-03M	B	USB 3.0 A-B	3	10.60	9.81
562-3023029-03M	3023029-03M	F	USB 3.0 A - MICRO B	3	11.80	10.92
562-3023031-03M	3023031-03M	H	USB 3.0 MICRO AB - MICRO B	3	12.84	11.88
562-3023033-03M	3023033-03M	C	USB 3.0 MICRO AB - B	3	12.32	11.40
562-3023035-03M	3023035-03M	D	USB 3.0 A - MICRO B + Power Cable	3	13.86	12.65

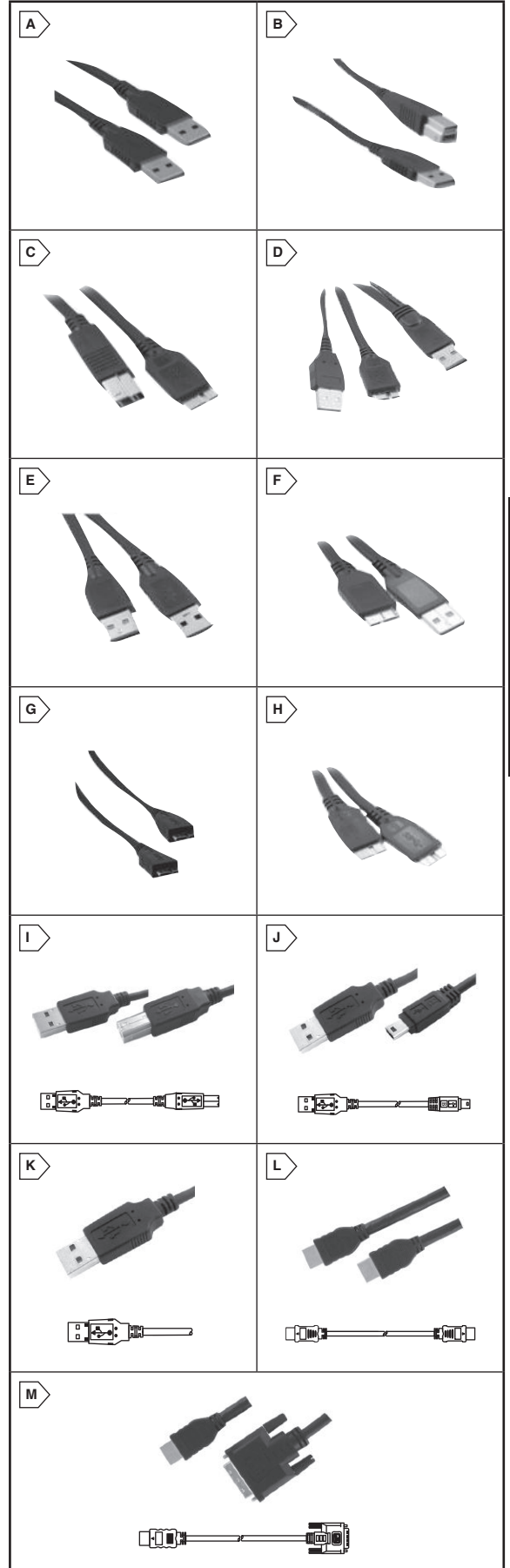

Cable Assemblies

Qualtek

USB CABLE ASSEMBLIES

Universal Serial Bus

Features:

- Transfer rates up to 480Mbps depending on USB version
- Connect an USB peripheral to an USB Hub or USB port on PC/MAC
- Compatible with USB specifications 1.0, 1.1, and 2.0
- Make plug and play connections for such devices as keyboards, mice, modems, printers, and other USB peripherals.
- Black



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Conn. Plating	Wire (AWG)	Length (m)	Price Each		
							1	10	25
562-3021001-03	3021001-03	J	A-B	Nickel	28/28	.914	2.02	1.67	1.58
562-3021003-03	3021003-03	J	A-mini B	Nickel	28/28	.914	2.27	2.20	2.17
562-3021005-03	3021005-03	K	A-Blunt	Nickel	28/28	.914	1.85	1.79	1.71
562-3021007-06	3021007-06	J	A-B	Nickel	26/28	1.83	2.82	2.74	2.70
562-3021009-06	3021009-06	J	A-mini B	Nickel	26/28	1.83	2.87	2.79	2.74
562-3021011-06	3021011-06	K	A-Blunt	Nickel	26/28	1.83	2.62	2.17	2.06
562-3021015-10	3021015-10	J	A-mini B	Nickel	26/28	3.05	4.60	4.36	4.14
562-3021017-10	3021017-10	K	A-Blunt	Nickel	26/28	3.05	4.51	4.35	4.19
562-3021019-16	3021019-16	I	A-B	Gold	24/26	4.88	6.13	5.82	5.52
562-3021021-16	3021021-16	J	A-mini B	Gold	24/26	4.88	9.40	9.05	8.70
562-3021023-16	3021023-16	K	A-Blunt	Gold	24/26	4.88	8.22	7.91	7.60
562-3021027-16	3021027-16	J	A-mini B	Gold	20/26	4.88	9.40	9.05	8.70
562-3021029-16	3021029-16	K	A-Blunt	Gold	20/26	4.88	8.21	7.91	7.61

HDMI CABLE ASSEMBLIES

High Definition Multimedia Interface

Broadcast quality digital video/audio, and inter component control signals all in one compact. High-performance connection!

Features:

- Three layers of shielding
- Nitrogen-injected dielectric, meticulous construction
- Black
- DTV Link to DVD player, D-VHS recorder, set-top box and camcorder



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Qualtek Part No.	Fig.	Description	Conn. Plating	Wire (AWG)	Length (m)	Price Each		
							1	10	25
562-1721001-03	1721001-03	L	Type A-Type A	Nickel	28	.914	8.19	8.08	7.78
562-1721003-03	1721003-03	M	Type A-DVI (18+1)	Nickel	28	.914	8.19	8.08	7.78
562-1721005-06	1721005-06	L	Type A-Type A	Nickel	28	1.83	12.38	11.89	11.01
562-1721007-06	1721007-06	M	Type A-DVI (18+1)	Nickel	28	1.83	10.38	10.24	9.86
562-1721009-10	1721009-10	L	Type A-Type A	Nickel	28	3.05	14.55	14.09	13.71
562-1721011-10	1721011-10	M	Type A-DVI (18+1)	Nickel	28	3.05	14.93	14.48	13.70
562-1721013-16	1721013-16	L	Type A-Type A	Nickel	26	4.88	21.79	20.76	19.22
562-1721015-16	1721015-16	M	Type A-DVI (18+1)	Nickel	26	4.88	23.64	23.06	21.26