


VOLEX 3-Conductor Power Cords

Volex

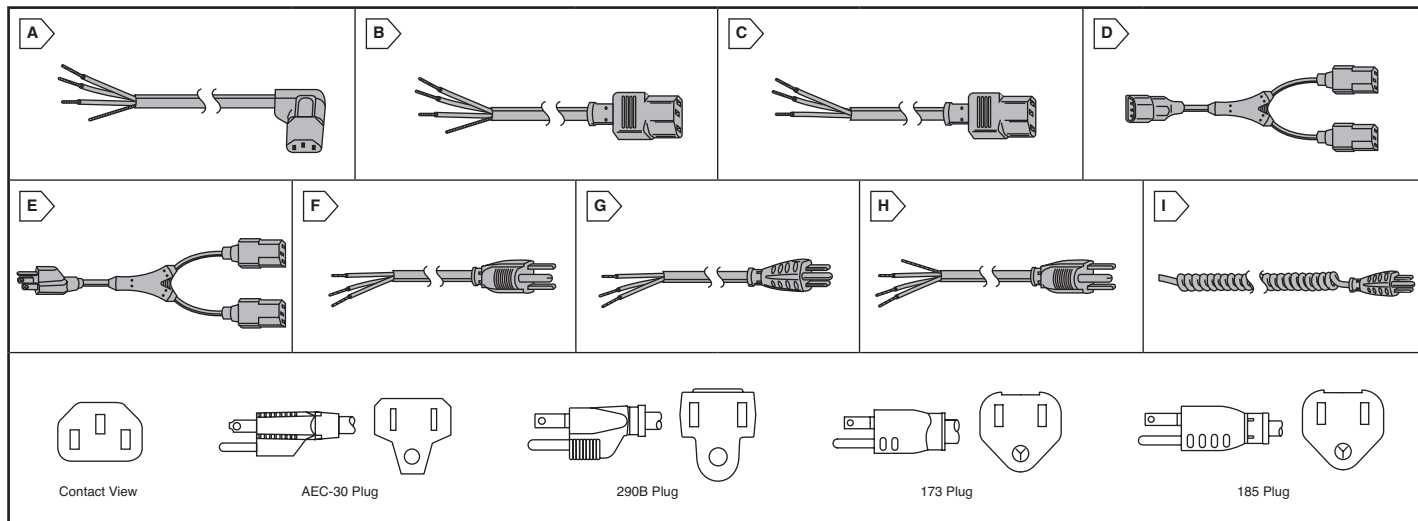

VOLEX 3-CONDUCTOR EQUIPMENT CORDS

- Outer Jacket Stripped 2"-51mm
- Conductors Stripped and Twisted 5/8"-16mm
- International Color Coding
- Temperature: 60°C
- Drain Wire: SVT-22AWG SJT - 20AWG

Shielded, Black Jacket Color - Right Angle



MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Cord	Price Each
686-17751	17751	A	6' 7"	18 (41x34)	.270	1250W/10A	SVT	9.46

Unshielded, PVC Black Jacket Color - Right Angle



MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Recap.	Cord	Price Each
686-17536	17536	A	6' 7"	18 (41x34)	.315	1250W/10A	PH910	SJT	7.36
686-17537	17537	A	9' 10"	18 (41x34)	.315	1250W/10A	PH910	SJT	10.28

Foil Shielded, PVC Jacketed Black Jacket Color



MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Recap.	Cord	Price Each
686-17749	17749	B	6' 7"	18 (41x34)	.270	1250W/10A	386A	SVT	13.57
686-17620	17620	B	6' 7"	16 (65x34)	.353	1625W/13A	386E	SJT	13.84
686-17621	17621	B	9' 10"	16 (65x34)	.353	1625W/13A	386E	SJT	23.18

Unshielded, PVC Jacketed, Black Jacket Color



MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Recap.	Cord	Price Each
686-17254	17254	C	7' 6"	18 (41x34)	.246	1250W/10A	386	SVT	6.60
686-17518	17518	C	6' 7"	18 (41x34)	.315	1250W/10A	386A	SJT	8.10
686-17520	17520	C	6' 7"	16 (26x30)	.340	1625W/13A	386E	SJT	10.81
686-17521	17521	C	9' 10"	16 (26x30)	.340	1625W/13A	386E	SJT	13.85

VOLEX Y-CORD TWIN END CORD SETS

- Color Coding North America
- Jack Color: Black
- Temperature Rating: 60°C
- Length of individual leg: 2ft.



MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Cord	Price Each	
								1	25
686-17268A	17268A	D	6'	18 (41x34)	.315	125V, 10A	---	13.97	12.58
686-17272A	17272A	E	6'	18 (41x34)	.315	125V, 10A	AEC-30	12.97	11.65
686-17274A	17274A	E	6'	16 (65x34)	.340	250V, 13A	AEC-30	16.06	14.52

© Copyright 2012 Mouser Electronics

VOLEX 3-CONDUCTOR PLASTIC NEMA 5-15P ORIGINAL EQUIPMENT CORDS

- Outer Jacket Stripped 2"-51mm
- Conductors Stripped and Twisted 5/8"-16mm
- Jacket Color: Black
- International Color Coding
- Temperature Rating: 60°C
- Drain Wire: SVT-22AWG, SJT-20AWG
- Temperature Rating: 105°C



Unshielded

MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Plug	Cord	Price Each
PVC Jacketed									
686-17512	17512	F	6' 7"	18 (41x34)	.315	1250W/10A	290B	SJT	5.14
686-17513	17513	F	9' 10"	18 (41x34)	.315	1250W/10A	290B	SJT	7.13
686-17514	17514	F	6' 7"	16 (65x34)	.340	1625W/13A	290B	SJT	10.03
686-17516	17516	F	6' 7"	14 (41x30)	.380	1875W/15A	173	SJT	8.46
686-17517	17517	F	9' 10"	14 (41x30)	.380	1875W/15A	173	SJT	17.96
686-17534	17534	F	6' 7"	18 (41x34)	.246	1250W/10A	290B	SVT	4.72
686-17535	17535	F	9' 10"	18 (41x34)	.246	1250W/10A	290B	SVT	6.55
* 686-17747	17747	F	6' 7"	18 (41x34)	.246	1250W/10A	290B	SVT	5.19
Gray PVC Jacketed									
686-17237	17237	F	6'	18 (41x34)	.246	1250W/10A	290B	SVT	8.85
686-17239	17239	F	8'	18 (41x34)	.246	1250W/10A	290B	SVT	5.49
686-17405	17405	F	6'	18 (16x30)	.315	1250W/10A	290B	SJT	5.34
686-17407	17407	F	8'	18 (16x30)	.315	1250W/10A	290B	SJT	7.83
686-17276	17276	F	20'	16 (26x30)	.340	1625W/13A	290B	SJT	24.18
Black Rubber or Neoprene Jacketed									
686-17238	17238	F	8'	18 (41x34)	.246	1250W/10A	290B	SV	8.52
686-17406	17406	G	6'	18 (16x30)	.315	1250W/10A	290B	SJ	10.00
686-17408	17408	G	8'	18 (16x30)	.315	1250W/10A	290B	SJ	9.51
686-17412	17412	G	12'	18 (16x30)	.315	1250W/10A	290B	SJ	16.06
686-17419	17419	G	9'	16 (26x30)	.340	1625W/13A	185	SJ	14.82
686-17422	17422	G	12'	16 (26x30)	.340	1625W/13A	185	SJ	18.14
68617629	17629	G	9'	14 (41x30)	.380	1875W/15A	173	SJ	26.02
686-17635	17635	G	15'	14 (41x30)	.380	1875W/15A	173	SJ	33.60

Shielded

MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Plug	Cord	Price Each
686-17614	17614	H	6' 7"	16 (65x34)	.365	1625W/13A	185	SJT	12.35
686-17615	17615	H	9' 10"	16 (65x34)	.365	1625W/13A	185	SJT	17.20
686-17720	17720	H	6' 7"	18 (41x34)	.270	1250W/10A	290B	SVT	10.06
* 686-17740	17740	H	6' 7"	18 (41x34)	.270	1250W/10A	290B	SVT	10.44
686-17741	17741	H	9' 10"	18 (41x34)	.270	1250W/10A	290B	SVT	12.12

Foil and Braid Shielded

RoHS Compliant

MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Plug	Cord	Price Each
686-17650	17650	H	6' 7"	18 (41x34)	.307	1250W/10A	290B	SVT	10.76

VOLEX RETRACTILE CORD

- Rubber Insulated, Neoprene Jacketed



MOUSER STOCK NO.	Volex Part No.	Fig.	Length	AWG (Stranded)	Nominal O.D. (in.)	Rating	Plug	Cord	Price Each
686-17449	17449	I	2 to 12'	16 (65x34)	1.37	1625W/13A	173	SJO	46.33

VOLEX REPLACEMENT CORD FOR LAPTOP COMPUTERS

- Designed to work with Dell, Compaq, and IBM Laptop Computers. 18AWG, 3 Conductor



MOUSER STOCK NO.	Volex Part No.	Nominal O.D. (in.)	Length	Rating	Price Each	
					1	25
686-17036	17036	.144 x .280	6'	125V/2.5A	9	5.35

© Copyright 2012 Mouser Electronics