


# VOLEX Power Cords and Retractable Cords

Volex

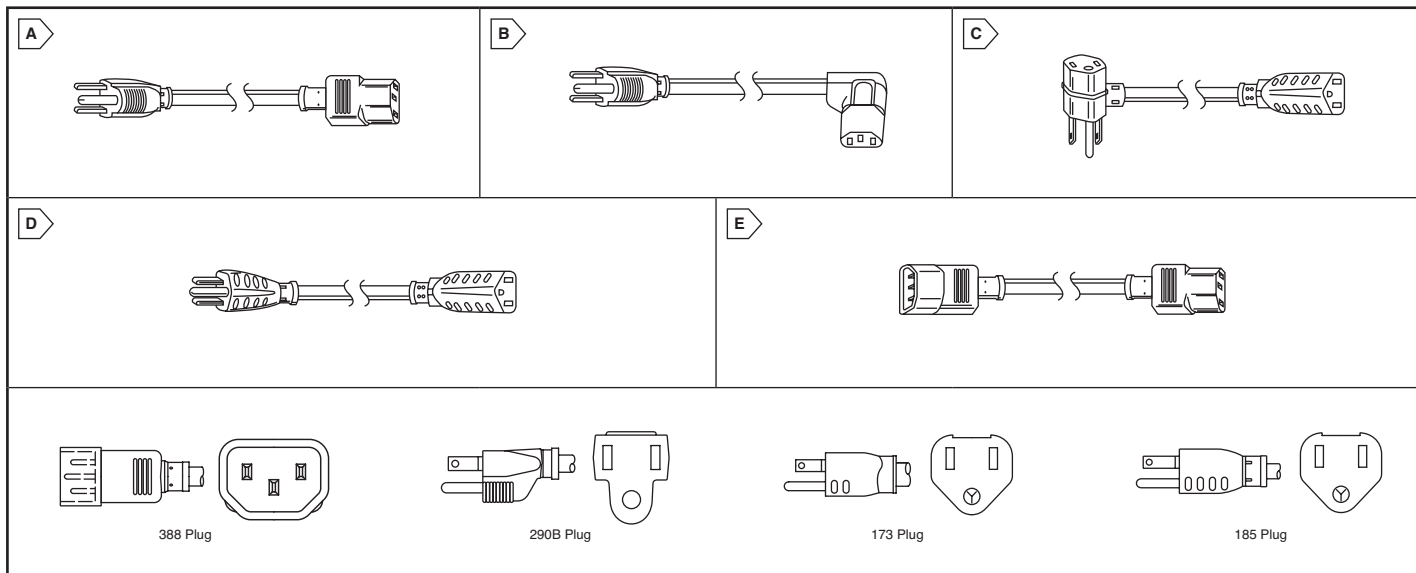

## VOLEX 3-CONDUCTOR DETACHABLE POWER SUPPLY CORDS

- Temperature: 60°C, 125V \* Rated 105°C
- International Color Coding

### Foil Shielded, Black PVC Jacketed



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17600</b>	17600	A	18 (41x34)	6' 7"	1250 W/10A	185	386A	SJT	<b>12.49</b>
<b>686-17601</b>	17601	A	18 (41x34)	9' 10"	1250 W/10A	185	386A	SJT	<b>10.77</b>
<b>686-17602</b>	17602	A	16 (65x34)	6' 7"	1625 W/13A	290B	386E	SJT	<b>16.93</b>
<b>686-17603</b>	17603	A	16 (65x34)	9' 10"	1625 W/13A	290B	386E	SJT	<b>20.75</b>
<b>686-17604</b>	17604	A	14 (41x30)	6' 7"	1875 W/15A	173	386E	SJT	<b>19.96</b>
<b>686-17605</b>	17605	A	14 (41x30)	9' 10"	1875 W/15A	173	386E	SJT	<b>25.87</b>
* <b>686-17725</b>	17725	A	18 (41x34)	6' 7"	1250 W/10A	290B	386A	SVT	<b>9.36</b>
<b>686-17742</b>	17742	A	18 (41x34)	6' 7"	1250 W/10A	290B	386A	SVT	<b>6.46</b>
<b>686-17743</b>	17743	A	18 (41x34)	9' 10"	1250 W/10A	290B	386A	SVT	<b>15.85</b>

### Foil and Braid Shielded, Black PVC Jacketed



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17660</b>	17660	A	18 (41x34)	6' 7"	1250 W/10A	290B	386A	SVT	<b>12.83</b>
<b>686-17661</b>	17661	A	18 (41x34)	9' 10"	1250 W/10A	290B	386A	SVT	<b>16.75</b>

### Foil Shielded, Black PVC Jacketed, Right Angle



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17606</b>	17606	B	18 (41x34)	6' 7"	1250 W/10A	290B	PH910	SJT	<b>15.46</b>
<b>686-17609</b>	17609	B	16 (65x34)	9' 10"	1625 W/13A	185	PH910	SJT	<b>20.98</b>
<b>686-17746</b>	17746	B	18 (41x34)	9' 10"	1250 W/10A	290B	PH910	SVT	<b>12.57</b>

### Add-A-Line - SJT Cord Unshielded, Black PVC Jacketed



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17462</b>	17462	C	16 (26x30)	.340"	8'	1625 W/13A	AEC-50	AEC-210	<b>18.77</b>
<b>686-17463</b>	17463	C	16 (26x30)	.340"	15'	1625 W/13A	AEC-50	AEC-210	<b>24.43</b>

## VOLEX 3-CONDUCTOR DETACHABLE CORD

### Unshielded, Black PVC Jacketed



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17249</b>	17249	A	18 (41x34)	6'	1250 W/10A	290B	386	SVT	<b>4.47</b>
<b>686-17250</b>	17250	A	18 (41x34)	7' 6"	1250 W/10A	290B	386	SVT	<b>5.45</b>
<b>686-17251</b>	17251	A	18 (41x34)	7' 6"	1250 W/10A	290B	386	SVT	<b>4.63</b>
<b>686-17500</b>	17500	A	18 (41x34)	6' 7"	1250 W/10A	290B	386A	SJT	<b>5.09</b>
<b>686-17501</b>	17501	A	18 (41x34)	9' 10"	1250 W/10A	290B	386A	SJT	<b>8.01</b>
<b>686-17000A</b>	17000A	A	18 (41x34)	3'	1250 W/10A	290B	386	SVT	<b>4.96</b>
<b>686-17002A</b>	17002A	A	18 (41x34)	1' 6"	1250 W/10A	290B	386A	SVT	<b>3.20</b>
<b>686-17001A</b>	17001A	A	16 (26x30)	3'	1625 W/13A	290B	386E	SJT	<b>6.54</b>
<b>686-17502</b>	17502	A	16 (26x30)	6' 7"	1625 W/13A	290B	386E	SJT	<b>9.74</b>
<b>686-17255</b>	17255	A	16 (26x30)	7' 6"	1625 W/13A	290B	386E	SJT	<b>13.88</b>
<b>686-17503</b>	17503	A	16 (26x30)	9' 10"	1625 W/13A	290B	386E	SJT	<b>13.33</b>
<b>686-17504</b>	17504	A	14 (41x30)	6' 7"	1875 W/15A	173	386E	SJT	<b>5.93</b>
<b>686-17757</b>	17757	A	18 (41x34)	7' 6"	1250 W/10A	290B	386A	SVT	<b>12.47</b>
* <b>686-17758</b>	17758	A	18 (41x34)	6' 7"	1250 W/10A	290B	386A	SJT	<b>10.95</b>

### Unshielded, Black PVC Jacketed, Right Angle



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17506</b>	17506	B	18 (41x34)	6' 7"	1250 W/10A	290B	910	SJT	<b>7.96</b>
<b>686-17507</b>	17507	B	18 (41x34)	9' 10"	1250 W/10A	290B	910	SJT	<b>11.24</b>
<b>686-17508</b>	17508	B	16 (26x30)	6' 7"	1625 W/13A	290B	910	SJT	<b>12.77</b>
<b>686-17509</b>	17509	B	16 (26x30)	9' 10"	1625 W/13A	290B	910	SJT	<b>12.62</b>

## VOLEX SJ CORD UNSHIELDED, BLACK PVC JACKETED



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>686-17461</b>	17461	D	16 (26x30)	.340"	10'	1625 W/13A	290B	108	<b>23.95</b>

## VOLEX JUMPER CORDS

- \* Rated 60°C, 125V



MOUSER STOCK NO.	Volex Part No.	Fig.	AWG (Stranded)	Length	Rating	Plug	Conn.	Cord	Price Each
<b>Foil Shielded</b>									
<b>686-17753</b>	17753	E	18 (41x34)	3' 3"	1250 W/10A	388A	386A	SVT	<b>6.22</b>
<b>Unshielded</b>									
<b>686-17524</b>	17524	E	18 (41x34)	3' 3"	1250 W/10A	388A	386A	SJT	<b>6.45</b>
<b>686-17525</b>	17525	E	16 (26x30)	3' 3"	1625 W/13A	388B	386E	SJT	<b>7.90</b>