


KOBICONN AC Inlets and Outlets

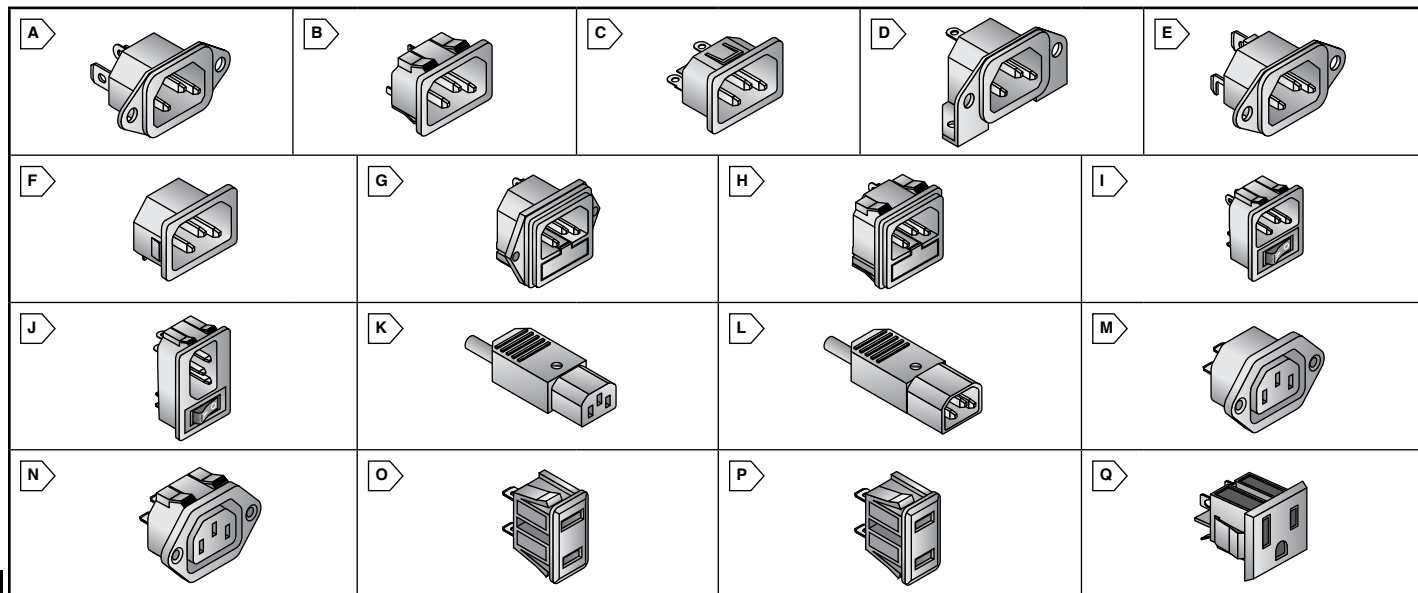

Common Features:

- Fuse Not Included
- RoHS Compliant



RoHS Compliant

IEC 60320 C14 INLETS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kobiconn Part No.	Fig.	Rating	Insulation Resistance	Mounting Type	Body Material	Price Each			
							1	10	100	500
161-R30148-E	R-301(48)	A	10A 250VAC	Over 100MΩ at 500VDC	Screw/Solder	Black Glass-Fiber Thermoplastic	1.83	1.66	1.51	1.37
161-R301SN-E	R-301SN(00)	B	15A 250VAC	Over 100MΩ at 500VDC	Screw/Solder	Nylon 66	.63	.57	.52	.47
161-R301SN01-E	R-301SN(01)	C	10A 250VAC	Over 100MΩ at 500VDC	Screw/Solder	Nylon 66	.77	.70	.64	.58
161-R3019013-E	R-30190(13)	D	10A 250VAC	Over 100MΩ at 500VDC	Screw/Solder	Black Glass-Fiber Thermoplastic	.97	.88	.80	.73
161-R301B07-E	R-301(B07)	E	10A 250VAC	Over 100MΩ at 500VDC	Snap On/PCB	Black Glass-Fiber Thermoplastic	1.11	1.01	.78	.60
161-R301SNC01-E	R-301SN(C01)	F	10A 250VAC	Over 100MΩ at 500VDC	Snap On/PCB	Black Glass-Fiber Nylon 66	.81	.74	.67	.61

INLETS WITH FUSE HOLDERS

- Suitable for 5x20mm Fuse

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kobiconn Part No.	Fig.	Rating	Insulation Resistance	Mounting Type	Body Material	Price Each			
							1	10	100	500
161-R3013-E	R-3013	G	10A 250VAC	Over 100MΩ at 500VDC	Screw/Solder	P.B.T.	2.00	1.82	1.65	1.50
161-R3014-E	R-3014	H	10A 250VAC	Over 100MΩ at 500VDC	Snap On/Solder	Nylon 66	2.00	1.82	1.65	1.50

INLETS / OUTLETS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kobiconn Part No.	Fig.	Rating	Insulation Resistance	Mounting Type	Body Material	Price Each			
							1	10	100	500
161-R30161-E	R-301SN(61)	I	15A 250VAC	Over 100MΩ at 500VDC	Solder/Snap on Panel	Thermoplastic	2.29	2.08	1.89	1.72
161-R301B12-E	R-301SN(B12)	J	10A 250VAC	Over 100MΩ at 500VDC	Solder/Snap on Panel	Black Glass Fiber Thermoplastic	2.02	1.84	1.67	1.52

CABLE CONNECTORS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kobiconn Part No.	Fig.	Rating	Insulation Resistance	Mounting Type	Body Material	Price Each			
							1	10	100	500
Outlet										
161-R332-E	R-332	K	10A 250VAC	Over 100MΩ at 500VDC	3 Wire Plug	Thermoplastic	2.83	2.57	2.34	2.13
Inlet										
161-R331-E	R-331	L	10A 250VAC	Over 100MΩ at 500VDC	3 Wire Plug	Thermoplastic	2.83	2.57	2.34	2.13

IEC 60320 C13 OUTLETS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kobiconn Part No.	Fig.	Rating	Insulation Resistance	Mounting Type	Body Material	Price Each			
							1	10	100	500
161-R30200-E	R-302(00)	M	10A 250VAC	Over 100MΩ at 500VDC	Screw/Solder	P.B.T.	.62	.56	.51	.46
161-R302SN-E	R-302SN(00)	N	10A 250VAC	Over 100MΩ at 500VDC	Snap/Solder	Nylon 66	.87	.79	.72	.65

NEMA OUTLETS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kobiconn Part No.	Fig.	Rating	Insulation Resistance	Mounting Type	Body Material	Price Each			
							1	10	100	500
161-RU0298-E	RU-02(98)	O	15A 125VAC	Over 100MΩ at 500VDC	Snap/Solder	Nylon 66	.55	.50	.45	.41
161-RU0299-E	RU-02(99)	P	15A 125VAC	Over 100MΩ at 500VDC	Snap/Solder	Nylon 66	.55	.50	.45	.41
161-RU0200-E	RU-02(00)	Q	15A 125VAC	Over 100MΩ at 500VDC	Snap/Solder	Nylon 66	.62	.56	.51	.46