

BULGIN Power Inlets and Outlets



IEC 320-1 FUSED POWER INLETS

5x20MM Single Fuse 10A 250VAC

• Room for spare fuse

• Fuses sold Separately



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|------------------|-----------------|------|---|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-PF0001/28 | PF0001/28 | A | Chassis mount 2.8mm solder tab | 2.82 | 2.59 | 2.31 | 1.92 |
| 161-PF0001/63 | PF0001/63 | A | Chassis mount 6.3mm faston tab | 2.87 | 2.64 | 2.35 | 1.96 |
| 161-PF0011/10/28 | PF0011/10/28 | B | Snap-in fit, 2.8mm solder tabs, 1mm panel thickness | 2.80 | 2.57 | 2.28 | 1.91 |
| 161-PF0011/15/28 | PF0011/15/28 | B | Snap-in fit, 2.8mm solder tabs, 1.5mm panel thickness | 2.80 | 2.57 | 2.28 | 1.91 |
| 161-PF0011/10/63 | PF0011/10/63 | B | Snap-in fit, 6.3mm faston tabs, 1mm panel thickness | 2.85 | 2.61 | 2.33 | 1.94 |
| 161-PF0011/15/63 | PF0011/15/63 | B | Snap-in fit, 6.3mm faston tabs, 1.5mm panel thickness | 2.85 | 2.61 | 2.33 | 1.94 |

Twin Fused 10A 250VAC

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|------------------|-----------------|------|---|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-PF0030/28 | PF0030/28 | C | Chassis mount, 2.8mm solder tabs | 4.29 | 3.93 | 3.50 | 2.93 |
| 161-PF0030/63 | PF0030/63 | C | Chassis mount, 6.3mm faston tabs | 3.96 | 3.80 | 3.54 | 2.96 |
| 161-PF0033/15/28 | PF0033/15/28 | D | Snap-in fit, 2.8mm solder tabs, 1.5mm panel thickness | 4.44 | 4.08 | 3.62 | 3.02 |
| 161-PF0033/15/63 | PF0033/15/63 | D | Snap-in fit, 6.3mm faston tabs, 1.5mm panel thickness | 4.29 | 3.93 | 3.50 | 2.93 |

IEC 320-1 POWER INLETS

15A, 250VAC, UL and CSA



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|------------------|-----------------|------|---|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-PX0575/10/28 | PX0575/10/28 | E | Snap-in fit, 2.8mm solder tabs, 1mm panel thickness | 1.46 | 1.34 | 1.19 | .997 |
| 161-PX0575/15/28 | PX0575/15/28 | E | Snap-in fit, 2.8mm solder tabs, 1.5mm panel thickness | 1.53 | 1.40 | 1.25 | 1.04 |
| 161-PX0575/10/63 | PX0575/10/63 | E | Snap-in fit, 6.3mm faston tabs, 1mm panel thickness | 1.55 | 1.42 | 1.25 | 1.05 |
| 161-PX0575/15/63 | PX0575/15/63 | E | Snap-in fit, 6.3mm faston tabs, 1.5mm panel thickness | 1.51 | 1.38 | 1.22 | 1.02 |
| 161-PX0580/28 | PX0580/28 | F | Chassis mount, 2.8mm solder tabs | 1.51 | 1.38 | 1.22 | 1.02 |
| 161-PX0580/63 | PX0580/63 | F | Chassis mount, 6.3mm faston tabs | 1.58 | 1.45 | 1.28 | 1.07 |
| 161-PX0580/PC | PX0580/PC | G | PC mount | 1.70 | 1.57 | 1.39 | 1.16 |

IEC 320-1 C20 POWER INLETS

20A, 250VAC, UL and CSA



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|------------------|-----------------|------|--|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-PX0596/63 | PX0596/63 | H | C20 Chassis mount, 6.3mm faston | 2.03 | 1.60 | 1.47 | 1.32 |
| 161-PX0598/15/63 | PX0598/15/63 | I | C20 Snap-in fit, 6.3mm faston, 1.5mm panel thickness | 2.21 | 2.03 | 1.81 | 1.51 |

IEC 320-2-2 POWER OUTLETS

15A, 250VAC, UL and CSA



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|---------------------|-----------------|------|----------------------------------|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-PX0675/28 | PX0675/28 | J | Chassis mount, 2.8mm solder tabs | 1.65 | 1.51 | 1.33 | 1.11 |
| 161-PX0675/63 | PX0675/63 | J | Chassis mount, 6.3mm faston tabs | 1.65 | 1.51 | 1.33 | 1.11 |
| 161-PX0675/PC | PX0675/PC | K | PC mount | 1.74 | 1.60 | 1.42 | 1.18 |
| 161-PX0675/PC/12599 | PC0675/PC/12600 | K | PC mount with rear cover | 3.76 | 3.46 | 3.07 | 2.82 |

IEC 320-2-2 POWER OUTLETS

15A, 250VAC, UL and CSA



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|------------------|-----------------|------|---|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-PX0695/15/28 | PX0695/15/28 | L | Snap-in fit, 2.8mm solder tabs, 1.5mm panel thickness | 1.77 | 1.62 | 1.43 | 1.20 |
| 161-PX0695/15/63 | PX0695/15/63 | L | Snap-in fit, 6.3mm faston tabs, 1.5mm panel thickness | 1.69 | 1.55 | 1.37 | 1.15 |

C14 IEC 320-1 FUSED INLETS

• Fuses sold Separately

Vertical Module Arrangement 10A, 250VAC



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|--------------------|-----------------|------|--|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-BZV01/Z0000/01 | BZV01/Z0000/01 | M | Snap-in fit, SP switch, 6.3mm faston tabs | 7.25 | 6.66 | 5.91 | 4.95 |
| 161-BZV01/Z0000/02 | BZV01/Z0000/02 | M | Snap-in fit, SP red neon switch, 6.3mm faston tabs | 10.02 | 9.20 | 8.18 | 6.83 |
| 161-BZV01/Z0000/10 | BZV01/Z0000/10 | M | Snap-in fit, DP switch, 6.3mm faston tabs | 7.68 | 7.05 | 6.27 | 5.23 |
| 161-BZV01/Z0000/11 | BZV01/Z0000/11 | M | Snap-in fit, DP red neon switch, 6.3mm faston tabs | 10.80 | 9.92 | 8.81 | 7.35 |


Retaining Clip Kit



RoHS Compliant

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | Bulgin Part No. | Fig. | Description | Price Each | | | |
|------------------|-----------------|------|--|------------|------|------|------|
| | | | | 1 | 25 | 50 | 100 |
| 161-KT0006 | KT0006 | N | Fits Bulgin PX0580, PX0590, PX0690, PX0793, & PX0739/1 | 2.73 | 2.51 | 2.23 | 1.86 |
| 161-KT0012 | KT0012 | N | Fits Bulgin PX0596 | 5.67 | 5.20 | 3.44 | 3.33 |

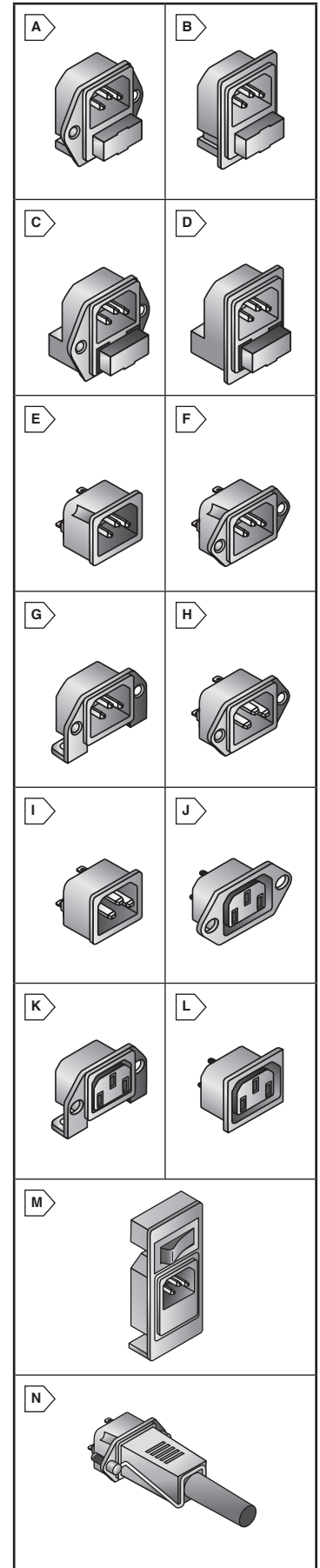

Bulgin AC Power Connectors