


# CORCOM Power Entry Modules



This product is RoHS compliant.

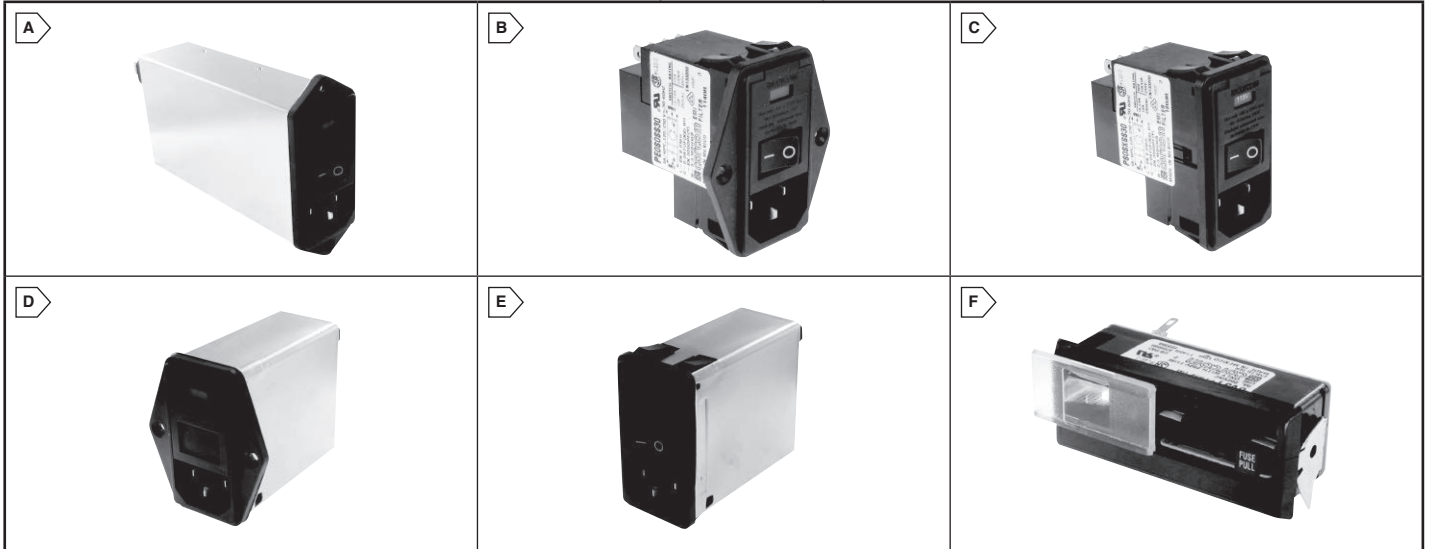

## P SERIES ADAPTABLE POWER ENTRY MODULES

- IEC power line connector
- Both North American and European fusing capabilities
- Optional DPST on/off switch
- Snap in mounting ears, horizontal or vertical



• 5 x 20mm fuse not included

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amps	Filtered	Fused	Switch Function	Voltage Rating	Price Each			
Mfr.	Mfr. Part No.							1	10	25	50
<b>Mounting Ears - Vertical - High Performance/Shield Options: Complete Can</b>											
	592—PM0S0DZ6C	A	6	Yes	Dual	DPST	120, 250 VAC	35.81	35.03	34.08	31.24
	592—PM0S0SZ6C	A	6	Yes	Single	DPST	120, 250 VAC	36.23	34.90	33.96	31.23
	592—PM0S0DZXC	A	10	Yes	Dual	DPST	120, 250 VAC	39.62	39.38	36.62	33.58
	592—PM0S0SZXC	A	10	Yes	Single	DPST	120, 250 VAC	41.61	39.75	37.82	34.74
<b>Medical - Mounting Ears - Vertical - High Performance/Shield Options: Complete Can</b>											
	592—PM0S0DL6C	A	6	Yes	Dual	DPST	120, 250 VAC	41.74	39.60	38.53	35.54
	592—PM0S0SL6C	A	6	Yes	Single	DPST	120, 250 VAC	41.60	37.85	35.01	34.71
	592—PM0S0DLXC	A	10	Yes	Dual	DPST	120, 250 VAC	41.61	37.83	37.30	34.71
	592—PM0S0SLXC	A	10	Yes	Single	DPST	120, 250 VAC	38.48	37.21	35.76	32.79
<b>Mounting Ears - Horizontal</b>											
	592—PE0S0SS30	B	3	Yes	Single	DPST	120, 250 VAC	20.38	18.53	18.13	17.01
	592—PE0S0SS6A	B	6	Yes	Single	DPST	120, 250 VAC	26.41	22.89	22.02	20.37
	592—PE0S0SSX0	B	10	Yes	Single	DPST	120, 250 VAC	19.08	18.78	18.48	18.20
	592—PE0S0DSXB	B	10	Yes	Dual	DPST	120, 250 VAC	28.56	24.73	23.82	21.90
	592—PE0S0SZXC	B	10	Yes	Single	DPST	120, 250 VAC	38.79	36.31	33.15	31.50
	592—PE0S0SSX0	B	10	Yes	Single	DPST	120, 250 VAC	22.03	19.88	19.15	17.57
<b>Medical - Mounting Ears - Horizontal</b>											
	592—PE0S0SH3B	B	3	Yes	Single	DPST	120, 250 VAC	24.93	21.77	21.63	19.82
	592—PE0S0SHXB	B	10	Yes	Single	DPST	120, 250 VAC	27.77	24.27	20.97	18.87
<b>Snap-In</b>											
	592—PS0SXSS30	C	3	Yes	Single	DPST	120, 250 VAC	19.51	18.63	17.75	16.27
	592—PS0SXSS60	C	6	Yes	Single	DPST	120, 250 VAC	20.27	19.91	18.45	17.18
	592—PS0S0SS60	C	6	Yes	Single	DPST	120, 250 VAC	19.54	17.77	16.29	16.00
	592—PS0SXDS6B	C	6	Yes	Dual	DPST	120, 250 VAC	25.20	21.57	21.07	20.41
	592—PS000SSXB	C	10	Yes	Single	None	120, 250 VAC	22.21	20.20	19.86	18.52
	592—PS00XD000	C	10	No	Dual	None	120, 250 VAC	11.53	10.86	10.49	9.63
	592—PS0S0S000	C	10	No	Single	DPST	120, 250 VAC	13.71	12.50	12.47	11.43
	592—PS0S0SBX0	C	10	Yes	Single	DPST	120, 250 VAC	14.46	13.45	12.63	11.73
	592—PS0S0DBX0	C	10	Yes	Dual	DPST	120, 250 VAC	16.84	16.07	15.31	14.09
	592—PS0S0DSXB	C	10	Yes	Dual	DPST	120, 250 VAC	22.45	20.44	19.01	18.19
	592—PS0S0SSXB	C	10	Yes	Single	DPST	120, 250 VAC	24.53	23.43	22.31	20.45
	592—PS0SX0000	C	10	No	Dual	DPST	120, 250 VAC	14.22	13.55	12.93	11.89
	592—PS0SX0000	C	10	No	Single	DPST	120, 250 VAC	14.11	12.84	12.81	11.79
<b>Medium Performance - Mounting Ears - Horizontal</b>											
	592—PE000SM3E	D	3	Yes	Single	None	120V, 250V	32.06	22.90	20.95	20.76
	592—PE000DM6E	D	6	Yes	Dual	None	120V, 250V	35.60	25.42	23.26	23.06
	592—PE0S0DM6E	D	6	Yes	Dual	DPST	120V, 250V	35.60	25.42	23.26	23.06
	592—PE0S0SMXE	D	10	Yes	Single	DPST	120V, 250V	36.14	25.80	23.61	23.40
<b>Medium Performance - Snap In</b>											
	592—PS0S0SM3E	E	3	Yes	Single	DPST	120V, 250V	33.82	24.15	22.10	21.91
	592—PS000SM6E	E	6	Yes	Single	None	120V, 250V	31.94	22.80	20.87	20.68
	592—PS0S0DM6E	E	6	Yes	Dual	DPST	120V, 250V	34.64	24.73	22.63	22.43
	592—PS000DMXE	E	10	Yes	Dual	None	120V, 250V	32.46	23.17	21.21	21.02

## J SERIES - VOLTAGE SELECTING AND FUSED CONNECTOR

6 Amps; 120 - 250 Volts AC; 50-60 Hz

• 5 x 20mm fuse not included

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Amps	Filtered	Filter Typ	Voltage Selection	Price Each			
Mfr.	Mfr. Part No.						1	10	25	50
	592—6VJ1	F	6	No	-	4	18.93	18.06	17.20	15.81
	592—6J4	F	6	Yes	General Purpose	4	29.39	28.93	26.22	24.35