


CORCOM Power Entry Modules



ReHS Compliant This product is RoHS compliant.
DIMENSIONS: in. (mm)

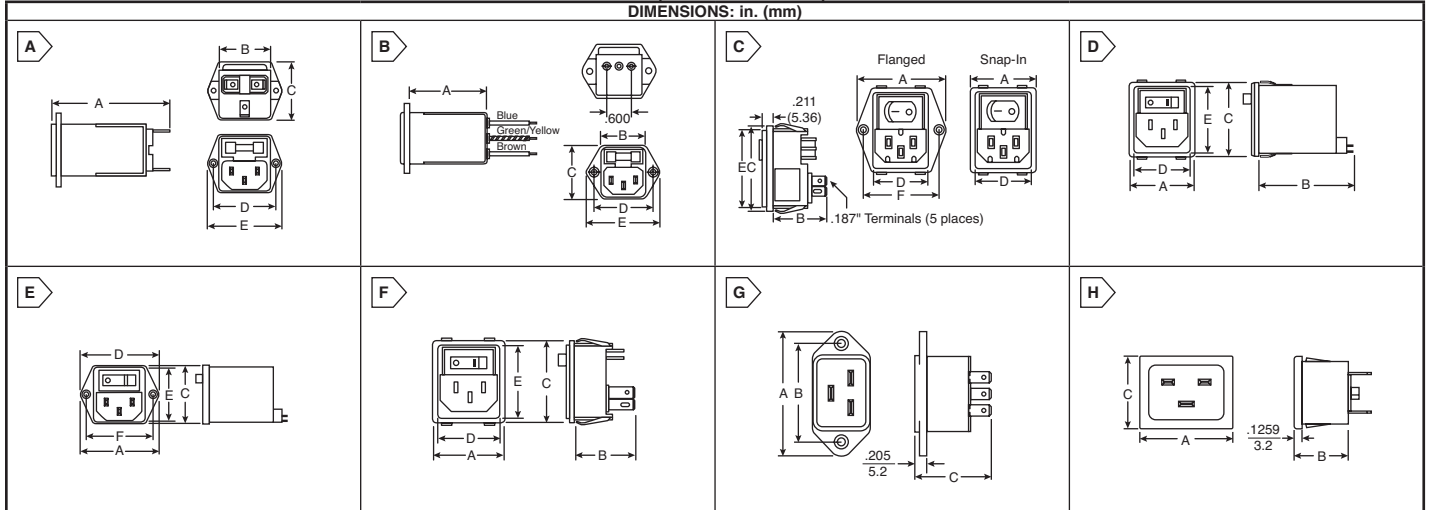

POWER-ENTRY MODULES WITH METRIC FUSE HOLDERS (GG SERIES)

• 5 x 20mm fuse not included

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | | Fig. | Amps | No. of Fuse Holders | Dimensions: in. (mm) | | | | | Price Each | | | |
|------------------|---------------|------|------|---------------------|----------------------|--------------|--------------|--------------|--------------|------------|-------|-------|-------|
| Mfr. | Mfr. Part No. | | | | A | B | C | D | E | 1 | 10 | 25 | 50 |
| 592-1EGG1-2 | | A | 1 | 2 | 1.66 (51.10) | 1.13 (28.70) | 1.29 (32.77) | 1.41 (33.30) | 1.76 (44.70) | 17.08 | 16.15 | 14.90 | 13.85 |
| 592-6EGG1-1 | | A | 6 | 1 | 1.66 (51.10) | 1.13 (28.70) | 1.29 (32.77) | 1.41 (33.30) | 1.76 (44.70) | 12.46 | 11.76 | 10.76 | 9.99 |
| 592-6EGG1-2 | | A | 6 | 2 | 1.66 (51.10) | 1.13 (28.70) | 1.29 (32.77) | 1.41 (33.30) | 1.76 (44.70) | 14.22 | 13.27 | 12.23 | 11.29 |
| 592-6EGG2-2 | | B | 6 | 2 | 2.02 (51.10) | 1.13 (28.70) | 1.29 (32.80) | 1.42 (36.00) | 1.76 (44.70) | 18.24 | 17.50 | 16.59 | 15.23 |
| 592-10EGG1-2 | | A | 10 | 2 | 2.15 (54.61) | 1.13 (28.70) | 1.29 (32.76) | 1.42 (36.06) | 1.76 (44.70) | 16.27 | 14.80 | 14.56 | 13.61 |

C SERIES - POWER ENTRY MODULE WITH IEC CONNECTOR

*Pre-Connected Terminals

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | | Fig. | Amps | Mount Type | Filtered | Dimensions: in. (mm) | | | | | | Price Each | | | |
|------------------|---------------|------|------|------------|----------|----------------------|--------------|--------------|--------------|--------------|--------------|------------|-------|-------|-------|
| Mfr. | Mfr. Part No. | | | | | A (Max.) | B (Max.) | C (Max.) | D | E | F | 1 | 10 | 25 | 50 |
| 592-3CFE1 | | C | 3 | Flange | Yes | 1.74 (44.20) | 2.53 (64.26) | 1.62 (41.17) | 1.12 (28.50) | 1.54 (39.12) | 1.42 (36.00) | 20.45 | 20.08 | 18.28 | 17.27 |
| 592-3CFS1 | | C | 3 | Snap-in | Yes | 1.23 (31.24) | 2.53 (64.26) | 1.62 (41.17) | 1.12 (28.50) | 1.54 (39.12) | --- | 20.30 | 19.14 | 17.65 | 16.35 |
| 592-6CFE1 | | C | 6 | Flange | Yes | 1.74 (44.20) | 2.53 (64.26) | 1.62 (41.17) | 1.12 (28.50) | 1.54 (39.12) | 1.42 (36.00) | 19.85 | 18.67 | 17.26 | 16.00 |
| 592-6CFS1 | | C | 6 | Snap-in | Yes | 1.23 (31.24) | 2.53 (64.26) | 1.62 (41.17) | 1.12 (28.50) | 1.54 (39.12) | --- | 18.92 | 17.83 | 16.46 | 15.27 |
| 592-10CE1 | | C | 10 | Flange | No | 1.74 (44.20) | 0.97 (24.64) | 1.62 (41.17) | 1.06 (26.92) | 1.54 (39.12) | 1.42 (36.00) | 7.25 | 6.64 | 6.58 | 6.02 |
| 592-10CFE1 | | C | 10 | Flange | Yes | 1.74 (44.20) | 2.53 (64.26) | 1.62 (41.17) | 1.12 (28.50) | 1.54 (39.12) | 1.42 (36.00) | 19.47 | 17.82 | 16.47 | 15.31 |
| 592-10CFS1 | | C | 10 | Snap-in | Yes | 1.23 (31.24) | 2.53 (64.26) | 1.62 (41.17) | 1.12 (28.50) | 1.54 (39.12) | --- | 19.70 | 18.04 | 16.70 | 15.44 |
| 592-10CS1 | | C | 10 | Snap-in | No | 1.23 (31.24) | 0.97 (24.64) | 1.62 (41.17) | 1.06 (26.92) | 1.54 (39.12) | --- | 7.19 | 6.88 | 6.57 | 6.01 |
| 592-15CBS1 | | C | 15 | Snap-in | No | 1.23 (31.24) | 0.97 (24.64) | 1.62 (41.17) | 1.06 (26.92) | 1.54 (39.12) | --- | 8.28 | 7.61 | 7.14 | 6.72 |
| * 592-15CE1 | | C | 15 | Flange | No | 1.74 (44.20) | 0.97 (24.64) | 1.62 (41.17) | 1.06 (26.92) | 1.54 (39.12) | 1.42 (36.00) | 7.54 | 7.06 | 6.56 | 6.10 |
| * 592-15CE1 | | C | 15 | Flange | No | 1.74 (44.20) | 0.97 (24.64) | 1.62 (41.17) | 1.06 (26.92) | 1.54 (39.12) | 1.42 (36.00) | 8.28 | 7.61 | 7.14 | 6.72 |

CU SERIES

Specifications:

- Filling the need for smaller versions of Corcom's Switched inlet filters.
- Compact 1U height (1 3/4")
- Provides complete shielding, shrouded quick connect terminals and basic filtering for 1A-15A applications

* Pre-Connected Terminals

For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | | Fig. | Amps | Mount Type | Filtered | Dimensions: in. (mm) | | | | | | Price Each | | | |
|------------------|---------------|------|------|------------|----------|----------------------|--------------|--------------|--------------|--------------|--------------|------------|-------|-------|-------|
| Mfr. | Mfr. Part No. | | | | | A (Max.) | B (Max.) | C (Max.) | D | E | F | 1 | 10 | 25 | 50 |
| 592-1CUFS1 | | D | 1 | Snap-In | Yes | 1.20 (30.60) | 1.80 (45.00) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (32.00) | --- | 25.48 | 24.40 | 23.18 | 21.29 |
| 592-3CUFS1 | | D | 3 | Snap-In | Yes | 1.20 (30.60) | 1.80 (45.00) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (32.00) | --- | 22.28 | 20.23 | 18.55 | 17.45 |
| 592-3CUFF1 | | E | 3 | Flange | Yes | 1.70 (43.10) | 1.80 (45.00) | 1.34 (34.10) | 1.21 (30.80) | 1.35 (34.30) | 1.45 (36.80) | 23.65 | 21.47 | 19.68 | 18.53 |
| 592-3CUFE1 | | E | 3 | Flange | Yes | 1.73 (43.90) | 1.75 (44.50) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (31.90) | 1.45 (36.80) | 22.41 | 21.03 | 20.14 | 18.91 |
| 592-6CUFS1 | | D | 6 | Snap-In | Yes | 1.20 (30.60) | 1.80 (45.00) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (32.00) | --- | 20.92 | 19.01 | 17.42 | 16.40 |
| 592-6CUFF1 | | E | 6 | Flange | Yes | 1.70 (43.10) | 1.80 (45.00) | 1.34 (34.10) | 1.21 (30.80) | 1.35 (34.30) | 1.45 (36.80) | 22.70 | 21.04 | 19.28 | 18.16 |
| 592-6CUFE1 | | E | 6 | Flange | Yes | 1.73 (43.90) | 1.75 (44.50) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (31.90) | 1.45 (36.80) | 20.61 | 18.96 | 17.37 | 16.21 |
| 592-10CUFS1 | | D | 10 | Snap-In | Yes | 1.20 (30.60) | 1.80 (45.00) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (32.00) | --- | 24.93 | 23.78 | 22.64 | 20.98 |
| 592-10CUFF1 | | E | 10 | Flange | Yes | 1.70 (43.10) | 1.80 (45.00) | 1.34 (34.10) | 1.21 (30.80) | 1.35 (34.30) | 1.45 (36.80) | 25.70 | 23.63 | 21.34 | 19.93 |
| 592-10CUFE1 | | E | 10 | Flange | Yes | 1.73 (43.90) | 1.75 (44.50) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (31.90) | 1.45 (36.80) | 22.39 | 20.57 | 18.87 | 17.62 |
| 592-15CUFF1 | | E | 15 | Flange | Yes | 1.70 (43.10) | 1.80 (45.00) | 1.34 (34.10) | 1.21 (30.80) | 1.35 (34.30) | 1.45 (36.80) | 27.60 | 25.50 | 23.39 | 22.00 |
| 592-15CUFE1 | | E | 15 | Flange | Yes | 1.73 (43.90) | 1.75 (44.50) | 1.34 (34.10) | 1.11 (28.10) | 1.26 (31.90) | 1.45 (36.80) | 22.67 | 20.58 | 18.88 | 17.76 |
| 592-15CUE1 | | F | 15 | Snap-In | No | 1.73 (43.90) | 0.96 (24.60) | 1.34 (34.10) | 1.06 (26.90) | 1.09 (27.60) | --- | 12.27 | 11.39 | 10.29 | 9.97 |
| 592-15CUBS1 | | D | 15 | Snap-In | No | 1.20 (30.60) | 0.97 (24.60) | 1.34 (34.10) | 1.04 (26.40) | 1.26 (32.00) | --- | 8.03 | 7.30 | 6.69 | 6.30 |
| * 592-15CUBE1 | | E | 15 | Flange | No | 1.73 (43.90) | 0.96 (24.60) | 1.34 (34.10) | 1.06 (26.90) | 1.09 (27.60) | 1.45 (36.80) | 11.46 | 10.41 | 9.54 | 8.99 |
| 592-15CU1S1 | | F | 15 | Snap-In | No | 1.20 (30.60) | 0.97 (24.60) | 1.34 (34.10) | 1.05 (26.70) | 1.24 (31.60) | --- | 11.85 | 10.99 | 9.94 | 9.62 |
| 592-15CU10S1 | | F | 15 | Snap-In | No | 1.20 (30.60) | 0.97 (24.60) | 1.34 (34.10) | 1.05 (26.70) | 1.24 (31.60) | --- | 7.66 | 6.59 | 6.04 | 5.69 |

SR SERIES 20A POWER INLET CONNECTORS

20 Amps; 120 - 250 Volts AC



For quantities greater than listed, call for quote.

| MOUSER STOCK NO. | | Fig. | Amps | Mount Type | Dimensions: in. (mm) | | | Price Each | | | |
|------------------|---------------|------|------|------------|----------------------|---------------|--------------|------------|------|------|------|
| Mfr. | Mfr. Part No. | | | | A (Max.) | B (Max.) | C (Max.) | 1 | 10 | 25 | 50 |
| 592-20ESRM-3 | | G | 20 | Flange | 2.087 (53.00) | 1.653 (42.00) | .999 (25.40) | 3.02 | 2.93 | 2.80 | 2.51 |
| 592-20ESRM-2 | | H | 20 | Snap-In | 1.377 (35.00) | .921 (23.40) | 1.06 (27.00) | 3.00 | 2.79 | 2.61 | 2.56 |

TE Connectivity AC Power Connectors