


# TE Power Entry Modules



## EEA SERIES FILTERS

• 1 to 10 Amps; 120/250 Volts AC; 50/60Hz

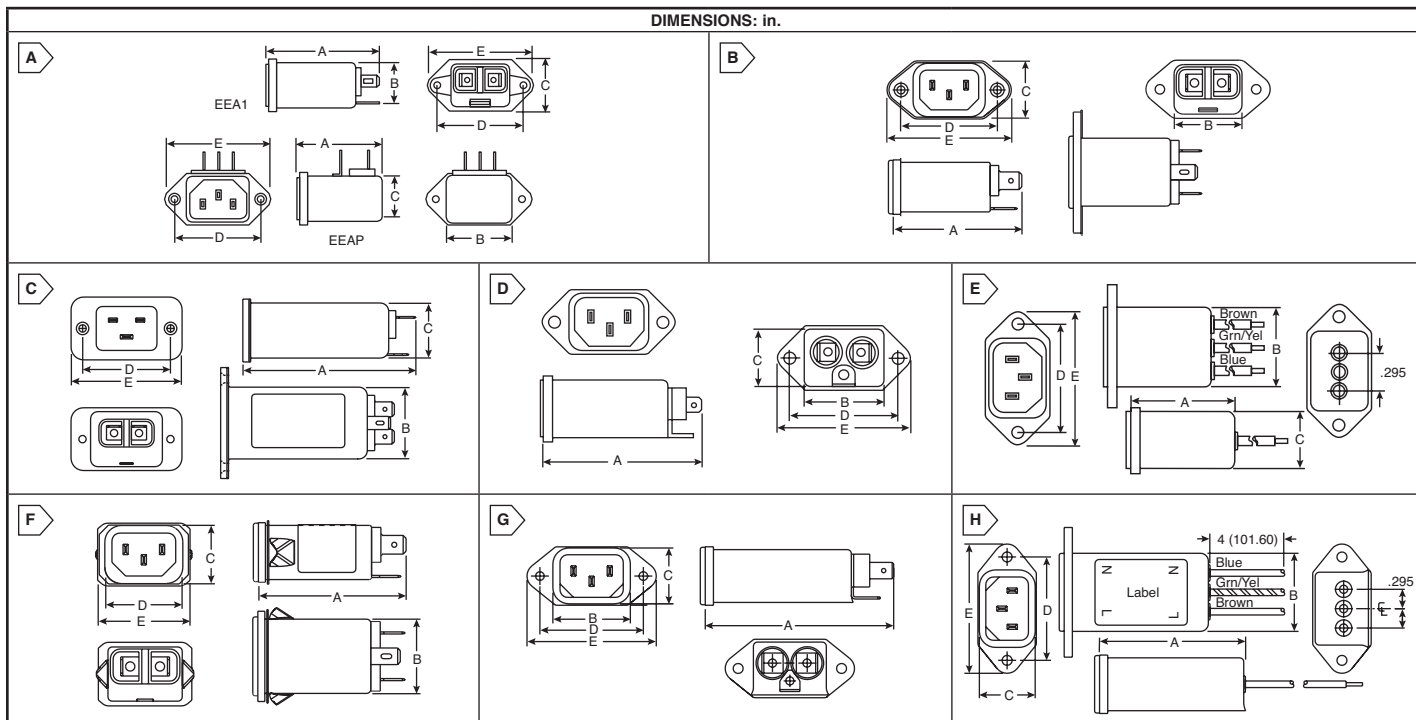

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-3EEA1	3EEA1	A	3	2.15 (53.8)	1.11 (28.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	9.22	8.67	7.98	7.42
592-6EEA1	6EEA1	A	6	2.15 (53.8)	1.11 (28.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	9.04	8.53	7.75	7.26
592-6EEAP	6EEAP	A	6	1.54 (39.2)	1.11 (28.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	10.10	9.54	8.74	8.11
592-10EEA1	10EEA1	A	10	2.15 (53.8)	1.11 (28.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	9.38	8.84	8.15	7.52

## EEJ SERIES Enhanced Performance Compact RFI Filter IEC Connector Package

• 3 to 20 Amps; 120/250 Volts AC; 50/60Hz



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-3EEJ1	3EEJ1	B	3	2.15 (54.61)	1.13 (28.7)	0.96 (24.38)	1.58 (40.00)	2.04 (51.76)	7.62	7.27	6.85	6.40
592-6EEJ1	6EEJ1	B	6	2.15 (54.61)	1.13 (28.7)	0.96 (24.38)	1.58 (40.00)	2.04 (51.76)	7.04	6.55	6.09	5.70
592-15EEJ1	15EEJ1	B	15	2.15 (54.61)	1.13 (28.7)	0.96 (24.38)	1.58 (40.00)	2.04 (51.76)	7.61	7.10	6.61	5.93
592-20EEJ1	20EEJ1	C	20	3.13 (79.38)	1.37 (34.79)	1.18 (29.99)	1.65 (42.01)	2.09 (53.00)	12.02	11.64	11.10	10.19

## EEF SERIES Compact RFI Filter with IEC Connectors

• 1 to 10 Amps; 120/250 Volts AC; 50-60Hz



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-1EF1F	1EF1F	D	1	2.20 (55.9)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	12.85	12.20	11.68	10.69
592-3EF1F	3EF1F	D	3	2.20 (55.9)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	10.74	10.63	9.98	9.24
592-6EF1	6EF1	D	6	2.20 (55.9)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	14.13	13.51	12.85	11.79
592-6EF1F	6EF1F	D	6	2.20 (55.9)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	11.48	10.62	10.03	9.29
592-6EF8	6EF8	E	6	1.55 (39.4)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	11.03	10.28	10.01	9.28
592-10EF1F	10EF1F	D	10	2.62 (66.5)	1.19 (30.2)	0.81 (20.6)	1.575 (40.01)	1.98 (50.3)	11.08	11.00	10.15	9.40

## EJS SERIES Enhanced Performance Snap-In Compact RFI Filter IEC Connector Package

• 3 to 15 Amps; 120/250 Volts AC; 50-60Hz



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-15EJS1	15EJS1	F	15	2.20 (55.88)	1.10 (27.94)	0.96 (24.38)	1.19 (30.10)	1.35 (34.21)	8.83	8.18	7.64	7.11

## EJT SERIES Compact RFI Filters with IEC Connector for Higher Frequency Applications

• 3 to 15 Amps; 120/250 Volts AC; 50-60Hz \* Wire leads



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Amps	Dimensions: in. (mm)					Price Each			
				A	B	C	D	E	1	10	25	50
592-6EJT1	6EJT1	G	6	2.87 (72.9)	1.19 (30.2)	0.875 (22.2)	1.575 (40.0)	1.98 (50.3)	14.19	13.26	12.54	11.47
592-10EJT1	10EJT1	G	10	2.87 (72.9)	1.19 (30.2)	0.875 (22.2)	1.575 (40.0)	1.98 (50.3)	14.20	13.77	13.05	11.98
592-15EJT1	15EJT1	G	15	2.87 (72.9)	1.19 (30.2)	0.875 (22.2)	1.575 (40.0)	1.98 (50.3)	16.16	15.06	14.00	13.13
* 592-15EJT8	15EJT8	H	15	2.23 (56.6)	1.19 (30.2)	0.875 (22.2)	1.575 (40.0)	1.98 (50.3)	15.75	14.58	13.65	12.83