


# SCHURTER Power Entry Modules

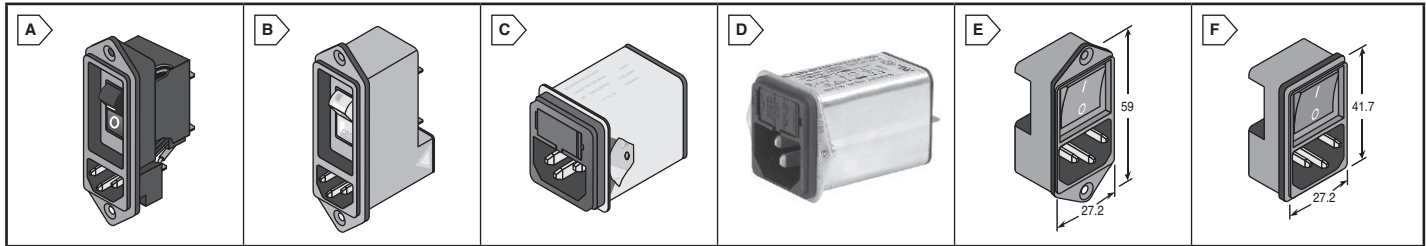

## SCHURTER DF11 SERIES POWER ENTRY MODULES

### Specifications:

- Two functions: Inlet protection Class I, fuseholder circuit breaker type TA45 2-pole
- Qualified for use in equipment according IEC/EN 60950
- Rating: IEC 10A @ 250VAC, 60Hz; UL/CSA 1-15A @ 250VAC, 60Hz
- Housing material: Thermoplastic, black, UL 94V-0
- Panel mount
- Quick connect terminals 6.3 x 0.8mm
- Thermal overload protection



\* Embossed Legend

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Protected Poles	Rated Current	Panel Thickness	Rocker Color	Rocker Legend	Price Each			
								1	25	50	100
693-DF111089001001	DF11.1089.0010.01	A	2	15 A	Screw terminals	Black	I-O Vertical	29.44	26.16	23.55	22.24
693-DF111089001002	DF11.1089.0010.02	A	2	15 A	Screw terminals	Black	I-O Vertical	28.29	25.36	22.98	21.63
693-DF111477001202	DF11.1477.0012.02	A	1	10 A	1.5mm	Black	ON-OFF Vertical	30.44	27.06	24.37	23.01
693-DF112078001001	DF11.2078.0010.01	A	2	10 A	Screw terminals	Black	ON-OFF Vertical	27.66	24.80	22.47	21.15
693-DF11217300101	DF11.2173.0012.01	A	1	10 A	1.5mm	Black	* I-O Vertical	30.44	27.06	24.37	23.01

Schurter AC Power Connectors

## SCHURTER DF12 SERIES POWER ENTRY MODULES WITH LINE FILTER

### Specifications:

- Three functions: Inlet protection Class I, fuseholder circuit breaker type TA45 2-pole, line filter in standard and medical version
- Qualified for use in equipment according IEC/EN 60950
- Rating: IEC 10 A @ Ta 40°C / 250VAC, 50Hz; UL/CSA 1-15A @ Ta 40°C / 250VAC, 60Hz
- Panel Mount
- Screw terminals
- Thermal overload protection
- Housing material: Thermoplastic, black, UL 94V-0



\* Embossed Legend

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Protected Poles	Rated Current	Rocker Color	Rocker Legend	Leakage Current	Price Each			
								1	25	50	100
693-DF12003191101	DF12.0031.9110.1	B	1	15 A	White	* I-O Vertical	Standard	53.24	47.32	42.60	40.24
693-DF12003193101	DF12.0031.9310.1	B	1	15 A	White	* I-O Vertical	Medical	57.23	50.86	45.79	43.25
693-DF12047073101	DF12.0470.7310.1	B	2	10 A	White	* I-O Vertical	Medical	62.76	58.18	55.73	51.01
693-DF12047093101	DF12.0470.9310.1	B	2	10 A	White	* I-O Vertical	Medical	52.57	46.73	42.05	39.71
693-DF12058651101	DF12.0586.5110.1	B	1	5 A	White	* I-O Vertical	Standard	47.33	42.07	37.87	35.77
693-DF12084753101	DF12.0847.5310.1	B	2	5 A	White	* I-O Vertical	Medical	63.57	56.51	50.84	48.01
693-DF12088591101	DF12.0885.9110.1	B	2	15 A	White	* I-O Vertical	Standard	46.71	40.26	35.93	34.34
693-DF12088593101	DF12.0885.9310.1	B	2	15 A	White	* I-O Vertical	Medical	56.51	50.23	45.20	42.68
693-DF12089093101	DF12.0890.9310.1	B	2	15 A	White	I-O Vertical	Medical	46.71	40.26	35.93	34.34
693-DF12135641101	DF12.1356.4110.1	B	2	4 A	White	* I-O Vertical	Standard	52.57	46.73	42.05	39.71
693-DF12159373101	DF12.1593.7310.1	B	2	8 A	White	I-O Vertical	Medical	63.57	56.51	50.84	48.01
693-DF12277091101	DF12.2770.9110.1	B	1	15 A	Black	ON-OFF Vertical	Standard	57.23	50.86	45.79	43.25
693-DF12285191101	DF12.2851.9110.1	B	2	15 A	Orange	* I-O Vertical	Standard	67.76	60.23	54.21	51.21
693-DF12300093101	DF12.3000.9310.1	B	1	15 A	Black	* I-O Vertical	Medical	57.23	50.86	45.79	43.25

## SCHURTER KFA SERIES POWER ENTRY MODULES WITH LINE FILTER

### Specifications:

- Three functions: Inlet protection Class I, fuseholder circuit breaker type TA45 2-pole, line filter in standard and medical version
- Qualified for use in equipment according IEC/EN 60950
- Rating: IEC 10 A @ Ta 40°C / 250VAC, 50Hz; UL/CSA 1-15A @ Ta 40°C / 250VAC, 60Hz
- Housing material: Thermoplastic, black, UL 94V-0
- Panel Mount
- Screw terminals
- Thermal overload protection
- Fuse drawers are not included



### Front Mount With Standard Filter

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Rated Current	Fuseholder	Price Each			
					1	25	50	100
693-4301.6012	4301.6012	C	2 A	1 pole	28.23	23.66	21.04	19.46
693-4301.6013	4301.6013	C	4 A	1 pole	28.58	25.40	22.85	21.59
693-4301.6014	4301.6014	C	6 A	1 pole	28.58	25.40	22.85	21.59
693-4301.6015	4301.6015	C	10 A	1 pole	28.58	25.40	22.85	21.59
693-4301.6004	4301.6004	C	6 A	2 pole	28.85	25.62	23.06	21.78

### Front Mount With Medical Filter

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Rated Current	Fuseholder	Price Each			
					1	25	50	100
693-4301.6201	4301.6201	C	1 A	2 pole	40.05	35.60	32.04	30.26
693-4301.6203	4301.6203	C	2 A	2 pole	40.05	35.60	32.04	30.26
693-4301.6205	4301.6205	C	4 A	2 pole	40.05	35.60	32.04	30.26

### Rear Mount With Metal Flange and Standard Filter

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Rated Current	Fuseholder	Price Each			
					1	25	50	100
693-4301.7001	4301.7001	D	1 A	2 pole	29.02	25.65	23.08	21.79
693-4301.7002	4301.7002	D	2 A	2 pole	29.02	25.65	23.08	21.79
693-4301.7003	4301.7003	D	4 A	2 pole	29.02	25.65	23.08	21.79
693-4301.7004	4301.7004	D	6 A	2 pole	29.02	25.65	23.08	21.79
693-4301.7005	4301.7005	D	10 A	2 pole	30.53	24.42	21.98	20.75

## SCHURTER KEB SERIES: AC INLETS WITH LINE SWITCH FOR PANEL MOUNT

### Specifications:

- For "cold" connections 65°C
- Class I level of protection (with ground terminal); IEC320/C14
- Rating: UL/CSA/VDE - 10A/250V
- SPST or DPST switch (On-Off)
- Terminals: .187" quick connect
- Screw mount from front or rear, snap-in from front



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Schurter Part No.	Fig.	Panel Thickness	No. of Poles (Switch)	Mounting Type	Price Each			
						1	25	50	100
693-4302.2001	4302.2001	E	6mm max.	2	Screw-on	11.31	10.14	9.19	8.65
693-4302.2002	4302.2002	F	2.0mm	2	Snap-in	11.87	10.64	9.64	9.08
<b>Accessories for KEB</b>									
693-0859.0075	0859.0075	--			Insulation cover, flexible plastic PVC, for 2-pole KEB	2.54	2.21	2.09	1.91
693-0888.0004	0888.0004	--			Cord retaining clamp for screw-on KEB	7.73	6.88	6.20	5.85