

KOBICONN DC Power and Custom Molding Plugs KOBICONN

DC POWER PLUGS

.7mm Solder Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-3218-EX	A	Barrel 0.7mm x 2.35mm x 9.5mm, black, 2A@3.15VDC	1.85	1.42	1.29	1.17
171-3118-EX	B	Barrel 0.7mm x 2.35mm x 9.5mm, R/A black, 2A@3.15VDC	1.85	1.42	1.29	1.17

1.3mm Solder Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-3209	C	Barrel 1.3mm x 3.5mm x 9.1mm, blk locking detent, 1A@12VDC	1.46	1.12	1.02	.93
171-3224-EX	D	Barrel 1.3mm x 3.4mm x 9mm, blk lkg detent R/A, 0.5A@12VDC works best with 163-4013	1.66	1.28	1.16	1.05
171-PA35135-E	A	Barrel 1.3mm x 3.5mm x 9.1mm, black w/relief, 0.5A@12VDC	1.26	.97	.88	.80
171-PA35135-1-E	E	Barrel 1.3mm x 3.5mm x 9.1mm, black, 0.5A@12VDC	1.14	.88	.84	.80
171-PP200-EX	E	Barrel 1.3mm x 3.4mm x 9mm, black, 0.5A@12VDC	1.61	1.24	1.13	1.03
171-3210-E	A	Barrel 1.3mm x 3.4mm x 8.9mm, black w/ relief, 2A@12VDC	1.61	1.24	1.13	1.03

1.4mm Male DC Power Plug

• Mates with most laptop computers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-6014-E	F	Barrel 1.4mm x 3.4mm x 6.5mm x 9mm, black, 5A@18VDC, use with 163-1203-E	1.27	.98	.93	.89

1.7mm Solder Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-3219-EX	A	Barrel 1.7mm x 4.0mm x 9.5mm, black, 2A@3.15V-6.3VDC	1.66	1.28	1.16	1.05
171-3220-EX	A	Barrel 1.7mm x 4.75mm x 9.5mm, black, 2A@6.3V-10.5VDC	1.66	1.28	1.16	1.05
171-3221-EX	B	Barrel 1.7mm x 4.0mm x 9.5mm R/A black, 2A@6.3VDC	1.79	1.38	1.25	1.14
171-3222-EX	B	Barrel 1.7mm x 4.75mm x 9.5mm R/A black, 2A@10.5VDC	1.79	1.38	1.25	1.14

2.1mm Solder Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-PA5521-1-E	G	Barrel 2.1mm x 5.5mm x 9.9mm, black, 0.5A@12VDC	1.26	.97	.88	.80
171-2122-EX	G	Barrel 2.1mm x 5.5mm x 14.0mm, gray, 0.5A@12VDC	1.11	.85	.77	.70
1710-2110	G	Barrel 2.1mm x 5.5mm x 9.5mm, black, 1.5A@24VDC	1.28	.85	.77	.70
171-PA5521A-1-E	G	Barrel 2.1mm x 5.5mm x 14.0mm, black, 2.A@12VDC	1.26	.97	.88	.80
171-PA5521-1GY-E	G	Barrel 2.1mm x 5.5mm x 9.5mm, gray, 1.5A@24VDC	1.39	1.07	1.02	.93
171-PA5521B-1-E	H	Barrel 2.1mm x 5.5mm x 9.5mm black locking, 1A@50VDC	1.40	1.08	.98	.89
171-3215-EX	I	Barrel 2.1mm x 5.5mm x 9.5mm, R/A black, 0.5A@12VDC	1.14	.88	.80	.73
171-3217-EX	A	Barrel 2.1mm x 5.5mm x 9.5mm, black w/ relief, 0.5A@12VDC	1.46	1.12	1.02	.93
171-PA5521-E	A	Barrel 2.1mm x 5.5mm x 9.5mm, black w/ relief, 1A@50VDC	1.26	.97	.88	.80
171-0721-EX	J	Locking, 1A @ 12VDC, use with 161-0721-EX and 163-1000-EX only	2.08	1.60	1.45	1.32
171-7391	K	Ring lock, Barrel 2.1mm x 5.5mm x 9.5mm use/w 163-7421	5.28	4.06	3.69	3.35

2.5mm Solder Terminals

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-PA5525-1-E	G	Barrel 2.5mm x 5.5mm x 9.9mm, black, 0.5A@12VDC	1.14	.88	.84	.80
1710-2510	H	Barrel 2.5mm x 5.5mm x 9.5mm black, 1.5A@24VDC	1.28	.85	.77	.70
1710-2511	H	Barrel 2.5mm x 5.5mm x 9.5mm, gray, 1.5A@24VDC	1.28	.85	.77	.70
171-PA5525B-1-E	H	Barrel 2.5mm x 5.5mm x 9.5mm black locking, 1A@50VDC	1.40	1.08	.98	.89
171-PA5525A-1-E	G	Barrel 2.5mm x 5.5mm x 14.0mm, black, 0.5A@12VDC	1.26	.97	.88	.80
171-3216-EX	I	Barrel 2.5mm x 5.5mm x 9.5mm, R/A black, 0.5A@12VDC	1.14	.88	.80	.73
171-0702-EX	A	Barrel 2.5mm x 5.5mm x 9.5mm, black w/ relief, 1A@12VDC	1.66	1.28	1.16	1.05
171-PA5525-E	A	Barrel 2.5mm x 5.5mm x 9.5mm, black w/ relief, 1A@50VDC	1.26	.97	.88	.80
171-0725-EX	J	Locking, 1A @ 12VDC, use with 161-0725-E and 163-1100-EX only	2.08	1.60	1.45	1.32
171-7395	K	Ring lock, Barrel 2.5mm x 5.5mm x 9.5mm use/w 163-7425	5.28	4.06	3.69	3.35

CUSTOM MOLDING PLUGS

• Nickel plated brass contacts
• Ideal for molding to your cable

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Price Each			
			1	10	100	500
171-0726-E	L	Locking, 1.0A@ 12VDC, use with 161-0725-E and 163-1100-EX only	.79	.61	.55	.50

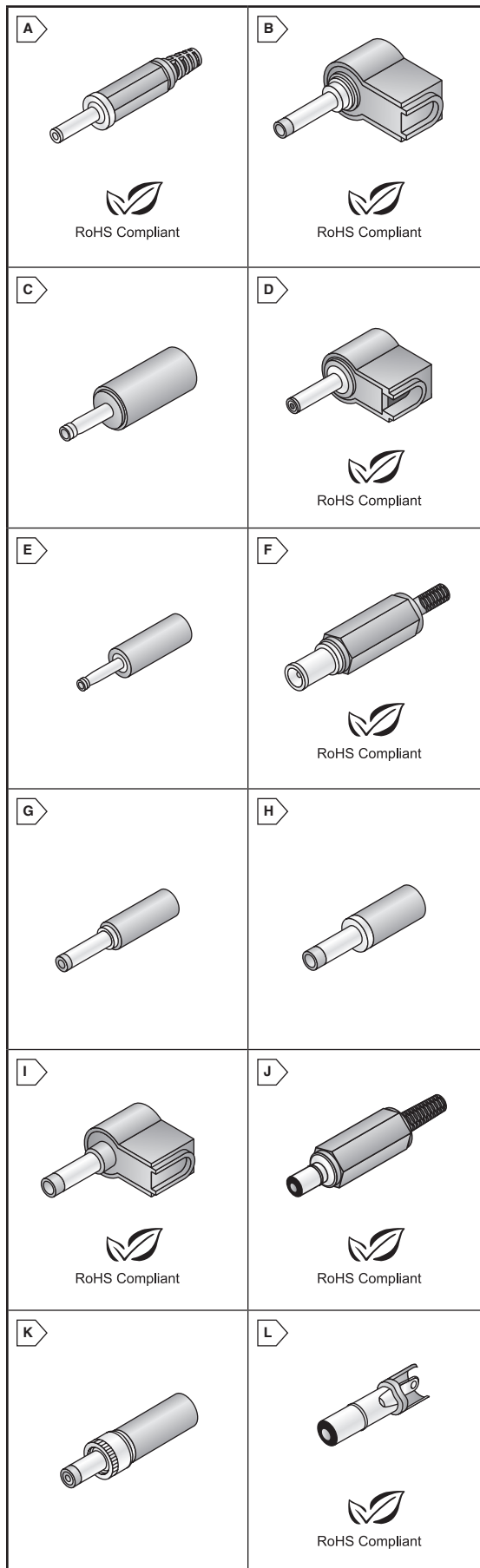

DC Power Connectors
Kobiconn