


DC Power Jacks

RoHS Compliant This product is RoHS compliant.

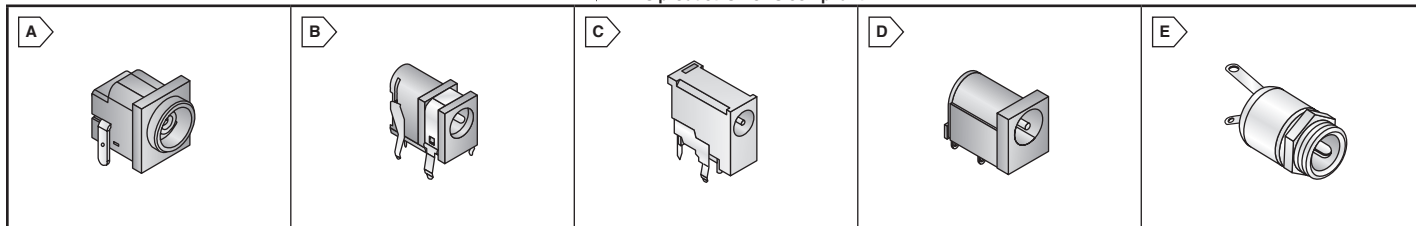


KOBI CONN PC MOUNT DC POWER JACKS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Voltage Rating	Current Rating	Mating/Plg. O.D. (mm)	Center Pin (mm)		Price Each			
						D	L	1	10	100	500
1.3mm											
163-1203-E	A	Black with NC switch	18VDC	2A	3.40	1.40	9.00	.87	.58	.53	.48
1.7mm											
163-4310-E	B	Molded snap mount with NC switch	6.3VDC	2A	4.00	1.65	8.50	1.66	1.28	1.16	1.05
163-4119-E	C	Molded NC switch, yellow	10.5VDC	2A	4.75	1.65	10.50	1.44	1.11	1.01	.92
2.1mm											
163-7620-E	D	Molded with NC switch	18VDC	1.5A	5.50	2.00	8.00	.63	.42	.38	.35
163-179PH-EX	D	Molded with NC switch	18VDC	1.5A	5.50	1.95	8.00	1.04	.80	.73	.66
163-7421	E	Positive ring lock use with 171-7391	3.15-13.5VDC	2A	5.50	2.00	- - -	6.40	4.92	4.47	4.06
2.5mm											
163-7625-E	D	Molded with NC switch	18VDC	1.5A	5.50	2.35	8.00	.64	.45	.41	.37
163-180PH-EX	D	Molded with NC switch	18VDC	1.5A	5.50	2.35	8.00	1.04	.80	.73	.66

DC Power Connectors

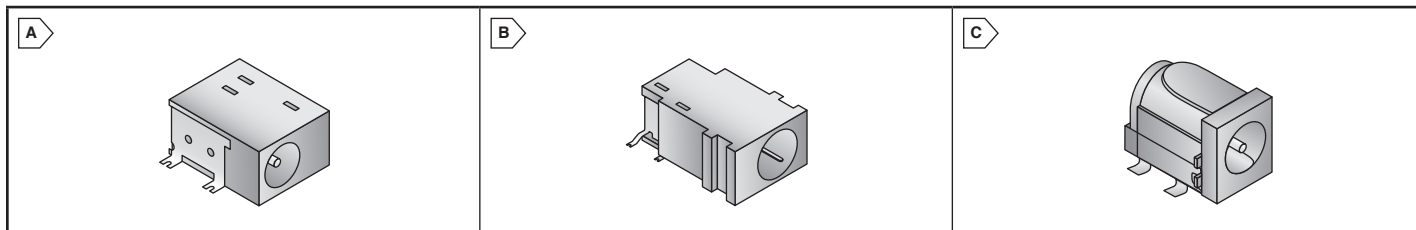

KOBI CONN SURFACE MOUNT DC POWER JACKS

- NC Switch, Black
- Operating Temperature: -25°C to +70°C
- Contact Resistance: 50mΩ Max.
- Nickel plated brass contacts
- Operating Life: 5000 cycles min.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Description	Voltage Rating	Current Rating	Mating/Plg. O.D. (mm)	Center Pin (mm)		Price Each			
						D	L	1	10	100	500
1.3mm											
* 163-7625-E	A	Molded with NC switch	18VDC	1.5A	5.50	2.35	8.00	.64	.45	.41	.37
1.7mm											
* 163-2217-E	B	SMT jack with Black NC Switch	12VDC	1A	5.20	1.60	8.50	.96	.641	.586	.53
2.1mm											
163-0179-EX	C	SMT jack with Black NC Switch	24VDC	3.5A	5.50	2.00	8.00	1.56	1.20	1.09	.99
2.5mm											
163-0180-EX	C	SMT jack with Black NC Switch	24VDC	3.5A	5.50	2.35	8.00	1.56	1.20	1.09	.99

*Available on tape and reel as special order. Add /TR to end of P/N.

KYCON HIGH CURRENT DC POWER JACKS

KYCON



PRODUCT NEW

Features:

- 2.0mm and 2.5mm
- Built in DC On/Off Switch
- PBT Thermoplastic, UL 94V-0 Rated, Color Black
- Rated Current : 5A
- Rated Voltage : 16VRMS

Applications:

- 250VDC: High frequency and
- Laptop and Palm Computers
- Portable Modems
- Radar Detectors
- Portable Device Applications

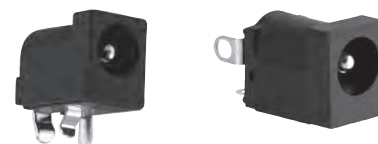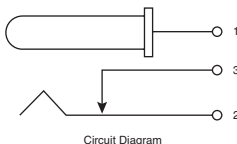

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Kycon Part No.	Inner Pin (mm)	Lead Stylet	Locking	Price Each			
					1	25	100	500
Right Angle								
806-KLDHCX-0202-A	KLDHCX-0202-A	2.0	Straight	No	.89	.809	.746	.701
806-KLDHCX-0202-AC	KLDHCX-0202-AC	2.0	Crimped	No	.89	.809	.746	.701
806-KLDHCX-0202-A-LT	KLDHCX-0202-A-LT	2.0	Straight	Yes	1.18	1.08	.992	.931
806-KLDHCX-0202-B	KLDHCX-0202-B	2.5	Straight	No	.89	.809	.746	.701
806-KLDHCX-0202-BC	KLDHCX-0202-BC	2.5	Crimped	No	.89	.809	.746	.701
806-KLDHCX-0202-B-LT	KLDHCX-0202-B-LT	2.5	Straight	Yes	1.18	1.08	.992	.931
Straight								
806-KLDVHCX-0202-A	KLDVHCX-0202-A	2.0	Straight	No	.68	.62	.57	.53
806-KLDVHCX-0202-B	KLDVHCX-0202-B	2.5	Straight	No	.68	.62	.57	.53