

BOMAR Between Series Adapters and RF Connectors



RoHS Compliant This product is RoHS compliant.

HIGH DENSITY BNC JACK



MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	5	10	25
678-361EHD704	361EHD704	A	End Launch Jack, E-Snap	6.15	5.62	5.17	4.79

BETWEEN SERIES ADAPTERS


Between series adapters solve a variety of connection problems where connectors of different types could ordinarily not be mated together. Each adapter has a different type coupling at each end allowing for a wide variety of interconnections to fit almost all interconnection situations. All adapters are constructed of machined brass and are nickel plated.

- RoHS Compliant per Bomar documentation
- * Plating: Tri-plate, a copper alloy composed of three components: 55% copper, 25% tin, and 20% zinc

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	10	25	50
Type N Adapters							
678-1303505	1303505	B	N Plug to BNC Plug	25.87	25.00	23.51	22.70
678-1313505	1313505	C	N Plug to BNC Jack	15.15	14.26	13.86	13.09
678-1307505	1307505	D	N Plug to UHF Plug	32.67	30.04	27.80	25.87
678-1317505	1317505	E	N Plug to UHF Jack	16.52	15.02	14.50	13.32
678-1308505	1308505	F	N Plug to F Plug	10.33	9.40	8.81	8.09
678-1318505	1318505	G	N Plug to F Jack	13.19	12.42	11.82	11.45
678-1309505	1309505	H	N Plug to SMA Plug	36.58	33.26	32.09	29.83
678-1319505	1319505	I	N Plug to SMA Jack	13.06	12.08	11.58	10.90
* 678-131150011	131150011	J	N Plug to 7/16 Jack	33.92	32.98	31.86	30.97
* 678-153115011	153115011	K	N Plug to 7/16 Plug	41.07	39.70	37.33	36.59
678-1323505	1323505	L	N Jack to BNC Jack	16.45	15.59	14.66	14.09
678-1327505	1327505	M	N Jack to UHF Jack	13.89	13.07	12.58	11.97
678-1329505	1329505	N	N Jack to SMA Jack	67.90	64.30	60.86	58.75
678-1325505	1325505	O	N Jack to TNC Jack	22.79	20.71	20.50	18.95
678-6311505	6311505	P	N Jack to Mini-UHF Plug	21.47	19.85	18.25	16.97
* 678-153155011	153155011	Q	N Jack to 7/16 Plug	34.26	33.12	31.14	30.23
* 678-153215011	153215011	R	N Jack to 7/16 Jack	34.08	32.94	30.98	30.66
Type 7/16 Adapters							
* 678-1513A5011	1513A5011	S	7/16 Plug to 7/16 Jack R/A	56.76	54.87	53.67	52.22
* 678-1532A5011	1532A5011	T	7/16 Jack to 7/16 Jack	38.11	36.84	34.64	34.00
Type BNC Adapters							
678-3315505	3315505	U	BNC Plug to TNC Jack	7.18	6.52	6.31	5.80
678-3316505	3316505	V	BNC Plug to Mini-UHF Jack	14.22	13.14	12.52	11.90
678-3307505	3307505	W	BNC Plug to UHF Plug	16.75	15.76	15.02	14.13
678-3317505	3317505	X	BNC Plug to UHF Jack	10.16	9.39	8.61	7.92
678-3318505	3318505	Y	BNC Plug to F Jack	4.92	4.48	4.32	3.97
678-3309505	3309505	Z	BNC Plug to SMA Plug	22.65	21.56	20.84	20.14
678-3319505	3319505	AA	BNC Plug to SMA Jack	8.52	7.78	7.27	7.01
678-3325505	3325505	BB	BNC Jack to TNC Jack	15.30	13.90	13.70	12.72
678-3327505	3327505	CC	BNC Jack to UHF Jack	17.78	16.76	16.49	15.34
678-3328505	3328505	DD	BNC Jack to F Jack	5.73	5.22	5.03	4.63
678-8313505	8313505	EE	BNC Jack to F Plug	5.12	4.87	4.21	4.07
678-6313505	6313505	FF	BNC Jack to Mini-UHF Plug	18.24	16.56	15.99	14.70
Type TNC Adapters							
678-5311505	5311505	GG	TNC Plug to N Jack	10.42	9.63	8.84	8.45
678-5313505	5313505	HH	TNC Plug to BNC Jack	5.58	5.07	4.89	4.49
678-5316505	5316505	II	TNC Plug to Mini-UHF Jack	10.12	9.19	8.86	8.14
678-5317505	5317505	JJ	TNC Plug to UHF Jack	13.97	13.15	12.95	12.86
678-5309505	5309505	KK	TNC Plug to SMA Plug	14.97	13.76	12.13	11.21
678-5319505	5319505	LL	TNC Plug to SMA Jack	25.79	24.92	24.17	23.82
678-5329505	5329505	MM	TNC Jack to SMA Jack	41.35	39.88	38.39	37.64
Type SMA Adapters							
678-9311505	9311505	NN	SMA Plug to N Jack	20.87	19.99	19.12	18.41
678-9313505	9313505	OO	SMA Plug to BNC Jack	11.92	11.02	10.57	9.98
678-9315505	9315505	PP	SMA Plug to TNC Jack	25.11	24.27	23.07	22.00
678-9306505	9306505	QQ	SMA Plug to Mini-UHF Jack	7.47	6.80	6.55	6.02
678-9316505	9316505	RR	SMA Plug to Mini-UHF Jack	27.46	26.54	25.39	24.24
Type UHF Adapters							
678-7311505	7311505	SS	UHF Plug to N Jack	14.03	13.20	12.33	11.55
678-7313505	7313505	TT	UHF Plug to BNC Jack	10.88	10.06	9.63	8.12
678-7316505	7316505	UU	UHF Plug to Mini-UHF Jack	14.87	13.99	13.54	12.24
678-7309505	7309505	VV	UHF Plug to SMA Plug	6.67	6.05	5.67	5.11
Type RCA Adapters							
678-R0842	R0842	WW	RCA Plug to BNC Plug	5.82	5.30	5.11	4.48
678-R0844	R0844	XX	RCA Plug to BNC Jack	3.98	3.62	3.49	3.06
678-R0849	R0849	YY	RCA Plug to F Jack	2.88	2.66	2.49	2.35
678-R0822	R0822	ZZ	RCA Plug to UHF Jack	6.83	6.22	6.00	5.29
678-R0811	R0811	AAA	RCA Jack to UHF Plug	4.82	4.78	4.73	4.33
678-R0843	R0843	BBB	RCA Jack to BNC Plug	3.94	3.23	2.81	2.32
678-R0851	R0851	CCC	RCA Jack to F Plug	2.91	2.65	2.55	2.46

Bomar RF Connectors

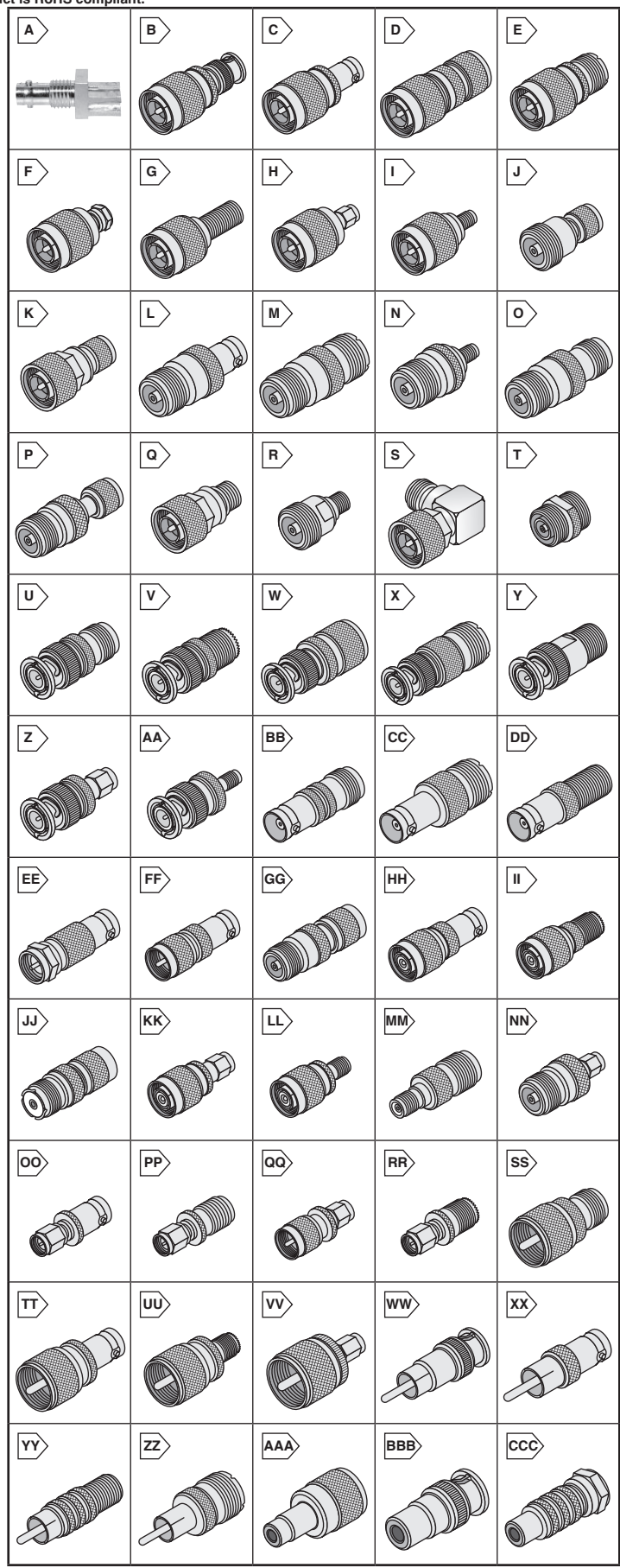

RF ADAPTER KITS

• RoHS Compliant per Bomar documentation

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Description	Price Each	
			1	10
Type UHF Adapters				
678-ADPT1	ADPT1	2 Male and Female of each: BNC, TNC, N, Mini-UHF, UHF, SMA, and 6 Universal adapters	176.99	166.49
Broadcast Grade Kit-40 pcs				
678-ADPT2	ADPT2	2 Male and Female of each: BNC, TNC, N, Mini-UHF, UHF, SMA, F, RCA, and 8 Universal adapters	309.67	291.74
7/16 Kit-8 pc				
678-ADPT3PA	ADPT3PA	1 Male and Female of each: 7/16 to N, N to N, and 7/16 to 7/16	318.52	305.35
Antenna Kit-42 pcs				
678-ADPT4RP	ADPT4RP	2 Male and Female of each: N, BNC, UHF, TNC, TNC-RP, SMA, SMA-RP, and 8 Universal adapters	311.50	294.45