

BOMAR Between Series Adapters and RF Connectors



RoHS Compliant This product is RoHS compliant.

HIGH DENSITY BNC JACK



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	5	10	25
678-361EHD704	361EHD704	A	End Launch Jack, E-Snap	6.15	5.62	5.17	4.79

BETWEEN SERIES ADAPTERS

Between series adapters solve a variety of connection problems where connectors of different types could ordinarily not be mated together. Each adapter has a different type coupling at each end allowing for a wide variety of interconnections to fit almost all interconnection situations. All adapters are constructed of machined brass and are nickel plated.

• RoHS Compliant per Bomar documentation

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Price Each			
				1	10	25	50
Type UHF Adapters							
678-7311505	7311505	B	UHF Plug to N Jack	14.03	13.20	12.33	11.55
678-7313505	7313505	C	UHF Plug to BNC Jack	10.88	10.06	9.63	8.12
678-7316505	7316505	D	UHF Plug to Mini-UHF Jack	14.87	13.99	13.54	12.24
678-7309505	7309505	E	UHF Plug to SMA Plug	6.67	6.05	5.67	5.11
Type RCA Adapters							
678-R0842	R0842	F	RCA Plug to BNC Plug	5.82	5.30	5.11	4.48
678-R0844	R0844	G	RCA Plug to BNC Jack	3.98	3.62	3.49	3.06
678-R0849	R0849	H	RCA Plug to F Jack	2.88	2.66	2.49	2.35
678-R0822	R0822	I	RCA Plug to UHF Jack	6.83	6.22	6.00	5.29
678-R0811	R0811	J	RCA Jack to UHF Plug	4.82	4.78	4.73	4.33
678-R0843	R0843	K	RCA Jack to BNC Plug	3.94	3.23	2.81	2.32
678-R0851	R0851	L	RCA Jack to F Plug	2.91	2.65	2.55	2.46

RF ADAPTER KITS

• RoHS Compliant per Bomar documentation

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Description	Price Each	
			1	10
Type UHF Adapters				
678-ADPT1	ADPT1	2 Male and Female of each: BNC, TNC, N, Mini-UHF, UHF, SMA, and 6 Universal adapters	176.99	166.49
Broadcast Grade Kit-40 pcs				
678-ADPT2	ADPT2	2 Male and Female of each: BNC, TNC, N, Mini-UHF, UHF, SMA, F, RCA, and 8 Universal adapters	309.67	291.74
7/16 Kit-8 pc				
678-ADPT3PA	ADPT3PA	1 Male and Female of each: 7/16 to N, N to N, and 7/16 to 7/16	318.52	305.35
Antenna Kit-42 pcs				
678-ADPT4RP	ADPT4RP	2 Male and Female of each: N, BNC, UHF, TNC, TNC-RT, TNC-RP, SMA, SMA-RP, and 8 Universal adapters	311.50	294.45

MCX AND MMCX CABLE CONNECTORS

- Brass body parts
- Plating: Gold over Nickel
- RoHS Compliant per Bomar documentation

For quantities greater than listed, call for quote.


MOUSER STOCK NO.	Bomar Part No.	Fig.	Imp. Ω	Description	RG Cable Type	Price Each			
						1	10	25	100
678-1210A204M	1210A204M	M	50	Straight Cable Plug	174/U	3.67	3.33	3.20	3.04
678-1213A204M	1213A204M	N	50	Right Angle Plug	174/U	3.75	3.41	3.28	3.10

BNC COAXIAL CRIMP PLUGS

- High quality machined construction
- Semi-captive contacts that "click" into place assuring perfect installation
- RoHS Compliant per Bomar documentation

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Imp. Ω	Description	RG Cable Type	Price Each			
						1	10	25	100
678-310A205F	310A205F	O	50	3 piece, dual crimp	58/U,58C/U,141	3.91	3.57	3.45	3.28
678-310A205G	310A205G	O	50	3 piece, dual crimp	59, 62, 210	2.48	2.25	2.18	2.00
678-310A205MV	310A205MV	O	50	3 piece, dual crimp	174, 179, 196	3.13	2.85	2.83	2.51
678-310A205P	310A205P	O	50	3 piece, dual crimp	223	3.54	3.22	3.01	2.83
678-310B205MV	310B205MV	O	75	3 piece, dual crimp	174, 178, 196	3.98	3.51	3.38	3.13
678-332A705	332A705	P	75	Inline Splice Adapter	----	3.62	3.29	3.17	2.80
678-332A505	332A505	P	50	Inline Splice Adapter	----	4.25	3.87	3.73	3.43

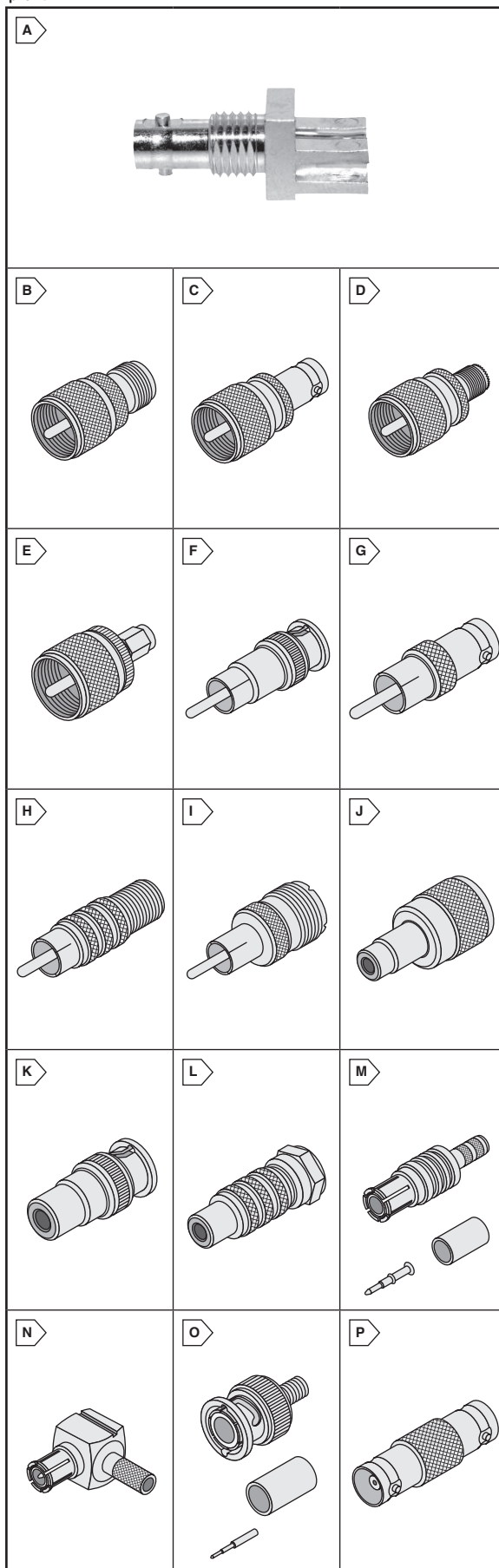

RF Connectors Bomar