


CONNECTOR CITY RF Connectors

CONNECTOR CITY
THE VALUE OF CONNECTIONS

RoHS compliant This product is RoHS compliant.

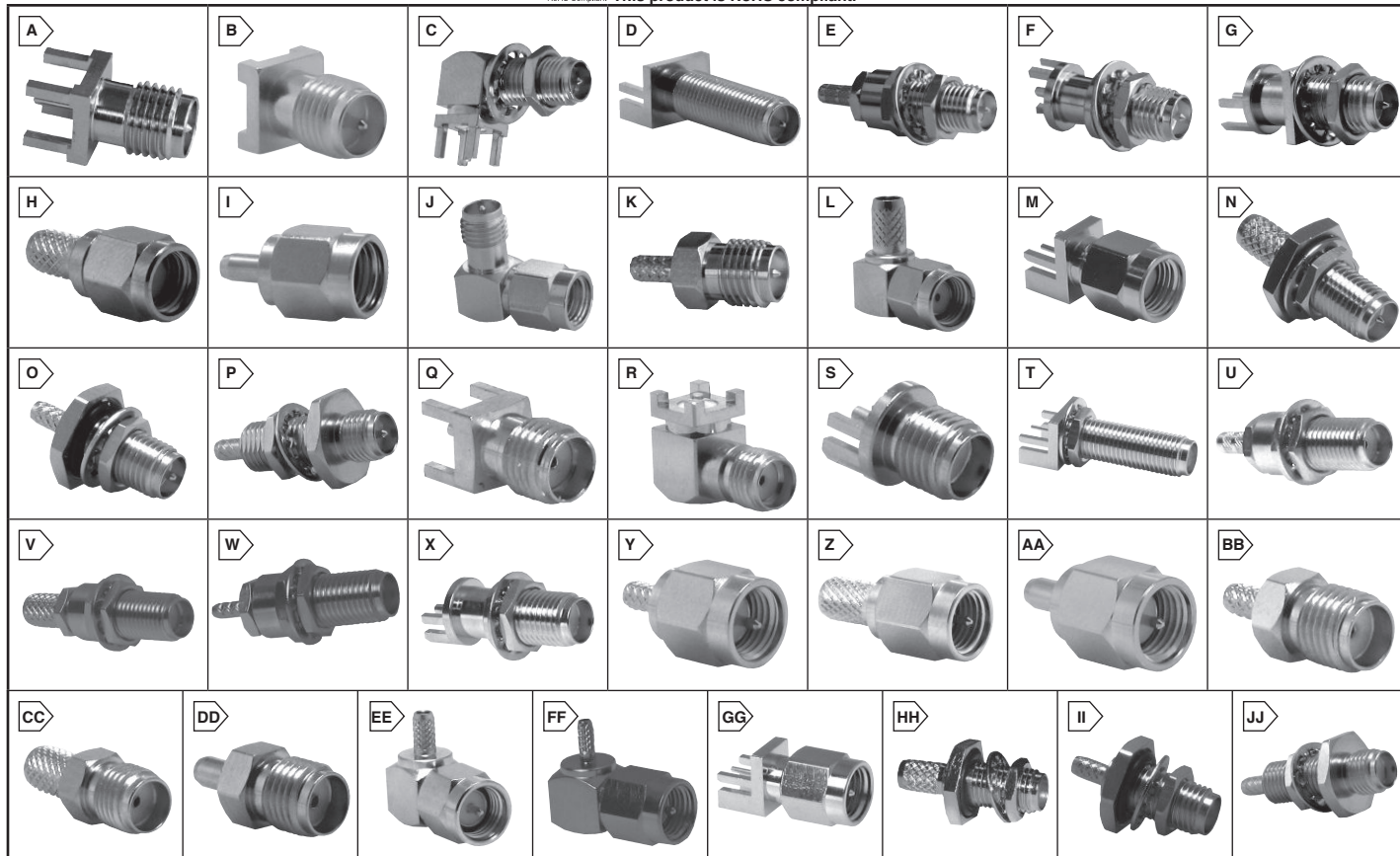

RF Connectors

REVERSE-POLARITY SMA CONNECTORS

Reverse-polarity connectors are designed to meet FCC Part 15 requirements and are ideal for any application requiring a reliable non-standard RF connection. The reverse-polarity design uses the same tooling as a standard SMA, but reverses the center connection.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Connector City Part No.	Fig.	Description	Cable Type	Price Each		
					1	25	50
712-CONREVSMA001	CONREVSMA001	A	RP-SMA Female PCB Mount	----	2.92	2.67	2.59
712-CONREVSMA001-SMD	CONREVSMA001-SMD	B	Female PCB Mount, SMD	----	4.04	3.69	3.58
712-CONREVSMA002-L	CONREVSMA002-L	C	Female Right Angle PCB Mount, Extended	----	4.17	3.80	3.68
712-CONREVSMA003031L	CONREVSMA003.031-L	D	Female Edge Mount for 0.031" Board, Extended	----	6.43	5.88	5.70
712-CONREVSMA005	CONREVSMA005	E	Female Bulkhead Mount Cable End Crimp	RG174, 188A, 316	4.46	4.08	3.95
712-CONREVSMA006.062	CONREVSMA006.062	F	Female Edge Multi-Mount for 0.062" Board	----	4.20	3.84	3.72
712-CONRRPSMA006062SQ	CONREVSMA006.062SQ	G	Female Edge Multi-Mount with Square Flange for 0.062" Board	----	7.07	6.45	6.25
712-CONREVSMA007-R58	CONREVSMA007-R58	H	Male Cable End Crimp	RG58, 58A, 141	4.29	3.90	3.79
712-CONREVSMA007R178	CONREVSMA007-R178	I	Male Cable End Crimp	RG178	3.12	2.84	2.76
712-CONREVSMA010	CONREVSMA010	J	Male to Female Right Angle Adaptor	----	6.20	5.58	3.85
712-CONREVSMA011	CONREVSMA011	K	Female Cable End Crimp	RG174, 188A, 316	2.58	2.36	2.29
712-CONREVSMA012-R58	CONREVSMA012-R58	L	Male Right Angle Cable End Crimp	RG58, 58A, 141	5.88	5.70	5.03
712-CONREVSMA013.031	CONREVSMA013.031	M	Male Edge Mount for 0.031" Board	----	7.10	6.51	6.25
712-CONREVSMA014-R58	CONREVSMA014-R58	N	Female Bulkhead Mount Cable End Crimp with O-Ring	RG58, 58A, 141	4.44	4.05	3.93
712-CONREVSMA014R178	CONREVSMA014-R178	O	Female Bulkhead Mount Cable End Crimp with O-Ring	RG174, 188A, 316	4.04	3.69	3.58
712-CONREVSMA015	CONREVSMA015	P	Female Bulkhead Front Mount Cable End Crimp with O-Ring	RG58, 58A, 141	4.73	4.32	4.18

SMA CONNECTORS

SMA connectors are popular and cost-effective devices which provide repeatable electrical performance from DC to 12.4GHz. SMA connectors are available in a broad variety of mounting styles, brass, stainless-steel body types, and assorted cable-attachment methods.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Connector City Part No.	Fig.	Description	Cable Type	Price Each		
					1	25	50
712-CON SMA001	CON SMA001	Q	Female PCB Mount	----	4.05	3.70	3.59
712-CON SMA002-SMD	CON SMA002-SMD	R	Female Right Angle Surface Mount	----	4.17	3.80	3.68
712-CON SMA003.031	CON SMA003.031	S	Female Edge Mount for 0.031" Board	----	3.48	3.18	3.08
712-CON SMA003.031-L	CON SMA003.031-L	T	Female Edge Mount for 0.031" Board, Extended	----	5.78	5.28	5.11
712-CON SMA005	CON SMA005	U	Female Bulkhead Mount Cable End Crimp	RG174, 188A, 316	5.14	4.70	4.55
712-CON SMA005-R58	CON SMA005-R58	V	Female Bulkhead Mount Cable End Crimp	RG58, 58A, 141	2.94	2.70	2.45
712-CON SMA005-R178	CON SMA005-R178	W	Female Bulkhead Mount Cable End Crimp	RG178	4.67	4.27	4.14
712-CON SMA006.031	CON SMA006.031	X	Female Edge Multi-Mount for 0.031" Board	----	5.72	5.22	5.06
712-CON SMA007	CON SMA007	Y	Male Cable End Crimp	RG174, 188A, 316	2.31	2.11	2.04
712-CON SMA007-R58	CON SMA007-R58	Z	Male Cable End Crimp	RG58, 58A, 141	2.53	2.31	2.24
712-CON SMA007-R178	CON SMA007-R178	AA	Male Cable End Crimp	RG178	2.31	2.11	2.04
712-CON SMA011	CON SMA011	BB	Female Cable End Crimp	RG174, 188A, 316	2.77	2.52	2.45
712-CON SMA011-R58	CON SMA011-R58	CC	Female Cable End Crimp	RG58, 58A, 141	2.77	2.52	2.45
712-CON SMA011-R178	CON SMA011-R178	DD	Female Cable End Crimp	RG178	3.82	3.47	3.38
712-CON SMA012	CON SMA012	EE	Male Right Angle Cable End Crimp	RG174, 188A, 316	3.36	3.07	2.97
712-CON SMA012-R58	CON SMA012-R58	EE	Male Right Angle Cable End Crimp	RG58, 58A, 141	3.36	3.07	2.97
712-CON SMA012-R178	CON SMA012-R178	FF	Male Right Angle Cable End Crimp	RG178	3.36	3.07	2.97
712-CON SMA013.031	CON SMA013.031	GG	Male Edge Mount for 0.031" Board	----	6.79	6.20	6.01
712-CON SMA014-R58	CON SMA014-R58	HH	Female Bulkhead Mount Cable End Crimp with O Ring	RG58, 58A, 141	4.17	3.80	3.68
712-CON SMA014-R178	CON SMA014-R178	II	Female Bulkhead Mount Cable End Crimp with O Ring	RG178	4.67	4.27	4.14
712-CON SMA015	CON SMA015	JJ	Female Bulkhead Mount Cable End Crimp	RG174, 188A, 316	7.46	6.82	6.60