

POMONA RF Connectors and Adapters

Pomona BNC WITHIN SERIES ADAPTERS

• Nickel plated brass For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—3847		A	BNC Jack/Jack Hermetically sealed 50Ω	PTFE	21.75	20.78	19.34
565—3534		B	BNC Jack/Plug Right Angle 50Ω	PTFE	9.17	8.80	8.51
565—3283		C	BNC Jack/Jack 50Ω	PTFE	4.93	4.73	4.57
565—3284		D	BNC Jack/Jack/Jack 50Ω	PTFE	15.25	14.57	13.56

Pomona BETWEEN SERIES ADAPTERS AND KITS

• Nickel plating For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
Adapters							
565—1269		E	BNC Jack to double stacking banana plug	ABS	7.94	6.70	6.57
565—1270		F	BNC Plug to double stacking banana plug	ABS	12.00	11.47	10.67
565—1452		G	BNC Jack to stackable binding posts	ABS	12.88	12.00	11.94
565—1296		H	BNC Plug to stackable binding posts	ABS	14.17	13.49	13.14
Kits							
565—5748		I	Maxi Universal coaxial RF adapter kit	-	333.00	318.09	296.00
565—5698		I	Universal Adapter Kit	-	204.00	194.87	181.34
565—6254		I	7/16 Din Adapter Kit	-	593.03	544.43	533.74

Pomona BNC TERMINATIONS, ATTENUATORS, AND WITHIN SERIES ADAPTERS

• Nickel plating For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
Terminations							
565—4119-50		J	BNC Feed-Thru Termination, 50Ω		40.00	38.40	35.58
565—4119-75		J	BNC Feed-Thru Termination, 75Ω		65.00	62.40	57.82
565—5297		K	BNC plug to jack with DC-blocking Series Cap, 1000pF, 600V		30.90	29.59	28.07
Adapters							
565—3846		L	BNC jack to BNC jack, 50Ω		8.91	8.51	7.92
565—3533		M	BNC plug to BNC plug, 50Ω		3.45	3.30	3.19
565—4896		N	BNC Plug/Jack/Jack, 50Ω		14.75	14.09	13.12
565—6700		O	BNC Jack/Plug/Jack, In-line space saving, 50Ω		17.25	16.48	15.34
565—6701		P	BNC Jack/Plug/Jack, Right angle space saving, 50Ω		19.64	19.08	18.12
565—3285		Q	BNC Jack/Plug/Jack, Standard, 50Ω		6.48	6.22	6.00
Attenuators							
* 565—4108-		R	BNC 50Ω Attenuator		80.00	76.80	71.16

*(select dB) -3DB, -6DB, -10DB, -14DB, -20DB

Pomona SMA 50 OHM WITHIN SERIES ADAPTERS & TERMINATORS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
Adapters							
565—4283		S	SMA plug to SMA plug, gold plated	Teflon	9.96	9.48	8.99
565—4284		T	SMA jack to SMA jack, gold plated	Teflon	10.25	9.80	9.12
565—4282		U	SMA jack to SMA plug, Right Angle, gold plated	Teflon	12.00	11.47	10.67
Terminators							
565—4286		V	SMA Terminator plug, 50Ω, gold plated	Teflon	48.00	45.86	42.67
565—5088		W	SMA Shorting Cap, gold plated	-	21.00	20.16	18.68

Pomona COAXIAL BETWEEN SERIES ADAPTERS


For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
SMA to BNC							
565—4288		X	SMA plug to BNC plug, gold plated	Teflon	11.50	10.99	10.23
565—4289		Y	SMA jack to BNC plug, gold plated	Teflon	9.01	8.57	8.13
565—4290		Z	SMA plug to BNC jack, gold plated	Teflon	9.60	9.17	8.53
565—4291		AA	SMA jack to BNC jack, gold plated	Teflon	9.10	8.69	8.09
SMA to TNC							
565—4292		BB	SMA Plug to TNC Plug, gold plated	PTFE	12.05	11.71	11.12
565—4293		CC	SMA Jack to TNC Plug, gold plated	PTFE	24.29	23.60	22.40
565—4294		DD	SMA Plug to TNC Plug, gold plated	PTFE	9.88	9.61	9.14
565—4295		EE	SMA Jack to TNC Plug, gold plated	PTFE	23.98	23.28	22.12
SMA to Type N							
565—4296		FF	SMA Plug to type N Plug, gold plated	PTFE	16.75	16.00	14.89
565—4297		GG	SMA Jack to type N Plug, gold plated	PTFE	19.25	18.39	17.12
565—4298		HH	SMA Plug to type N Jack, gold plated	PTFE	19.50	18.63	17.34
565—4299		II	SMA Jack to type N Jack, gold plated	PTFE	17.46	17.19	16.56
565—5300		JJ	BNC Jack to Plug Triax, nickel plated brass	PTFE	33.46	32.36	30.32

Pomona AUDIO/VIDEO ADAPTERS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Fig.	Description	Insulation	Price Each		
Mfr.	Mfr. Part No.				1	25	50
565—4054		KK	BNC plug to phono jack, nickel plating	-	22.19	20.01	19.06
565—5319		LL	BNC female to phono plug	-	7.60	7.26	6.75

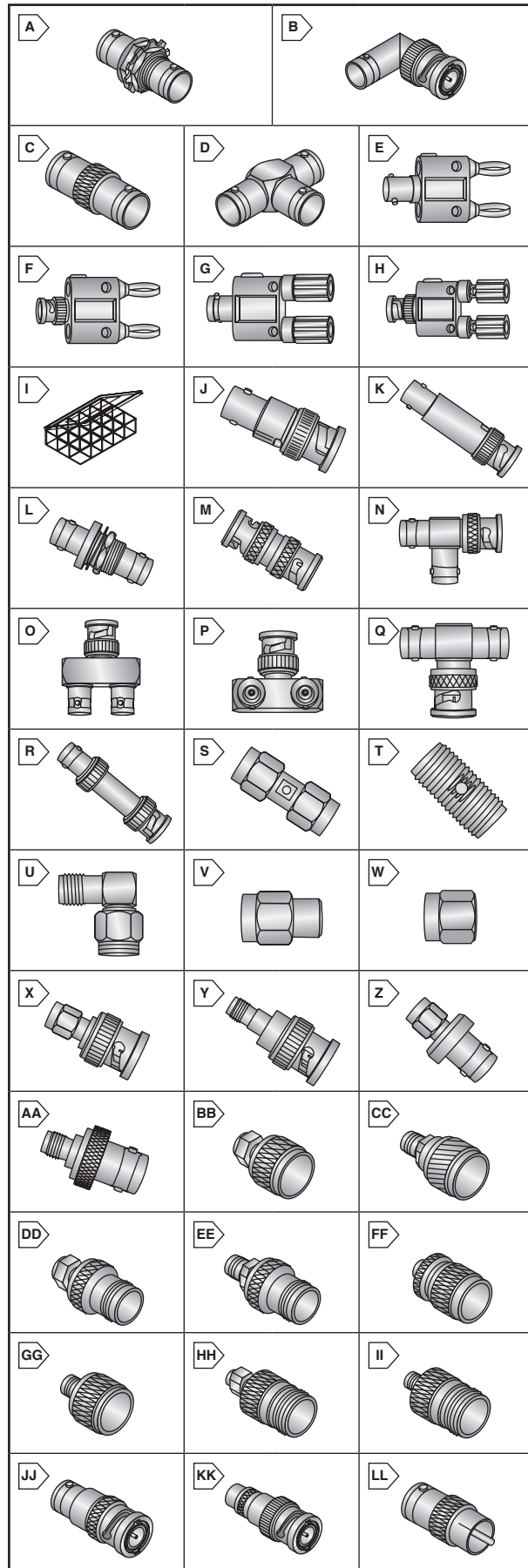

RF Connectors Pomona