


Modular Connectors and Tools

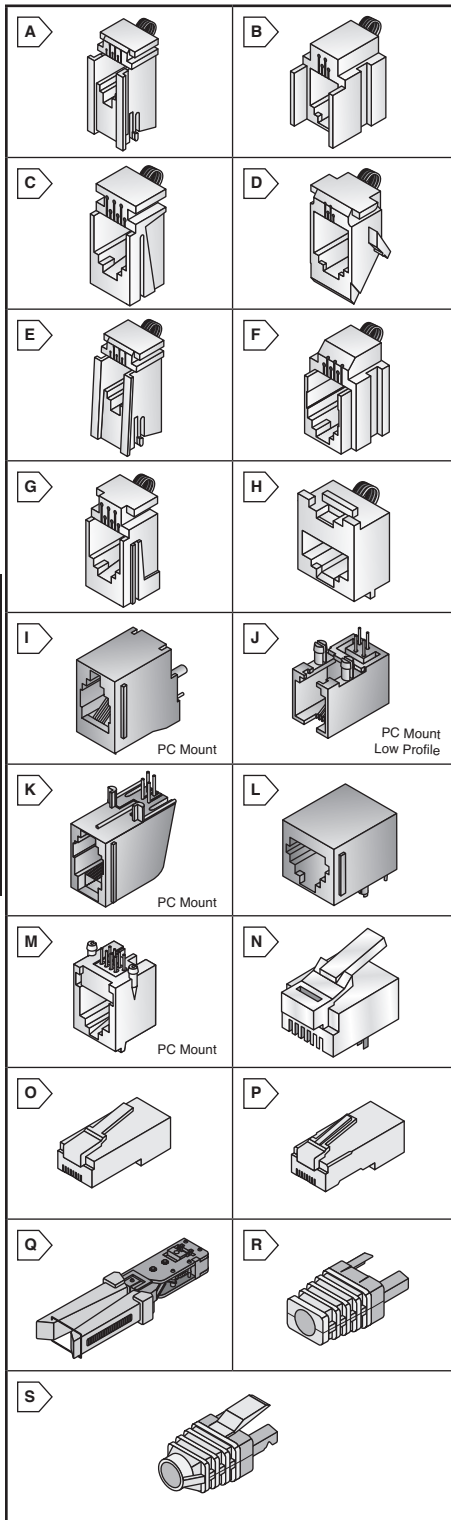

KOBICONN MODULAR JACKS WITH 4" WIRE LEADS

(Types marked with † have 50µ" gold plated contacts, all others have 6µ" gold plated contacts)

• All wire leads have stripped and tinned terminations

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	USOC Type	Positions-Contacts	Western * Electric Type	Color	Price Each			
						1	10	100	500
154-7616D	A	Handset	4-4	616D	Gray	1.71	1.32	1.20	1.09
† 154-UL616M	B	Handset	4-4	616M	Gray	1.73	1.57	1.43	1.30
154-7616M	B	Handset	4-4	616M	Gray	1.23	1.08	.95	.87
154-7616P	C	Handset	4-4	616P	Gray	1.53	1.18	1.07	.97
154-7616W	D	Handset	4-4	616W	Gray	1.23	1.08	.95	.87
154-7623D4	E	RJ11	6-4	623D4	Gray	1.55	1.20	1.09	.99
† 154-UL623K4	F	RJ11	6-4	623K4	Gray	2.13	2.01	1.83	1.67
154-7623K4	F	RJ11	6-4	623K4	Gray	2.03	1.56	1.42	1.29
† 154-UL623K6	F	RJ12	6-6	623K6	Gray	2.94	2.45	2.23	2.03
154-7623K6	F	RJ12	6-6	623K6	Gray	1.44	1.20	1.00	.91
154-7623P4	G	RJ11	6-4	623P4	Gray	1.70	1.15	1.03	.94
154-7623P6	G	RJ12	6-6	623P6	Gray	1.05	.81	.73	.67
† 154-UL641D	H	RJ45	8-8	641D	Gray	3.60	2.77	2.52	2.29
154-7641D	H	RJ45	8-8	641D	Gray	1.98	1.52	1.38	1.26
154-7647	H	RJ45	8-8K	647	Gray	1.14	.76	.69	.63

KOBICONN MODULAR JACKS WITH PCB LEADS

(Types marked with † have 50µ" gold plated contacts, all others have 6µ" gold plated contacts)

• Glass filled nylon • PC Mount

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	USOC Type	Positions-Contacts	Western * Electric Type	Color	Price Each			
						1	10	100	500
† 154-UL6442	I	Handset	4-4	616PCB	Black	.95	.73	.66	.60
† 154-UL6443	J	Handset	4-4	616PCB	Black	1.82	1.40	1.27	1.15
† 154-UL6641	K	RJ11	6-4	623PCB	Black	1.17	.91	.83	.75
† 154-UL6661	K	RJ12	6-6	623PCB	Black	1.27	.98	.89	.81
† 154-UL6642	L	RJ11	6-4	623PCB	Black	1.09	.84	.76	.70
† 154-UL6662	L	RJ12	6-6	623PCB	Black	1.48	1.13	1.03	.94
† 154-UL6643	J	RJ11	6-4	623PCB	Black	2.73	2.10	1.90	1.74
† 154-UL6663	J	RJ12	6-6	623PCB	Black	4.72	3.63	3.30	3.00
† 154-UL6881	L	RJ45	8-8	641PCB	Black	1.52	1.17	1.06	.97
† 154-UL6882	I	RJ45	8-8	641PCB	Black	1.72	1.32	1.20	1.09
† 154-UL6883	J	RJ45	8-8	641PCB	Black	4.72	4.29	3.90	3.55
† 154-7641PCB	M	RJ45	8-8	641PCB	Gray	1.37	1.05	.96	.87

KOBICONN MODULAR PLUGS

(Types marked with † have 50µ" gold plated contacts, all others have 6µ" gold plated contacts)

* 616 Type - 4 conductor for handset to telephone use; 623 type - 4 or 6 conductor for telephone to wall use; 641 type - 8 conductor for telephone to wall or modern dialer use.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	USOC Type	Positions-Contacts	Western * Electric Type	Color	Price Each			
						1	10	100	500
† 154-UL6164	N	Handset	4-4	616	Clear	.27	.21	.19	.17
154-7616	N	Handset	4-4	616	Clear	.34	.26	.24	.22
† 154-UL6234	N	RJ11	6-4	623	Clear	.24	.20	.19	.17
154-7623-4	N	RJ11	6-4	623	Clear	.26	.21	.18	.16
† 154-UL6236	N	RJ12	6-6	623	Clear	.35	.27	.25	.23
154-7623-6	N	RJ12	6-6	623	Clear	.25	.21	.17	.14
† 154-UL6418	N	RJ45	8-8	641	Clear	.86	.66	.60	.54
154-7641	N	RJ45	8-8	641	Clear	.68	.54	.47	.34


BOMAR EZ-RJ45™ CATEGORY 5 AND 6 MODULAR SYSTEM

• EZ-RJ45™ connector simplifies installation by allowing the pairs to be passed through the connector and then trimmed to the edge of the plug.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bomar Part No.	Fig.	Description	Mount/Cable Type	Price Each			
					1	10	25	100
678-300566EZ	300566EZ	O	6P 6C EZ-Plug	12	.62	.56	.545	.50
678-300568EZ	300568EZ	O	8P 8C CAT5 EZ-Plug	45	1.27	1.16	1.12	1.03
678-300668EZ	300668EZ	O	8P 8C CAT6 EZ-Plug	45	1.36	1.24	1.20	1.10
678-300668SEZ	300668SEZ	P	8P 8C CAT 6 Shielded EZ-Plug	45	2.94	2.67	2.50	2.24
678-BD45000	BD45000	Q	Crimp and trimming tool for EZ-RJ	11, 12, 45	87.94	81.17	call	call
678-CXB300EZGY	CXB300EZGY	R	Cat 6 Boot for EZRJ45	---	.59	.54	.525	.484
678-CXB500EZ	CXB500EZ	S	Cat 5 Snagless boot for EZ	---	.64	.584	.572	.53
678-CXB600EZ	CXB600EZ	S	Cat 6 Snagless boot for EZ	---	.65	.595	.589	.535

eagle MODULAR CRIMPING TOOL

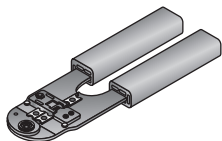

Heavy Duty, Modular Plug Crimping Tool

Economy 3-Way Crimping Tools

- Cuts, strips, and crimps
- Hardened steel frame
- Black oxide finish
- Lightweight and durable

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Type of Use	Price Each	
		1	5
382-2094C	For 4P 4C and 4P 2C plugs	13.35	8.01