

# AMPHENOL D-Subminiature Connectors Amphenol®

RoHS Compliant This product is RoHS compliant.

## RIGHT ANGLE CONNECTORS (.318" FOOTPRINT)

### Specifications:

- Temperature Range: -67°F to 221°F
- Voltage Rating: 300V
- Current Rating: 5A
- 4-40 Threaded Mounting Hole
- 30 microns Gold

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig.	No. of Positions	Type	Price Each			
					1	10	50	100
523-6E17-C009P-AJ121	6E17-C009P-AJ121	A	9	Male	3.83	3.43	3.16	2.83
523-6E17-C009S-AJ120	6E17-C009S-AJ120	A	9	Female	3.73	3.35	3.02	2.71
523-6E17-C025P-AJ121	6E17-C025P-AJ121	A	25	Male	6.66	5.63	5.05	4.40
523-6E17-C025S-AJ120	6E17-C025S-AJ120	A	25	Female	9.03	7.04	6.43	5.58
523-6E17C009SAJ220	6E17C009SAJ220	A	9	Female	3.69	3.34	3.05	2.81

## HIGH DENSITY

### Materials:

- Shells: Steel, tin plated
- Insulator: Black Thermoplastic, UL94V-0
- Contact: Brass
- Contact Plating: Gold Flash

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig.	No. of Positions	Type	Price Each			
					1	10	50	100
<b>Right Angle</b>								
523-17EBH-015SAM010	17EBH-015S-AM010	A	15	Female	6.46	5.34	4.44	4.01
<b>Solder Cup</b>								
523-17EHD-015P-AA000	17EHD-015P-AA000	B	15	Male	2.10	1.81	1.68	1.54
523-17EHD-015S-AA000	17EHD-015S-AA000	B	15	Female	1.75	1.59	1.35	1.21
523-17EHD-026P-AA000	17EHD-026P-AA000	B	26	Male	2.90	2.56	2.32	1.99
523-17EHD-026S-AA000	17EHD-026S-AA000	B	26	Female	2.31	2.10	1.91	1.76
523-17EHD-044P-AA000	17EHD-044P-AA000	B	44	Male	4.01	3.64	3.33	3.08
523-17EHD-044S-AA000	17EHD-044S-AA000	B	44	Female	4.01	3.64	3.33	3.08
523-17EHD-062P-AA000	17EHD-062P-AA000	B	62	Male	5.93	5.34	4.92	4.53
523-17EHD-078P-AA000	17EHD-078P-AA000	B	78	Male	4.78	4.31	3.94	3.63

## DUST COVERS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig.	No. of Pos.	Type	Price Each			
					1	10	50	100
523-L17D4K63010	L17D4K63010	C	9	Metal Dust Cap for Receptacles	1.17	1.00	.849	.764
523-L17D4K63016	L17D4K63016	C	15	Metal Dust Cap for Receptacles	.97	.88	.803	.731
523-L17D4K63026	L17D4K63026	C	25	Metal Dust Cap for Receptacles	1.21	1.08	.962	.861
523-L17D4K63110	L17D4K63110	C	9	Metal Dust Cap for Plugs	1.08	.95	.867	.782
523-L17D4K63116	L17D4K63116	C	15	Metal Dust Cap for Plugs	1.20	1.05	.94	.848
523-L17D4K63126	L17D4K63126	C	25	Metal Dust Cap for Plugs	1.07	.946	.847	.77

## PLASTIC BACKSHELLS 2-PIECE DESIGN

### Features:

- Fits most standard and high-density D-Subs
- Split Grommets

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig.	No. of Pos.		Type	Price Each			
			STD Shell	HD Shell		1	10	50	100
523-17E-1724-1	17E-1724-1	D	9	15	Plastic	2.43	2.17	2.03	1.85
523-17E-1725-1	17E-1725-1	D	15	26	Plastic	2.50	2.28	2.09	1.87
523-17E-1726-1	17E-1726-1	D	25	44	Plastic	2.47	2.22	2.01	1.85
523-17E-1727-1	17E-1727-1	D	37	62	Plastic	3.32	3.02	2.77	2.56
523-17E-1728-1	17E-1728-1	D	50	78	Plastic	3.14	2.84	2.62	2.44

## PLATED PLASTIC BACKSHELLS 2-PIECE DESIGN

### Features:

- Fits most standard and high-density D-Subs
- Meets FCC 20780 Requirements
- EMI/RFI shielding

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig.	No. of Pos.		Type	Price Each			
			STD Shell	HD Shell		1	10	50	100
523-17E-1724-2	17E-1724-2	D	9	15	Metallized	3.38	3.00	2.99	2.69
523-17E-1725-2	17E-1725-2	D	15	26	Metallized	3.72	3.38	3.10	2.87
523-17E-1726-2	17E-1726-2	D	25	44	Metallized	4.41	3.76	3.44	3.19
523-17E-1727-2	17E-1727-2	D	37	62	Metallized	6.84	6.21	5.48	4.90
523-17E-1728-2	17E-1728-2	D	50	78	Metallized	7.34	6.71	5.83	5.22

## METAL BACKSHELLS 2-PIECE DESIGN

### Features:

- Fits most standard and high-density D-Subs
- Meets FCC 20780 Requirements
- All metal shell provides EMI/RFI shielding and durability


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Fig.	No. of Pos.		Type	Price Each			
			STD Shell	HD Shell		1	10	50	100
523-17E-1657-09	17E-1657-09	E	9	15	Metal	5.10	4.62	4.22	3.88
523-17E-1657-15	17E-1657-15	E	15	26	Metal	5.42	5.17	4.71	4.30
523-17E-1657-25	17E-1657-25	E	25	44	Metal	6.40	6.09	5.97	5.33
523-17E-1657-37	17E-1657-37	E	37	62	Metal	8.66	7.97	7.35	6.98

## SCREW LOCK ASSEMBLIES

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Amphenol Part No.	Description	Price Each			
			1	10	50	100
523-L17D20419EX	L17D20419EX	#4-40 Male for 9, 15, 25, & 37 D-Sub, 10 Pack	6.99	6.36	4.96	4.46
523-L17D20418-2-TX	L17D20418-2-TX	#4-40 Female Standoff, 10 Pack	6.29	5.85	4.87	4.40

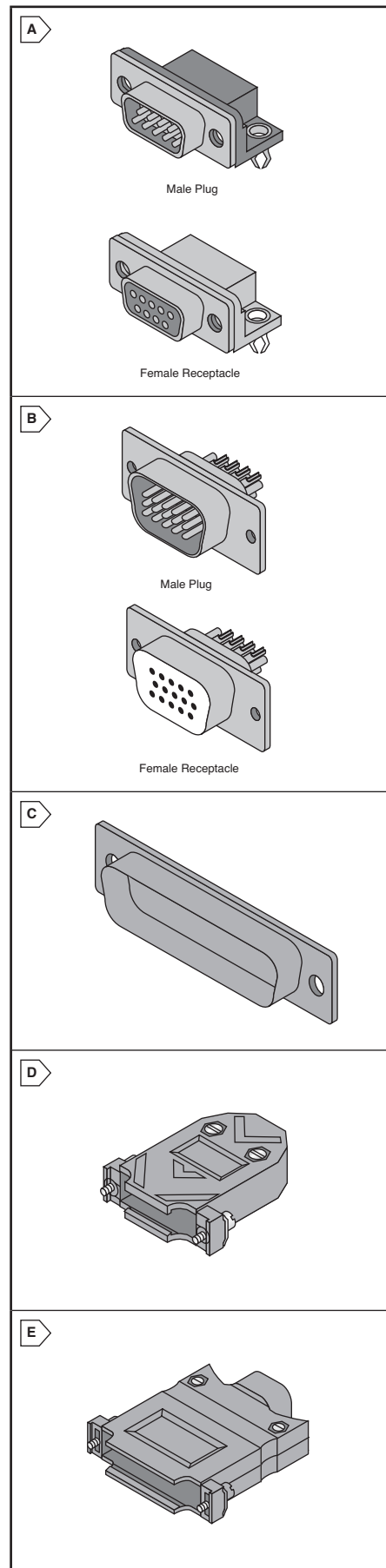

"D" Connectors

Amphenol