


CONEC D-Subminiature Connectors

RoHS Compliant This product is RoHS compliant.

CONEC
TECHNOLOGY IN CONNECTORS™

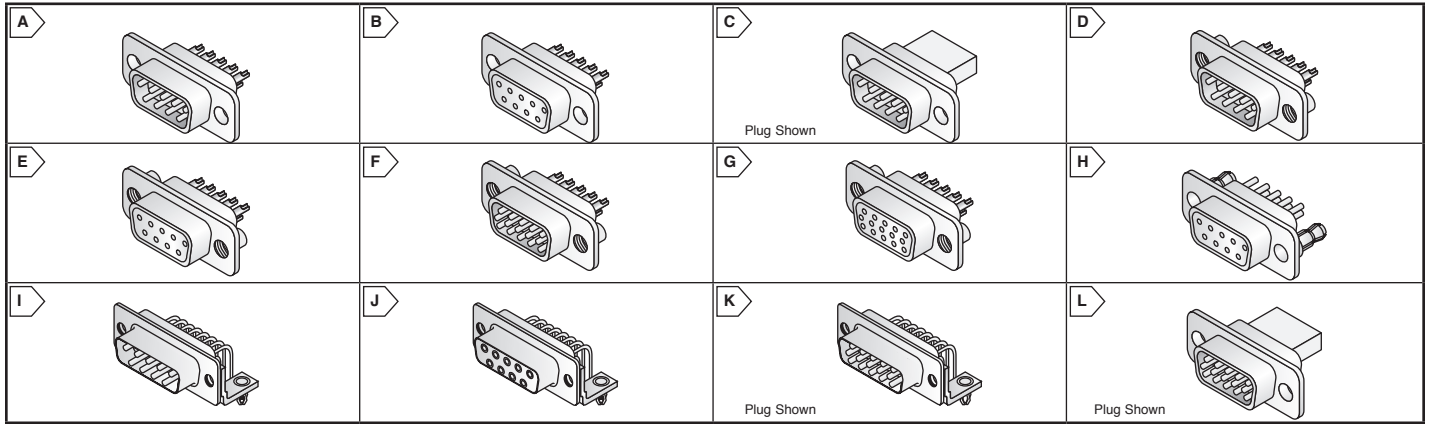

NON-FILTERED D-SUBS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	No. of Positions	Type	Description	Price Each		
						1	10	100
Through Hole								
706-163A11069X	163A11069X	A	9	Plug	Solder Cup	3.39	2.32	1.84
706-163A11079X	163A11079X	A	15	Plug	Solder Cup	4.14	2.83	2.25
706-163A11089X	163A11089X	A	25	Plug	Solder Cup	5.16	3.53	2.80
706-163A11099X	163A11099X	A	37	Plug	Solder Cup	6.39	4.67	3.87
706-163A11109X	163A11109X	A	50	Plug	Solder Cup	7.55	5.52	4.57
706-164A10019X	164A10019X	B	9	Socket	Solder Cup	2.99	2.11	1.74
706-164A10029X	164A10029X	B	15	Socket	Solder Cup	5.25	3.59	2.85
706-164A10039X	164A10039X	B	25	Socket	Solder Cup	7.29	4.98	3.96
706-164A10049X	164A10049X	B	37	Socket	Solder Cup	8.74	6.39	5.29
706-164A10059X	164A10059X	B	50	Socket	Solder Cup	11.49	8.40	6.96
706-163X10019X	163X10019X	C	9	Plug	Crimp	1.84	1.19	.916
706-163X10029X	163X10029X	C	15	Plug	Crimp	2.19	1.42	1.08
706-163X10039X	163X10039X	C	25	Plug	Crimp	1.91	1.24	.951
706-163X10049X	163X10049X	C	37	Plug	Crimp	3.17	2.05	1.57
706-163X10059X	163X10059X	C	50	Plug	Crimp	3.87	2.64	2.10
706-164X11769X	164X11769X	C	9	Socket	Crimp	1.88	1.40	1.07
706-164X11779X	164X11779X	C	15	Socket	Crimp	2.24	1.55	1.19
706-164X11789X	164X11789X	C	25	Socket	Crimp	2.37	1.64	1.26
706-164X11799X	164X11799X	C	37	Socket	Crimp	3.21	2.23	1.71
706-164X11809X	164X11809X	C	50	Socket	Crimp	3.87	2.64	2.10
4-40 UNC Threaded								
706-163A11269X	163A11269X	D	9	Plug	Solder Cup	3.72	2.54	2.02
706-163A11279X	163A11279X	D	15	Plug	Solder Cup	4.74	3.24	2.58
706-163A11289X	163A11289X	D	25	Plug	Solder Cup	5.13	3.51	2.79
706-163A11299X	163A11299X	D	37	Plug	Solder Cup	6.87	5.02	4.16
706-164A10219X	164A10219X	E	9	Socket	Solder Cup	4.47	3.05	2.43
706-164A10229X	164A10229X	E	15	Socket	Solder Cup	5.85	4.00	3.18
706-164A10239X	164A10239X	E	25	Socket	Solder Cup	6.67	4.87	4.03
706-164A10249X	164A10249X	E	37	Socket	Solder Cup	9.22	6.74	5.58
706-164A10259X	164A10259X	E	50	Socket	Solder Cup	10.28	7.53	6.51
706-163A16649X	163A16649X	F	15	Plug	Solder Cup High Density	6.21	4.25	3.38
706-163A16659X	163A16659X	F	26	Plug	Solder Cup High Density	8.08	5.91	4.89
706-163A16669X	163A16669X	F	44	Plug	Solder Cup High Density	11.79	8.62	7.14
706-164A17059X	164A17059X	G	15	Socket	Solder Cup High Density	6.14	4.54	3.76
706-164A17069X	164A17069X	G	26	Socket	Solder Cup High Density	10.55	7.72	6.39
706-164A17079X	164A17079X	G	44	Socket	Solder Cup High Density	11.80	10.72	9.07
With Threaded Spacer Clip								
706-164A16569X	164A16569X	H	9	Socket	PC Mount-Vertical	6.15	4.20	3.34
706-164A16579X	164A16579X	H	15	Socket	PC Mount-Vertical	7.32	5.00	3.98
706-164A16589X	164A16589X	H	25	Socket	PC Mount-Vertical	7.47	5.46	4.52
With Metal Bracket Threaded Insert and Clip								
706-163A17529X	163A17529X	I	9	Plug	PC Mount-Right Angle	7.93	5.80	4.80
706-163A17539X	163A17539X	I	15	Plug	PC Mount-Right Angle	9.97	7.29	6.04
706-163A17549X	163A17549X	I	25	Plug	PC Mount-Right Angle	11.72	8.97	7.59
706-164A17939X	164A17939X	J	9	Socket	PC Mount-Right Angle	8.28	6.05	5.01
706-164A17949X	164A17949X	J	15	Socket	PC Mount-Right Angle	10.61	7.75	6.42
706-164A17959X	164A17959X	J	25	Socket	PC Mount-Right Angle	12.47	9.54	8.08
High Density With Metal Bracket Threaded Insert and Clip								
706-163A17769X	163A17769X	K	15	Plug	PC Mount-Right Angle	12.99	9.94	8.41
706-164A18179X	164A18179X	K	15	Socket	PC Mount-Right Angle	15.20	11.63	9.85
High Density Shell for Screw Machine Contacts with Through Hole								
706-163X10169X	163X10169X	L	15	Plug	Crimp	3.78	2.58	2.05
706-163X10179X	163X10179X	L	26	Plug	Crimp	4.77	3.26	2.59
706-163X10189X	163X10189X	L	44	Plug	Crimp	3.09	2.11	1.68
706-164X11949X	164X11949X	L	15	Socket	Crimp	4.77	3.26	2.59
706-164X11959X	164X11959X	L	26	Socket	Crimp	5.37	3.67	2.92
706-164X11969X	164X11969X	L	44	Socket	Crimp	4.56	3.12	2.48

CONTACTS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Type	Description	Price Each		
				1	10	100
Crimp						
706-161A18299X	161A18299X	Male	20-24 AWG	.56	.33	.225
706-161A18309X	161A18309X	Male	24-28 AWG	.62	.36	.246
706-162A18709X	162A18709X	Female	20-24 AWG	.89	.63	.554
706-162A18719X	162A18719X	Female	24-28 AWG	.98	.808	.591
Screw Machine High Density Crimp Contacts						
706-161A18009X	161A18009X	Male	22 AWG	.37	.209	.135
706-162A18419X	162A18419X	Female	22 AWG	.39	.25	.17