
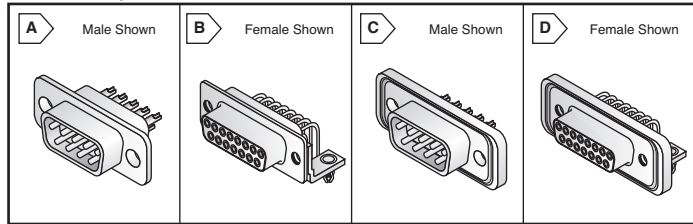


# CONEC D-Subminiature Connectors

RoHS Compliant This product is RoHS compliant.

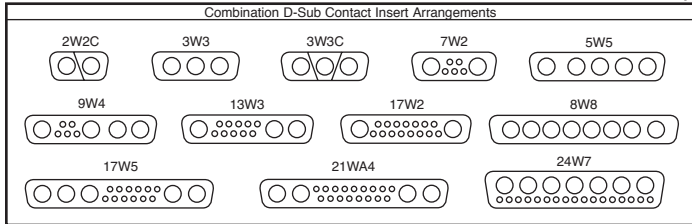

## COMBINATION D-SUBS

- Shell: Tin Plated Steel
- Mating Cycles: 500
- RoHS Compliant per CONEC documentation
- Insulator: UL94V-0

\* 4-40 Threaded insert For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Contact Arrangement	Price Each		
			1	10	100
<b>Crimp Style - Female - Contacts Sold Separately</b>					
706-302W2CSXX99A10X	302W2CSXX99A10X	2W2C	2.54	1.97	1.57
* 706-302W2CSXX99A30X	302W2CSXX99A30X	2W2C	3.97	2.88	2.40
706-303W3CSXX99A10X	303W3CSXX99A10X	3W3C	2.45	1.83	1.58
* 706-303W3CSXX99A30X	303W3CSXX99A30X	3W3C	4.11	2.81	2.23
706-3003W3SXX99A10X	3003W3SXX99A10X	3W3	2.43	1.90	1.62
* 706-3003W3SXX99A30X	3003W3SXX99A30X	3W3	3.31	2.47	2.29
706-3005W5SXX99A10X	3005W5SXX99A10X	5W5	3.67	2.50	1.85
* 706-3005W5SXX99A30X	3005W5SXX99A30X	5W5	3.14	2.56	2.40
706-3008W8SXX99A10X	3008W8SXX99A10X	8W8	3.12	2.34	2.09
* 706-3008W8SXX99A30X	3008W8SXX99A30X	8W8	4.33	2.92	2.40
<b>Crimp Style - Male - Contacts Sold Separately</b>					
706-302W2CPXX99A10X	302W2CPXX99A10X	2W2C	1.76	1.27	1.18
* 706-302W2CPXX99A30X	302W2CPXX99A30X	2W2C	2.48	1.81	1.63
706-303W3CPXX99A10X	303W3CPXX99A10X	3W3C	2.31	1.69	1.40
* 706-303W3CPXX99A30X	303W3CPXX99A30X	3W3C	2.99	1.93	1.56
706-3005W5PXX99A10X	3005W5PXX99A10X	5W5	2.99	1.93	1.56
* 706-3005W5PXX99A30X	3005W5PXX99A30X	5W5	3.01	2.34	1.91
<b>Solder Cup - Female - Power Contacts Sold Separately</b>					
706-3007W2SCM99A10X	3007W2SCM99A10X	7W2	4.25	3.24	2.62
* 706-3007W2SCM99A30X	3007W2SCM99A30X	7W2	7.93	5.85	4.74
706-3009W4SCM99A10X	3009W4SCM99A10X	9W4	5.78	4.22	3.87
* 706-3009W4SCM99A30X	3009W4SCM99A30X	9W4	4.64	3.38	2.97
706-3017W2SCM99A10X	3017W2SCM99A10X	17W2	12.00	9.05	7.42
* 706-3017W2SCM99A30X	3017W2SCM99A30X	17W2	16.63	11.76	10.66
706-3013W3SCM99A10X	3013W3SCM99A10X	13W3	11.94	8.73	7.23
* 706-3013W3SCM99A30X	3013W3SCM99A30X	13W3	6.53	4.77	4.18
706-3017W5SCM99A10X	3017W5SCM99A10X	17W5	9.70	8.48	7.87
* 706-3017W5SCM99A30X	3017W5SCM99A30X	17W5	10.14	8.23	7.74
706-321WA4SCM99A10X	321WA4SCM99A10X	21WA4	8.75	6.26	5.71
* 706-321WA4SCM99A30X	321WA4SCM99A30X	21WA4	12.91	10.64	9.85
706-3024W7SCM99A10X	3024W7SCM99A10X	24W7	9.29	6.74	6.06
* 706-3024W7SCM99A30X	3024W7SCM99A30X	24W7	9.45	7.27	6.85
<b>Solder Cup - Male - Power Contacts Sold Separately</b>					
706-3007W2PCM99A10X	3007W2PCM99A10X	7W2	4.47	3.18	2.84
* 706-3007W2PCM99A30X	3007W2PCM99A30X	7W2	4.10	2.93	2.67
706-3017W2PCM99A10X	3017W2PCM99A10X	17W2	6.94	5.24	4.69
* 706-3017W2PCM99A30X	3017W2PCM99A30X	17W2	5.93	4.32	4.05
706-321WA4PCM99A10X	321WA4PCM99A10X	21WA4	10.16	7.92	7.34
* 706-321WA4PCM99A30X	321WA4PCM99A30X	21WA4	12.91	10.64	9.85
<b>PC Mount - Female - Right Angle</b>					
706-302W2CSXX56N40X	302W2CSXX56N40X	2W2C	14.02	10.45	8.81
* 706-302W2CSXX56N40X	302W2CSXX56N40X	2W2C	29.36	25.62	23.75
706-3007W2SCT56N40X	3007W2SCT56N40X	7W2	19.73	14.53	13.03
* 706-3007W2SCT56N40X	3007W2SCT56N40X	7W2	27.65	19.98	17.77
706-3013W3SCT56N40X	3013W3SCT56N40X	13W3	12.12	10.93	10.12
* 706-3013W3SCT56N40X	3013W3SCT56N40X	13W3	12.12	10.93	10.12

## COAX CONTACTS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Cable Type	Price Each		
			1	10	100
<b>Female</b>					
706-132J20019X	132J20019X	178, 196, 404	5.84	4.62	4.23
706-132J20029X	132J20029X	174, 188, 316	6.57	4.81	3.85
706-132J20049X	132J20049X	58	9.00	7.36	6.14
* 706-132J30019X	132J30019X	179, 187	6.15	4.48	3.58
<b>Male</b>					
706-131J20019X	131J20019X	178, 196, 404	5.83	4.09	3.41
706-131J20029X	131J20029X	174, 188, 316	5.94	4.36	3.59
706-131J20049X	131J20049X	58	9.00	7.36	6.14
* 706-131J30019X	131J30019X	179, 187	6.37	4.62	3.69

## FILTERED D-SUBS

- Shell: Tin plated Brass/Steel
- Contacts: Copper Alloy with Gold over Nickel
- RoHS Compliant per CONEC documentation

\* High Density Version For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	Number of Positions	Price Each		
				1	10	100
<b>C-Filter Adapter - Male/Female with Jack Screws</b>						
706-243A10050X	243A10050X	---	9	12.15	9.68	9.03
706-243A10060X	243A10060X	---	15	13.77	11.18	11.03
* 706-243A10070X	243A10070X	---	25	21.82	16.70	14.14
<b>Solder Cup - Female - Through Hole</b>						
706-242A26860X	242A26860X	A	9	11.64	8.51	7.05
706-242A26870X	242A26870X	A	15	14.44	11.04	9.35
<b>Solder Cup - Female - Threaded Insert</b>						
706-242A27020X	242A27020X	A	9	12.97	9.92	8.40
706-242A27030X	242A27030X	A	15	13.70	11.60	10.77
<b>Solder Cup - Male - Through Hole</b>						
706-241A26960X	241A26960X	A	9	11.29	8.26	6.83
706-241A26970X	241A26970X	A	15	13.67	10.46	8.85
706-241A26980X	241A26980X	A	25	14.54	11.67	11.22
<b>Solder Cup - Male - Threaded Insert</b>						
706-241A27120X	241A27120X	A	9	12.70	9.71	8.22
<b>PCB Mount - Female - Threaded Insert - Right Angle</b>						
706-242A17660X	242A17660X	B	9	16.56	12.67	10.73
<b>PCB Mount - Male - Threaded Insert - Right Angle</b>						
706-241A16060X	241A16060X	B	9	11.93	9.15	8.79
706-241A16070X	241A16070X	B	15	14.22	11.33	10.74
<b>PCB Mount - Female - Threaded Spacer Clip - Vertical</b>						
706-242A15030X	242A15030X	A	9	13.55	10.37	8.78
706-242A15050X	242A15050X	A	25	25.91	20.60	17.75

## HIGH POWER CONTACTS

- Contacts: Copper Alloy with Gold over Nickel
- For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Current	Wire Range	Price Each		
				1	10	100
<b>Female - Crimp</b>						
706-132C11019X	132C11019X	10A	16-20AWG	2.86	2.12	1.62
706-132C11029X	132C11029X	20A	12-14AWG	2.69	2.03	1.55
706-132C11039X	132C11039X	30A	10-12AWG	3.08	2.14	1.64
706-132C11049X	132C11049X	40A	8-10AWG	2.49	1.75	1.45
<b>Male - Crimp</b>						
706-131C11019X	131C11019X	10A	16-20AWG	2.30	1.71	1.31
706-131C11029X	131C11029X	20A	12-14AWG	2.53	1.76	1.34
706-131C11039X	131C11039X	30A	10-12AWG	2.53	1.76	1.34
706-131C11049X	131C11049X	40A	8-10AWG	2.53	1.76	1.34
<b>Female - Solder Cup</b>						
706-132C10019X	132C10019X	10A	16-20AWG	2.86	2.14	1.64
706-132C10029X	132C10029X	20A	12-14AWG	3.24	2.21	1.76
706-132C10039X	132C10039X	30A	10-12AWG	2.86	2.14	1.64
706-132C10049X	132C10049X	40A	8-10AWG	2.86	2.14	1.64
<b>Male - Solder Cup</b>						
706-131C10019X	131C10019X	10A	16-20AWG	2.06	1.42	1.12
706-131C10029X	131C10029X	20A	12-14AWG	2.45	1.83	1.40
706-131C10039X	131C10039X	30A	10-12AWG	2.48	1.85	1.41
706-131C10049X	131C10049X	40A	8-10AWG	2.25	1.87	1.43

## WATER RESISTANT D-SUBS

- Shell: Tin plated Brass/Steel
- Contacts: Copper Alloy with Gold over Nickel
- Operating Temperature: -40°C to +105°C
- Voltage: 125V
- RoHS Compliant per CONEC documentation
- IP67
- Current: 5A

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	CONEC Part No.	Fig.	No. of Positions	Price Each		
				1	10	100
<b>Solder Cup - Female</b>						
706-6STD09SCM99B30X	6STD09SCM99B30X	C	9	23.22	18.46	15.91
706-6STD15SCM99B30X	6STD15SCM99B30X	C	15	28.72	22.84	19.68
706-6STD25SCM99B30X	6STD25SCM99B30X	C	25	26.12	23.75	21.76
<b>Solder Cup - Male - PCB Mount - Die Cast</b>						
706-6STD09PCM99B30X	6STD09PCM99B30X	C	9	21.33	17.51	16.52
706-6STD25PCM99B30X	6STD25PCM99B30X	C	25	16.34	13.60	12.96
<b>Solder Cup - Male - Sealed - No Frame</b>						
706-4STD09PCM99A10X	4STD09PCM99A10X	A	9	9.80	9.28	8.59
706-4STD25PCM99A10X	4STD25PCM99A10X	A	25	17.22	15.67	14.20
<b>Solder Pin - Female - Right Angle</b>						
706-6STD09SCT99S40X	6STD09SCT99S40X	D	9	15.60	11.49	10.56
706-6STD15SCT99S40X	6STD15SCT99S40X	D	15	15.52	13.06	12.09
<b>Hoods</b>						
706-165X14819XE	165X14819XE	---	9	23.79	17.48	16.32
706-165X14829XE	165X14829XE	---	15	20.15	15.42	13.05