

TE D-Sub Backshell Kits



PLASTIC D-SUB BACKSHELLS

- Compact attractive design
- Complete with jackscrews
- 3.0mm to 11.0mm cable sizes
- Quick and easy to assemble



This product is RoHS compliant.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Shell Size	No. of Positions	Cable Dia. Range (mm)	Price Each		
						1	25	50
571-1991253-9	1991253-9	A	1	9	3.0-11.0	2.21	1.97	1.78
571-1-1991253-5	1-1991253-5	A	2	15	3.0-11.0	2.28	2.05	1.85
571-2-1991253-5	2-1991253-5	A	3	25	3.0-11.0	2.22	2.01	1.81
571-3-1991253-7	3-1991253-7	A	4	37	3.0-11.0	2.71	2.43	2.22

DIE-CAST BACKSHELLS

- Straight or 45 degree cable entry
- Rugged compact design
- Excellent EM/RFI shielding
- Lightweight and cost effective



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Shell Size	No. of Positions	Cable O.D. (max.)	Price Each		
						1	25	50
Straight Entry								
571-2198617-9	2198617-9	B	1	9	.512	6.34	5.76	5.28
571-1-2198617-5	1-2198617-5	B	2	15	.512	6.40	5.81	5.33
571-2-2198617-5	2-2198617-5	B	3	25	.512	6.92	6.29	5.76
571-3-2198617-7	3-2198617-7	B	4	37	.512	8.16	7.41	6.80
45 Degree Entry								
571-2198618-9	2198618-9	C	1	9	.512	6.34	5.76	5.28
571-1-2198618-5	1-2198618-5	C	2	15	.512	6.40	5.81	5.33
571-2-2198618-5	2-2198618-5	C	3	25	.512	6.92	6.29	5.76
571-3-2198618-7	3-2198618-7	C	4	37	.512	8.16	7.41	6.80

UNSHIELDED CABLE CLAMP KITS

These cable clamp assemblies can be used on either a plug or socket. All parts are packaged unassembled.

- Use with HDP metal shell
- Each kit includes: 1 hinged plastic clamp, 2 self-tapping screws, 1 strain-relief clip, 1 cable exit gate plug

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Shell Size	Cable O.D. (max.)	Price Each		
					1	10	100
Box and Lid, Straight / 90° Exit, Black Thermoplastic							
571-2074671	207467-1	D	1	.25"	3.65	3.03	2.43
571-2074701	207470-1	D	2	.325"	6.99	6.32	5.85
571-2073451	207345-1	E	3	.50"	4.39	3.63	2.91
+ 571-2074731	207473-1	E	4	.675"	7.23	4.98	4.56
Box and Lid, Straight / 90° Exit w/ Male Screw Retainers							
571-5207908-1	5207908-1	D	1	.25"	5.66	5.17	4.53
571-5207908-4	5207908-4	D	2	.325"	5.75	5.23	4.43
571-5207908-7	5207908-7	E	3	.50"	4.40	4.05	3.59
+ 571-1-5207908-0	1-5207908-0	E	4	.675"	7.56	6.29	5.03
Clam Shell, Straight / 45° Exit, Black Thermoplastic							
571-5205729-1	5205729-1	F	1	.256"	3.42	3.12	2.61
571-5205730-1	5205730-1	F	2	.320"	4.45	2.53	2.22
571-5205718-1	5205718-1	F	3	.420"	2.97	2.72	2.47
571-5205731-1	5205731-1	F	4	.490"	5.78	3.43	3.03
2 Piece Gray Nylon Housing							
571-5206471-1	5206471-1	G	2	.350"	4.49	4.08	3.45
571-5206472-1	5206472-1	G	3	.335"	5.48	3.72	3.29
571-5745081-1	5745081-1	G	4	.675"	4.06	3.60	2.98
571-5745082-1	5745082-1	G	5	.775"	5.10	4.24	3.39

† 90° Cable O.D.: .50" max.

STRAIGHT EXIT RF/EMI SHIELDS FOR JACKETED CABLE

- Metal-plated plastic shield: Thermoplastic, plated nickel over copper
- Die cast shield: Zinc alloy, plated bright nickel over bright copper

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Shell Size	Cable O.D. (max.)	Price Each		
					1	10	100
Metal Plated Plastic Shield Kits							
571-5745854-3	5745854-3	H	1	.25"	5.43	4.23	3.62
571-5745854-1	5745854-1	H	1	.37"	6.47	5.88	4.97
571-5747099-3	5747099-3	H	2	.38"	6.90	6.32	5.42
571-5745833-7	5745833-7	H	3	.35"	10.53	8.49	7.19
571-5745833-5	5745833-5	H	3	.43"	5.77	5.25	4.44
Die Cast Shield Kits							
571-5745171-1	5745171-1	H	1	.25"	10.84	9.86	8.70
571-5745172-2	5745172-2	H	2	.30"	9.48	8.99	7.78
571-5745173-3	5745173-3	H	3	.43"	11.77	9.79	8.00
571-5745174-4	5745174-4	H	4	.43"	8.10	6.74	5.39
571-5745174-3	5745174-3	H	4	.50"	9.57	8.77	7.52
571-5745175-1	5745175-1	H	5	.75"	12.10	11.52	7.66
Die Cast Shield Kits with Grommets							
571-5748676-1	5748676-1	H	1	.32"	6.76	6.29	5.80
571-5748676-2	5748676-2	H	2	.32"	6.00	5.20	4.55
571-5748676-3	5748676-3	H	3	.47"	8.57	7.71	6.46
571-5748676-4	5748676-4	H	4	.47"	8.59	7.99	7.54
571-5748676-5	5748676-5	H	5	.47"	14.55	13.22	11.19

HDP-20, ENCLOSURE KITS

Each kit contains: connector, inner shield, outer shield, enclosure, and two jackscrews. Contacts and Ferrules must be ordered separately.

- Connector shell and shields: steel, tin plated
- Enclosure: PVC
- Connector insert: UL 94V-0 black thermoplastic


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Shell Size	No. of Positions	Cable O.D. (max.)	Price Each		
						1	10	100
Plug Kits								
571-1658655-1	1658655-1	I	1	9	.335"	12.85	11.68	9.92
571-1658659-1	1658659-1	I	3	25	.455"	14.40	12.82	10.89
Receptacle Kits								
571-1658654-1	1658654-1	J	1	9	.335"	12.94	11.76	9.99
571-1658658-1	1658658-1	J	3	25	.455"	10.99	9.17	7.34

© Copyright 2012 Mouser Electronics



© Copyright 2012 Mouser Electronics

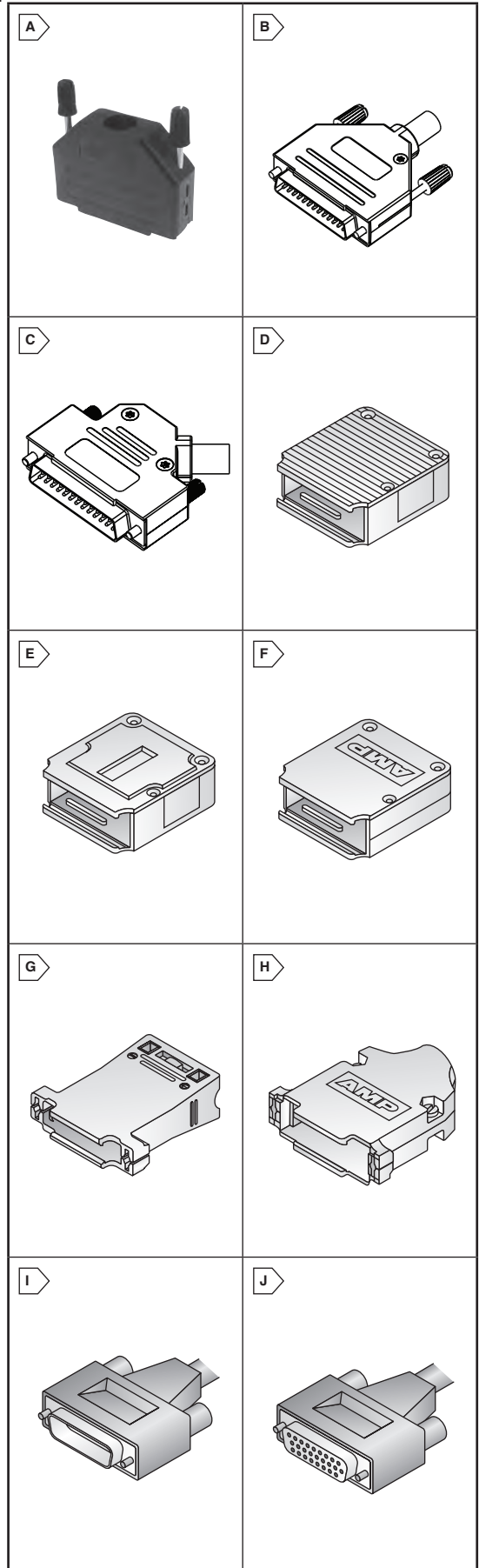

TE Connectivity "D" Connectors