

BULGIN Mini and SMB Buccaneer® Sealed Connectors **B BULGIN**

RoHS Compliant This product is RoHS compliant.

MINI BUCCANEER® ENVIRONMENTALLY SEALED CONNECTORS

- Sealed to IP68 when mated
- Cable range from 3.5 to 9mm
- Diameter over coupling ring 26mm
- Positive locating keyways - cannot be mis-mated
- Flammability rating UL94V-0
- Compact design
- Easy assembly - no special tools required on screw terminal versions
- RoHS Compliant per Bulgin documentation



RoHS Compliant

Flex Cable Connector

- Mates with flex in-line or panel mounting versions
- Cable Acceptance: 3.5 - 9mm (Standard 5 - 7mm)
- Suitable for plug or socket inserts sold separately
- Screw locking ring

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0800	PX0800	A	Flex cable body	5.09	4.49	4.15	3.46

In-Line Flex Cable Connector

- Mates with flex cable version
- Cable Acceptance: 3.5 - 9mm (Standard 5 - 7mm)
- Suitable for plug or socket inserts sold separately

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0801	PX0801	B	In-line flex cable body	4.67	4.14	3.85	3.22

Right Angle Panel Mounting Connector

- Mates with flex cable version
- Right angle cable entry
- Suitable for plug or socket inserts sold separately
- Single hole fixing

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0803	PX0803	C	Right angle panel mount body	4.59	4.14	3.76	3.14

Straight Panel Mounting Connector

- Mates with flex cable version
- Complete with sealing cap and retaining clip
- Suitable for plug or socket inserts sold separately
- Single hole fixing

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0805	PX0805	D	Straight panel mount body	4.32	3.86	3.49	3.15

Screw Terminal Inserts

- Fits all body styles above
- Nickel plated contacts

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	No. of Poles	Gender	Price Each			
					1	25	50	100
177-SA3320	SA3320	E	2	Plug	6.39	5.71	5.37	4.68
177-SA3230	SA3230	E	3	Plug	4.91	4.42	4.02	3.61
177-SA3241	SA3241	E	4	Plug	6.07	5.81	5.42	4.52
177-SA3243	SA3243	E	6	Plug	7.30	6.52	6.01	5.02
167-SA3319	SA3319	F	2	Socket	5.29	4.86	4.32	3.60
167-SA3229	SA3229	F	3	Socket	9.02	8.06	7.29	6.54
167-SA3242	SA3242	F	4	Socket	9.20	8.23	7.44	6.65
167-SA3244	SA3244	F	6	Socket	8.90	8.36	7.60	6.75

Mini Buccaneer® Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Description	Price Each			
			1	25	50	100
157-PX0811	PX0811	Sealing cap for PX0800	1.55	1.42	1.27	1.06
157-PX0810	PX0810	Sealing cap for PX0801-PX0805	1.55	1.42	1.27	1.06
157-PX0812	PX0812	Gland 3 pack - 3.5-5mm, 6-8mm, 7-9mm	.40	.37	.34	.28

SMB BUCCANEER® ENVIRONMENTALLY SEALED CONNECTORS

- Sealed to IP68 when mated
- 50Ω Impedance SMB connector
- Frequency range 0-4GHz
- Gold plated contacts
- Diameter over coupling ring 19mm
- Body moulding: Nylon UL94V-0 rated



RoHS Compliant

Pre-Wireable Flex Connector

- Mates with panel mounting version
- Supplied with SMB plug
- For RG-174 cable

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0415/1	PX0415/1	G	Re-wireable connector with SMB Plug	13.70	13.07	11.67	10.89

Pre-Wired Flex Connectors

- Mates with panel mounting version
- Supplied with SMB jack terminated with RG-174 cable
- Overmoulded construction

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0416/1M00	PX0416/1M00	H	Pre-wired with SMB plug - 1m cable length	14.30	13.75	13.24	12.35
157-PX0416/3M00	PX0416/3M00	H	Pre-wired with SMB plug - 3m cable length	21.30	19.78	17.51	14.45
157-PX0416/5M00	PX0416/5M00	H	Pre-wired with SMB plug - 5m cable length	23.47	21.81	17.62	15.94

Panel Mounting Connectors

- Mates with re-wireable and pre-wired flex versions
- Supplied with SMB jack terminated with RG-174 cable
- Single hole fixing


For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Fig.	Description	Price Each			
				1	25	50	100
157-PX0414/0M50	PX0414/0M50	I	Panel mount with SMB jack - 0.5m cable length	20.56	18.36	17.13	16.58
157-PX0414/1M00	PX0414/1M00	I	Panel mount with SMB jack - 1.0m cable length	27.60	25.63	22.66	18.71
157-PX0414/1M50	PX0414/1M50	I	Panel mount with SMB jack - 1.5m cable length	29.09	27.00	23.89	19.74

SMB Buccaneer® Accessories

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Bulgin Part No.	Description	Price Each			
			1	25	50	100
157-PX0480	PX0480	Sealing Cap for PX0414 panel mount connector	1.59	1.45	1.29	1.09
157-PX0481	PX0481	Sealing Cap for PX0415 re-wireable flex connector	1.52	1.39	1.23	1.04
157-PX0485	PX0485	Sealing Cap for PX0416 overmoulded flex connector	1.59	1.45	1.29	1.09

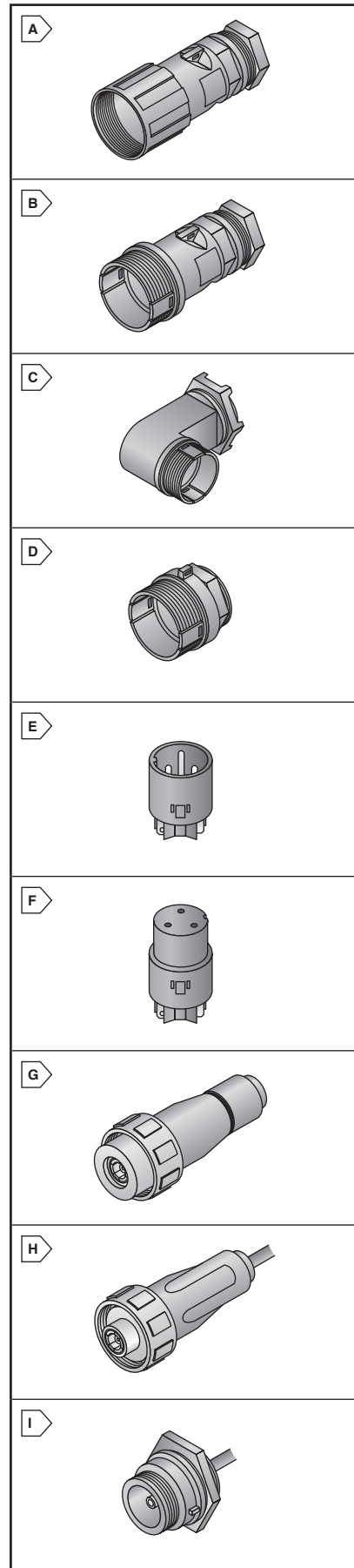

Circular Connectors Bulgin