


HIROSE Circular Connectors



HIROSE ELECTRIC CO., LTD.

RoHS Compliant This page of product is compliant.

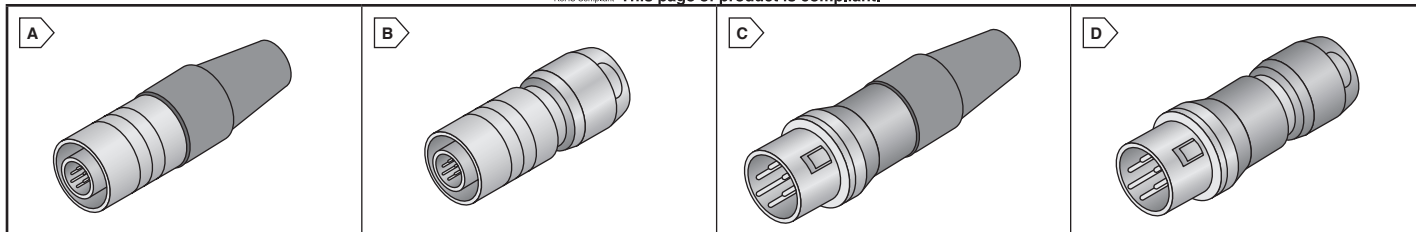

HR10 SERIES, PUSH-PULL METAL CONNECTORS

Plugs

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	Number of Contacts	Shell Size	Price Each		
					1	10	50
Economy Crimp Type - Male							
798-HR10A-7P-4PC73	HR10A-7P-4PC(73)	A	4	7	12.56	11.61	10.41
798-HR10A-7P-6PC73	HR10A-7P-6PC(73)	A	6	7	11.82	10.92	9.79
798-HR10A-10P-10PC73	HR10A-10P-10PC(73)	A	10	10	13.83	13.01	11.80
798-HR10A-10P-12PC73	HR10A-10P-12PC(73)	A	12	10	13.47	12.67	11.48
Economy Crimp Type - Female							
798-HR10A-7P-4SC73	HR10A-7P-4SC(73)	A	4	7	12.70	11.74	10.54
798-HR10A-7P-6SC73	HR10A-7P-6SC(73)	A	6	7	12.70	11.74	10.54
798-HR10A-10P-10SC73	HR10A-10P-10SC(73)	A	10	10	14.09	13.26	12.02
798-HR10A-10P-12SC73	HR10A-10P-12SC(73)	A	12	10	14.09	13.26	12.02
Solder Type - Male - Gold							
798-HR10-7P-6P73	HR10-7P-6P(73)	B	6	7	16.39	15.42	13.98
798-HR10-7P-4P73	HR10-7P-4P(73)	B	4	7	15.46	14.55	13.19
798-HR10-10P-12P73	HR10-10P-12P(73)	B	12	10	18.00	17.39	16.19
Economy Solder Type - Male - Gold							
798-HR10A7P4P74	HR10A-7P-4P(74)	A	4	7	13.58	12.56	11.27
798-HR10A7P6P74	HR10A-7P-6P(74)	A	6	7	14.32	13.24	11.88
798-HR10A10P10P74	HR10A-10P-10P(74)	A	10	10	15.59	14.66	13.29
798-HR10A13P20P74	HR10A-13P-20P(74)	A	20	13	36.45	35.23	32.80
Solder Type - Female - Gold							
798-HR10-7P-4S73	HR10-7P-4S(73)	B	4	7	16.05	15.51	14.44
798-HR10-7P-6S73	HR10-7P-6S(73)	B	6	7	18.00	17.40	16.20
798-HR10-10P-12S73	HR10-10P-12S(73)	B	12	10	25.35	24.50	22.81
Economy Solder Type - Female - Gold							
798-HR10A7P6S74	HR10A-7P-6S(74)	A	6	7	13.94	12.89	11.57
798-HR10A10P10S74	HR10A-10P-10S(74)	A	10	10	14.02	13.19	11.96
Economy Solder Type - Male - Silver							
798-HR10A-7P-4P73	HR10A-7P-4P(73)	A	4	7	12.96	11.98	10.75
798-HR10A-7P-5P73	HR10A-7P-5P(73)	A	5	7	13.44	12.42	11.14
798-HR10A-7P-6P73	HR10A-7P-6P(73)	A	6	7	13.72	12.68	11.37
798-HR10A-10P-10P73	HR10A-10P-10P(73)	A	10	10	14.07	13.24	11.99
798-HR10A-10P-12P73	HR10A-10P-12P(73)	A	12	10	16.19	15.24	13.81
798-HR10A-13P-20P73	HR10A-13P-20P(73)	A	20	13	34.05	32.90	30.63
Economy Solder Type - Female - Silver							
798-HR10A-7P-4S73	HR10A-7P-4S(73)	A	4	7	12.70	11.73	10.53
798-HR10A-7P-5S73	HR10A-7P-5S(73)	A	5	7	12.84	11.86	10.65
798-HR10A-7P-6S73	HR10A-7P-6S(73)	A	6	7	13.00	12.01	10.78
798-HR10A-10P-10S73	HR10A-10P-10S(73)	A	10	10	15.52	14.34	12.87
798-HR10A-10P-12S73	HR10A-10P-12S(73)	A	12	10	15.06	14.17	12.83
798-HR10A-13P-20S73	HR10A-13P-20S(73)	A	20	13	40.74	38.69	37.09
Economy Threaded Coupling - Solder Type - Male - Silver							
798-HR10A7TP6P73	HR10A-7TP-6P(73)	A	6	7	17.55	16.96	15.79
798-HR10A10TP12P73	HR10A-10TP-12P(73)	A	12	10	22.50	21.74	20.24
Economy Threaded Coupling - Solder Type - Female - Silver							
798-HR10A10TPA12S73	HR10A-10TPA-12S(73)	A	12	10	23.25	22.46	20.91
Economy Threaded Coupling - Solder Type - Female - Gold							
798-HR10A13TPD20S74	HR10A-13TPD-20S(74)	A	20	13	52.50	49.87	47.80
Economy Threaded Coupling - Solder Type - Male - Silver							
798-HR10A10WTP12P73	HR10A-10WTP-12P(73)	A	12	10	22.80	22.03	20.51
Economy Threaded Coupling - Solder Type - Male - Gold							
798-HR10A10WTP12P74	HR10A-10WTP-12P(74)	A	12	10	24.00	23.19	21.59

Jacks

For quantities greater than listed, call for quote.

Economy Crimp Type - Female							
798-HR10A10J10SC73	HR10A-10J-10SC(73)	C	10	10	13.89	13.07	11.84
Solder Type - Male - Gold							
798-HR10-7J-4P73	HR10-7J-4P(73)	D	4	7	13.41	12.62	11.44
798-HR10-7J-6P73	HR10-7J-6P(73)	D	6	7	14.29	13.45	12.19
798-HR10-10J-12P73	HR10-10J-12P(73)	D	12	10	15.91	15.37	14.30
Economy Solder Type - Male - Gold							
798-HR10A7J6P74	HR10A-7J-6P(74)	C	6	7	13.56	12.54	11.25
798-HR10A10J12P74	HR10A-10J-12P(74)	C	12	10	17.17	16.16	14.64
Solder Type - Female - Gold							
798-HR10-7J-4S73	HR10-7J-4S(73)	D	4	7	16.19	15.24	13.81
798-HR10-7J-6S73	HR10-7J-6S(73)	D	6	7	16.20	15.64	14.56
798-HR10-10J-12S73	HR10-10J-12S(73)	D	12	10	23.26	22.48	20.92
Economy Solder Type - Female - Gold							
798-HR10A7J6S74	HR10A-7J-6S(74)	C	6	7	13.00	12.02	10.78
798-HR10A10J10S74	HR10A-10J-10S(74)	C	10	10	13.92	13.10	11.88
798-HR10A10J12S74	HR10A-10J-12S(74)	C	12	10	16.58	15.60	14.13
Economy Solder Type - Male - Silver							
798-HR10A-7J-4P73	HR10A-7J-4P(73)	C	4	7	12.20	11.28	10.12
798-HR10A-7J-6P73	HR10A-7J-6P(73)	C	6	7	12.82	11.85	10.64
798-HR10A-10J-10P73	HR10A-10J-10P(73)	C	10	10	14.67	13.81	12.50
798-HR10A-10J-12P73	HR10A-10J-12P(73)	C	12	10	16.24	15.28	13.84
Economy Solder Type - Female - Silver							
798-HR10A-7J-4S73	HR10A-7J-4S(73)	C	4	7	11.88	10.98	9.85
798-HR10A-7J-6S73	HR10A-7J-6S(73)	C	6	7	12.24	11.31	10.15
798-HR10A-10J-10S73	HR10A-10J-10S(73)	C	10	10	14.52	13.43	12.04
798-HR10A-10J-12S73	HR10A-10J-12S(73)	C	12	10	14.86	13.99	12.68