


HIROSE Circular Connectors



This page of product is compliant.

HIROSE ELECTRIC CO., LTD.

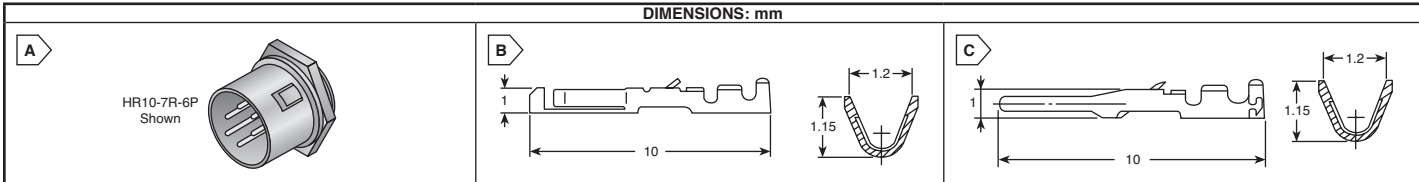

HR10 SERIES, PUSH-PULL METAL CONNECTORS (CONT.)

Receptacles

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Contacts	Shell Size	Price Each		
					1	10	50
Economy Crimp Type - Male							
798-HR10A-7R-4PC73	HR10A-7R-4PC(73)	A	4	7	7.25	6.13	5.15
798-HR10A-7R-6PC73	HR10A-7R-6PC(73)	A	6	7	7.25	6.13	5.15
798-HR10A-10R-10PC71	HR10A-10R-10PC(71)	A	10	10	8.96	7.80	7.01
798-HR10A-10R-12PC71	HR10A-10R-12PC(71)	A	12	10	8.96	7.80	7.01
Economy Crimp Type - Female							
798-HR10A-7R-4SC73	HR10A-7R-4SC(73)	A	4	7	6.88	5.82	4.90
798-HR10A-7R-6SC73	HR10A-7R-6SC(73)	A	6	7	6.89	5.83	4.90
798-HR10A-10R-10SC71	HR10A-10R-10SC(71)	A	10	10	9.29	8.08	7.26
798-HR10A-10R-12SC71	HR10A-10R-12SC(71)	A	12	10	8.97	7.80	7.01
798-HR10A13R20SC73	HR10A-13R-20SC(73)	A	20	13	15.75	15.23	14.18
Dip Type - Male - Silver							
798-HR10-7R-4P73	HR10-7R-4P(73)	A	4	7	11.36	9.88	8.88
Economy Dip Type - Male - Silver							
798-HR10A-7R-4PB73	HR10A-7R-4PB(73)	A	4	7	8.06	6.82	5.71
798-HR10A-7R-6PB73	HR10A-7R-6PB(73)	A	6	7	8.83	7.46	6.28
798-HR10A-10R-10PB71	HR10A-10R-10PB(71)	A	10	10	10.69	9.30	8.37
798-HR10A-10R-12PB71	HR10A-10R-12PB(71)	A	12	10	11.88	10.34	9.29
798-HR10A13R20PB73	HR10A-13R-20PB(73)	A	20	13	19.95	19.28	17.95
Dip Type - Female - Silver							
798-HR10-7R-4S73	HR10-7R-4S(73)	A	4	7	13.72	12.68	11.38
Economy Dip Type - Female - Silver							
798-HR10A-7R-4SB73	HR10A-7R-4SB(73)	A	4	7	7.49	6.34	5.32
798-HR10A-7R-6SB73	HR10A-7R-6SB(73)	A	6	7	8.05	6.81	5.72
798-HR10A-10R-10SB71	HR10A-10R-10SB(71)	A	10	10	9.70	8.44	7.59
798-HR10A-10R-12SB71	HR10A-10R-12SB(71)	A	12	10	10.55	9.18	8.26
Dip Type - Male - Gold							
798-HR10-7R-6PA73	HR10-7R-6PA(73)	A	6	7	11.40	10.54	9.45
798-HR10-10R-12PA73	HR10-10R-12PA(73)	A	12	10	15.72	14.53	13.03
Economy Dip Type - Male - Gold							
798-HR10A7R6PB74	HR10A-7R-6PB(74)	A	6	7	9.10	7.69	6.47
798-HR10A10R12PB72	HR10A-10R-12PB(72)	A	12	10	12.94	11.96	10.73
Dip Type - Female - Gold							
798-HR10-7R-4SA73	HR10-7R-4SA(73)	A	4	7	13.00	12.02	10.78
798-HR10-7R-6SA73	HR10-7R-6SA(73)	A	6	7	15.52	14.35	12.87
798-HR10-10R-12SA73	HR10-10R-12SA(73)	A	12	10	16.35	15.79	14.70
Economy Dip Type - Female - Gold							
798-HR10A7R6SB74	HR10A-7R-6SB(74)	A	6	7	9.10	7.69	6.47
798-HR10A10R10SB72	HR10A-10R-10SB(72)	A	10	10	10.81	9.40	8.46
Economy Solder Type - Male - Silver							
798-HR10A-7R-4P73	HR10A-7R-4P(73)	A	4	7	8.06	6.82	5.72
798-HR10A7R5P73	HR10A-7R-5P(73)	A	5	7	8.27	6.99	5.88
798-HR10A-7R-6P73	HR10A-7R-6P(73)	A	6	7	8.83	7.46	6.28
798-HR10A-10R-10P73	HR10A-10R-10P(73)	A	10	10	10.88	9.46	8.51
798-HR10A-10R-12P73	HR10A-10R-12P(73)	A	12	10	10.50	9.71	8.72
798-HR10A13R20P73	HR10A-13R-20P(73)	A	20	13	20.10	19.43	18.09
Economy Solder Type - Female - Silver							
798-HR10A-7R-4S73	HR10A-7R-4S(73)	A	4	7	7.49	6.34	5.32
798-HR10A-7R-6S73	HR10A-7R-6S(73)	A	6	7	7.67	6.48	5.44
798-HR10A-10R-10S71	HR10A-10R-10S(71)	A	10	10	9.70	8.44	7.59
798-HR10A-10R-12S71	HR10A-10R-12S(71)	A	12	10	10.55	9.18	8.26
798-HR10A13R20S73	HR10A-13R-20S(73)	A	20	13	39.00	37.70	35.10
Economy Solder Type - Male - Gold							
798-HR10A7R4P74	HR10A-7R-4P(74)	A	4	7	8.63	7.30	6.14
798-HR10A7R6P74	HR10A-7R-6P(74)	A	6	7	8.51	7.40	6.65
Economy Solder Type - Female - Gold							
798-HR10A7R6S74	HR10A-7R-6S(74)	A	6	7	8.92	7.54	6.34
798-HR10A10R10S72	HR10A-10R-10S(72)	A	10	10	11.66	10.14	9.12
798-HR10A10R12S72	HR10A-10R-12S(72)	A	12	10	11.02	10.19	9.14
798-HR10A13R20S74	HR10A-13R-20S(74)	A	20	13	38.78	36.84	35.32

Crimp Contacts

For quantities greater than listed, call for quote.

Crimp Contacts (Reels)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	Plating	AWG	Price Each			MOUSER STOCK NO.	Hirose Part No.	Plating	AWG	Reel Quantity	Price Per Piece
					1	10	50						
Female													
798-HR12-SC-111	HR12-SC-111	B	Gold	26-30	.54	.33	.26	798-HR12-SC-211	HR12-SC-211	Gold	26-30	10000	.14
798-HR12-SC-112	HR12-SC-112	B	Silver	26-30	.76	.53	.385	798-HR12-SC-212	HR12-SC-212	Silver	26-30	10000	.10
Male													
798-HR10-PC-111	HR10-PC-111	C	Gold	26-30	.52	.31	.261	798-HR10-PC-211	HR10-PC-211	Gold	26-30	10000	.14
798-HR10-PC-112	HR10-PC-112	C	Silver	26-30	.41	.25	.20	798-HR10-PC-212	HR10-PC-212	Silver	26-30	10000	.11

Accessories & Tools

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Description	Price Each		
			1	10	50
798-HR10-7R-C	HR10-7R-C	Cap for Shell Size 7	3.41	2.82	2.36
798-HR10-10R-C	HR10-10R-C	Cap for Shell Size 10	3.42	2.82	2.36
798-HR12-SC-TC	HR12-SC-TC	Manual Crimping Tool	703.30	-	-
798-HR12-SC-TP	HR12-SC-TP	Extractor Tool	13.46	-	-
798-HR10A-TC-02	HR10A-TC-02	Cable Crimping Tool	364.47	-	-
798-HR10-13P-T05	HR10-13P-T05	Wiring Tool for HR10-13P Connectors	76.44	-	-
798-HR10-13J-T06	HR10-13J-T06	Wiring Tool for HR10-13J Connectors	76.44	-	-
798-HR10-7P-T01	HR10-7P-T01	Wiring Tool for HR10-7P Connectors	218.12	-	-
798-HR10-10P-T02	HR10-10P-T02	Wiring Tool for HR10-10P Connectors	218.12	-	-
798-HR10-7J-T03	HR10-7J-T03	Wiring Tool for HR10-7J Connectors	218.12	-	-
798-HR10-10J-T04	HR10-10J-T04	Wiring Tool for HR10-10J Connectors	218.12	-	-

