


HARTING Housings, Hoods and Frames



Pushing Performance

This page of product is compliant

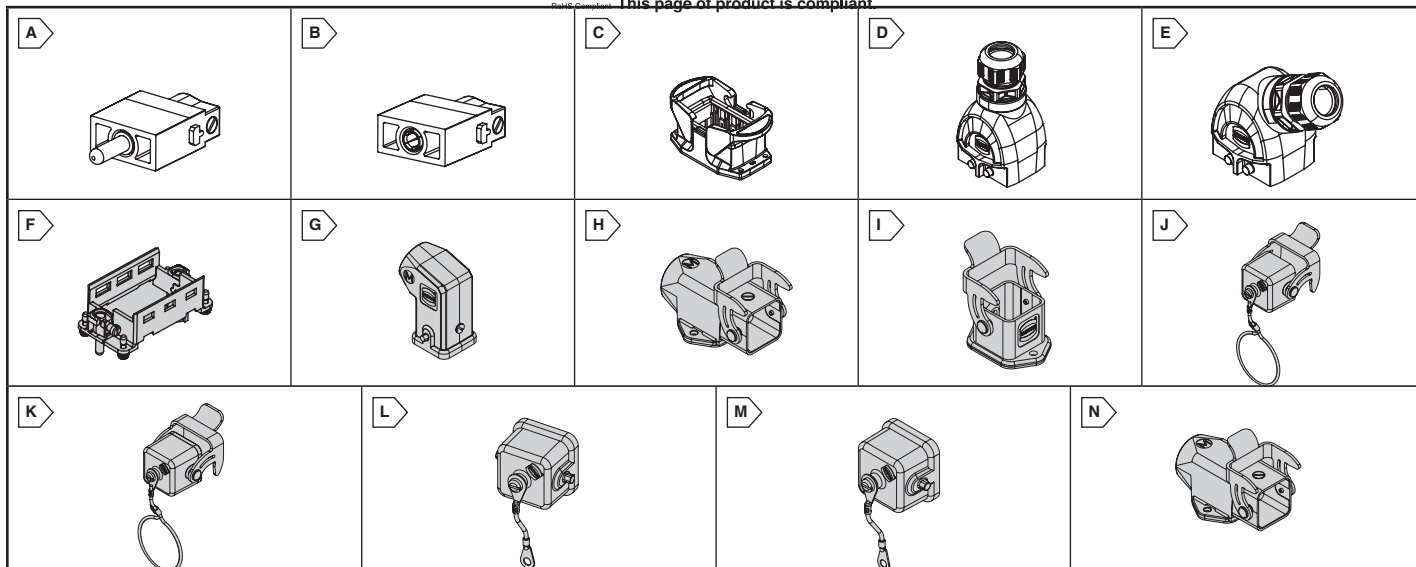

HAN-ECO® SERIES

- Available in sizes 6B, 10B, 16B and 24B including integrated cable glands
- Capable for applications according protection class II
- Same panel cut out as Han® B housings, bulkhead mounting
- Not mating compatible with series Han® B



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	Han-Eco® Hood & Housing Size	Description	Price Each		
					1	10	25
617-19410012600	19 41 001 2600	A	-	Male insert contact module	11.05	9.93	9.37
617-19410012700	19 41 001 2700	B	-	Female insert contact module	11.05	9.93	9.37
617-19410060301	19 41 006 0301	C	6B	6B Bulkhead mounting housing	11.25	10.11	9.54
617-19410100301	19 41 010 0301	C	10B	10B Bulkhead mounting housing	16.35	14.70	13.88
617-19410160301	19 41 016 0301	C	16B	16B Bulkhead mounting housing	17.15	15.42	14.55
617-19410240301	19 41 024 0301	C	24B	24B Bulkhead mounting housing	18.24	16.39	15.47
617-19411060422	19 41 106 0422	D	6B	6B Top Entry Hood	23.88	21.47	20.26
617-19411060522	19 41 106 0522	E	6B	6B Side Entry Hood	23.88	21.47	20.26
617-19411100422	19 41 110 0422	D	10B	10B Top Entry Hood	26.39	23.73	22.39
617-19411100522	19 41 110 0522	E	10B	10B Side Entry Hood	26.39	23.73	22.39
617-19411160423	19 41 116 0423	D	16B	16B Top Entry Hood	38.49	34.60	32.66
617-19411160523	19 41 116 0523	E	16B	16B Side Entry Hood	38.49	34.60	32.66
617-19411240423	19 41 124 0423	D	24B	24B Top Entry Hood	42.49	38.20	36.05
617-19411240523	19 41 124 0523	E	24B	24B Side Entry Hood	42.49	38.20	36.05

HINGED FRAMES

- Grounding system according to VDE
- Modules can only be assembled polarized to guarantee correct orientation
- Both male and female modules may be mounted in the same hinged frame
- Hinged frames are mountable in standard hoods/housings
- High mechanical reliability of modules in case of vibrations and impact stress
- DIN VDE 0627, DIN VDE 0110, DIN EN 61 984
- RoHS Compliant per HARTING documentation
- Rigid die cast zinc frame
- Alphabetical marking of module positions
- No tool necessary to remove modules



RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	Han® Hood & Housing Size	Frame Size	Frame Marking	Price Each		
						1	10	25
617-09-14-006-0303	09 14 006 0303	F	6B	Holds 2 Modules	A-B	20.69	17.50	16.42
617-09-14-006-0313	09 14 006 0313	F	6B	Holds 2 Modules	a-b	23.50	21.15	19.97
617-09-14-010-0303	09 14 010 0303	F	10B	Holds 3 Modules	A-C	22.35	20.25	19.10
617-09-14-010-0313	09 14 010 0313	F	10B	Holds 3 Modules	a-c	22.80	20.51	19.38
617-09-14-016-0303	09 14 016 0303	F	16B	Holds 4 Modules	A-D	22.94	20.64	19.50
617-09-14-016-0313	09 14 016 0313	F	16B	Holds 4 Modules	a-d	22.94	20.64	19.50
617-09-14-024-0303	09 14 024 0303	F	24B	Holds 6 Modules	A-F	23.98	21.57	20.39
617-09-14-024-0313	09 14 024 0313	F	24B	Holds 6 Modules	a-f	23.98	21.57	20.39
Accessory								
617-09-14-000-9960	09 14 000 9960	-		Locking Element for frames - 20 locks per piece		4.17	4.12	4.05

HAN-INOX® STAINLESS STEEL HOUSINGS AND HOODS

- Features:**
- Stainless steel hoods and housings
 - Stainless steel locking elements
 - Resistant against aggressive detergents
 - Suitable for all standard inserts that fit into size Han® 3A

- Applications:**
- Food and beverage industry
 - Water and sewage industry
 - Pharmaceutical industry
 - Chemical industry
 - Offshore and shipbuilding



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	HARTING Part No.	Fig.	Han® Size	Description	Price Each		
					1	10	25
617-19440031640	19 44 003 1640	G	3A	M20 Side Entry Stainless Steel Hood	78.76	73.14	67.52
617-19440031643	19 44 003 1643	G	3A	M20 Side Entry Stainless Steel Hood with Glued Gasket	81.37	75.56	69.75
617-19440031250	19 44 003 1250	H	3A	Right Angled Surface Mounted Housing M20	86.05	79.91	73.75
617-19440030301	19 44 003 0301	I	3A	Bulkhead Housing Stainless Steel	49.84	40.78	37.38
617-19440035422	19 44 003 5422	J	3A	Cover for Hood for Male Inserts	45.90	42.62	39.35
617-19440035421	19 44 003 5421	K	3A	Cover for Hood for Female Inserts	58.42	54.25	50.07
617-19440035426	19 44 003 5426	L	3A	Cover for Housing for Male Inserts	44.71	41.52	38.32
617-19440035425	19 44 003 5425	M	3A	Cover for Housing for Female Inserts	50.08	46.51	42.93
617-19440030801	19 44 003 0801	N	3A	Right Angled Bulkhead Mounted Housing	77.21	71.70	66.18