


# PANASONIC LEDs

# Panasonic

RoHS Compliant This product is RoHS compliant.

DIMENSIONS: mm

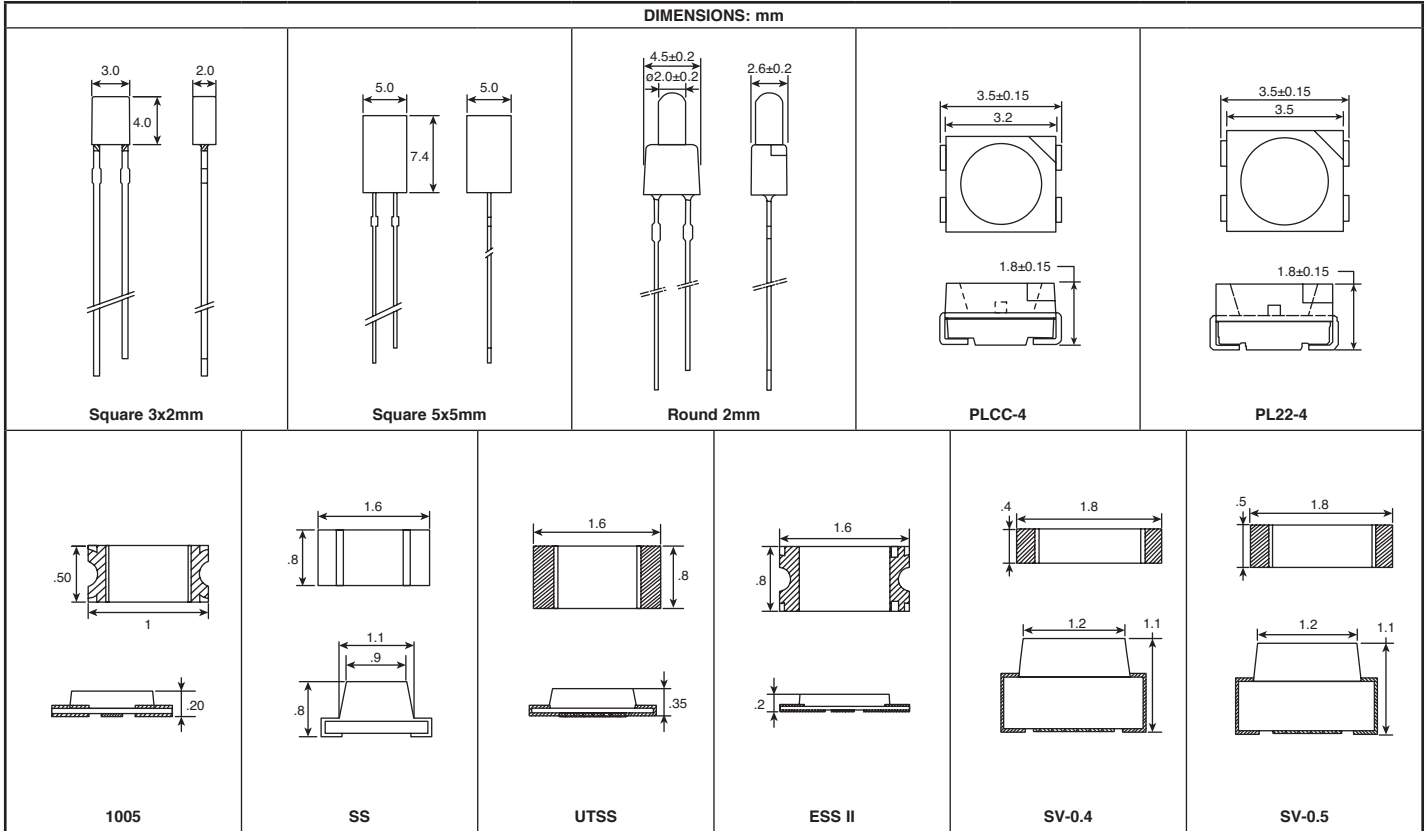

## PANASONIC THRU-HOLE LEDs

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Panasonic Part No.	Package	Color	Wavelength (nm)	Luminous Intensity Max. (mcd)	Forward Voltage Max. (V)	Price Each		
							1	25	100
<a href="#">667-LN260RPX</a>	LN260RPX	Square 3x2mm	Red Diffused	700	0.7	2.8	.61	.448	.384
<a href="#">667-LN873RPX</a>	LN873RPX	Square 5x5mm	Orange	630	3	2.8	.61	.448	.384
<a href="#">667-LN882RPX</a>	LN882RPX	Round 2mm	Orange	630	6	2.8	.43	.313	.268

## PANASONIC SURFACE MOUNT LEDs

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Panasonic Part No.	Package	Color	Wavelength (nm)	Luminous Intensity Max. (mcd)	Forward Voltage Max. (V)	Price Each		
							1	25	100
<a href="#">667-LNJ047X8ARA</a>	LNJ047X8ARA	1005	White	-	111	3.2	.60	.393	.322
<a href="#">667-LNJ208R8ARA</a>	LNJ208R8ARA	SS	Red	660	6.7	2.5	.56	.329	.265
<a href="#">667-LNJ247W82RA</a>	LNJ247W82RA	1005	Red	645	26.8	2.3	.51	.297	.24
<a href="#">667-LNJ214R82RA</a>	LNJ214R82RA	UTSS	Red	645	15	1.92	.48	.32	.264
<a href="#">667-LNJ252W82RA</a>	LNJ252W82RA	SV-0.4	Red	645	40	2.5	.53	.349	.286
<a href="#">667-LNJ826W83RA</a>	LNJ826W83RA	UTSS	Orange	630	47.3	2.1	.46	.304	.25
<a href="#">667-LNJ847W83RA</a>	LNJ847W83RA	1005	Orange	630	47.3	2.3	.51	.297	.24
<a href="#">667-LNJ853W83RA</a>	LNJ853W83RA	SV-0.5	Orange	630	52.5	2.3	.17	.162	.158
<a href="#">667-LNJ8L4C18RAA</a>	LNJ8L4C18RAA	PLCC-4	Red	617	1130	2.65	1.52	1.20	1.08
<a href="#">667-LNJ8L4C28RAA</a>	LNJ8L4C28RAA	PLCC-4	Red	617	1810	2.65	1.64	1.29	1.16
<a href="#">667-LNJ826W86RA</a>	LNJ826W86RA	UTSS	Soft Orange	610	16.9	2.5	.46	.304	.25
<a href="#">667-LNJ853W86RA</a>	LNJ853W86RA	SV-0.5	Soft Orange	610	23	2.3	.38	.304	.25
<a href="#">667-LNJ847W86RA</a>	LNJ847W86RA	1005	Soft Orange	610	60.5	2.3	.51	.297	.24
<a href="#">667-LNJ447W84RA1</a>	LNJ447W84RA1	1005	Amber	595	30	1.95	.17	.162	.158
<a href="#">667-LNJ426W83RA</a>	LNJ426W83RA	UTSS	Amber	595	102	2.5	.46	.304	.25
<a href="#">667-LNJ347W83RA</a>	LNJ347W83RA	1005	Green	575	28	2.3	.51	.297	.24
<a href="#">667-LNJ326W83RA</a>	LNJ326W83RA	UTSS	Green	575	50	2.5	.48	.281	.227
<a href="#">667-LNJ308G8TRA</a>	LNJ308G8TRA	SS	Yellow Green	565	5	2.6	.46	.258	.196
<a href="#">667-LNJ926W8CRA</a>	LNJ926W8CRA	UTSS	Blue	465	24.6	3.15	.71	.493	.423
<a href="#">667-LNJ937W8CRA</a>	LNJ937W8CRA	ESS II	Blue	465	30	3.2	.48	.316	.26
<a href="#">667-LNJ953W8CRA</a>	LNJ953W8CRA	SV-0.5	Blue	465	34.7	3.2	.79	.325	.316
<a href="#">667-LNJ947W8CRA</a>	LNJ947W8CRA	1005	Blue	465	55	3.2	.52	.342	.28