


HIROSE 2.00mm Double Row Connectors



HIROSE ELECTRIC CO., LTD.

RoHS Compliant This product is RoHS compliant.

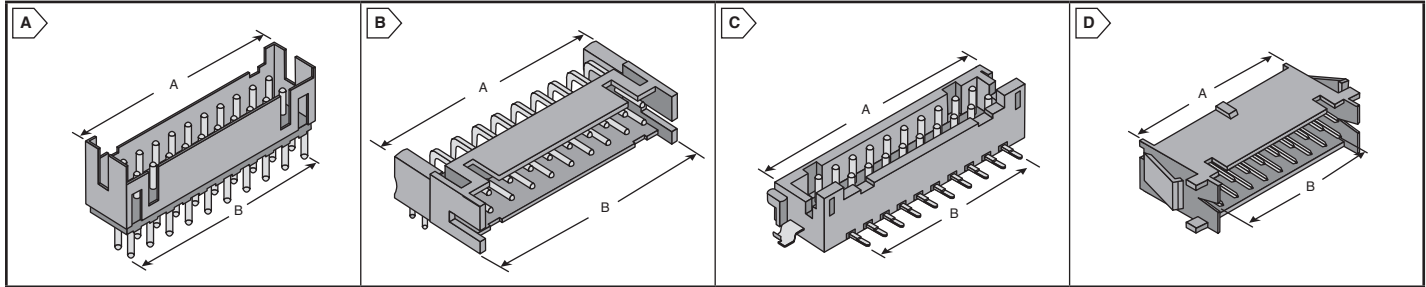

DF11 SERIES DOUBLE ROW CONNECTORS

Headers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim. (mm)		Price Each		
				A	B	1	25	100
Vertical - Tin - Thru-Hole								
798-DF11-4DP-2DSA08	DF11-4DP-2DSA(08)	A	4	6	2	.37	.18	.134
798-DF11-4DP-2DSA24	DF11-4DP-2DSA(24)	A	4	6	2	.62	.37	.289
798-DF11-6DP-2DSA08	DF11-6DP-2DSA(08)	A	6	8	4	.43	.20	.156
798-DF11-6DP-2DSA24	DF11-6DP-2DSA(24)	A	6	8	4	.68	.41	.316
798-DF11-8DP-2DSA08	DF11-8DP-2DSA(08)	A	8	10	6	.51	.229	.182
798-DF11-8DP-2DSA24	DF11-8DP-2DSA(24)	A	8	10	6	.59	.42	.341
798-DF11-10DP-2DSA08	DF11-10DP-2DSA(08)	A	10	12	8	.42	.24	.196
798-DF11-10DP-2DSA24	DF11-10DP-2DSA(24)	A	10	12	8	.71	.50	.416
798-DF11-12DP-2DSA08	DF11-12DP-2DSA(08)	A	12	14	10	.43	.25	.209
798-DF11-12DP-2DSA24	DF11-12DP-2DSA(24)	A	12	14	10	.76	.55	.442
798-DF11-14DP-2DSA08	DF11-14DP-2DSA(08)	A	14	16	12	.51	.29	.236
798-DF11-14DP-2DSA24	DF11-14DP-2DSA(24)	A	14	16	12	.88	.63	.512
798-DF11-16DP-2DSA08	DF11-16DP-2DSA(08)	A	16	18	14	.55	.32	.257
798-DF11-16DP-2DSA24	DF11-16DP-2DSA(24)	A	16	18	14	.95	.68	.554
798-DF11-18DP-2DSA08	DF11-18DP-2DSA(08)	A	18	20	16	.62	.36	.293
798-DF11-18DP-2DSA24	DF11-18DP-2DSA(24)	A	18	20	16	.99	.71	.582
798-DF11-20DP-2DSA08	DF11-20DP-2DSA(08)	A	20	22	18	.68	.39	.313
798-DF11-20DP-2DSA24	DF11-20DP-2DSA(24)	A	20	22	18	1.18	.84	.695
798-DF11-22DP-2DSA08	DF11-22DP-2DSA(08)	A	22	24	20	.76	.44	.357
798-DF11-22DP-2DSA24	DF11-22DP-2DSA(24)	A	22	24	20	1.26	.90	.735
798-DF11-24DP-2DSA08	DF11-24DP-2DSA(08)	A	24	26	22	.79	.46	.371
798-DF11-24DP-2DSA24	DF11-24DP-2DSA(24)	A	24	26	22	1.30	.94	.765
798-DF11-26DP-2DSA08	DF11-26DP-2DSA(08)	A	26	28	24	.62	.45	.374
798-DF11-26DP-2DSA24	DF11-26DP-2DSA(24)	A	26	28	24	1.40	1.01	.824
798-DF11-28DP-2DSA08	DF11-28DP-2DSA(08)	A	28	30	26	.66	.46	.392
798-DF11-28DP-2DSA24	DF11-28DP-2DSA(24)	A	28	30	26	1.49	1.06	.875
798-DF11-30DP-2DSA08	DF11-30DP-2DSA(08)	A	30	32	28	.70	.51	.414
798-DF11-30DP-2DSA24	DF11-30DP-2DSA(24)	A	30	32	28	1.52	1.09	.895
798-DF11-32DP-2DSA08	DF11-32DP-2DSA(08)	A	32	34	30	.84	.60	.494
798-DF11-32DP-2DSA24	DF11-32DP-2DSA(24)	A	32	34	30	1.60	1.16	.945
Vertical - Gold - Thru-Hole								
798-DF11-4DP-2DSA01	DF11-4DP-2DSA(01)	A	4	6	2	.76	.55	.442
798-DF11-6DP-2DSA01	DF11-6DP-2DSA(01)	A	6	8	4	.99	.72	.585
798-DF11-8DP-2DSA01	DF11-8DP-2DSA(01)	A	8	10	6	1.17	.76	.692
798-DF11-10DP-2DSA01	DF11-10DP-2DSA(01)	A	10	12	8	1.40	1.00	.825
798-DF11-12DP-2DSA01	DF11-12DP-2DSA(01)	A	12	14	10	1.63	1.17	.965
798-DF11-14DP-2DSA01	DF11-14DP-2DSA(01)	A	14	16	12	1.82	1.30	1.07
798-DF11-16DP-2DSA01	DF11-16DP-2DSA(01)	A	16	18	14	1.76	1.34	1.08
798-DF11-18DP-2DSA01	DF11-18DP-2DSA(01)	A	18	20	16	1.95	1.49	1.20
798-DF11-20DP-2DSA01	DF11-20DP-2DSA(01)	A	20	22	18	2.14	1.63	1.32
798-DF11-22DP-2DSA01	DF11-22DP-2DSA(01)	A	22	24	20	2.37	1.82	1.46
798-DF11-24DP-2DSA01	DF11-24DP-2DSA(01)	A	24	26	22	2.53	1.94	1.56
798-DF11-26DP-2DSA01	DF11-26DP-2DSA(01)	A	26	28	24	2.73	2.10	1.68
798-DF11-30DP-2DSA01	DF11-30DP-2DSA(01)	A	30	32	28	3.08	2.38	1.90
798-DF11-32DP-2DSA01	DF11-32DP-2DSA(01)	A	32	34	30	3.27	2.51	2.02
Right Angle - Tin - Thru-Hole								
798-DF11-4DP-2DS24	DF11-4DP-2DS(24)	B	4	6	2	.70	.41	.316
798-DF11-6DP-2DS24	DF11-6DP-2DS(24)	B	6	8	4	.64	.46	.378
798-DF11-8DP-2DS24	DF11-8DP-2DS(24)	B	8	10	6	.71	.50	.412
798-DF11-10DP-2DS24	DF11-10DP-2DS(24)	B	10	12	8	.87	.62	.512
798-DF11-12DP-2DS24	DF11-12DP-2DS(24)	B	12	14	10	.98	.71	.582
798-DF11-14DP-2DS24	DF11-14DP-2DS(24)	B	14	16	12	1.17	.85	.698
798-DF11-16DP-2DS24	DF11-16DP-2DS(24)	B	16	18	14	1.40	1.00	.825
798-DF11-18DP-2DS24	DF11-18DP-2DS(24)	B	18	20	16	1.40	1.00	.825
798-DF11-20DP-2DS24	DF11-20DP-2DS(24)	B	20	22	18	1.60	1.14	.935
798-DF11-22DP-2DS24	DF11-22DP-2DS(24)	B	22	24	20	1.71	1.22	1.00
798-DF11-24DP-2DS24	DF11-24DP-2DS(24)	B	24	26	22	1.93	1.39	1.14
798-DF11-26DP-2DS24	DF11-26DP-2DS(24)	B	26	28	24	1.73	1.33	1.06
798-DF11-28DP-2DS24	DF11-28DP-2DS(24)	B	28	30	26	1.82	1.39	1.12
798-DF11-30DP-2DS24	DF11-30DP-2DS(24)	B	30	32	28	1.92	1.48	1.18
798-DF11-32DP-2DS24	DF11-32DP-2DS(24)	B	32	34	30	2.05	1.56	1.26

Headers (Cont.)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim. (mm)		Price Each		
				A	B	1	25	100
Right Angle - Gold - Thru-Hole								
798-DF11-4DP-2DS52	DF11-4DP-2DS(52)	B	4	6	2	1.18	.84	.695
798-DF11-6DP-2DS52	DF11-6DP-2DS(52)	B	6	8	4	1.48	1.06	.875
798-DF11-8DP-2DS52	DF11-8DP-2DS(52)	B	8	10	6	1.89	1.36	1.12
798-DF11-10DP-2DS52	DF11-10DP-2DS(52)	B	10	12	8	1.85	1.41	1.14
798-DF11-12DP-2DS52	DF11-12DP-2DS(52)	B	12	14	10	2.17	1.66	1.34
798-DF11-14DP-2DS52	DF11-14DP-2DS(52)	B	14	16	12	2.40	1.83	1.48
798-DF11-16DP-2DS52	DF11-16DP-2DS(52)	B	16	18	14	2.76	2.12	1.70
798-DF11-18DP-2DS52	DF11-18DP-2DS(52)	B	18	20	16	3.01	2.31	1.86
798-DF11-20DP-2DS52	DF11-20DP-2DS(52)	B	20	22	18	3.31	2.54	2.04
798-DF11-22DP-2DS52	DF11-22DP-2DS(52)	B	22	24	20	3.21	2.49	1.98
798-DF11-24DP-2DS52	DF11-24DP-2DS(52)	B	24	26	22	3.50	2.71	2.17
798-DF11-26DP-2DS52	DF11-26DP-2DS(52)	B	26	28	24	3.76	2.93	2.33
798-DF11-28DP-2DS52	DF11-28DP-2DS(52)	B	28	30	26	3.99	3.10	2.48
798-DF11-30DP-2DS52	DF11-30DP-2DS(52)	B	30	32	28	4.25	3.30	2.64
798-DF11-32DP-2DS52	DF11-32DP-2DS(52)	B	32	34	30	4.49	3.48	2.78
Vertical - Tin - SMT								
798-DF11GZ-4DP-2V20	DF11GZ-4DP-2V(20)	C	4	8.5	2	1.29	.92	.765
798-DF11GZ-6DP-2V20	DF11GZ-6DP-2V(20)	C	6	10.5	4	1.40	1.00	.825
798-DF11GZ-8DP-2V20	DF11GZ-8DP-2V(20)	C	8	12.5	6	1.51	1.09	.894
798-DF11GZ-10DP-2V20	DF11GZ-10DP-2V(20)	C	10	14.5	8	1.62	1.17	.964
798-DF11GZ-12DP-2V20	DF11GZ-12DP-2V(20)	C	12	16.5	10	1.75	1.25	1.04
798-DF11GZ-14DP-2V20	DF11GZ-14DP-2V(20)	C	14	18.5	12	1.89	1.36	1.12
798-DF11GZ-16DP-2V20	DF11GZ-16DP-2V(20)	C	16	20.5	14	1.73	1.33	1.06
798-DF11GZ-18DP-2V20	DF11GZ-18DP-2V(20)	C	18	22.5	16	1.81	1.39	1.12
798-DF11GZ-20DP-2V20	DF11GZ-20DP-2V(20)	C	20	24.5	18	1.92	1.46	1.18
798-DF11GZ-22DP-2V20	DF11GZ-22DP-2V(20)	C	22	26.5	20	2.04	1.56	1.26
798-DF11GZ-24DP-2V20	DF11GZ-24DP-2V(20)	C	24	28.5	22	2.18	1.67	1.34
798-DF11GZ-26DP-2V20	DF11GZ-26DP-2V(20)	C	26	30.5	24	2.30	1.77	1.42
798-DF11GZ-28DP-2V20	DF11GZ-28DP-2V(20)	C	28	32.5	26	2.47	1.90	1.52
798-DF11GZ-30DP-2V20	DF11GZ-30DP-2V(20)	C	30	34.5	28	2.57	1.96	1.58
798-DF11GZ-32DP-2V20	DF11GZ-32DP-2V(20)	C	32	36.5	30	2.65	2.03	1.64
Vertical - Gold - SMT								
798-DF11G-4DP-2V50	DF11G-4DP-2V(50)	C	4	8.5	2	1.89	1.36	1.12
798-DF11G-6DP-2V50	DF11G-6DP-2V(50)	C	6	10.5	4	1.82	1.39	1.12
798-DF11G-8DP-2V50	DF11G-8DP-2V(50)	C	8	12.5	6	2.05	1.56	1.26
798-DF11G-10DP-2V50	DF11G-10DP-2V(50)	C	10	14.5	8	2.31	1.78	1.42
798-DF11G-12DP-2V50	DF11G-12DP-2V(50)	C	12	16.5	10	2.60	2.00	1.60
798-DF11G-14DP-2V50	DF11G-14DP-2V(50)	C	14	18.5	12	2.82	2.18	1.74
798-DF11G-16DP-2V50	DF11G-16DP-2V(50)	C	16	20.5	14	3.11	2.39	1.92
798-DF11G-18DP-2V50	DF11G-18DP-2V(50)	C	18	22.5	16	3.31	2.54	2.04
798-DF11G-20DP-2V50	DF11G-20DP-2V(50)	C	20	24.5	18	3.19	2.48	1.98
798-DF11G-22DP-2V50	DF11G-22DP-2V(50)	C	22	26.5	20	3.50	2.71	2.17
798-DF11G-24DP-2V50	DF11G-24DP-2V(50)	C	24	28.5	22	3.76	2.91	2.33
798-DF11G-26DP-2V50	DF11G-26DP-2V(50)	C	26	30.5	24	4.11	3.18	2.54
798-DF11G-30DP-2V50	DF11G-30DP-2V(50)	C	30	34.5	28	4.60	3.56	2.85
798-DF11G-32DP-2V50	DF11G-32DP-2V(50)	C	32	36.5	30	4.84	3.75	3.00
798-DF11G-40DP-2V50	DF11G-40DP-2V(50)	C	40	44.5	38	5.97	4.62	3.69
Adapter - Male-Male - Panel Locks								
798-DF11-4DEP-2A	DF11-4DEP-2A	D	4	11	2	.72	.52	.422
798-DF11-6DEP-2A	DF11-6DEP-2A	D	6	13	4	.79	.525	.472
798-DF11								