


HIROSE 2.0mm for Double Row Connections

RoHS Compliant This product is RoHS compliant.

HRS
HIROSE ELECTRIC CO., LTD.

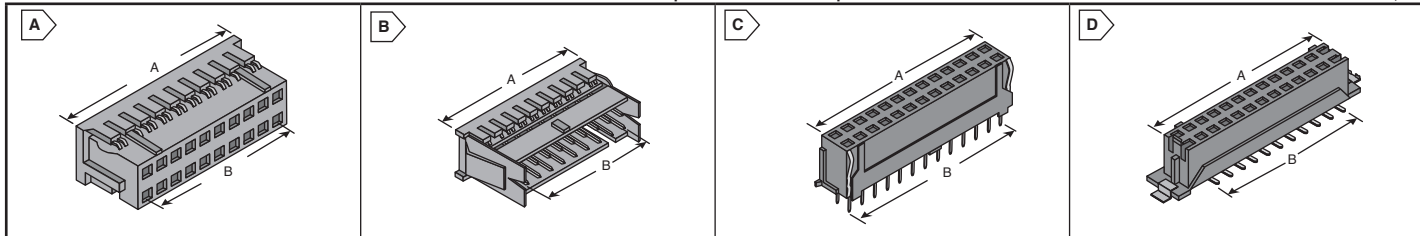

DF11 SERIES DOUBLE ROW CONNECTORS

Housings

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Contacts	Dim.		Price Each		
				A	B	1	25	100
Crimp Receptacle Housings								
798-DF11-4DS-2C	DF11-4DS-2C	A	4	6	2	.29	.14	.105
798-DF11-6DS-2C	DF11-6DS-2C	A	6	8	4	.31	.15	.115
798-DF11-8DS-2C	DF11-8DS-2C	A	8	10	6	.37	.18	.135
798-DF11-10DS-2C	DF11-10DS-2C	A	10	12	8	.38	.18	.138
798-DF11-12DS-2C	DF11-12DS-2C	A	12	14	10	.41	.189	.136
798-DF11-14DS-2C	DF11-14DS-2C	A	14	16	12	.44	.20	.158
798-DF11-16DS-2C	DF11-16DS-2C	A	16	18	14	.47	.22	.168
798-DF11-18DS-2C	DF11-18DS-2C	A	18	20	16	.49	.23	.17
798-DF11-20DS-2C	DF11-20DS-2C	A	20	22	18	.51	.24	.18
798-DF11-22DS-2C	DF11-22DS-2C	A	22	24	20	.54	.25	.19
798-DF11-24DS-2C	DF11-24DS-2C	A	24	26	22	.57	.26	.20
798-DF11-26DS-2C	DF11-26DS-2C	A	26	28	24	.44	.25	.202
798-DF11-28DS-2C	DF11-28DS-2C	A	28	30	26	.47	.26	.211
798-DF11-30DS-2C	DF11-30DS-2C	A	30	32	28	.51	.28	.232
798-DF11-32DS-2C	DF11-32DS-2C	A	32	34	30	.56	.32	.251
Crimp Plug Housings								
798-DF11-4DEP-2C	DF11-4DEP-2C	B	4	11	2	.54	.31	.241
798-DF11-6DEP-2C	DF11-6DEP-2C	B	6	13	4	.56	.32	.251
798-DF11-8DEP-2C	DF11-8DEP-2C	B	8	15	6	.58	.34	.264
798-DF11-10DEP-2C	DF11-10DEP-2C	B	10	17	8	.60	.35	.284
798-DF11-12DEP-2C	DF11-12DEP-2C	B	12	19	10	.62	.36	.286
798-DF11-14DEP-2C	DF11-14DEP-2C	B	14	21	12	.65	.38	.304
798-DF11-16DEP-2C	DF11-16DEP-2C	B	16	23	14	.68	.39	.316
798-DF11-18DEP-2C	DF11-18DEP-2C	B	18	25	16	.70	.40	.326
798-DF11-20DEP-2C	DF11-20DEP-2C	B	20	27	18	.72	.41	.328
798-DF11-22DEP-2C	DF11-22DEP-2C	B	22	29	20	.73	.43	.346
798-DF11-24DEP-2C	DF11-24DEP-2C	B	24	31	22	.78	.45	.359
798-DF11-26DEP-2C	DF11-26DEP-2C	B	26	33	24	.60	.43	.347
798-DF11-28DEP-2C	DF11-28DEP-2C	B	28	35	26	.62	.43	.358
798-DF11-30DEP-2C	DF11-30DEP-2C	B	30	37	28	.63	.443	.369
798-DF11-32DEP-2C	DF11-32DEP-2C	B	32	39	30	.65	.46	.38

Crimp Contacts

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	Plating	AWG	Price Each		
					1	25	100
Female							
798-DF11-22SC	DF11-22SC	-	Tin	22	.27	.13	.072
798-DF11-2428SC	DF11-2428SC	-	Tin	24-28	.24	.11	.062
798-DF11-30SC	DF11-30SC	-	Tin	30	.24	.17	.083
798-DF11-22SCA	DF11-22SCA	-	Gold	22	.36	.22	.127
798-DF11-2428SCA	DF11-2428SCA	-	Gold	24-28	.35	.20	.127
798-DF11-30SCA	DF11-30SCA	-	Gold	30	.34	.20	.117
Male							
798-DF11-EP2428PC	DF11-EP2428PC	-	Tin	24-28	.32	.12	.093
798-DF11-EP2428PCA	DF11-EP2428PCA	-	Gold	24-28	.37	.22	.127

Crimp Contacts (Reels)

MOUSER STOCK NO.	Hirose Part No.	Fig.	Plating	AWG	Reel Qty.	Price Each
798-DF11-22SCF	DF11-22SCF	-	Tin	22	10000	.03
798-DF11-2428SCF	DF11-2428SCF	-	Tin	24-28	10000	.02
798-DF11-30SCF	DF11-30SCF	-	Tin	30	10000	.03
798-DF11-22SCFA	DF11-22SCFA	-	Gold	22	10000	.06
798-DF11-2428SCFA	DF11-2428SCFA	-	Gold	24-28	10000	.063
798-DF11-2428SCFA04	DF11-2428SCFA(04)	-	Gold	24-28	10000	.029
798-DF11-30SCFA	DF11-30SCFA	-	Gold	30	10000	.063
Male						
798-DF11-EP2428PCF	DF11-EP2428PCF	-	Tin	24-28	10000	.03
798-DF11-EP2428PCFA	DF11-EP2428PCFA	-	Gold	24-28	10000	.075

Crimp Contacts (Tooling)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Description	Price Each
798-DF11-TA2428HC	DF11-TA2428HC	Tool with Die 24-28 AWG Fem	591.85
798-DF11-TA30HC	DF11-TA30HC	Tool 30AWG Fem	887.90

Receptacles

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Hirose Part No.	Fig.	No. of Circuits	Dim.		Price Each		
				A	B	1	25	100
PCB Receptacles - Vertical - Tin - Thru-Hole								
798-DF11-6DS-2DSA05	DF11-6DS-2DSA(05)	C	6	8	4	1.06	.76	.622
798-DF11-8DS-2DSA05	DF11-8DS-2DSA(05)	C	8	10	6	1.13	.82	.672
798-DF11-10DS-2DSA05	DF11-10DS-2DSA(05)	C	10	12	8	1.26	.90	.735
798-DF11-12DS-2DSA05	DF11-12DS-2DSA(05)	C	12	14	10	1.36	.97	.805
798-DF11-14DS-2DSA05	DF11-14DS-2DSA(05)	C	14	16	12	1.45	1.05	.855
798-DF11-16DS-2DSA05	DF11-16DS-2DSA(05)	C	16	18	14	1.60	1.16	.945
798-DF11-18DS-2DSA05	DF11-18DS-2DSA(05)	C	18	20	16	1.71	1.23	1.01
798-DF11-20DS-2DSA05	DF11-20DS-2DSA(05)	C	20	22	18	1.86	1.34	1.10
798-DF11-22DS-2DSA05	DF11-22DS-2DSA(05)	C	22	24	20	1.94	1.39	1.14
798-DF11-24DS-2DSA05	DF11-24DS-2DSA(05)	C	24	26	22	1.76	1.34	1.08
798-DF11-26DS-2DSA05	DF11-26DS-2DSA(05)	C	26	28	24	1.85	1.41	1.14
798-DF11-28DS-2DSA05	DF11-28DS-2DSA(05)	C	28	30	26	1.95	1.49	1.20
798-DF11-32DS-2DSA05	DF11-32DS-2DSA(05)	C	32	34	30	2.11	1.62	1.30
PCB Receptacles - Vertical - Gold - Thru-Hole								
798-DF11-6DS-2DSA06	DF11-6DS-2DSA(06)	C	6	8	4	1.68	1.20	.985
798-DF11-8DS-2DSA06	DF11-8DS-2DSA(06)	C	8	10	6	1.70	1.30	1.04
798-DF11-10DS-2DSA06	DF11-10DS-2DSA(06)	C	10	12	8	1.95	1.49	1.20
798-DF11-12DS-2DSA06	DF11-12DS-2DSA(06)	C	12	14	10	2.24	1.72	1.38
798-DF11-14DS-2DSA06	DF11-14DS-2DSA(06)	C	14	16	12	2.50	1.92	1.54
798-DF11-16DS-2DSA06	DF11-16DS-2DSA(06)	C	16	18	14	2.80	2.15	1.72
798-DF11-18DS-2DSA06	DF11-18DS-2DSA(06)	C	18	20	16	3.06	2.35	1.88
798-DF11-20DS-2DSA06	DF11-20DS-2DSA(06)	C	20	22	18	3.38	2.59	2.08
798-DF11-24DS-2DSA06	DF11-24DS-2DSA(06)	C	24	26	22	3.48	2.69	2.16
798-DF11-26DS-2DSA06	DF11-26DS-2DSA(06)	C	26	28	24	3.74	2.90	2.32
798-DF11-32DS-2DSA06	DF11-32DS-2DSA(06)	C	32	34	30	4.43	3.44	2.75
PCB Receptacles - Vertical - Tin - SMT								
798-DF11Z-6DS-2V20	DF11Z-6DS-2V(20)	D	6	10.5	4	1.25	.90	.735
798-DF11Z-10DS-2V20	DF11Z-10DS-2V(20)	D	10	14.5	8	1.47	1.06	.874
798-DF11Z-12DS-2V20	DF11Z-12DS-2V(20)	D	12	16.5	10	1.63	1.17	.965
798-DF11Z-14DS-2V20	DF11Z-14DS-2V(20)	D	14	18.5	12	1.74	1.25	1.03
798-DF11Z-16DS-2V20	DF11Z-16DS-2V(20)	D	16	20.5	14	1.93	1.38	1.13
798-DF11Z-20DS-2V20	DF11Z-20DS-2V(20)	D	20	24.5	18	1.92	1.48	1.18
798-DF11Z-22DS-2V20	DF11Z-22DS-2V(20)	D	22	26.5	20	2.01	1.54	1.24
798-DF11Z-24DS-2V20	DF11Z-24DS-2V(20)	D	24	28.5	22	2.21	1.68	1.36
798-DF11Z-26DS-2V20	DF11Z-26DS-2V(20)	D	26	30.5	24	2.40	1.84	1.48
798-DF11Z-28DS-2V20	DF11Z-28DS-2V(20)	D	28	32.5	26	2.40	1.85	1.48
798-DF11Z-30DS-2V20	DF11Z-30DS-2V(20)	D	30	34.5	28	2.66	2.05	1.64
798-DF11Z-32DS-2V20	DF11Z-32DS-2V(20)	D	32	34	30	2.83	2.18	1.74
798-DF11Z-40DS-2V20	DF11Z-40DS-2V(20)	D	40	44.5	38	3.10	2.88	1.91
PCB Receptacles - Vertical - Gold - SMT								
798-DF11Z-10DS-2V50	DF11Z-10DS-2V(50)	D	10	14.5	8	2.28	1.75	1.40
798-DF11Z-12DS-2V50	DF11Z-12DS-2V(50)	D	12	16.5	10	2.57	1.97	1.58
798-DF11Z-14DS-2V50	DF11Z-14DS-2V(50)	D	14	18.5	12	2.67	2.05	1.64
798-DF11Z-16DS-2V50	DF11Z-16DS-2V(50)	D	16	20.5	14	3.12	2.39	1.92
798-DF11Z-18DS-2V50	DF11Z-18DS-2V(50)	D	18	22.5	16	3.41	2.63	2.10
798-DF11Z-20DS-2V50	DF11Z-20DS-2V(50)	D	20	24.5	18	3.27	2.53	2.02
798-DF11Z-24DS-2V50	DF11Z-24DS-2V(50)	D	24	28.5	22	3.85	2.99	2.39
798-DF11Z-26DS-2V50	DF11Z-26DS-2V(50)	D	26	30.5	24	3.96	3.07	2.45
798-DF11Z-28DS-2V50	DF11Z-28DS-2V(50)	D	28	32.5	26	4.18	3.24	2.59

Rectangular Connectors Hirose