


MOLEX .093" Pin and Socket Connectors

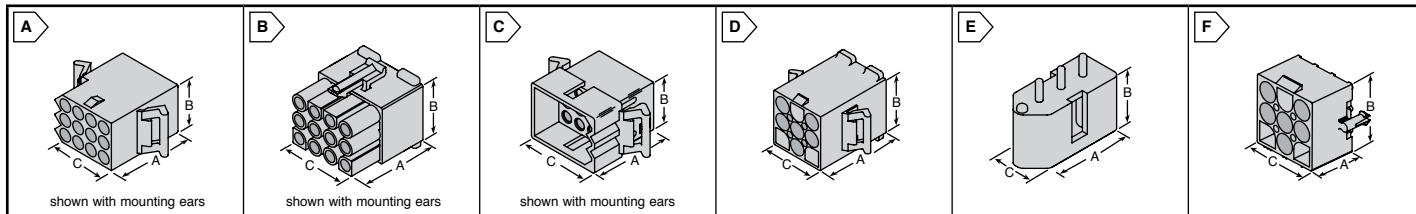

.093" RECEPTACLES

* Male and female terminals may be used in receptacle housings

*.248" grid spacing

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Cir.	Circuit Pattern	Dimensions: in.			Price Each		
					A	B	C	1	10	100
Standard .198" Panel Mount Receptacles - 94V-2										
* 538-03-09-1027	03-09-1027	A	2	In-line	1.03	.25	.54	.26	.23	.13
538-03-09-1081	03-09-1081	A	3	In-line	1.01	.24	.67	.44	.38	.262
538-03-09-1040	03-09-1040	A	4	Matrix	1.03	.43	.43	.69	.543	.364
538-03-09-1041	03-09-1041	A	4	In-line	1.03	.24	.87	.61	.40	.25
538-03-09-1061	03-09-1061	A	6	Matrix	1.02	.63	.43	.68	.296	.24
538-03-09-1091	03-09-1091	A	9	Matrix	1.03	.63	.67	.69	.54	.392
538-03-09-1125	03-09-1125	A	12	Matrix	1.02	.63	.87	.78	.471	.349
538-03-09-1151	03-09-1151	A	15	Matrix	1.02	.63	1.07	1.09	.58	.43
Standard .198" Free-Hanging Receptacles - 94V-2										
538-03-09-1011	03-09-1011	A	1	In-line	1.03	.23	-	.15	.12	.092
538-03-09-1022	03-09-1022	A	2	In-line	1.02	.25	.54	.38	.20	.12
538-03-09-1032	03-09-1032	A	3	In-line	1.01	.24	.67	.45	.31	.15
538-03-09-1042	03-09-1042	A	4	In-line	1.06	.27	1.03	.25	.22	.21
538-03091049	03-09-1049	A	4	Matrix	1.03	.43	.43	.69	.61	.411
538-03-09-1064	03-09-1064	A	6	Matrix	1.05	.63	.63	.71	.34	.26
538-03-09-1094	03-09-1094	A	9	Matrix	1.03	.63	.67	.71	.554	.371
538-03-09-1126	03-09-1126	A	12	Matrix	1.02	.63	.87	.87	.47	.34
538-03-09-1157	03-09-1157	A	15	Matrix	1.02	.63	1.07	1.04	.623	.415
.264" Receptacles - 94V-0 - 3191 Series										
538-19-09-1016†	19-09-1016	B	1	In-line	1.18	.42	.30	.57	.23	.17
538-19-09-1026	19-09-1026	B	2	In-line	1.18	.50	.56	.73	.65	.449
538-19-09-1036	19-09-1036	B	3	In-line	1.18	.52	.85	.80	.46	.34
538-19-09-1046	19-09-1046	B	4	In-line	1.18	.50	1.09	1.01	.794	.533
538-19-09-1066	19-09-1066	B	6	Matrix	1.18	.76	.83	1.00	.775	.59
538-19-09-1096	19-09-1096	B	9	Matrix	1.18	.83	1.03	1.05	.818	.623
538-19-09-1126	19-09-1126	B	12	Matrix	1.18	.83	1.09	1.19	.782	.594
538-19-09-1156	19-09-1156	B	15	Matrix	1.18	.83	1.35	1.52	.996	.757
.264" Receptacles - 94V-2 - 3191 Series										
538-19-09-1019	19-09-1019	B	1	In-line	1.18	.42	.30	.32	.23	.181
538-19-09-1029	19-09-1029	B	2	In-line	1.18	.50	.56	.59	.465	.312
538-19-09-1039	19-09-1039	B	3	In-line	1.18	.52	.85	.48	.36	.296
538-19-09-1049	19-09-1049	B	4	In-line	1.18	.50	1.09	.69	.55	.33
538-19-09-1069	19-09-1069	B	6	Matrix	1.18	.76	.83	.75	.41	.31
538-19-09-1099	19-09-1099	B	9	Matrix	1.18	.83	1.03	.79	.47	.419
538-19-09-1129	19-09-1129	B	12	Matrix	1.18	.83	1.09	1.00	.785	.527
538-19-09-1159	19-09-1159	B	15	Matrix	1.18	.83	1.35	1.21	.96	.732

Rectangular Connectors

Molex

.093" PLUGS (CONT.)

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Cir.	Circuit Pattern	Dimensions: in.			Price Each		
					A	B	C	1	10	100
.264" Panel Mount Plugs - 94V-2 - 3191 Series										
538-19-09-2018	19-09-2018	D	2	In-line	1.18	.42	.30	.37	.31	.205
538-19-09-2028	19-09-2028	D	2	In-line	1.18	.52	.59	.59	.39	.296
538-19-09-2038	19-09-2038	D	3	In-line	1.18	.52	.85	.46	.34	.286
538-19-09-2048	19-09-2048	D	4	In-line	1.18	.50	1.09	.61	.54	.455
538-19-09-2068	19-09-2068	D	6	Matrix	1.18	.42	.30	.45	.41	.353
538-19-09-2098	19-09-2098	D	9	Matrix	1.18	.52	.59	.88	.687	.461
538-19-09-2128	19-09-2128	D	12	Matrix	1.18	.52	.85	1.00	.77	.49
538-19-09-2158	19-09-2158	D	15	Matrix	1.18	.50	1.09	1.21	.96	.732
.264" Free-Hanging Plugs - 94V-0 - 3191 Series										
538-19-09-2016	19-09-2016	D	1	In-line	1.18	.42	.30	.27	.25	.211
538-19-09-2026	19-09-2026	D	2	In-line	1.18	.52	.59	.60	.50	.455
538-19-09-2036	19-09-2036	D	3	In-line	1.18	.52	.85	.54	.45	.424
538-19-09-2046	19-09-2046	D	4	In-line	1.18	.50	1.09	.96	.90	.774
538-19-09-2126	19-09-2126	D	12	Matrix	1.18	.52	.85	.87	.78	.741
.264" Free-Hanging Plugs - 94V-2 - 3191 Series										
538-19-09-2019	19-09-2019	D	1	In-line	1.18	.42	.30	.31	.26	.18
538-19-09-2029	19-09-2029	D	2	In-line	1.18	.52	.59	.51	.32	.292
538-19-09-2039	19-09-2039	D	3	In-line	1.18	.52	.85	.58	.23	.18
538-19-09-2049	19-09-2049	D	4	In-line	1.18	.50	1.09	.63	.35	.26
538-19-09-2069	19-09-2069	D	6	Matrix	1.18	.42	.30	.72	.40	.29
538-19-09-2099	19-09-2099	D	9	Matrix	1.18	.52	.59	.48	.44	.392
538-19-09-2129	19-09-2129	D	12	Matrix	1.18	.52	.85	.53	.525	.389
538-19-09-2159	19-09-2159	D	15	Matrix	1.18	.50	1.09	.86	.666	.507

.093" HEADERS

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Cir.	Circuit Pattern	Dimensions: in.			Price Each		
					A	B	C	1	10	100
.198" Shrouded Headers - Mates with Standard .093 receptacles										
538-10-18-1032	10-18-1032	E	3	In-line	.33	.42	.77	1.76	1.21	.946
538-10-18-1041	10-18-1041	E	4	In-line	.33	.42	.97	2.01	1.39	1.08
538-10-18-1061	10-18-1061	E	6	Matrix	.54	.42	.74	2.14	1.48	1.15
538-10-18-1090	10-18-1090	E	9	Matrix	.77	.42	.73	2.78	2.30	1.70
.264" Shrouded Headers - Mates with 3191 Series Receptacles										
538-15-31-1026	15-31-1026	F	2	In-line	.37	.42	.77	1.40	.915	.69
538-15-31-1036	15-31-1036	F	3	In-line	.37	.42	.85	1.54	1.01	.769
538-15-31-1046	15-31-1046	F	4	In-line	.37	.42	1.11	1.72	1.33	1.01
538-15-31-1066	15-31-1066	F	6	Matrix	.64	.42	.85	2.28	1.57	1.40
538-15-31-1096	15-31-1096	F	9	Matrix	.90	.42	.85	4.34	3.59	2.69

.093" PLUGS

* Male and female terminals may be used in plug housings

*.248" grid spacing † Has positive lock rather than detent lock

RoHS Compliant

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Molex Part No.	Fig.	No. of Cir.	Circuit Pattern	Dimensions: in.			Price Each		
					A	B	C	1	10	100
Standard .198" Panel Mount Plugs										
* 538-03-09-2021	03-09-2021	C	2	In-line	1.00	.35	.64	.33	.29	.187
538-03-09-2031	03-09-2031	C	3	In-line	1.00	.34	.77	.48	.34	.272
538-03-09-2041	03-09-2041	C	4	In-line	1.00	.34	.97	.48	.41	.27
538-03-09-2040	03-09-2040	C	4	Matrix	1.02	.54	.54	.65	.561	.376
538-03-09-2061	03-09-2061	C	6	Matrix	1.00	.73	.54	.57	.49	.319
538-03-09-2091	03-09-2091	C	9	Matrix	1.00	.73	.77	.69	.54	.371
538-03-09-2122	03-09-2122	C	12	Matrix	.98	.74	.98	.65	.598	.401
538-03-09-2159	03-09-2159	C	15	Matrix	1.01	.63	1.07	1.42	1.10	.841
Standard .198" Free-Hanging Plugs										
538-03-09-2011	03-09-2011	C	1	In-line	1.00	.36	-	.14	.12	.084
538-03-09-2022	03-09-2022	C	2	In-line	1.00	.35	.64	.26	.21	.158
538-03-09-2032	03-09-2032	C	3	In-line	1.00	.34	.77	.40	.34	.187
538-03-09-2042	03-09-2042	C	4	In-line	1.00	.34	.97	.44	.38	.253
538-03-09-2049	03-09-2049	C	4	Matrix	1.02	.54	.54	.72	.561	.376
538-03-09-2062	03-09-2062	C	6	Matrix	1.00	.73	.54	.54	.42	.301
538-03-09-2092	03-09-2092	C	9	Matrix	1.00	.73	.77	.65	.549	.315
538-03-09-2121	03-09-2121	C	12	Matrix	.98	.74	.98	.77	.63	.445
.264" Panel Mount Plugs - 94V-0 - 3191 Series										
538-19-09-2017	19-09-2017	D	1	In-line	1.18	.42	.30	.45	.44	.255
538-19-09-2027	19-09-2027	D	2	In-line	1.18	.52	.59	.85	.516	.382
538-19-09-2037	19-09-2037	D	3	In-line	1.18	.52	.85	1.07	.74	.50
538-19-09-2047	19-09-2047	D	4	In-line	1.18	.50	1.09	1.01	.794	.533
538-19-09-2067	19-09-2067	D	6	Matrix	1.18	.42	.30	1.00	.775	.59
538-19-09-2097	19-09-2097	D	9	Matrix	1.18	.52	.59	1.05	.818	.623
538-19-09-2127	19-09-2127	D	12	Matrix	1.18	.52	.85	1.19	.923	.703
538-19-09-2157	19-09-2157	D	15	Matrix	1.18	.50	1.09	1.52	1.17	.897