


TE .100" Series IDC Connectors

RoHS Compliant This product is RoHS compliant.

TE Authorized Distributor
connectivity

Specifications:

- Voltage rating: 250VAC
- Current rating: 4A max.
- Low-level resistance: 5mΩ max. initial
- Operating temp.: -55°C to +105°C
- Dielectric withstanding Voltage: 750VAC/1min.
- Insulation resistance: 5000MΩ min. initial
- Pre-loaded with contacts

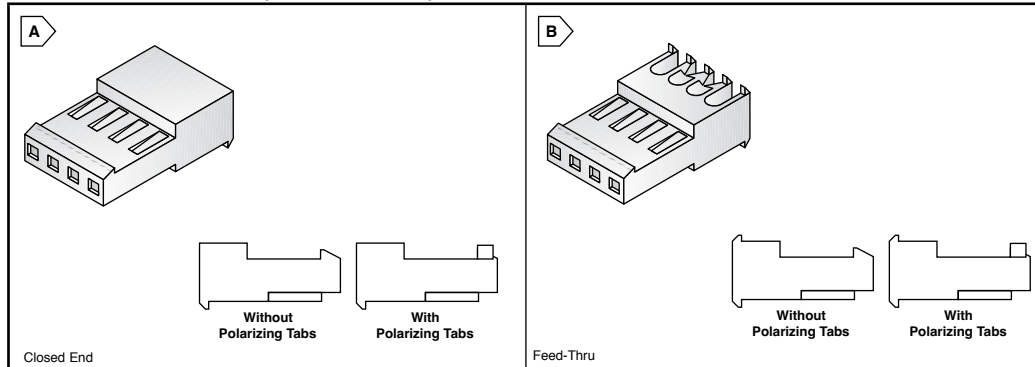

CLOSED END STYLE

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Closed End without Polarizing Tabs								
571-3-640440-2	3-640440-2	A	2	22	Red	.16	.142	.115
571-3-640440-3	3-640440-3	A	3	22	Red	.20	.177	.164
571-3-640440-4	3-640440-4	A	4	22	Red	.21	.183	.176
571-3-640440-5	3-640440-5	A	5	22	Red	.33	.281	.269
571-3-640440-6	3-640440-6	A	6	22	Red	.35	.30	.288
571-3-640440-7	3-640440-7	A	7	22	Red	.48	.433	.368
571-3-640440-8	3-640440-8	A	8	22	Red	.50	.47	.36
571-3-640440-9	3-640440-9	A	9	22	Red	1.26	1.21	1.15
571-4-640440-0	4-640440-0	A	10	22	Red	.68	.619	.527
571-3-640441-2	3-640441-2	A	2	24	White	.12	.107	.103
571-3-640441-3	3-640441-3	A	3	24	White	.19	.169	.157
571-3-640441-4	3-640441-4	A	4	24	White	.15	.132	.123
571-3-640441-5	3-640441-5	A	5	24	White	.35	.304	.292
571-3-640441-6	3-640441-6	A	6	24	White	.31	.282	.25
571-3-640441-7	3-640441-7	A	7	24	White	.48	.433	.368
571-3-640441-8	3-640441-8	A	8	24	White	.54	.49	.42
571-3-640441-9	3-640441-9	A	9	24	White	1.40	1.25	.901
571-4-640441-0	4-640441-0	A	10	24	White	.72	.68	.52
571-3-640442-2	3-640442-2	A	2	26	Blue	.14	.124	.115
571-3-640442-3	3-640442-3	A	3	26	Blue	.26	.226	.185
571-3-640442-4	3-640442-4	A	4	26	Blue	.28	.238	.229
571-3-640442-5	3-640442-5	A	5	26	Blue	.35	.304	.292
571-3-640442-6	3-640442-6	A	6	26	Blue	.41	.37	.315
571-3-640442-7	3-640442-7	A	7	26	Blue	.51	.48	.36
571-3-640442-8	3-640442-8	A	8	26	Blue	.58	.54	.42
571-3-640442-9	3-640442-9	A	9	26	Blue	1.47	1.23	.92
571-4-640442-0	4-640442-0	A	10	26	Blue	.59	.52	.371
571-3-640443-2	3-640443-2	A	2	28	Green	.14	.124	.115
571-3-640443-3	3-640443-3	A	3	28	Green	.24	.206	.198
571-3-640443-4	3-640443-4	A	4	28	Green	.28	.238	.229
571-3-640443-5	3-640443-5	A	5	28	Green	.35	.304	.292
571-3-640443-6	3-640443-6	A	6	28	Green	.37	.329	.315
571-3-640443-7	3-640443-7	A	7	28	Green	.51	.48	.33
571-3-640443-8	3-640443-8	A	8	28	Green	.54	.52	.40
571-4-640443-0	4-640443-0	A	10	28	Green	.73	.68	.52

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Closed End with Polarizing Tabs								
571-3-643813-2	3-643813-2	A	2	22	Red	.18	.142	.115
571-3-643813-3	3-643813-3	A	3	22	Red	.22	.19	.182
571-3-643813-4	3-643813-4	A	4	22	Red	.28	.238	.229
571-3-643813-5	3-643813-5	A	5	22	Red	.35	.30	.292
571-3-643813-6	3-643813-6	A	6	22	Red	.67	.628	.544
571-3-643813-7	3-643813-7	A	7	22	Red	.45	.40	.32
571-3-643813-8	3-643813-8	A	8	22	Red	.60	.566	.433
571-3-643813-9	3-643813-9	A	9	22	Red	1.49	1.08	.834
571-4-643813-0	4-643813-0	A	10	22	Red	.68	.619	.527
571-3-643814-2	3-643814-2	A	2	24	White	.14	.124	.115
571-3-643814-3	3-643814-3	A	3	24	White	.28	.262	.183
571-3-643814-4	3-643814-4	A	4	24	White	.30	.261	.251
571-3-643814-5	3-643814-5	A	5	24	White	.43	.40	.29
571-3-643814-6	3-643814-6	A	6	24	White	.40	.38	.29
571-3-643814-7	3-643814-7	A	7	24	White	.42	.40	.33
571-3-643814-8	3-643814-8	A	8	24	White	.54	.438	.42
571-3-643814-9	3-643814-9	A	9	24	White	1.33	1.17	.916
571-4-643814-0	4-643814-0	A	10	24	White	.70	.68	.49
571-3-643815-2	3-643815-2	A	2	26	Blue	.14	.124	.115
571-3-643815-3	3-643815-3	A	3	26	Blue	.23	.195	.188
571-3-643815-4	3-643815-4	A	4	26	Blue	.28	.238	.229
571-3-643815-5	3-643815-5	A	5	26	Blue	.41	.35	.292
571-3-643815-6	3-643815-6	A	6	26	Blue	.28	.275	.202
571-3-643815-7	3-643815-7	A	7	26	Blue	.48	.433	.368
571-3-643815-8	3-643815-8	A	8	26	Blue	.58	.438	.42
571-3-643815-9	3-643815-9	A	9	26	Blue	1.82	1.22	.889
571-4-643815-0	4-643815-0	A	10	26	Blue	.61	.51	.39
571-3-643816-2	3-643816-2	A	2	28	Green	.18	.16	.11
571-3-643816-3	3-643816-3	A	3	28	Green	.26	.22	.14
571-3-643816-4	3-643816-4	A	4	28	Green	.28	.238	.229
571-3-643816-5	3-643816-5	A	5	28	Green	.44	.35	.29
571-3-643816-6	3-643816-6	A	6	28	Green	.35	.302	.218
571-3-643816-7	3-643816-7	A	7	28	Green	.40	.37	.262
571-3-643816-8	3-643816-8	A	8	28	Green	.51	.49	.38
571-4-643816-0	4-643816-0	A	10	28	Green	.58	.519	.37

Rectangular Connectors TE Connectivity

FEED-THRU STYLE

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Feed-Thru without Polarizing Tabs								
571-3-640620-2	3-640620-2	B	2	22	Red	.21	.186	.178
571-3-640620-3	3-640620-3	B	3	22	Red	.29	.253	.243
571-3-640620-4	3-640620-4	B	4	22	Red	.28	.238	.229
571-3-640620-5	3-640620-5	B	5	22	Red	.44	.41	.29
571-3-640620-6	3-640620-6	B	6	22	Red	.43	.40	.31
571-3-640620-7	3-640620-7	B	7	22	Red	.51	.48	.36
571-3-640620-8	3-640620-8	B	8	22	Red	.49	.438	.42
571-3-640620-9	3-640620-9	B	9	22	Red	1.39	1.18	.898
571-4-640620-0	4-640620-0	B	10	22	Red	.68	.65	.48
571-3-640621-2	3-640621-2	B	2	24	White	.21	.185	.178
571-3-640621-3	3-640621-3	B	3	24	White	.22	.20	.14
571-3-640621-4	3-640621-4	B	4	24	White	.34	.28	.22
571-3-640621-5	3-640621-5	B	5	24	White	.44	.418	.292
571-3-640621-6	3-640621-6	B	6	24	White	.44	.41	.31
571-3-640621-8	3-640621-8	B	8	24	White	.52	.50	.38
571-4-640621-0	4-640621-0	B	10	24	White	.59	.52	.371
571-3-640622-2	3-640622-2	B	2	26	Blue	.19	.167	.119
571-3-640622-3	3-640622-3	B	3	26	Blue	.25	.24	.169
571-3-640622-4	3-640622-4	B	4	26	Blue	.32	.30	.21
571-3-640622-5	3-640622-5	B	5	26	Blue	.26	.25	.191
571-3-640622-6	3-640622-6	B	6	26	Blue	.35	.302	.223

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Number of Positions	Wire Size (AWG)	Color	Price Each		
						1	10	100
Feed-Thru with Polarizing Tabs								
571-3-644540-2	3-644540-2	B	2	22	Red	.21	.185	.178
571-3-644540-3	3-644540-3	B	3	22	Red	.28	.241	.232
571-3-644540-4	3-644540-4	B	4	22	Red	.30	.255	.245
571-3-644540-5	3-644540-5	B	5	22	Red	.37	.35	.25
571-3-644540-6	3-644540-6	B	6	22	Red	.44	.41	.31
571-3-644540-8	3-644540-8	B	8	22	Red	.46	.406	.294
571-3-644563-2	3-644563-2	B	2	24	White	.21	.179	.172
571-3-644563-3	3-644563-3	B	3	24	White	.27	.235	.226
571-3-644563-4	3-644563-4	B	4	24	White	.30	.28	.19
571-3-644563-5	3-644563-5	B	5	24	White	.44	.41	.29
571-3-644563-6	3-644563-6	B	6	24	White	.34	.302	.223
571-3-644563-8	3-644563-8	B	8	24	White	.47	.426	.307
571-3-644563-9	3-644563-9	B	9	24	White	1.28	1.16	.993
571-3-644565-4	3-644565-4	B	4	28	Green	.37	.34	.24