


TE Accessories and CST-100 Connectors



RoHS Compliant This product is RoHS compliant.

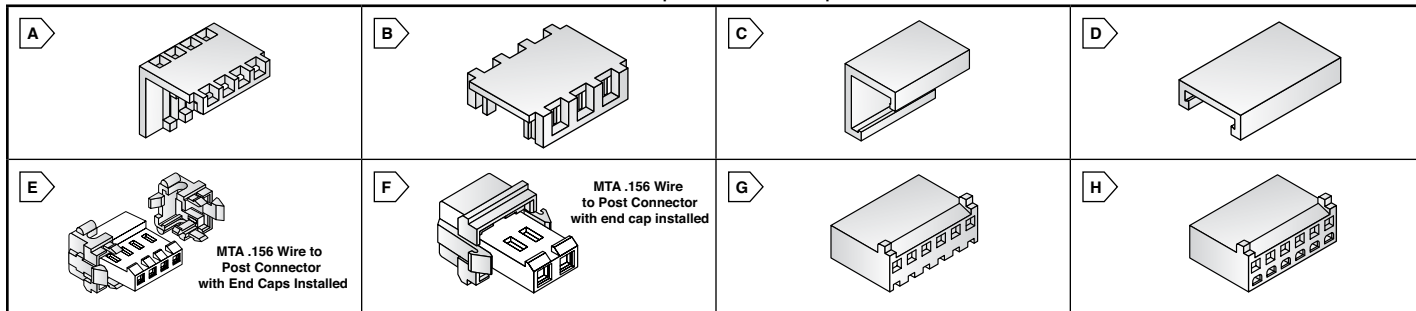

TE .100" CONNECTOR ACCESSORIES

Strain Relief Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
Closed End Strain Relief Covers						
571-6430752	643075-2	A	2	.30	.25	.20
571-6430753	643075-3	A	3	.59	.57	.51
571-6430754	643075-4	A	4	.30	.27	.24
571-6430755	643075-5	A	5	.62	.598	.515
571-6430756	643075-6	A	6	.30	.271	.268
571-6430757	643075-7	A	7	.74	.52	.47
571-6430758	643075-8	A	8	.65	.598	.537
571-16430750	1-643075-0	A	10	.60	.472	.431
571-16430752	1-643075-2	A	12	.65	.59	.54
571-16430754	1-643075-4	A	14	.60	.572	.499
571-16430756	1-643075-6	A	16	.70	.613	.566
Feed-Thru Strain Relief Covers						
571-6430772	643077-2	B	2	.38	.239	.211
571-6430773	643077-3	B	3	.41	.302	.273
571-6430774	643077-4	B	4	.39	.33	.276
571-6430775	643077-5	B	5	.60	.523	.477
571-6430776	643077-6	B	6	.67	.499	.484
571-6430778	643077-8	B	8	.74	.572	.53
571-6430779	643077-9	B	9	.69	.572	.52
571-16430770	1-643077-0	B	10	.60	.554	.534
571-16430772	1-643077-2	B	12	.61	.561	.519
571-16430774	1-643077-4	B	14	.62	.541	.493

Dust Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
Closed End Dust Covers						
571-6405502	640550-2	C	2	.10	.078	.064
571-6405503	640550-3	C	3	.11	.10	.09
571-6405504	640550-4	C	4	.15	.124	.103
571-6405505	640550-5	C	5	.14	.13	.12
571-6405506	640550-6	C	6	.20	.181	.14
571-6405507	640550-7	C	7	.21	.177	.153
571-6405508	640550-8	C	8	.32	.18	.16
571-6405509	640550-9	C	9	.23	.187	.17
571-16405500	1-640550-0	C	10	.37	.262	.22
571-16405502	1-640550-2	C	12	.32	.301	.244
571-16405504	1-640550-4	C	14	.38	.348	.28
571-16405506	1-640550-6	C	16	.37	.37	.264
Feed-Thru Dust Covers						
571-6406423	640642-3	D	3	.14	.084	.077
571-6406424	640642-4	D	4	.13	.114	.094
571-6406425	640642-5	D	5	.14	.114	.103
571-6406426	640642-6	D	6	.23	.155	.14
571-6406427	640642-7	D	7	.21	.195	.163
571-6406428	640642-8	D	8	.23	.197	.175
571-16406420	1-640642-0	D	10	.28	.239	.204

Note: No 2 position Feed-Thru Dust Cover available

Keying Plug

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Price Each		
			1	10	100
571-6419941	641994-1	-	.13	.115	.106

TE .156" CONNECTOR ACCESSORIES

Strain Relief Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
Closed End Strain Relief Covers						
571-6430672	643067-2	A	2	.28	.26	.25
571-6430673	643067-3	A	3	.64	.572	.51
571-6430674	643067-4	A	4	.59	.53	.48
571-6430675	643067-5	A	5	.68	.578	.523
571-6430676	643067-6	A	6	.66	.59	.51
571-6430677	643067-7	A	7	.77	.612	.562
571-6430678	643067-8	A	8	.66	.53	.52
571-6430679	643067-9	A	9	.73	.634	.481
571-16430670	1-643067-0	A	10	.57	.513	.491
571-16430672	1-643067-2	A	12	.87	.61	.57
571-16430674	1-643067-4	A	14	.61	.577	.512
571-16430676	1-643067-6	A	16	.58	.45	.411
Feed-Thru Strain Relief Covers						
571-6430712	643071-2	B	2	.21	.167	.152
571-6430713	643071-3	B	3	.33	.271	.238
571-6430714	643071-4	B	4	.44	.37	.29
571-6430715	643071-5	B	5	.55	.50	.355
571-6430716	643071-6	B	6	.58	.489	.445
571-6430717	643071-7	B	7	.62	.581	.527
571-6430718	643071-8	B	8	.83	.743	.592
571-6430719	643071-9	B	9	.72	.581	.52
571-16430710	1-643071-0	B	10	.80	.708	.592
571-16430716	1-643071-6	B	16	.66	.621	.555

Dust Covers

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
Closed End Dust Covers						
571-640551-2	640551-2	C	2	.15	.101	.07
571-640551-3	640551-3	C	3	.17	.128	.10
571-640551-4	640551-4	C	4	.17	.152	.123
571-640551-5	640551-5	C	5	.24	.17	.15
571-640551-6	640551-6	C	6	.24	.177	.149
571-640551-7	640551-7	C	7	.20	.18	.16
571-640551-8	640551-8	C	8	.29	.208	.189
571-640551-9	640551-9	C	9	.31	.271	.241
571-1640551-0	1-640551-0	C	10	.32	.279	.233
571-1640551-2	1-640551-2	C	12	.38	.348	.281
571-1640551-4	1-640551-4	C	14	.48	.403	.384
571-1640551-6	1-640551-6	C	16	.43	.392	.271
Feed-Thru Dust Covers						
571-640643-3	640643-3	D	3	.18	.136	.098
571-640643-4	640643-4	D	4	.22	.15	.122
571-640643-5	640643-5	D	5	.20	.155	.137
571-640643-6	640643-6	D	6	.24	.145	.133
571-640643-8	640643-8	D	8	.25	.184	.168
571-640643-9	640643-9	D	9	.31	.24	.216
571-1640643-0	1-640643-0	D	10	.34	.304	.245
571-1640643-2	1-640643-2	D	12	.38	.339	.282

Note: No 2 position Feed-Thru Dust Cover available

Keying Plug

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Price Each		
			1	10	100
Flush, Used with Keyed Headers					
571-6406291	640629-1	-	.10	.08	.07

Panel Mount End Caps

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
571-6414401	641440-1	E	3/24	1.07	.83	.782
571-6415331	641533-1	F	2	.70	.595	.523

CST-100 CONNECTORS

Mates with .100 MTA Headers, except the shrouded version.

• AWG: 26-22 • Color: White

CST-100 Receptacle Housings

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
571-770602-2	770602-2	G	2	.14	.094	.078
571-770602-3	770602-3	G	3	.15	.136	.11
571-770602-4	770602-4	G	4	.22	.21	.14
571-770602-5	770602-5	G	5	.21	.18	.173
571-770602-6	770602-6	G	6	.33	.31	.20
571-770602-7	770602-7	G	7	.33	.28	.20
571-770602-8	770602-8	G	8	.43	.42	.29
571-770602-9	770602-9	G	9	.40	.351	.26
571-1-770602-0	1-770602-0	G	10	.49	.45	.35
571-1-770602-1	1-770602-1	G	11	.44	.392	.307
571-1770602-2	1-770602-2	G	12	.59	.54	.42
571-1-770602-3	1-770602-3	G	13	.69	.633	.453
571-1-770602-4	1-770602-4	G	14	.68	.618	.437
571-1-770602-5	1-770602-5	G	15	.81	.738	.524

CST-100 Contacts

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Plating	Price Each		
			1	100	500
571-770666-1	770666-1	Tin	.12	.062	.051
571-770666-2	770666-2	Gold	.45	.366	.306

CST-100 II Receptacle Housings

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	No. of Pos.	Price Each		
				1	10	100
571-1375820-2	1375820-2	H	2	.12	.09	.07
571-1375820-3	1375820-3	H	3	.16	.154	.106
571-1375820-4	1375820-4	H	4	.22	.192	.156
571-1375820-5	1375820-5	H	5	.23	.198	.183
571-1375820-6	1375820-6	H	6	.28	.24	.173
571-1375820-7	1375820-7	H	7	.32	.281	.202
571-1375820-8	1375820-8	H	8	.37	.323	.291
571-1375820-9	1375820-9	H	9	.41	.384	.333
571-1-1375820-0	1-1375820-0	H	10	.31	.29	.25
571-1-1375820-2	1-1375820-2	H	12	.58	.53	.39

CST-100 II Contact

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Plating	Price Each		
			1	100	500
571-14453361	1445336-1	Tin	.10	.079	.066

TOOLS FOR MTA CONNECTORS

For quantities greater than listed, call for quote.