


KOBICONN Insulated/Uninsulated Terminals

KOBICONN

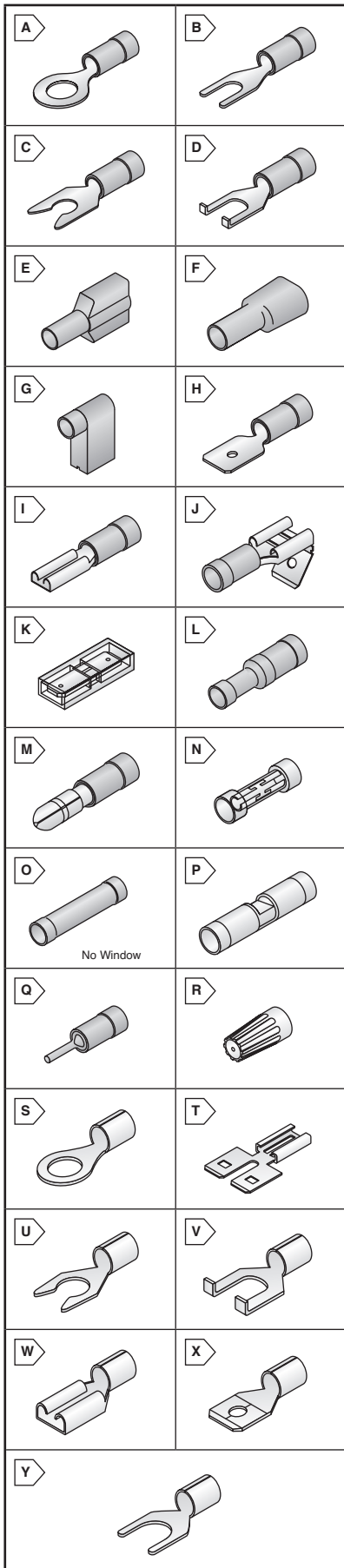

INSULATED SOLDERLESS TERMINALS

Ring Terminals Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-2201	A	Red	1/4"	22-16	.18	.13	.10	.09
159-2202	A	Red	5/16"	22-16	.18	.12	.10	.08
159-2204	A	Red	#4	22-16	.15	.10	.09	.08
159-2206	A	Red	#6	22-16	.15	.10	.08	.07
159-2208	A	Red	#8	22-16	.16	.10	.09	.07
159-2210	A	Red	#10	22-16	.15	.09	.08	.07
159-1601	A	Blue	#4	16-14	.15	.10	.09	.07
159-1602	A	Blue	1/4"	16-14	.16	.13	.11	.09
159-1603	A	Blue	5/16"	16-14	.18	.14	.13	.12
159-1606	A	Blue	#6	16-14	.15	.10	.08	.07
159-1608	A	Blue	#8	16-14	.14	.10	.08	.071
159-1610	A	Blue	#10	16-14	.15	.09	.08	.07
159-1201	A	Yellow	#6	12/10	.16	.12	.10	.08
159-1202	A	Yellow	#8	12/10	.22	.18	.13	.11
159-1203	A	Yellow	#10	12/10	.20	.15	.12	.10
159-1204	A	Yellow	1/4"	12/10	.19	.16	.14	.12
159-1205	A	Yellow	5/16"	12/10	.35	.21	.19	.16
159-1206	A	Yellow	3/8"	12/10	.20	.14	.13	.117

Spade Terminals Vinyl Insulated

159-2226	B	Red	#6	22-16	.15	.09	.08	.07
159-2228	B	Red	#8	22-16	.15	.09	.08	.07
159-2220	B	Red	#10	22-16	.13	.09	.08	.07
159-1626	B	Blue	#6	16-14	.16	.10	.09	.07
159-1628	B	Blue	#8	16-14	.16	.10	.09	.07
159-1620	B	Blue	#10	16-14	.15	.10	.09	.07
159-1207	B	Yellow	#8	12/10	.21	.15	.13	.10
159-1208	B	Yellow	#10	12/10	.20	.15	.12	.11

Locking Spade Terminals Vinyl Insulated

159-2203	C	Red	#6	22-16	.15	.11	.09	.07
159-2207	C	Red	#8	22-16	.15	.09	.08	.07
159-1605	C	Blue	#6	16-14	.15	.09	.08	.07
159-1607	C	Blue	#8	16-14	.16	.10	.08	.07

Flanged Spade Terminals Vinyl Insulated

159-2236	D	Red	#6	22-16	.15	.10	.09	.07
159-2238	D	Red	#8	22-16	.18	.10	.09	.07
159-2230	D	Red	#10	22-16	.18	.12	.11	.10
159-1636	D	Blue	#6	16-14	.15	.09	.08	.06
159-1638	D	Blue	#8	16-14	.19	.13	.12	.11
159-1630	D	Blue	#10	16-14	.15	.09	.08	.07

Couplers (Male) Nylon Insulated

MOUSER STOCK NO.	Fig.	Color	Wire Size (AWG)	Tab Width (in.)	Price Each			
					1	100	1000	5000
159-3251	E	Red	.250x.032	22-16	.26	.21	.16	.11
159-7251	E	Blue	.250x.032	16-14	.26	.21	.19	.14

Couplers (Female) Vinyl Insulated

159-2215	F	Red	.250x.032	22-16	.19	.13	.11	.09
159-1618	F	Blue	.250x.032	16-14	.19	.13	.11	.09

Couplers (Female) Nylon Insulated

159-3250	F	Red	.250x.032	22-16	.26	.21	.17	.11
159-7250	F	Blue	.250x.032	16-14	.31	.24	.22	.15

Flag Disconnects (Female) Nylon Insulated

159-2225	G	Red	.250x.032	22-16	.27	.22	.20	.15
159-1625	G	Red	.250x.032	16-14	.24	.16	.14	.13

Disconnects Vinyl Insulated

MOUSER STOCK NO.	Fig.	Color	Tab Width (in.)	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-2250	H	Red	.250x.032	22-16	.18	.10	.09	.07
159-6250	H	Blue	.250x.032	16-14	.16	.10	.09	.07
159-1210	H	Yellow	.250x.032	22-10	.12	.10	.09	.08
159-2211	I	Red	.110x.020	22-16	.16	.10	.09	.07
159-2187	I	Red	.187x.020	22-16	.19	.10	.09	.08
159-2205	I	Red	.205x.020	22-16	.15	.09	.08	.07
159-2251	I	Red	.250x.032	22-16	.18	.10	.09	.08
159-1604	I	Blue	.110x.020	16-14	.13	.10	.08	.07
159-6187	I	Blue	.187x.020	16-14	.13	.10	.08	.07
159-6205	I	Blue	.205x.020	16-14	.15	.10	.09	.07
159-6251	I	Blue	.250x.032	16-14	.18	.10	.09	.08
159-1209	I	Yellow	.250x.032	12/10	.17	.12	.11	.08
159-2212	J	Red	.250x.032	22-16	.24	.14	.13	.12
159-1611	J	Blue	.250x.032	16-14	.18	.11	.10	.09

Adapter- Male to Male Disconnect Vinyl Insulated

159-1502	K	Clear	.250x.032	----	.24	.16	.14	.13
----------	---	-------	-----------	------	-----	-----	-----	-----

Bullet Connectors Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-2156	L	Red	0.157	22-16	.18	.13	.11	.09
159-3156	M	Red	0.157	22-16	.18	.11	.10	.09
159-1612	L	Blue	0.157	16-14	.21	.12	.11	.10
159-1613	L	Blue	0.195	16-14	.21	.12	.11	.10
159-1615	M	Blue	0.157	16-14	.18	.11	.09	.08
159-1616	M	Blue	0.195	16-14	.16	.10	.09	.07

Adapter- Bullet to Bullet Connector Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Tab Width (in.)	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-1501	N	Yellow	----	0.156	.28	.18	.17	.14

Butt Connectors Vinyl Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Color	Tab Width (in.)	Wire Size (AWG)	Price Each			
					1	100	1000	5000
159-1622	O	Red	----	22-16	.19	.10	.09	.07
159-1614	O	Blue	----	16-14	.18	.10	.09	.07
159-1213	O	Yellow	----	12/10	.30	.18	.16	.14
159-2252	P	Red	----	22-16	.42	.28	.25	.23

Pin Terminals Vinyl Insulated

For quantities greater than listed, call for quote.

159-2213	Q	Red	0.074	22-16	.18	.15	.10	.09
159-1617	Q	Blue	0.074	16-14	.16	.11	.09	.08
159-1211	Q	Yellow	0.11	12/10	.29	.20	.15	.14

Wire Nuts

For quantities greater than listed, call for quote.

159-2216	R	Gray	----	22-16	.16	.10	.09	.076
159-2214	R	Orange	----	22-14	.13	.09	.08	.07
159-1803	R	Yellow	----	18-12	.15	.10	.09	.08
159-1804	R	Red	----	18-10	.15	.10	.09	.08

UNINSULATED SOLDERLESS TERMINALS

Brazed Seam Except Where Noted

Ring Terminals Non-Insulated

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Fig.	Stud/Tab Size	Wire Size (AWG)	Price Each			
				1	100	1000	5000
159-2222	S	#4	22-16	.10	.08	.07	.06
159-2223	S	#6	22-16	.11	.07	.06	.05
159-2224	S	#8	22-16	.15	.08	.06	.05
159-2227	S	#10	22-16	.15	.09	.08	.07
159-2229	S	1/4"	22-16	.11	.08	.07	.06
159-2231	S	5/16"	22-16	.11	.09	.08	.07
159-1627	S	#4	16-14	.11	.08	.06	.05
159-1629	S	#6	16-14	.15	.09	.08	.06
159-1632	S	#10	16-14	.12	.09	.08	.07
159-1218	S	#10	12/10	.17	.13	.10	.09
159-1219	S	1/4"	12/10	.19	.13	.11	.10
159-1220	S	5/16"	12/10	.17	.12	.11	.10
159-1221	S	3/8"	12/10	.20	.14	.11	.10

Double Male/Female Adapter

For quantities greater than listed, call for quote.

159-1226	T	.250 x .032	----	.22	.14	.13	.10
----------	---	-------------	------	-----	-----	-----	-----

Locking Spade Terminals Non-Insulated

For quantities greater than listed, call for quote.

159-2241	U	#6	22-16	.10	.06	.05	.04
159-2242	U	#8	22-16	.10	.08	.07	.06
159-1644	U	#6	16-14	.10	.08	.07	.05

Flange Spade Terminals Non-Insulated Butted Seam

For quantities greater than listed, call for quote.

159-2244A	V	#6	22-16	.08	.06	.05	.04
159-2245	V	#8	22-16	.11	.07	.06	.05

Disconnects Non-Insulated Butted Seam

For quantities greater than listed, call for quote.

159-2235	W	.110 x .020	22-16	.07	.05	.04	.03
159-2237	W	.187 x .020	22-16	.11	.08	.06	.05
159-2239A	W	.205 x .020	22-16	.10	.06	.05	.04
159-2240	W	.250 x .032	22-16	.11	.08	.06	.05
159-1640	W	.110 x .020	16-14	.08	.06	.05	.04
159-1641	W	.187 x .020	16-14	.10	.06	.05	.04
159-1642	W	.205 x .020	16-14	.10	.07	.06	.05
159-1643	W	.250 x .032	16-14	.11	.08	.07	.06
159-1224	W	.250 x .032	12/10	.14	.09	.08	.06
159-1650	X	.250 x .032	16-14	.10	.08	.07	.06
159-1225	X	.250 x .032	12/10	.12	.08	.07	.06

Spade Terminals Non-Insulated

For quantities greater than listed, call for quote.

159-2232	Y	#6	22-16	.09	.07	.06	.05
159-2233	Y	#8	22-16	.13	.08	.07	.06
159-2234	Y	#10	22-16	.11	.08	.07	.06
159-1635	Y	#6	16-14	.11	.09	.07	.06
159-1637	Y	#8	16-14	.09	.08	.06	.05
159-1222	Y	#8	12/10	.19	.13	.11	.09