

TE Terminals, Splices and Wire Caps



RoHS Compliant This product is RoHS compliant.

SOLISTRAND UNINSULATED TERMINALS

Short Spring Spade Tongue Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Stud Size	Wire Size (AWG)	Dimensions L x W	Price Each			
						1	100	500	1000
571-531751	53175-1	A	4	22-16	.576 x .203	.28	.19	.17	.14
571-531201	53120-1	A	6	22-16	.576 x .250	.31	.276	.246	.186
571-531231	53123-1	A	6	16-14	.576 x .250	.23	.198	.193	.158
571-531261	53126-1	A	6	12-10	.636 x .250	.37	.341	.30	.214

DIAMOND GRIP UNINSULATED TERMINALS

Ring Tongue Terminals

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Stud Size	Wire Size (AWG)	Dimensions L x W	Price Each			
						1	100	500	1000
571-31518	31518	B	2	26-22	.464 x .140	.55	.52	.44	.40
571-31094	31094	B	4	22-16	.603 x .218	.43	.311	.296	.244
571-30996	30996	B	8	22-16	.775 x .312	.42	.354	.292	.261
571-30927	30927	B	8	16-14	.790 x .343	.55	.45	.36	.29

RING TONGUE RADIATION RESISTANT TERMINALS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
						1	100	500	1000
571-696422-5	696422-5	C	Red	8	22-16	.55	.495	.475	.422
571-696422-6	696422-6	C	Red	10	22-16	.64	.596	.559	.485

PIDG RING TONGUE INSULATION RESTRICTING TERMINALS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
						1	100	500	1000
571-13205513	1-320551-3	D	Red/Red	8	22-16	.44	.322	.30	.251
571-13205514	1-320551-4	D	Red/White	8	22-16	.72	.63	.539	.40
571-2361535	2-36153-4	D	Red/White	10	22-16	.68	.63	.52	.39
571-518649	51864-9	D	Blue/Green	10	16-14	.72	.63	.53	.40
571-23205634	2-320563-4	D	Blue/Green	1/4	14	.69	.60	.54	.49
571-2361614	2-36161-4	D	Yellow/Brown	10	10	.70	.603	.461	.439

PIDG OFFSET AND SLOTTED RING TONGUE TERMINALS

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Color	Stud Size	Wire Size (AWG)	Price Each			
						1	100	500	1000
571-323011	323011	E	Yellow	6	26-22	.49	.44	.402	.344
571-36954	36954	E	Red	8	22-16	.42	.297	.296	.284

PIDG SPARE WIRE CAPS

* Not sealed

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Cap Insulation Color	Wire Size (AWG)	Price Each			
					1	100	500	1000
Unstripped Wire								
571-324484	324485	F	Red	---	.36	.24	.21	.19
Stripped Wire								
571-328307	328307	G	Red	22-18	.34	.26	.24	.23

CLOSED END SPLICES


Splice Marking

- VS 300V, 90°C
- ECV 600V max. Building wiring 1000V max.
- Fixtures and signs, 105°C UL, 90°C CSA
- ECN 300V 105°C
- EC 600V max. Building wiring 1000V max; Fixtures and signs, 105°C

* Max. recommended operating temperature, 150°C

For quantities greater than listed, call for quote.

MOUSER STOCK NO.	TE Part No.	Fig.	Material	Color	Length	Wire Size (AWG)	Splice Marking	Price Each			
								1	100	500	1000
Vinyl BOMB-TAIL Splices											
571-34306	34306	H	Copper	Blue	0.750	22-16	VS	.35	.302	.267	.216
571-23283753	2-328375-3	H	Copper	Purple	0.775	22-14	VS	.18	.166	.152	.112
571-532341	53234-1	H	Copper	Transparent	1.500	22-12	ECV	.25	.212	.191	.122
Nylon Molded Splices											
571-35115	35115	I	Copper	Transparent	0.680	22-14	ECN	.23	.21	.199	.148
571-35653	35653	I	Copper	Transparent	0.775	22-10	ECN	.28	.249	.212	.158
* 571-559291	55929-1	I	Copper	Black	0.970	22-10	EC	.42	.27	.23	.19
571-328730	328730	I	Copper	Transparent	0.720	22-10	EC	.30	.26	.22	.17

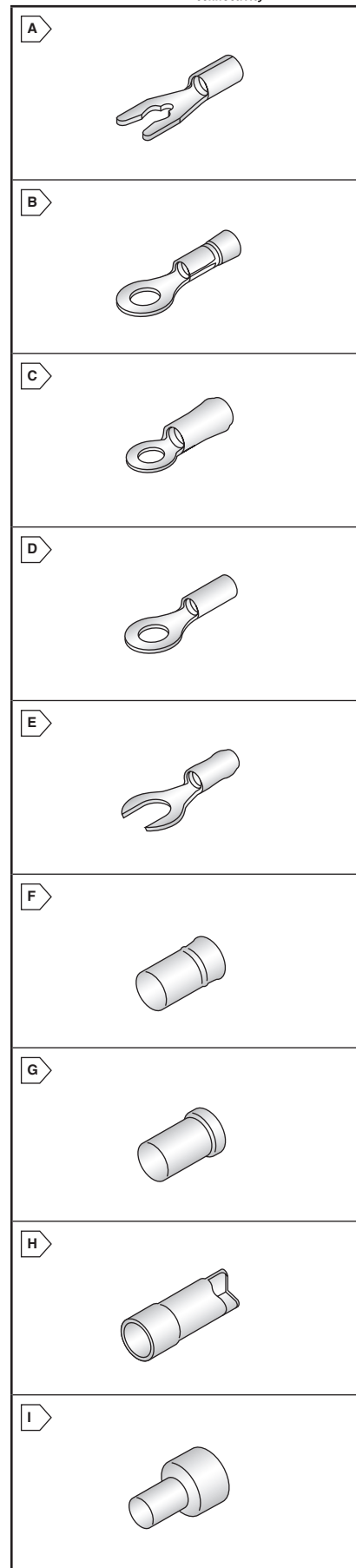

Terminals

TE Connectivity