

PHOENIX CONTACT Cipline DIN Rail Terminal Blocks




RoHS Compliant This product is RoHS compliant.

UT UNIVERSAL TERMINAL SCREW CONNECTION

Universal for every application. This screw connection system features a multi-conductor connection and maximum contact forces. The screw connection system is known and accepted throughout the world and can be used in any application.

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Fig.	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
2-Conductor Feed-Thru Terminal Blocks														
651—3064085		UT 2.5-MTD	A	Gray	26-12	400	20A	49.1	57.8	5.2	1.13	1.01	.913	.851
651—3064098		UT 2.5-MTD P/P	A	Gray	26-12	630	24A	47.5	57.8	5.2	1.46	1.30	1.18	1.09
651—3044076		UT 2.5	A	Gray	26-12	800	32A	47.5	46.9	5.2	1.01	.899	.857	.784
651—3044089		UT 2.5 BU	A	Blue	26-12	800	32A	47.5	46.9	5.2	1.01	.888	.805	.752
651—3045088		UT 2.5 BK	A	Black	26-12	800	32A	47.5	46.9	5.2	1.17	1.06	.997	.917
651—3045062		UT 2.5 RD	A	Red	26-12	800	32A	47.5	46.9	5.2	1.06	.938	.855	.792
651—3044102		UT 4	A	Gray	26-10	800	41A	47.5	46.9	6.2	.96	.864	.758	.727
651—3044115		UT 4 BU	A	Blue	26-10	800	41A	47.5	46.9	6.2	1.10	1.04	.927	.885
651—3045143		UT 4 BK	A	Black	26-10	800	41A	47.5	46.9	6.2	1.14	1.01	.914	.852
651—3045127		UT 4 RD	A	Red	26-10	800	41A	47.5	46.9	6.2	1.14	1.01	.914	.852
651—3046184		UT 4-MTD	A	Gray	26-10	800	41A	47.5	56.8	6.2	1.06	.96	.88	.80
651—3044131		UT 6	A	Gray	24-8	800	57A	47.5	46.9	8.2	1.45	1.34	1.28	1.19
651—3045208		UT 6 BK	A	Black	24-8	800	57A	47.5	46.9	8.2	1.50	1.33	1.22	1.12
651—3047413		UTMED 6	A	Gray	24-8	500V	30A	49.6	100.8	8.2	6.06	5.59	5.01	4.61
651—3044160		UT 10	A	Gray	20-6	1000	76A	47.5	46.9	10.2	2.04	1.97	1.80	1.66
651—3046320		UT 10 BK	A	Black	20-6	1000	76A	47.5	46.9	10.2	2.12	1.89	1.72	1.59
651—3046304		UT 10 RD	A	Red	20-6	1000	76A	47.5	46.9	10.2	2.12	1.89	1.71	1.59
651—3044199		UT 16	A	Gray	16-4	600V	85A	54.8	52.8	12	2.18	2.09	2.05	1.92
651—3044225		UT 35	A	Gray	14-1/0	600V	150A	65.7	60.2	16	5.15	4.76	4.53	4.12
Ground Terminal Blocks														
651—3044092		UT 2.5-PE	B	Gr/Yel	26-12	---	---	47.5	46.9	5.2	3.66	3.29	3.00	2.84
651—3044128		UT 4-PE	B	Gr/Yel	26-10	---	---	47.5	46.9	6.2	4.08	3.65	3.45	3.16
651—3044157		UT 6-PE	B	Gr/Yel	24-8	---	---	47.5	46.9	8.2	4.64	4.16	3.91	3.60
651—3044173		UT 10-PE	B	Gr/Yel	20-6	---	---	47.5	46.9	10.2	5.12	4.54	4.33	3.83
651—3047442		UTMED 6-PE	B	Gr/Yel	24-8	500V	30A	49.6	100.8	8.2	12.14	11.20	10.05	9.25
651—3044212		UT 16 PE	B	Gr/Yel	16-4	---	---	54.8	52.8	12	5.58	5.20	4.94	4.49
651—3044241		UT 35 PE	B	Gr/Yel	14-1/0	---	---	65.7	60.2	16	8.18	7.28	6.62	6.15
Knife Disconnect Terminal Blocks *Current and Voltage are determined by the plug used.														
651—3046362		UT 2.5-MT	C	Gray	26-12	300	20A	49.1	57.8	5.2	3.61	3.22	2.93	2.72
651—3046375		UT 2.5-MT P/P	C	Gray	26-12	300	20A	49.1	57.8	5.2	3.77	3.36	3.05	2.84
651—3046388		UT 2.5-TG	C	Gray	26-12	300	20A	49.1	57.8	5.2	2.54	2.26	2.05	1.91
651—3046391		UT 2.5-TG P/P	C	Gray	26-12	300	20A	49.1	57.8	5.2	2.88	2.59	2.41	2.23
651—3046139		UT 4-MT	C	Gray	26-10	500*	16A*	47.5	56.8	6.2	2.91	2.60	2.43	2.19
651—3046171		UT 4-MT-P/P	C	Gray	26-10	500*	16A*	47.5	56.8	6.2	3.13	2.87	2.65	2.48
651—3047400		UTME 6	C	Gray	24-8	500V	30A	49.6	100.8	8.2	8.65	7.98	7.16	6.59
Fuse Terminal Blocks *If used as fuse terminal block.														
651—3046032		UT 4-HESI(5X20)	D	Black	26-10	250*	6.3A	73.0	56.8	6.2	5.60	4.92	4.83	4.38
651—3046090		UT 4-HESILED 24(5X20)	D	Black	26-10	250*	6.3A	73.0	56.8	6.2	9.01	8.01	7.28	6.77
651—3046100		UT 4-HESILA 250(5X20)	D	Black	26-10	250*	6.3A	73.0	56.8	6.2	9.26	8.32	7.57	7.21
651—3046401		UT 6-HESI (6.3X32)	D	Black	24-8	600V	10A	73	56.8	8.2	6.92	6.51	6.00	5.64
651—3046414		UT 6-HESILED 24(6.3X32)	D	Black	24-8	600V	10A	73	56.8	8.2	12.64	11.90	10.99	10.30
651—3046430		UT 6-HESILA 250(6.3X32)	D	Black	24-8	600V	10A	73	56.8	8.2	12.48	10.88	10.20	9.84
Plugs for Disconnect Terminal Blocks *If used as disconnect terminal block.														
651—3036796		P-CO	--	Gray	---	400*	6A	21.0	24.0	5.0	4.79	4.29	4.08	3.72
651—3036806		P-FU 5 X 20	--	Black	---	400*	6.3A	25.0	28.0	6.0	4.15	3.72	3.54	3.22
651—3036819		P-FU 5 X 20 LED 24	--	Black	---	400*	16A	25.0	28.0	6.0	9.32	8.36	7.91	7.23

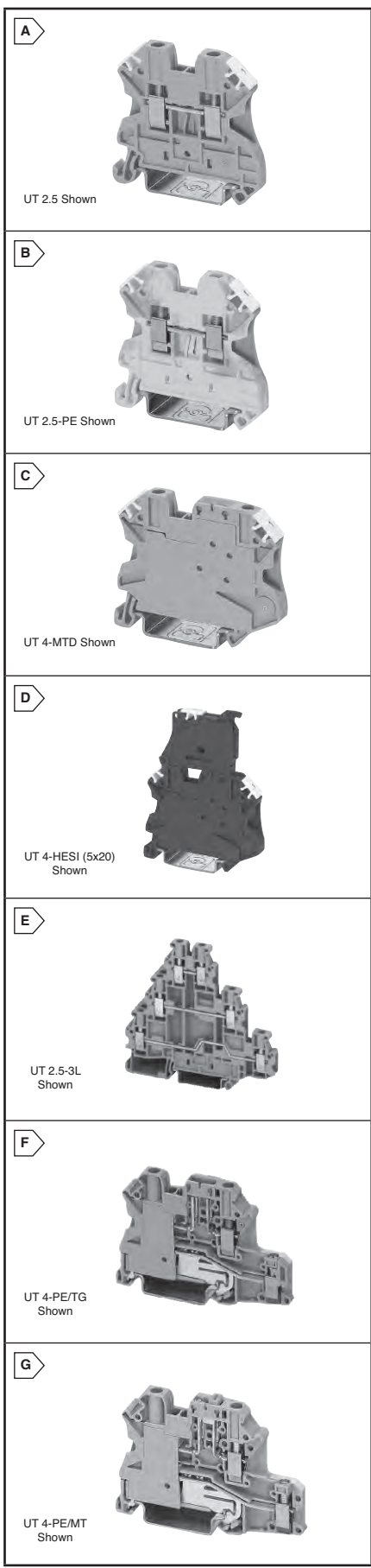

Terminal Blocks Phoenix Contact

UT 2.5-3L MODULAR TERMINAL BLOCKS



For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Fig.	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
Multi-level														
651—3214259		UT 2.5-3L	E	Gray	26-12	500	20	85	90	5.2	4.74	4.38	4.05	3.76
Terminal block with voltage potential														
651—3214262		UT 2.5-3PV	E	Gray	26-12	500	20	85	90	5.2	4.74	4.38	4.05	3.76
Terminal block with light indication														
651—3214288		UT 2.5-3L-LA24RD/	E	Gray	26-12	500	20	85	90	5.2	10.03	9.28	8.56	7.95
Ground terminal blocks														
651—3214275		UT 2.5-3PE	E	Grn/Yel	26-12	-	-	85	90	5.2	8.02	7.42	6.85	6.36
651—3214291		UT 2.5-3PE/L/N	E	Grn/Yel	26-12	-	-	85	90	5.2	11.29	10.44	9.64	8.95
651—3214301		UT 2.5-3PE/L/L	E	Grn/Yel	26-12	-	-	85	90	5.2	7.38	6.83	6.30	5.85
End plate														
651—3214314		D-UT 2.5-3L	-	Gray	-	-	-	69.8	90	2.2	.94	.87	.80	.75

UT4 WITH INTEGRATED GROUND (PE) FOOT

- Adds a ground claw/foot to the standard UT4 series.
- Same electrical specifications as standard UT4 terminal blocks
- Provides a reliable and space-saving termination for grounding
- Accepts CLIPLINE Complete marking solutions and accessories.
- Realdyne Principle for safe and maintenance-free screw clamp connection

For quantities greater than listed, call for quote.

MOUSER STOCK NO.		Phoenix Type	Fig.	Color	AWG	Voltage Rating	Current Rating	Dimensions (mm)			Price Each			
Mfr.	Mfr. Part No.							H	L	W	1	10	50	100
651—3070024		UT 4-PE/TG	F	Gray	26-10	500V	20A	47.5	57.8	6.2	7.05	6.52	5.84	5.45
651—3070037		UT 4-PE/TG P/P	F	Gray	26-10	500V	20A	47.5	57.8	6.2	6.75	6.01	5.46	5.07
651—3046235		UT 4-PE/L-DIO R/L	-	Gray	26-10	500V	20A	47.5	57.8	6.2	8.73	7.77	7.07	6.57
651—3046834		UT 4-PE/L-DIO L/R	-	Gray	26-10	500V	20A	47.5	57.8	6.2	8.73	7.77	7.07	6.57
651—3073995		UT 4-PE/HESI	-	Black	26-10	500V	20A	80.5	57.8	6.2	9.54	8.74	8.08	7.51
651—3074004		UT 4-PE/HEDI	-	Black	26-10	500V	20A	80.5	57.8	6.2	10.49	10.08	9.04	8.46
651—3070011		UT 4-PE/MT	G	Gray	26-10	500V	20A	55	57.8	6.2	7.99	7.68	6.65	6.44
651—3046140		UT 4-PE/MT	G	Gray	26-10	500V	20A	55	57.8	6.2	8.21	7.31	6.64	6.18

